



**eclipse**<sup>SM</sup>

**Pro'sKit**<sup>®</sup>

Professional Tool Solutions Since 1991

## 2015 New Products Supplement

INNOVATION · QUALITY · SERVICE



# 2015 New Products

To our Valued Customers,

We are proud to bring you our 2015 New Products Supplement catalog. We recommend you and your customers try our new MT-7071 LCD Cable Length Toner & Probe Kit. It features cable length measurement up to 1200M (4000ft), locates and verifies the cable status and troubleshoots wiring. The new Environmental Meter Series and Laser Distance Measurers are worth a try too, they're designed with even better functions, comply with CE and RoHS, and the upgraded features will help you penetrate your market.

We also introduce Fiber Optic tools with multi power meter, visual fault locator, cleaners and tool kit to meet FTTH installation and maintenance requirements. For the 1000V Insulated series, we offer a complete range of tool kits to make the job more efficient and safe. Finally, don't miss our new 20V cordless drill which comes with a heavy duty high torque gear box, Lithium-Ion battery and LED battery level indicators. Making it more durable and powerful!

## Test Instruments

page.1-6



MT-7071

MT-4615

NT-8560

MT-1508

## Pliers / Crimpers / Strippers

page.7-13



902-514


CP-148

PM-760

CP-509

## Soldering

page.14

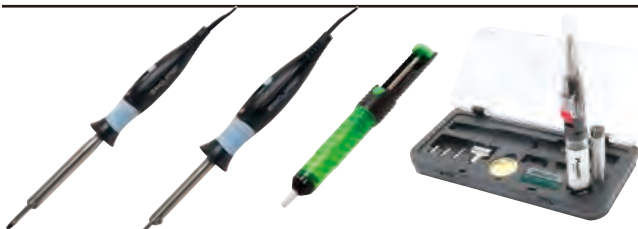

902-512

902-513

DP-366J

GS-23K

## Screwdrivers & Socket

page.15-19



SD-T860

HW-T series

SD-T635 series

SD-9828

## Magnifier Lamps / Power Tools

page.20-23



MA-1601A

MA-1006A

902-492

## Fiber Optic Tools

page.24-26



MT-7602

FB-C008/FB-009

PK-9458

## Tool case / Miscellaneous / Tool Kits

page.27-32



902-516

500-038

PK-9112

PK-2836M

## MT-5211 3 1/2 Digital LCR Multimeter



### Fully featured with LCR & DMM Multimeter

- 3 1/2 digits 1999 counts.
- Dual slope A/D conversion.
- Large backlight LCD display.
- Extra functions: Continuity with beeper, Diode test, Data hold, Auto power off, Low battery indication, Overload indication, Backlight, Transistor Tester.
- Ideal for a wide variety of electrical and electronic testing applications.

Specification	
DC Voltage (V)	200mV/2V/20V/200V±(0.5%+3d),1000V±(1.0%+5d)
AC Voltage (V)	200mV±(1.2%+3d),2V/20V/200V±(0.8%+5d),750V±(1.2%+5d)
DC Current (A)	2mA/20mA±(0.8%+3d),200mA±(1.2%+4d),20A±(2.0%+5d)
AC Current (A)	2mA/20mA±(1.0%+5d),200mA±(2.0%+5d),20A±(3.0%+10d)
Resistance (Ω)	200±(0.8%+5d),2K/20K/200K/2MΩ±(0.8%+3d),
Capacitance (uF)	20MΩ±(1.0%+15d),2000MΩ±(5.0%(reading-10)+20d)
Inductance (L)	20nF/200nF/2uF±(2.5%+20d),20uF/200uF±(5.0%+5d)
Temperature (T)	2mH/20mH/200mH/2H/20H±(2.5%+20d)
(-20~1000°C)	<400°C±(1.0%+4d), ≥ 400°C±(1.5%+15d)
Frequency (Hz)	2k/20k/200k/2000K/10M Hz±(1.0%+10d)
Power source	9V 6F22 battery (not included)
Weight	390g (not including battery)
Dimension(D×W×H) (mm/inch)	189×97.5×35mm / 7.4x3.8x1.3"
Accessories	Test lead, thermocouple, test socket
Individual packing	Color box



Transistor hFE test



Transistor hFE test



Accessories

## MT-1508 Pocket Autorange Multimeter



### Non-Contact ACV Detector, LCD Backlight, Data Hold, Auto Power Off, Auto Range

- Comes with a backlight, 3 1/2 digits 1999 counts easy for reading.
- Auto range functions provide accuracy, easy to use.
- Extra function: Auto power off, low battery indication, Data hold, Over range indication.
- Pocket size design for easy carrying.
- Non contact ACV detector and built-in LED flash light.

Specification	
DC Voltage (V)	200mV/2V/20V/200V±(0.5%+3d) 600V±(0.8%+5d)
AC Voltage (V)	2V/20V/200V±(0.8%+3d)600V±(1.0%+5d)
DC Current (A)	200μA/2000μA /20mA/200mA±(1.8%+5d)
AC Current (A)	200μA/2000μA /20mA/200mA±(2.0%+5d)
Resistance (Ω)	200Ω/2kΩ/20kΩ/200kΩ/2MΩ±(1.0%+3d) 20MΩ±(1.2%+15d)
Functions	Non contact ACV detector, Diode test, Continuity with beep
Power source	2x1.5V AAA battery (not included)
Weight	152g (not including battery)
Dimension(D×W×H) (mm/inch)	125x60x26mm / 4.9x2.4x1.0"
Individual packing	Blister card



# MT-7071 LCD Cable Length Toner & Probe Kit



Including transmitter, receiver and standard remote unit, RJ45 cable patch cord, RJ11/12 cable patch cord, alligator clips patch cord, earbud, carrying bag.



Detects AC Voltage from 90 to 1000V



Wire tracing



LED light for user convenience



Max support to 8 remote units (optional)



Locate break point and length measurement



Verify LAN/ Telephone/ Coaxial cable condition

The MT-7071 lets you measure cable length up to 1200M (4000ft), locates and verifies the cable status and troubleshoots wiring. Ideal for all installation and maintenance fields of telecommunication, networking, datacom, audio/video, cable TV, and all weather cabling, etc.

### Cable Length Measurement up to 1200M

Measures cable length from tester to an open in the cable (break or end) up to 1200M without remote being attached

### Calibration Parameters

It can determine actual calibration parameters with known length of cable for cable length test, allows setting 1-7 calibration parameters.

### Wire Tracing up to 3KM

Easily track wire directly in connection with live telecommunication equipment and router.

### Cable Mapping & Status Indication up to 610M

Display the result of cable mapping and troubleshoot wiring for continuity, short, open and crossover.

### Max. support 8 remote units

For cable mapping on RJ45 LAN cable Cat 5, 5e, 6 (UTP), RJ11/12 Telephone cable Cat. 3 (2/4/6 pin) & BNC connector coaxial cable.

### Non Contact Voltage Detection

Tests voltage from 90 ~ 1000V before testing for circuit protection.

MT-7071 Transmitter specifications	
Cable types tested	RJ45 LAN cable Cat 5, 5e, 6, (UTP/STP), RJ11/12 telephone cable Cat 3 (2/4/6 pin), coaxial cable & normal solid / stranded wire by alligator clips patch cord
Cable test modes	580/1160 Hz two-note tones for location and isolating cables, wire mapping for validate (detects wire continuity, shorts, opens, miswired, crossover) and open length tested
Measurement technology	Cable capacitance method
Max. distance to opens for test	1,200 meter (4,000 feet/1,300 yard), approx
Min. distance to opens for test	2 meter (6.8 feet/ 2.2 yard)
Typical accuracy of length test	2~10 meter (6.8~33 feet/2.2~11yard) for reference 10~610 meter (33~2000 feet/ 11~666 yard.): ±5.0% 610~1,200 meter (2000~4000feet/ 666~1300 yard.) for reference, default measuring Cat.5e cable
Calibration accuracy of length test	10~610 meter (33~2,000 feet/11~666 yard) ±3.0%, standard cable:10~50meter(33~164 feet/11~55 yard), default measuring Cat.5e cable
Resolution & Unit of length test	0.1 meter/ feet/ yard, Rate:1~3 sec./time
Calibrating parameters memory	1~7 sets, allowing rewrite by new calibrating parameters
Max. distance of transmission & cable map	≥ 3 km (580/1160 Hz) & 610 meter (2,000 feet/666 yard)
Min. distance of cable map	Twisted pair:1Meter (3 feet/ 1yard), normal wire:1.25Meter (4feet/1.35yard)
Cable map & Shielded indication	LCD 1~8 & G
Other functions	Continuity test, current protection< 5 mA & voltage protection AC 60V or DC 48V, live telecommunication equipment test and router test, auto power off, low battery display
Dimension(D×W×H) (mm/inch)	138×80×35 mm / 5.4x3.1x1.4"
MT-7071 Receiver specifications	
Signal status indication	580/1160 Hz
NCV indication & LED illumination	1 LED (AC90~1000V) & 1 LED
Dimension(D×W×H) (mm/inch)	198×45×33 mm / 7.8x1.8x1.3"
MT-7071 Remote unit specifications	
Remote unit	1 pc, max. support to 8 pcs (optional remotes: MT-7071U)
Compatible connectors	RJ45(8 pin), RJ11/12(6 pin), BNC connectors
Remote unit dimension (L×W×D) (mm/inch)	90×32×30mm / 3.5x1.3x1.2"
Individual packing	Color box



# MT-7028 Network Toner & Probe Kit



The MT-7028 lets you easily to locate and verify the cable status and troubleshoot wiring for continuity, shorts, opens and crossover on RJ45 LAN cable Cat 5/5e/6/7 (UTP/STP)/RJ11/12 telephone cable Cat. 3 (2/4/6 pin) & normal solid/stranded wire by alligator clips patch cord. Ideal for all installation and maintenance fields of telecommunication, networking, datacom, audio/video, cable TV, and all weather cabling, etc.

### Wire Tracing up to 3KM

The tone and probe kit lets you easily track wire directly in connection with live telecommunication equipment and router

### Cable Mapping & Status Indication up to 300M

- Fast/Slow scan function options
- Display the result of pin to pin cable mapping
- Display cable status and troubleshoot wiring for continuity, shorts, opens and crossover.

### Non Contact Voltage Detection

Tests voltage from 90 ~ 1000V, special design to make sure the power is off before testing for circuit protection

### Energy Saving

Automatically powers off after 1 hour of no operation

### Polarity Indication

Identify the telephone line polarity easily



TEST INSTRUMENTS

MT-7028 Transmitter specifications	
Tone frequency	1kHz
Max. distance of transmission & Cable map	≥ 3km & 300m
Tone mode	Hi/Low two-note tone
Compatible connectors	RJ45(8 pin)/RJ11(6 pin) compatible connectors for RJ45(8 pin), RJ11/12(6P/2C/4C/6C) cable map and RJ45 tone, RJ-11(6 pin) connectors for RJ11/12(6P/2C/4C/6C) tone
Cable types tested	RJ45 LAN cable Cat 5, 5e, 6, 7 (UTP/STP), RJ11/12 Telephone cable Cat 3 (6P/2C/4C/6C)
Continuity test	1 LED ( $\leq 300\Omega$ ), coaxial cable & normal solid/stranded wire by alligator clips patch cord.
Cable map & Shielded indication	8 LEDs & 1 LED, Fast/Slow dual speed
Phone line polarity indication	1 Dual color LED
Other function Live telecommunication equipment test and router test	Live telecommunication equipment test and router test, voltage protection AC 60V or DC 48V, auto power off, low battery display
MT-7028 Receiver specifications	
Frequency & Compatible connectors	1kHz & RJ45(8 pin)/RJ11(6 pin)
Signal status indication	1 LED & Buzzer, ear bud jack
Cable map & Shielded indication	8 LEDs & 1LED
NCV indication & LED illumination	1 LED (AC90~1000V) & 1 LED
Battery type	DC 9.0V (NEDA 1604/ 6F22 DC9V *1pcs)
Dimension (L×W×D)(mm/inch)	198×45×33 mm / 7.8x1.8x1.3"
Individual packing	Color box



RJ45 cable patch cord, RJ11 cable patch cord, alligator clips patch cord, ear bud, pouch bag



Detects AC voltage from 90 to 1000V



LED light for user convenience



Verify LAN/telephone cable condition



Wire tracing

## MT-4616 Temperature / Humidity / Dew Point Meter



**99 Data Memories, 3 Types of Temperatures**



- Tests ambient temperature, relative humidity, wet bulb, dew point temperature.
- Data memory up to 99 memories.
- Unit °F/°C selection, high precision & portable for measuring.
- Extra functions: Max./Min. value, low battery indication, auto power off, backlight, data hold.

Specification	
Temperature Range	-20~60°C(-4°F~140°F)
Temperature Accuracy	±1°C(0~45°C), ±1.5°C(-20~0°C, 45~60°C)
Humidity Range	0~100%RH
Humidity Accuracy	±3%(20%~80%), ±4%(0~20%, 80%~100%)
Wet Bulb Temperature Range	-20~60°C(-4~140°F)
Wet Bulb Temperature Accuracy	±1°C(0~45°C), ±1.5°C(-20~0°C, 45~60°C)
Dew Point Range	-50~60°C(-58~140°F)
Dew Point Accuracy	±1°C(0~45°C), ±1.5°C(-50~0°C, 45~60°C)
Resolution	0.1C/F ; 0.1%
Data Memory	Max. 99 of data
Unit selection	°C / °F
Auto power off	After 30mins, on/off selection
Power source	AAA 1.5V x 4 (not included)
Weight	114g (not including battery)
Dimension (L×W×D) (mm/inch)	184 x 60 x 29mm / 7.2 x 2.4 x 1.1"
Accessory	Storage Bag
Individual Packing	Double blister

## MT-4617 Light Intensity Meter



**Auto/Manual Range, Zero Calibration, Relative & Peak Value**



- Measures the visible light produced by fluorescent lamp, metal-halide lamp, high voltage sodium lamp or electric incandescent lamp.
- Built-in precision photo diode sensor and color correction filter.
- Automatic and manual measured range switching.
- Relative and peak value measurement.
- Measures up to 200,000 lux / 20,000 FC.
- Extra functions: Max./Min. value, over load indication/low battery indication, auto power off, data hold, zero calibration.

Specification	
Range	20, 200, 2000, 20000, 200000 Lux, 20, 200, 2000, 20000 FC
Ring spectral range	320~730nm
Accuracy	±3% (When at 2854K calibrated in accordance with the ordinary incandescent) ±6% (when at other visible light source)
Unit	Lux., FC
Sensor	Silicon photodiode
Sampling time	≥2 times/sec.
Auto power off	After 10 min.
Operation sound	on/off Selection
Low battery indicate	<7V
Operation environment	0~85%RH, -10, 50°C (no condense)
Storage environment	0~70%RH, -10, 50°C (no condense)
Operating altitude	Max. 2000m
Power source	9V (not included)
Weight	154 g (not including battery)
Dimension(L×W×D) (mm/inch)	170 x 85 x 45mm / 6.7 x 3.3 x 1.8"
Accessory	Storage bag
Individual packing	Double blister

## MT-4618 Sound Level Meter



**Auto Range, Over Range Indication, Weighted Sound Pressure Frequency**



- A & C weighting network selection
- Measuring range from 30 to 130 dB
- LCD display with backlight
- High speed (FAST)/Low speed (SLOW) response rate selection
- Extra functions: Max./Min. value, data hold, auto range, backlight, good anti-interference performance, auto power off

Specification	
Range	30—130dBA, 35—130dBC, 30—80db, 40—90db, 50—100db, 60—110db, 70—120db, 80—130db, 30~130 db is auto range
Accuracy	±1.5dB (94dB@1KHz), ±5dB (94dB@8KHz)
Resolution	0.1dB
Response frequency	30Hz — 8KHz
Dynamic sound pressure	50 dB (at each range) FAST 125ms, SLOW 1sec
Frequency weighting	A and C type
Sensor	Polarized condenser microphone
Sampling time	2 times/sec. , Analog 20 times/sec.
Operating environment	10~80%RH, 0°C~40°C (Non-condensing)
Storage environment	10~70%RH, -10°C~60°C (Non-condensing)
Low battery indication	<5V
Power source	1.5V AAA battery x 4 (not included)
Weight	174 g (not including battery)
Dimension(L×W×D) (mm/inch)	174 x 60 x 29mm / 6.9 x 2.4 x 1.1"
Accessory	Storage bag
Individual packing	Double blister

## MT-4615 Anemometer



Specification	
Measuring range	0.8~40m/s
Accuracy	0.80~30.00 m/s, 1.40~108.00 km/h, 1.30~98.50 ft/s, 0.80~58.30 knots, 0.90~67.20 mil/h, 78~5900 ft/m, $\pm(2.0\% + 50D)$ , 30.00~40.00 m/s, 108.0~144.0 km/h, 98.50~131.20 ft/s, 58.30~77.70 knots, 67.20~90.00 mil/h, 5900~7874 ft/m, (only for reference)
Resolution	0.01m/s, 0.01km/h, 0.01 ft/s, 0.01knots, 0.01mile/h, 1ft/m
Unit	Air Velocity, m/s, km/h, mil/h, ft/m, ft/s, knots, Air Volume, CMS (m <sup>3</sup> /s), CMM m <sup>3</sup> /min, CFM (ft <sup>3</sup> /min), 30~40m/s only for reference
Sensor	Conventional arm angle to the impeller
Sampling time	0.4s
Auto power off	10 minutes (adjustable)
Low battery indication	<7V
Operation environment	0~85%RH, 0°C~40°C (no condense)
Fan Operation environment	0~95%RH, -20°C~80°C (no condense)
Storage environment	0~80%RH, -20°C~80°C (no condense)
Operating altitude	Max. 2000m
Power source	9V 6F22 (not included)
Weight	154 g (not including battery)
Dimension (L×W×D) (mm/inch)	170 x 85 x 40mm / 6.7 x 3.3 x 1.6"
Accessory	Storage bag
Individual Packing	Double blister

**Air Velocity, Analog Bar Graphic, Variety of units, Air Volume, LCD Backlight, MAX./MIN Value**

- Measuring air velocity and air volume.
- Large LCD backlight for easy reading even in dark area.
- Variety of units to choose from.
- Extra functions: Max./Min. value, low battery indication, auto power off, data hold.



## MT-4611 Combustible Gas Detector

**Sound & Light Alarm, Quick-response Sensor**

- Quickly identifies & pinpoints gas leaks, provides visible & audible alarm.
- Detection at 10% ~ 40% lower explosion limited.
- Adjustable sensitivity setting helps precisely locate leaks.
- Rugged ergonomic & easy-to-use design.
- 35cm flexible probe allows location and detection of leak in hard-to-reach and confined spaces.

Specification	
Sound and LED light alarm	Measuring distance 1 meter, beep about 65dB
Resolution	50 ppm (methane)
Test range	10%~40% LEL
Response time	< 2S (40% LEL)
Sensor	Catalytic combustion
Low battery indicate	<5V
Operation environment	10~90%RH, 0°C~50°C (no condense)
Storage environment	10~70%RH, -10°C~60°C (no condense)
Power source	1.5V / AA battery x 4 (not included)
Weight	290 g (not including battery)
Dimension (L×W×D) (mm/inch)	Meter, 200x75x50mm / 7.9 x 3.0 x 2.0", flexible probe, Ø8x350mm / Ø0.3 x 13.8"
Accessory	Storage bag
Individual packing	Double blister




## MT-4612 Infrared Thermometer

**Non-Contact Measurement, Fast Response,**

- Dual laser for accurately aiming with fast (500 ms) response time
- Ergonomic design and rugged construction
- Extra functions: unit selection, backlight, auto power off, low battery indication, Data hold, Max./Min./average/difference record, high/low temperature alarm

Specification	
Temperature Range	-50°C~580°C (-58°F ~1076°F)
Accuracy	$\pm 2^\circ\text{C}$ or $\pm 2\%^\circ\text{C}$
Distance Spot Ratio	16:1
Emissivity	0.1~1.0
Laser class	Class II, <1mW
Response time & Wavelength	500ms / 8-14 $\mu\text{m}$
Repeatability	$\pm 1^\circ\text{C}$ or $\pm 1\%^\circ\text{C}$
Resolution	0.1°C
Unit selection	C° / F°
Data memory	9 memories
Laser target point	Dual Laser / can be selected on / off
Storage temperature	-20~50°C (-4~122°F)
Operating temperature	0~50°C, 10~95%RH
Power source	6F22(9V) (not included)
Weight	204g (not including battery)
Dimension(L×W×D) (mm/inch)	175 x 130 x 45mm / 6.9 x 5.1 x 1.8"
Individual packing	Double blister

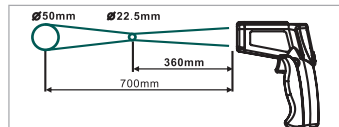

Air conditioning



Ice chest



CPU

Power supply



▶ NT-8540 / NT-8560 / NT-8580 **Laser Distance Measurer**



**Multi-Measurements, Extra Side Key, Spray Proof, Dustproof**

Ideal for measuring factory layout, facilities safety area, trench depth for solar installation, building maintenance, ceilings maintenance, road works, water level, sheet rock measurement.



**Outdoor / Indoor Use**

Comply with IP54 rated as dust-protection and spray-poof.

**Extra Side Key**

One touch extra side key for using easily and quickly.

**Integrated Multi-measuring Functions**


Area, volume, pythagorean measurement allows easy measuring in many different applications.

**LCD Display**

Comes with large LCD display with backlight allows for data reading in dark areas.

**Fold-out Extension**

Extension allows offset reference point for convenience.

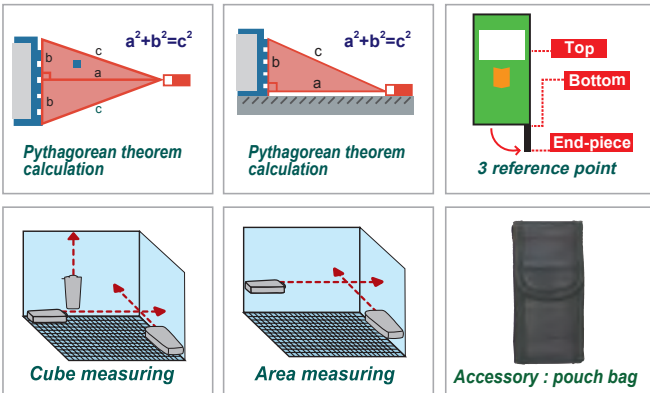

Model No.	NT-8540	NT-8560	NT-8580
Measuring range	0.2~40M	0.2~60M	0.2~80M
Measuring accuracy	±1.5mm		
LCD display	4-line display with backlight		
Measuring functions	Length / Area / Volume		
Continuous measurement	Yes		
Min, Mix measurement	Yes		
Pythagorean 1	Yes		
Pythagorean 2	Yes		
Add/Subtraction	Yes		
Data memory	20 record		
Unit selection	M / ft / in / ft+in		
Beep indication	Yes		
Auto power off	After 3min.		
Auto laser power off	30s		
Low battery indicate	Y		
Laser class	Class 2M		
Laser power	635 nm≤1mW		
Operation temperature	0°C-40°C		
Storage temperature	-10°C-60°C		
Power source	2 x 1.5V AAA batteries(not included)		
Weight	113g (not including battery)		
Dimension(L×W×D) (mm/inch)	115 x 52 x 32.5mm / 4.5x 2.0 x1.3"		
Individual packing	Color Box		



# PRECISION CUTTERS

 


- Ergonomic, non-slip handle which ensures great operator comfort.
- Leaf spring, energy saving design for efficient work.




Individual packing: Blister Card

## ▶ PM-771 Diagonal Cutter Oval Head




Material	HRC		Application	OAL. (mm/inch)
	Body	Cutting edge		
65 CRM	55°±3°	55°±3°	Ø 0.1-1.3mm	115/4.5

## ▶ PM-773 Diagonal Cutter Tapered And Relieved Head

 


Material	HRC		Application	OAL. (mm/inch)
	Body	Cutting edge		
65 CRM	55°±3°	55°±3°	Ø 0.1-1.3mm	115/4.5

## ▶ PM-774 Diagonal Cutter Tapered Head

 


Material	HRC		Application	OAL. (mm/inch)
	Body	Cutting edge		
65 CRM	55°±3°	55°±3°	Ø 0.1-1.3mm	115/4.5

## ▶ PM-760 Diagonal Cutter Oval Head

 


Material	HRC		Application	OAL. (mm/inch)
	Body	Cutting edge		
65 CRM	55°±3°	55°±3°	Ø 0.2-1.3mm Copper	115/4.5

## ▶ PM-761 Diagonal Cutter Oval Head

 


Material	HRC		Application	OAL. (mm/inch)
	Body	Cutting edge		
65 CRM	55°±3°	55°±3°	Ø 0.1-1.3mm Copper	115/4.5

## ▶ PM-763 Diagonal Cutter Tapered And Relieved Head

 


Material	HRC		Application	OAL. (mm/inch)
	Body	Cutting edge		
65 CRM	55°±3°	55°±3°	Ø 0.1-1.3mm Copper	115/4.5

## ▶ PM-764 Diagonal Cutter Tapered Head

 

Material	HRC		Application	OAL. (mm/inch)
	Body	Cutting edge		
65 CRM	55°±3°	55°±3°	Ø 0.1-1.3mm Copper	115/4.5

## ▶ PM-765 Diagonal Cutter Tapered Head

 

Material	HRC		Application	OAL. (mm/inch)
	Body	Cutting edge		
65 CRM	55°±3°	55°±3°	Ø 0.2-1.3mm Copper	115/4.5

## PM-396K Stainless Cutting Plier



### Super Slim

 
- Made of AISI 420 stainless steel which assure cleanliness and corrosion-resistance.
- Dual color non-slip TPR handles for max user comfort
- Polyoxymethylene (POM) spring for self-opening action to supply smooth operation.



Super Slim Style for Narrow Space



Precise Cutting Ø0.1~1.0mm



Material	HRC	Application			Individual packing
		Copper	OAL. (mm/inch)		
AISI 420	48°±3°	Ø 0.1-1.0mm	115/4.53	Blister Card	

## PM-808 Plastic Cutting Plier



### Perfect for cutting parts off the sprue

 
- Made of high carbon steel with fine polish finish.
- Perfectly aligned cutter blades, all cutting edges tempered and hardened.
- Tapered and relieved head is thin and slim allowing use in hard to reach areas.



Super Slim Style



Cut off parts from sprue



Material	HRC	Application			Individual packing
		Body	Handle	Copper	
High carbon steel	PVC	45°±2°	59°±2°	Ø 0.3-1.3mm	136/5.35 Blister Card

## 902-514 8" Diagonal Cutter



- Closed box joint construction ensures smooth action and no handle wobble
- Body corrosion resistant finish and hardened cutting edge for long life
- Nonslip handle for comfort and ease of identification.




Material	HRC		Application			OAL. (mm/inch)	Individual packing
	Body	Cutting edge	Hard steel	Soft steel	Copper		
AISI 6150	45°±3°	62°±2°	20AWG	16AWG	14AWG	210/8	Blister Card

## 902-515 8" Long-Nosed Plier



- Made of hardened steel for great durability
- Cutting edges are precision ground and hardened for long life
- Forged box joint construction gives strength and precision

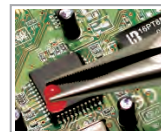

Material	HRC		Application			OAL. (mm/inch)	Individual packing
	Body	Cutting edge	Hard steel	Soft steel	Copper		
AISI 6150	45°±3°	62°±2°	20AWG	16AWG	14AWG	210/8	Blister Card

## 902-520 Crimper with Weatherpack Die



**Special design to be used with weatherpack weathertight connectors**

- Reliable: Parallel action crimping performance is consistent and accurate
- Practical: Safety crimp release helps eliminate rejected terminations due to incorrect positioning.
- Comfortable: Ergonomically shaped non-slip TPR handle for comfortable use in all conditions
- Versatile: Interchangeable die sets for wide range of applications.



Pin



Sealing Plug



**902-519 Weatherpack Die**

Material		HRC	OAL (mm/inch)	Individual packing
Body	Handle			
S50C	TPR	45 ±3'	254/10	Blister card

Model No.	Description	Crimp die profile	Application	Terminals
902-519	Die only		Weather Pack Terminals & Seals Crimp size : AWG 14-16/18-20/22-24	
902-520	Crimper with Weatherpack Die			



## 902-498 Terminal Crimp Kit w/ 100-002



This crimper is for generic red, blue & yellow insulated and non-insulated terminals.



OAL.(mm/inch):235/9.3

**Bolt cutter :**  
4-40, 6-32, 8-32, 10-24, 10-32

**Material :** SAE 1008  
**Hardness :** HV 450~800

**Crimp :**  
Insulation: 22-18, 16-14, 12-10  
Non-insulation: 22-18, 16-14, 12-10 AWG


**Wire strip :**  
AWG: 22-20, 18, 16, 14, 12, 10

PVC

Included Connectors	
Butt Splice Connector, Insulated PVC, Copper Tubular	
30 Pcs , 22-16AWG, Red	
20 Pcs , 16-14AWG, Blue	
15 Pcs , 12-10AWG, Yellow	
Ring Terminal, Insulated PVC, Brazed Seam	
50 Pcs , 22-16AWG, #6 Stud Size, Red	
40 Pcs , 16-14AWG, #8 Stud Size, Blue	
20 Pcs , 12-10AWG, #10 Stud Size, Yellow	
Individual packing	Plastic wrapped



## CP-333 Modular Plug Crimping Tool

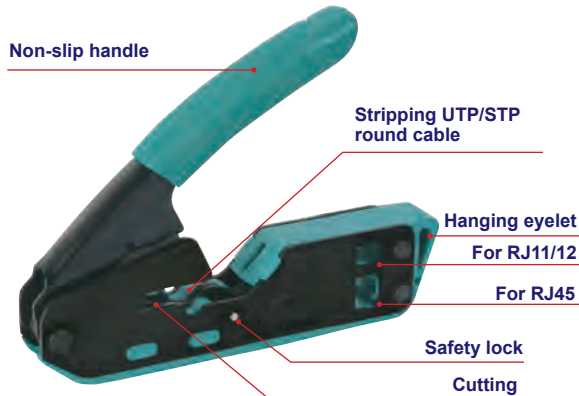

- For crimping RJ-45 (8P8C) and RJ-11/12 (6P6C/6P4C/6P2C) modular plugs.
- The round cable stripping hole is for removing UTP/STP cable outer jacket without damaging the inner conductors.
- Comes with cutting function.
- Reliable and consistent steel mechanical design with Parallel Action features precise crimping and force saving.
- Non-slip grip for user comfort.
- Built-in safety lock to keep tool in closed position during storage.
- Built-in eyelet for a lanyard provides convenient hanging.



Cutting round cable    Stripping UTP/STP round cable    Crimping 6P/8P

Material		Application	OAL (mm/inch)	Individual packing
Handle	Body			
PVC coated	ABS + Carbon Steel	For stripping UTP/STP cable and cutting function For crimping R.J-45 (8P8C), R.J-11/12(6P6C/6P4C/6P2C) modular plugs	143/5.6	Blister card

## CP-316 Adjustable Compression Tool




- For crimping waterproof connector F, BNC, RCA, IEC, MINI F on RG58, RG59, RG6 coaxial cable.
- Has body scale to easily adjust plunger from 21 to 46mm.
- Comes with integrated handle lock for easy storage.
- Steel body with black oxide finish.



RCA waterproof connectors    BNC waterproof connectors    F waterproof connectors    Mini F connectors    IEC connectors


Material		Hardness of main parts	Application	OAL (mm/inch)	Individual packing
Handle	Body				
ABS	S50C	HR15N 75-79°	For crimping connector F, BNC, RCA, IEC, MINI F coaxial cables	146/5.7	Blister card

## CP-418 Copper Clad Steel Coaxial Cable Crimper

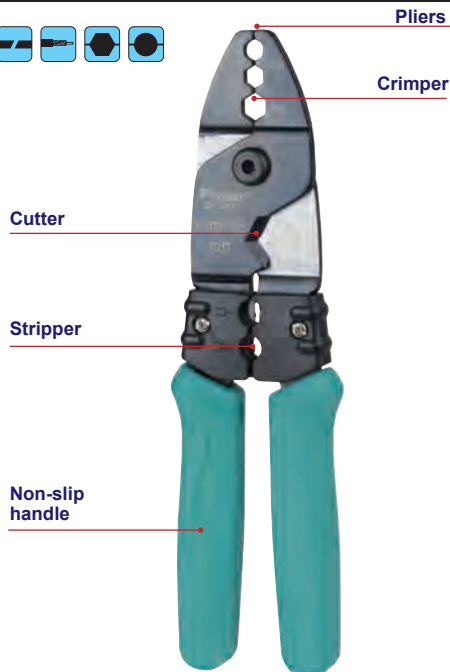

### 3 in 1 for Cutting, Stripping, Crimping

Stripping length guide

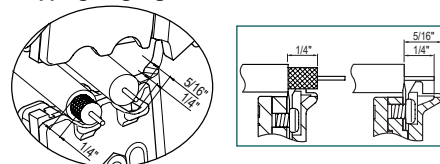

- All in one design-  
For cutting & stripping & crimping RG6 and RG59 coaxial cable.
- Strips coaxial cable-  
By 2 steps for outer jacket at 1/4" & center core at 1/4" or 5/16".
- Precision stripping hole-  
For removing inner dielectric insulation without damaging the center conductor.

Material		Application	OAL.(mm/inch)	Individual packing
Body	Handle			
S45C	PVC	RG6, RG59	207.5/8.5	Blister card


## CP-151B/CP-353

# Non-Insulated Terminals Ratchet Crimping Tool




- High leverage handles, compound action mechanism provide superior mechanical advantage.
- The accurate crimping mold and self locking / releasing mechanical unit design ensure high crimping quality when crimping repeatedly.
- Made of high quality carbon steel with black oxide finish for anti-rust
- Ergonomically shaped non-slip TPR handle with eyelet design for user comfort and easy storage.

**NEW MECHANICAL FORCE SAVING**  
up to **35%**

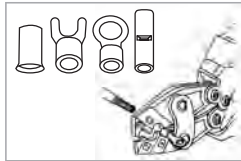


Wire size stamped on terminals

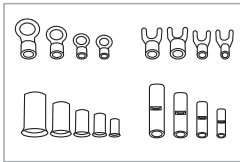

For non-insulated terminals



CP-151B

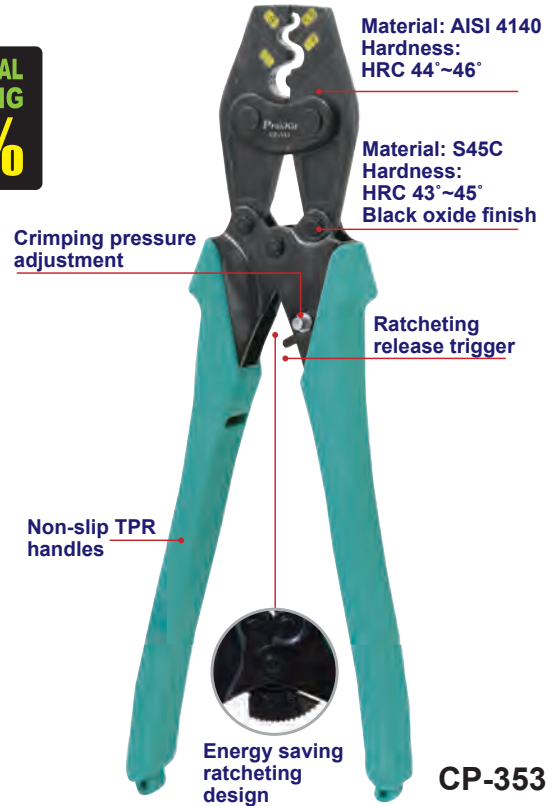

CP-353


Model No.	Material	HRC	Handle	Crimper die profile	Application	OAL (mm/inch)	Individual packing
CP-151B	Frame:S45C Die: AISI 4140	40' - 42'	TPR		Non-insulated spade/ring terminals, AWG 22-16/16-14/12/10, JIS 1.25/2.0/3.5/5.5 mm <sup>2</sup> , DIN 1.5/2.5/4.0/6.0 mm <sup>2</sup>	176/7.0	Blister card
CP-353	Frame:S45C Die: AISI 4140	45'±3'	TPR		AWG 12-10 / 8 / 6 / 4, DIN 4-6 / 10 / 16 / 25 mm <sup>2</sup> , JIS 5.5 / 8.0 / 14 / 22 mm <sup>2</sup>	332/13.0	

## 8PK-CT016

# Ratchet Crimping Tool For Non-Insulated Terminal



- Ideal for electronics, electrical and home electricity installation purpose
- Adjustable ratchet and lever action construction make using convenient

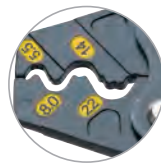

Material	HRC	Handle	Crimper die profile
Frame:S45C Die:SK5	40'±2'	PVC	
Application		OAL (mm/inch)	Individual packing
Non-insulated Terminal AWG 12-10/8/6/4 DIN 4.0-6.0/10/16/25 mm <sup>2</sup> JIS 5.5/8.0/14/22 mm <sup>2</sup>		350/13.8	Blister card

## CP-386

# Snap Plier

- Ergonomic and light weight design for less fatigue, save effort up to 65%.
- Die set contains both male stud & eyelet and female cap & socket snaps.
- Includes hex wrench for loosening and tightening die.



Accessories:  
Hex wrench and die set




Material		Application	OAL (mm/inch)	Individual packing
Handle	Die			
Aluminum	Steel	Perfect for 12mm-15mm snap on all canvas covers, tarps, tent, static-dissipative mat and more.	180	Blister card

## CP-148 Cutter/Stripper & Crimper



- Stripper: 0.8 and 1.4mm stripping holes for AWG 24/22 & 20/18/16
- Pliers: Long nose design for easy wire bending, pulling and holding
- Cutter: Steel body with black oxide finish
- Crimper: For UR/UY/UG, AMP tel splice connector, 709 series connectors

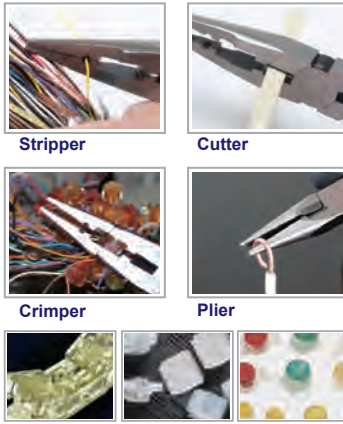

Thomas & Betts/ Belden 709 connectors  
AMP tel splice connectors  
3M Scotchlok UR/UY/UG tel splice connectors

Material		HRC		OAL (mm/inch)	Individual packing
Body	Handle	Body	Cutting edge		
S55C	PVC	46°-48°	55°-65°	168/6.6	Blister card

## 902-499 4-Way Indent Crimper-Deutsch



**Ideal for crimping deutsch closed barrel terminals found on motorcycles, trucks and other heavy duty vehicles.**

- This economical crimp tool delivers the same type of crimp the more expensive MIL-Spec tools provide.
- Built-in locator assures accurate positioning of the pin and socket prior to the crimping action.
- Full cycle ratchet insures a complete and perfect crimp each and every time.
- Cushioned grips.
- Compact 6 1/2" size



For use with 12-20 AWG closed barrel terminals.

Material		HRC		OAL (mm/inch)	Individual packing
Body	Handle	Body	Cutting edge		
S55C	PVC	44°±1°	55°-65°	163/6.4	Blister card

## 902-491 Longitudinal Cable Slitter



Longitudinal cable slitter is a high quality tool used for the slitting and removal of all types of insulation of cable 1.0" or greater in diameter. It is ideal for fiber optic drop lines. The cutting depth can be adjusted from 0 – 13/64" to accommodate various insulation thicknesses. It can slit along the length of cable or around the circumference of the cable.

- For slitting and stripping round cables exceeding 1" diameter.
- Removes all kinds of insulation layers
- Suitable for longitudinal and circular cutting
- Knob adjusts cutting depth up to 13/64" for different cable sheath thickness
- Blade fully retracts inside body for storage
- Replaceable blade (both sides can be used) is available.

Nonslip grip for user comfort and safety

Slits and strips round cables exceeding 1" diameter

Rolling design for force saving and safety

Knob adjusts cutting depth up to 13/64"

Open for operation

Fully retracts inside for storage



Material		HRC	Replaceable blade	OAL (mm/inch)	Individual packing
Body	Handle				
Nylon	Powder metallurgy	57°±3°	902-491-BLADE Longitudinal Cable Slitter Blade	210/8.2	Blister card



Longitudinal cutting



Circular cutting



Adjustable cutting depth

## ▶ CP-507 Coaxial Cable Stripper & Cutter



- Designed for easy single operation of stripping and cutting RG-59, RG-6 cable.
- Unique, safe design construction to avoid blade exposure and accidents.
- Black hook and loop for folding back the braided shield.
- Finger loop promotes rotation during use.
- Pocket clip design for convenient carrying.



**Black Hook and Loop for folding back the braided shield**



**Unique, Safe Design construction**

Material		Application	OAL. (mm/inch)	Individual packing
Body	Blade			
ABS	SK5	RG-59/6	111/4.4	Blister card

 
## ▶ CP-509 Coaxial Stripping Tool



- With hex wrench for easy installing or removing F connector from splitter.
- Durable SK5 preset cutting blades provide precise, accurate cable stripping.



**Remove F connector**




Material		Application	OAL. (mm)	Individual packing
Body	Blade			
ABS	SK5	RG-59/6/7/11	130/5.1	Blister card

## ▶ CP-512 Rotary Coaxial Cable Stripper



 - Designed for easy single operation of one-step stripping RG-59/6/7/11 coaxial cable.
- Unique, safe design construction to avoid blade exposure and accidents.
- Finger loop promotes rotation during use, more user friendly.
- Black hook for folding back the braided shield.
- Compact and ergonomic design for convenient carrying and use.



**Replacement blade cassette:  
5CP-505-RG(1pcs/pack)**



**Black hook for folding back the braided shield**



**Quick strips  
RG59/RG6/RG7/RG11**



Material		Application	OAL. (mm/inch)	Individual packing
Body	Blade			
ABS	SK5	RG-59/6/7/11	94/3.7	Blister card

## ▶ CP-521 Coaxial Stripping Tool



- Designed for stripping RG-58/59/6/62 coaxial cable
- Durable SK5 steel preset cutting blades provide precise, accurate cable stripping
- Special POM (Polyoxymethylene) structure, easy operation and force saving



Material		Application	OAL. (mm/inch)	Individual packing
Body	Blade			
POM	SK5	RG-58/59/6/62	115/4.5	Blister card



## ▶ 902-512 / 902-513 Dual Wattage Soldering Iron



**DUAL WATTAGE professional soldering iron, excellent for all electronics hobbyists as well as industrial users.**

- Selectable switch lets you easily swap the power setting.
- Tailor your temperature depending on your project.
- Ergonomic handle with comfortable grip for max. user comfort.
- Comes with long life tip and safety stand.
- Includes sheet metal stand.

**902-512** 15/30W Dual Wattage Soldering Iron

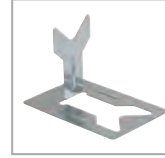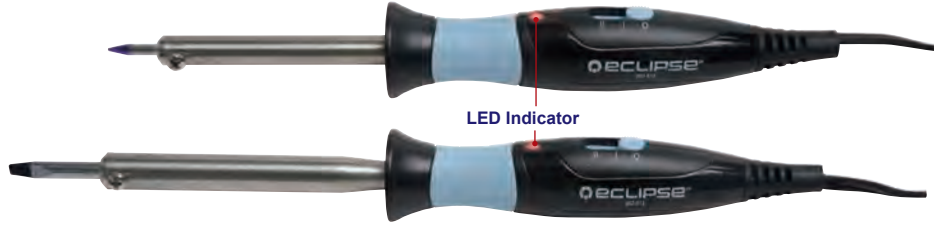

Iron Stand

**902-513** 30/60W Dual Wattage Soldering Iron

Model. No	Voltage	Consumption	Standard plug	Individual packing
902-512	120V	15/30W	A	Blister card
902-513	120V	30/60W	A	Blister card

## ▶ DP-366J Desoldering Pump



Transparent tube to easily check the residues



Piston with double O-rings suction capability: 32cm-hg

- Piston with double O-rings avoids the air leakage and maximizes suction power.
- Suction Capability: 32cm-Hg, quick and easy to clean solder residues.
- Transparent tube makes it easy to check the volume of solder residues.
- Replacement heat-resistant Teflon tip resists distortion.
- Nonslip handle design to hold the pump tightly.
- Compact size for one hand operation.



Piston with double O-rings avoids air leakage



Detachable pump is simple to clean solder residues



Transparent tube is easy to check solder residue

Material	Suction Capability	Size (mm/inch)	Individual packing
PC	32cm-hg	210/8.3	Blister card

## ▶ GS-23K Auto Ignite Gas Soldering Iron



- Auto ignition for starting and operating easily and safely under any condition.
- Safety ignition switch complies with CPSC standard to prevent children misuse.
- Comes with TR90 high transparent nylon gas tank features long service life and more safety.
- With Ceramic heater for long service life.
- Adjustable flame control for precision use.
- Butane is easy to refill and check with see-through fuel window.
- Complete kit comes in a plastic case and meets a variety of operating applications.



Hot blow up to 600°C



Torch up to 1300°C



Soldering up to 500°C



Stand support for convenient work



Soldering Temperature	Hot Blow Temperature	Torch Temperature	Fuel Capacity	Time	Size (mm/inch)	Individual packing
500°C	600°C	1300°C	15ml	90min	245 x Ø 29mm/ 9.6xØ1.1"	Color Box



## SD-T860 12 PC VDE Torque Screwdriver Set



- Dual color VDE torque handle, torque adjustable 1-6 Nm, Includes torque adjusting tool for easy torque setting. Insulated metal bit holder locks all bits reliably.
- Individually tested protective insulation 1000 VAC, VDE and GS tested. Includes 10pcs common use bits to satisfy most applications. Made by AISI 8660 Cr-Mo-V steel.
- For controlled fastening on live cable or parts up to 1000VAC, such as power plants, refrigeration and air conditioning systems, electrical engineering installation and maintenance...etc.
- Arranged properly in a high quality and rugged bag, could be used as convenient storage bag and waist working bag.

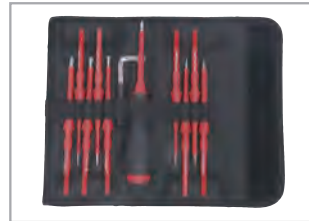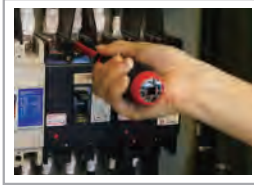

### Specification

Torque adjustable: 1~6Nm, Accuracy±6%, recommend calibration after 5000 cycle

### Contents

Dual Color PP/TPR/POM Handle, length:127mm

 
10PCS AISI 8660 Bits, length:195mm:

⊖ SL2.5, SL3.0, SL4.0, SL5.5, SL6.5 ⊕ PH0, PH1, PH2, ⊕ PZ0, PZ1

Square 8mm torque adjusting tool, length:99mm/40mm

Individual packing Color Box

## SD-T636 12 PC Torque Screwdriver Set



- Dual color torque handle, torque adjustable 1 - 6 Nm, Includes torque adjusting tool for easy torque setting.
- Includes 10pcs double end bits, common use 20 bits size to satisfy most applications. Made by AISI 8660 Cr-Mo-V steel.
- For controlled fastening on electrical engineering installation and maintenance, and more.
- Arranged properly in a high quality and rugged bag, could be used as convenient storage bag and waist working bag.



### Specification

Torque adjustable: 1~6Nm, Accuracy±6%, recommend calibration after 5000 cycle

### Contents

Dual Color PP/TPR/POM Handle, length:137mm

10PCS AISI 8660 double end hex Bits, length:175mm:


⊖ SL3.0+SL4.0, SL5.5+SL6.5, ⊕ PH0+PH1, PH2+PZ2, ⊕ PZ0+PZ1, ⊕ T10H+T15H, T20H+T25H, ⊕ H2H+H3H, H4HxH5H, ⊕ PZ/FL1+PZ/FL2

Square 8mm torque adjusting tool, length:99mm/40mm

Individual packing Color Box

**SD-T635 Series Adjustable Torque Screwdriver**

**DIN** ISO 6789 **ASME** B107.300-2010

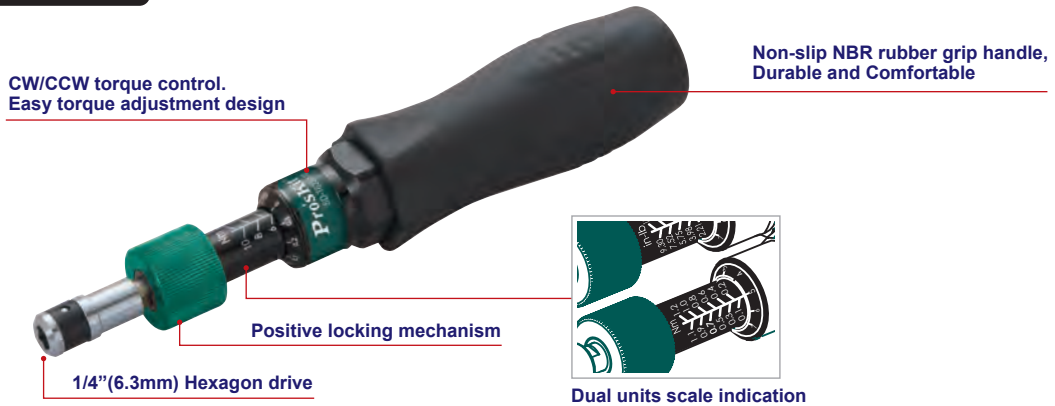

Ideal for electronic, computer, communication, motorcycle, bicycle, automobile, truck, heavy machinery, ship, cruise, aerospace industry, high-speed rail and more.

**Accuracy of torque ±6.0 %**

- Each torque wrench laser serial no. and calibration certificate for future tracing.

**Dual units scale indication**

- Dual units N.m and lbf.in or lbf.ft scale indication.

**CW/CCW torque control**

- Applied to both clockwise and counter clockwise bi-directional torque control.
- Signals by impulse when torque setting is reached.

**Easy Torque adjustment**

- Easy torque-adjusting design brings energy-saving benefit. Positive locking mechanism avoids accidental setting alterations.

**Reliable Mechanism**

- Quality meets DIN ISO 6789 & ASME B107.300-201

Model No.	SD-T635-0112	SD-T635-16	SD-T635-510
Drive	1/4"/6.35mm Hexagon		
Unit	N-m/lbf.in Dual units		
Torque Range	0.1~1.2 N-m 1.33~10.18 lbf-in	1.0~6.0 N-m 13.28~48.68 lbf-in	5.0~10 Nm 48.68~84.08 lbf-in
Accuracy	±6.0 %		
Graduation	0.01 N-m	0.1 N-m	
OAL.(mm/inch)	180 / 7	200 / 7.9	
Individual packing	Plastic box+Color label		

**SD-9817 6 In 1 Ratchet Screwdriver Set**



- Pivoting head locks in 3 operating positions allowing better control & access to confined areas
- Ergonomic dual color TPR+PP handle with bits storage inside
- Magnetized hex opening holds all standard driver bits, and allows quick removal and replacement
- 3 position ratchet features forward, reverse and locked


Contents
6 pcs 1/4" Bits: ⊖ 4,5,6mm ⊕ #1, #2, #3
1pcs 3-way ratchet screwdriver handle
Individual packing
Blister card

## SD-9828 58 PC Driver Kit



Ideal for opening smartphones, tablets, notebooks, electronic device case and most branded video games such as Apple, HTC, Samsung, LG, Nokia, Sony, Sega, Microsoft, Nintendo and more.

Contents		
42 pcs $\Phi 4.0 \times 28$ mm, material : AISI 8660 Cr-Mo-V steel		
#000, #00, #0, #1, #2	#0, #1, #2	
1.0, 1.3, 1.5, 2.0, 2.5, 3.0, 3.5, 4.0 mm		
T5H, T6H, T7H, T8H, T9H, T10H, T15H, T20H		
T3, T4		
0.7, 0.9, 1.3, 1.5, 2.0, 2.5, 3.0, 3.5, 4.0 mm		
#0, #1	3.0 mm	
3.0 mm		
Pentalobe  P2, P5, P6 (iPhone, MacBook Air, MacBook Pro)		
6 pcs $\Phi 4.0 \times 30$ mm, material : 50BV30 Cr-V steel		
2.5, 3.0, 3.5, 4.0, 4.5, 5.0 mm		
5 pcs $\Phi 1/4'' (6.3) \times 25$ mm, material : AISI 6150 Cr-V steel		
#2	6.0 mm	4.5, 5.0, 6.0 mm
2 pcs $\Phi 1/4'' (6.3) \times 38$ mm, material : AISI 6150 Cr-V steel		
Torx plus <sup>®</sup> socket  TS3.8, TS4.5		
1 pc $\Phi 4.0$ mm to $\Phi 1/4''$ adaptor 50 mm		
1 pc $\Phi 4.0 \times 125$ mm extension bar		1 pc TPR non-slip handle
Individual packing	Color sleeve+Shrink pack	

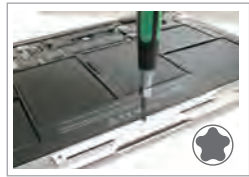

The TS3.5/TS4.5 Torx Plus<sup>®</sup> sockets are for Nintendo, SONY, SEGA products.

P2, P5, P6 pentalobe tips are special for Apple products

## MS-3176 4 PC Open Repair Tool Set



- Ideal for most brands of smartphones, video games, notebooks, electronic devices.
- Opening, prying and disconnecting small electronic components without damaging housing or parts.



Contents	
Metal spudger tool (123 mm / 4.8")	
Point-blade solder aid tools (155 mm / 6.1")	
Spudger solder aid tools (140 mm / 5.5")	
Fork-blade solder aid tools (173 mm / 6.8")	
Individual packing	Blister card

## SD-3502 6 PC Star Tip Screwdriver Set



The precision screwdriver set comes with AISI 8660 Cr-Mo-V alloy steel blade, rotating cap and nonslip ABS handle, durable and easy operation. Ideal for mobile, video games and electronic devices repair purpose.



Contents	
T4  T5H, T6H, T7H, T8H, T9H	
Blade length: 20mm , OAL.: 110mm / 4.3"	
Carrying case: 121x93x18mm / 4.8x3.7x0.7"	
Individual packing	Plastic box+Color box

**SD-600 Series Ergonomic Cushion Grip Screwdriver/Nut Driver**



**Meets the DIN, ISO and ANSI standards.**

- Ergonomic and soft cushion handle fits your hand and provides best comfort and firm grip for users.
- Acetate and TPV materials of handle provide nonslip and resistance to chemical, oil and most solvents.
- The blade of screwdriver is made of special high quality SVCM alloy steel, nut driver is made by CR-V, through-hardened with satin chrome or chrome plating.
- Blade tip ensures a perfect fit in every screw head.
- The screw symbol and tip size marking is on the handle end, easy to find the right screwdriver for the job.



Ergonomic and soft cushion handle



The screw symbol and tip size marking is on the handle end

**— SLOTTED SCREWDRIVER + PHILLIPS SCREWDRIVER**

Model No.	SIZE	OAL (inch)
800-097	3/16" X3"	6.69
800-099	3/16" X4"	7.68
800-095	3/16" X 6"	9.65
800-093	1/4" X4"	8.27
800-152	1/4" X 6"	10.24
800-153	1/4" X8"	12.20
800-154	1/4" X10"	14.17
800-101	1/4" X1-1/2"	3.62

Model No.	SIZE	OAL (inch)
800-098	#1 X 3"	6.69
800-100	#1 X 4"	7.68
800-094	#2 X 4"	8.27
800-103	#2 X 6"	10.24
800-096	#2 X8"	12.20
800-104	#2 X10"	14.17
800-102	#2 X 1-1/2"	3.62

**★ STAR TIP SCREWDRIVER**

Model No.	SIZE	OAL (inch)
800-109	T15 X 4"	7.68
800-110	T20 X 4"	7.68
800-111	T25 X 4"	8.27
800-112	T27 X 4"	8.27
800-113	T30 X 4"	8.27

**■ SQUARE SCREWDRIVER**

Model No.	SIZE	OAL (inch)
800-105	S0 X4"	8.27
800-106	S1 X 4"	8.27
800-107	S2 X 4"	8.27
800-108	S3 X 4"	8.27

**● HOLLOW-SHAFT NUT DRIVER**


Model No.	SIZE	OAL (inch)
902-231	3/16" X 3"	7.28
902-232	1/4" X 3"	7.28
902-233	5/16" X 3"	7.28
902-234	11/32" X 3"	7.28
902-235	3/8" X 3"	7.28
902-236	7/16" X 3"	7.28
902-237	1/2" X 3"	7.87

## HW-T Series Adjustable Torque Wrench With Reversible Ratchet

**DIN**  
ISO 6789

**ASME**  
B107.300 -2010

Industrial Application

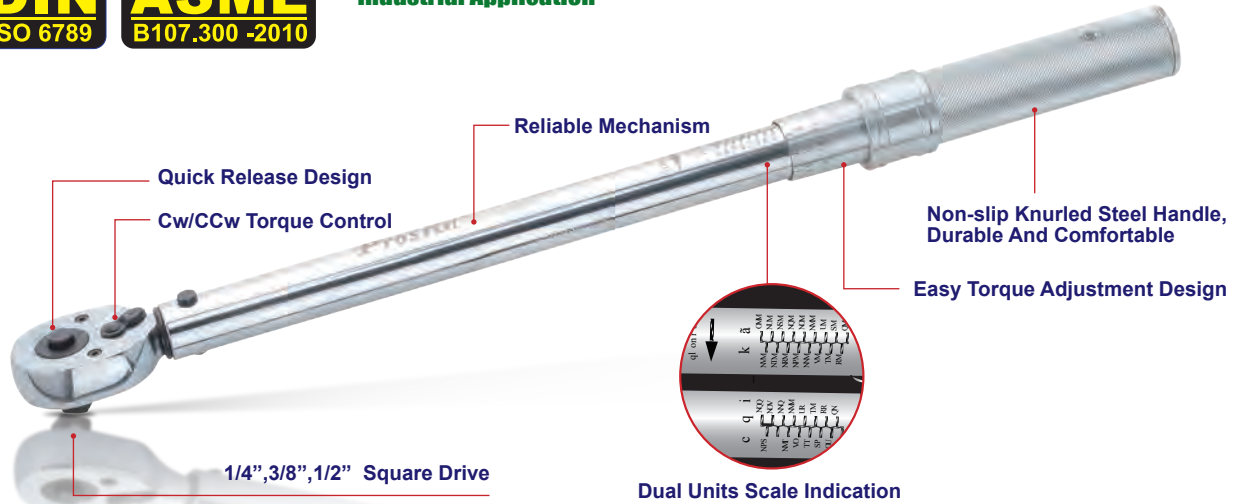

SOCKET WRENCHES

### Accuracy of torque $\pm 3.0\%$

- Each torque wrench laser serial no. and calibration certificate for future tracing.

### Dual units scale indication

- Dual units N.m and lbf.in or lbf.ft scale indication.

### CW/CCW torque control

- Applied to both clockwise and counter clockwise bi-directional torque control.
- Signals by impulse when torque setting is reached.

### Easy Torque adjustment

- Easy torque-adjusting design brings energy-saving benefit. Positive locking mechanism avoids accidental setting alterations.


### Quick release design

- Comes with quick release design, allows changing socket quickly.

### Reliable Mechanism

- Quality meets DIN ISO 6789 & ASME B107.300-2010

Ideal for motorcycles, bicycle, automobile, truck, heavy machinery, ships, cruise, aerospace industry, high-speed rail and more.

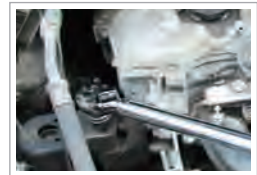

Model No.	HW-T41-315	HW-T41-525	HW-T83-20100	HW-T21-40200	HW-T21-60340
Drive	1/4"/6.35mm Square	1/4"/6.35mm Square	3/8"/9.53mm Square	1/2"/12.70mm Square	1/2"/12.70mm Square
Unit	N-m/lbf.ft Dual units	N-m/lbf.ft Dual units	N-m/lbf.ft Dual units	N-m/lbf.ft Dual units	N-m/lbf.ft Dual units
Torque Range	3.0~15 N-m 31~128 lbf.ft	5.0~25 N-m 53~212 lbf.ft	20~100 N-m 16.6~71.9 lbf.ft	40~200 N-m 33~144 lbf.ft	60~340 N-m 52~243 lbf.ft
Accuracy	$\pm 3.0\%$	$\pm 3.0\%$	$\pm 3.0\%$	$\pm 3.0\%$	$\pm 3.0\%$
Graduation	0.1 N-m	0.2 N-m	0.5 N-m	1.0 N-m	2.0 N-m
Gear teeth	64 T	64 T	32 T	32 T	32 T
OAL	210 mm (8.3")	248 mm (9.8")	433 mm (17")	530 mm (21")	610 mm (24")
Individual packing	Plastic box+Color Label	Plastic box+Color Label	Plastic box+Color Label	Plastic box+Color Label	Plastic box+Color Label

## HW-T716-3 7/16" Preset Torque Spanner


**RoHS**  
COMPLIANT

- Proper connections at "F" connector interface with factory preset torque setting 30 lbf-in(3.4NM).
- Narrow head design helps work in tight density space.
- Audible click sound alerts user when full pressure has been applied. Ergonomic & cushion handle for user comfort and protection.



Material		Torque range	Drive	Individual packing
Handle	HEX			
TPR	ANSI4140	30 lbf-in(3.4NM)	7/16"(11.1mm)	Blister card

## ▶ MA-1601A LED Working Lamp

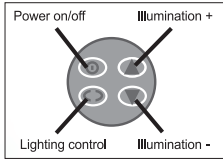

Control panel for power on/off and lighting adjustment



- The adjustable arm allows easy placement in any position you need.
- Comes with switching adapter, provides even more stable performance.
- Designed with 84pcs SMD LED, features long service life, super bright and energy-saving.
- Both high light and dim light for choices.




Energy consumption	Color temperature	Luminance	Overall length	Voltage	Standard plug	Individual packing
2-21 W	6000-7000 Kelvin	1200 Lumen	92 x 58 x 18 cm	AC 110V~120V	A (I)	Color Box

## ▶ MA-1004A LED Desk Type Magnifier Lamp



- Comes with 56 LEDs which provide bright lighting and only 9W consumption.
- LED technology features long-life, up to 50,000 hours, which is 20 times longer than incandescent lamps.
- Designed with 3D(1.75X) magnification Glass Lens, great for working on hobbies, PCB and documents.
- The adjustable arm allows angling and pointing the light to where you need.

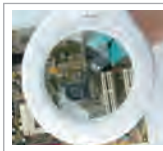

Model No.	Lens material	Magnification	Lens size	Illumination	Luminance	Voltage	Standard plug	Individual packing
MA-1004A	Glass	3D(1.75X)	127×79 mm / 5x3.1"	56 pcs LEDs	650 Lumen	AC 110V~120V	A (I)	Color Box
MA-1006A	Glass	3D(1.75X)	115×73 mm / 4.5x2.9"	30 pcs LEDs	300 Lumen	AC 110V~120V	A (I)	Color Box

## ▶ MA-1006A LED Desk Type Magnifier Lamp



- Comes with 30 LEDs which provide bright lighting and only 5.5W consumption.
- LED technology features long-life, up to 50,000 hours, which is 20 times longer than incandescent lamps.
- Designed with 3D(1.75X) magnification Glass Lens, great for working on hobbies, PCB and documents.
- The adjustable arm allows angling and pointing the light to where you need.



## ▶ MA-023 Handheld LED Light Magnifier



High quality 10D(3.5X) Acrylic lens, Ø50mm

High quality 76D (20X) Acrylic lens, Ø18mm

Comes with 2 LEDs allowing use in dimly lit places

Soft handle



- Pull-out with dual lenses ,10D(3.5X)/76D(20X) to meet many applications.
- Comes with 2 LEDs allow use in dimly lit places.
- Nonslip handle with rubber provides comfortable operation.



PCB checking



Jewelry work

Len Material	Magnification & Lens size		Light Source	Battery	Individual packing
Acrylic	Big Lens	Small Lens	2 LEDs	1.5V AAA x3pcs (not included)	Blister card
	10D(3.5X) Ø50mm / 2"	76D(20X) Ø18mm / 0.7"			

## ▶ 902-492 20V Cordless Drill

- 1/2 Inch Keyless Metal Chuck
- Heavy-Duty High Torque
- Two Speed Gear Box (0-400 rpm / 0-1700 rpm)
- Variable Speed Trigger with Forward/Reverse Switch
- Built-in High Output LED Light Illuminates Work Surface for Increased Visibility
- Includes 6 Drill Bits, 6 Screwdriver Bits and 1 Bit Extender
- Includes 20V Lithium-Ion Battery with LED Battery Level Indicators
- Intelligent Charger Prevents Damage to Battery

Input Power	20V
No Load Speed	0-400 rpm / 0-1700 rpm
Impact Rate	-
Torque Settings	19+1
Soft Torque	221 in-lbs
Hard Torque	310 in-lbs
Battery Power	1.3 Ah Lithium-Ion
Charge Time	1 Hour
Drill Weight	3.7 lbs (with case 7.6 lbs.)



## ▶ 902-493 20V Cordless Hammer Drill

- 1/2 Inch Keyless Metal Chuck
- Heavy-Duty High Torque
- Two Speed Gear Box (0-400 rpm / 0-1700 rpm / 0-19200 bpm Impact)
- Variable Speed Trigger with Forward/Reverse Switch
- Built-in High Output LED Light Illuminates Work Surface for Increased Visibility
- Includes 6 Drill Bits, 6 Screwdriver Bits and 1 Bit Extender
- Includes 20V Lithium-Ion Battery with LED Battery Level Indicators
- Intelligent Charger Prevents Damage to Battery

Input Power	20V
No Load Speed	0-400 rpm / 0-1700 rpm
Impact Rate	0-19200 bpm
Torque Settings	19+1
Soft Torque	221 in-lbs
Hard Torque	310 in-lbs
Battery Power	1.3 Ah Lithium-Ion
Charge Time	1 Hour
Drill Weight	3.7 lbs (with case 7.6 lbs.)



▶ **902-494 20V Cordless Impact Driver**



- Universal 1/4 Inch Hex Drive
- Quick Release Chuck
- Heavy Duty High Torque Gear Box, 1350 in/lbs of Driving Force
- Three Built-in LED Lights Illuminate Work Surface for Increased Visibility
- Variable Speed Trigger With Forward/Reverse Switch
- Includes 4 Nut Driver Sockets
- Includes 20V Lithium-Ion Battery with LED Battery Level Indicators
- Intelligent Charger Prevents Damage to Battery

Input Power	20V
No Load Speed	0-2200 rpm
Impact Rate	0-3200 bpm
Hard Torque	110 ft-lbs
Hex Drive	1/4 Inch
Battery Power	1.3 Ah Lithium-Ion
Charge Time	1 Hour
Drill Weight	3.3 lbs (with case 7.2 lbs.)

▶ **902-495 20V Spare Battery 1.5Ah Li-Ion, for Cordless Drill**

Compatible with 902-492, 902-493, and 902-494.



▶ **902-496 Charger for 20V Cordless Drill**

Replacement charger for 20V cordless drills. Compatible with 902-492, 902-493, and 902-494.



▶ **PT-5203A Electric Engraver**



**Speed 7100 spm, 9 position stroke setting, LED light**



- 9 position stroke setting regulates engraving depth from fine lines to deep grooves.
- Soft TPR handle provides extra comfort and control.
- Comes with LED light allows operating even in dark area.
- Replaceable solid carbide point gives you the power to engrave on different surfaces.
- Light and compact design provides comfortable use for precision engraving performance.
- Ideal for engraving or decorating metal, glass, stone and more.



Accessories:  
2 solid carbide tips  $\Phi 3.0 \times 20$  mm and 1 hex wrench included



Voltage	AC 120V 60Hz
Consumption	10W
Speed	7,100 spm
Stroke setting	9 Position
Engraver point holder	$\Phi 3.0$ mm
Standard plug	A [ ]
Individual packing	1.3 Ah Lithium-Ion



## ▶ 902-508/902-509 Sheet Metal Installation Tools

- Sheet metal installation tools for drilling and driving 1/4-inch or 5/16-inch head sheet metal screws
- One piece drill and drive tool with a 1/4-inch quick change shank
- Retractable 1/8-inch heavy duty high speed drill bit.
- No loose sockets.

### 902-510 Tool Accessories Kit

Tool Accessories Kit Includes:

- 3/32-in. Allen wrench and three 10-32 set screws
- Includes three 1/8-in. heavy duty high speed drill bits
- Handy storage case



Model No.	Description	Length (Inch)	Width (Inch)	Depth (Inch)	Weight (Oz)
902-508	1/4-in. Sheet Metal Installation Tool	6	1	1	2.8
902-509	5/16-in. Sheet Metal Installation	6	1	1	2.8
902-510	Sheet Metal Tool Accessories Kit	6	1	1	0.8



**902-508**  
**1/4"**  
**Sheet Metal**  
**Installation T**



**902-509**  
**5/16"**  
**Sheet Metal**  
**Installation**

## ▶ Steel Auger Installer Bits

- Ultra-sharp threads for better pulling power.
- Wire fishing holes in the head and shank.
- Three flat non-slip grip on the chuck end of the flexible spring steel shank.
- Application: Wood



Model No.	Description	Length (Inch)	Drill DIA. (Inch)	Shank DIA. (Inch)	Weight (Oz)
902-500	3/8 in. x 36 in. Auger Installer Bit	36	3/8"	3/16"	4.6
902-501	3/8 in. x 54 in. Auger Installer Bit	54	3/8"	3/16"	6.9
902-502	3/8 in. x 72 in. Auger Installer Bit	72	3/8"	3/16"	9.1
902-503	9/16 in. x 36 in. Auger Installer Bit	36	9/16"	3/16"	7.0
902-504	9/16 in. x 54 in. Auger Installer Bit	54	9/16"	3/16"	8.8
902-505	9/16 in. x 72 in. Auger Installer Bit	72	9/16"	3/16"	11.0

## ▶ 902-506/902-507 Flexible Extender

- Three flat non-slip grip on the chuck end
- Flexible spring steel shank
- Wire fishing accommodation holes in the shank
- For use with 3/16" Diameter flex drills



Model No.	Description	Length (Inch)	Width (Inch)	Depth (Inch)	Weight (Oz)
902-506	3/16-in. X 36 in. Installer Bit Extension	36	0.5	0.5	6.3
902-507	3/16-in. X 54 in. Installer Bit Extension	54	0.5	0.5	8.2

## ▶ 500-036 Hole Saw Kit

- 11pcs hole saw
- Long lasting bi-metal material
- Very sharp, cut through material fast
- Cut through wood, plaster, mild steel
- 3 different sized arbors
- Triangular shank 1/4" fits hole saws 7/8", 1-1/8"
- Triangular shank 7/16" fits hole saws 1-3/8" 1-1/2", 1-3/4", 2", 2 1/2", 3", 3-5/8", 4-1/8", 4-1/2"
- SDS plus shank fits hole saws 7/8", 1-1/8"
- Extension Bar: 12" length fits hex shank 7/16" arbor
- Hex Key: 4mm



Contents	
11pcs hole saw	7/8", 1-1/8", 1-3/8", 1-1/2", 1-3/4", 2", 2-1/2", 3", 3-5/8", 4-1/8", 4-1/2"
12" extension arbor	
1/4" arbor, 7/16" arbor	
SDS plus arbor	
Sturdy blow-molded case	
Individual packing	Color Label

## ▶ MT-7601 Fiber Optical Power Meter



Compatible connectors (LC with optional adaptor)



Fiber optic power test



Additional shock-proof cover & pouch bag

- Adapts to FC/SC/ST connectors
- Automatically auto power off after 10min of no operation.
- 850nm/ 1300nm/ 1310nm/ 1490nm/ 1550nm/ 1625nm
- Comfortable LCD backlight display
- Can store the current laser source as a new reference value

Specifications	
Detector Type	InGaAs
Optical Connector	FC/SC/ST& 2.5mm Universal
Calibrated Wavelengths	850, 1300, 1310, 1490, 1550,1625
Measurement Range	+6 ~ -70 dBm
Accuracy	(1550nm, 1310nm)±0.2dB/ (1490nm, 1625nm)±0.3dB/ (850nm, 1300nm)±0.4dB
Power Measurement Linearity	±2.0%
Display Resolution	+6 ~ -60dBm:0.01 dB, -60 ~ -70dB m:0.1 dB
Power Display Units	dBm, mW, μW, nW
Reference comparison value	Yes
Modulation Detection	270Hz, 1KHz, 2KHz (850, 1300, 1310, 1490, 1550, 1625)
Operation voice prompts	Yes
Backlight	Yes
Automatic Power Off	10 min.(Can be cancelled)
Low Battery Warning	Low battery energy
Body protection	Yes
Battery Life	> 160 hours
Operating Temperature	-10 ~ +60 °C, < 90%
Storage Temperature	-20 ~ +70°C, < 90%
Power source	AA/LR6 1.5V×2 pcs (not included)
Size(mm/inch)	165×80×35 mm / 6.5x3.1x1.4"
Weight	180g (w/o battery)
Optional Accessory	LC adaptor (5MT-7601-LC)
Individual packing	Color box

## ▶ MT-7602 4 In 1 Fiber Optical Power Multimeter



RJ-11/RJ-45 Cable Tester (Remote)



Fiber optic power test



Cable tester



Break in fiber test



LED flashlight

1. FIBER POWER METER
2. VISUAL FAULT LOCATOR
3. CABLE TESTER
4. LED FLASHLIGHT

- Simple 3 push-button operation.
- Built-in USB connector for battery charger.
- Auto power off for energy saving.

Specifications	
Detector Type	InGaAs
Optical Connector	ST/SC/FC & 2.5mm Universal
Calibrated Wavelengths	850/1300/1310/1490/1550/1625 nm
Measurement Range	+6 ~ -70 dBm
Accuracy	(1550nm, 1310nm)±0.2dB/ (1490nm, 1625nm)±0.3dB/ (850nm, 1300nm)±0.4dB
Power Measurement Linearity	± 0.1 dB
Display Resolution	± 0.01 dB
Power Display Units	dBm, μW, mW
Output Power	<1mW
Range	3~5 kΩ @SM
Connector	ST/SC/FC & 2.5mm Universal
Laser Safety Rating	Class 2
Wavelength	650nm±20nm
Output Modes	Continuous (CW) , 2 Hz pulsed
Reverse Battery Protection	Yes
Connector	RJ45 & RJ11
Cable	UTP LAN cable(8P8C), Telecom cable(6P2C/6P4C/6P6C)
Measuring Length Max.	600 meter
Automatic Power Off	10 min.(Can be cancelled)
Low Battery Warning	Low battery energy
Battery Life	> 160 hours (only OPM)
Power Source	AA/LR6 1.5V rechargeable battery ×2 (not included)
Size(mm/inch)	105×52×34 mm / 4.1x2.0x1.3"
Optional Accessory	LC adaptor (5MT-7601-LC)
Individual packing	Color box

## ▶ MT-7501 / MT-7505 Fiber Optic Visual Fault Locator

**1 Sec. Quick Illuminate**  
To make checking work convenient

**2 Operation Modes**  
Locating fault accurately

**3 Supported Connectors**  
To give more versatile choice (FC/SC/ST)

- Portable, durable and easy to use.
- Both continuous and flashing modes available.
- Additional pouch bag for convenient storage.
- Supports 2.5mm(0.1") universal connectors (for FC/SC/ST).
- Dust-proof & crash-proof cap design for laser head.

**1 mW MT-7501**



FDA

**5 mW MT-7505**



FDA

Model No.	MT-7501	MT-7505
Wavelength	650 nm±10 nm	
Output power	1 mW	5 mW
Light source	CLASS II	CLASS IIIA
Tested fiber length	3-5km/3281-5468yd	6-7km/6562-7655yd
Power (batteries)	AA (1.5 V) x 2	
Connector	2.5mm(0.1") universal connector for FC, ST and SC	
OAL(mm/inch)	175mm/6.9"	
Operating temperature	-10~55°C	
Storage temperature	-10~70°C	
Optional accessory	LC adaptor (5MT-7601-LC)	
Individual packing	color box	



Compatible connectors (LC with optional adaptor)



Continuity test



Locate break point



Accessory

## ▶ FB-C008 / FB-C009 Fiber Optic One Click Cleaner

**800 cleans for**  
FC/PC, ST, SC or LC Connectors  
and Bulkheads

**Cleaning system**  
rotates 180° for a full sweep

**Dry cleaning**  
cloth eliminates the need for solvents

**Easy pushing motion**  
engages cleaner with audible click sound

**Extendable nozzle**  
makes it easy to reach the recessed connectors

**Indication Window**  
for easy checking

**FB-C008**




**FB-C009**

**FB-C009**

**1.25MM FIBER OPTIC ONE CLICK CLEANER**

**FB-C008**

**2.5MM FIBER OPTIC ONE CLICK CLEANER**

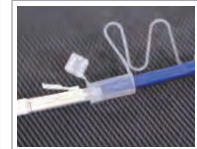

Model NO.	Applications	Length		Cleaning capacity	Individual packing
		Standard	Extended		
FB-C008	2.5 mm FC/PC, ST and SC Connectors and Bulkheads	175 mm / 6.9"	210 mm / 8.3"	800 times	Blister card
FB-C009	1.25 mm LC Connectors and Bulkheads				

## ▶ FB-C010 Fiber Optic Connector Cleaner

**Refillable cleaning tape**

**Full cleaning** for SC, FC, MU, LC, ST, D4, DIN Connectors

- Special non-alcohol high density textile fiber type eliminates the need for solvents.
- Offering over 500 cleans for SC, FC, MU, LC, ST, D4, DIN Connectors.
- Indication see through window for easy checking.
- The refillable cleaning tape: Model No.5FB-C010-RPM.

Material	Cleaning times	Applications	Dimensions	Individual packing
High density textile fibers	500/per box	For cleaning SC, FC, ST, MU, LC, D4, DIN connector	115×79×32 mm / 4.5×3.1×1.3"	Blister card



## PK-9458 FTTH Fiber Optic Tool Kit



Contents	
MT-7602	4 in 1 fiber optic power multimeter
FB-C008/FB-C009	1.25/2.5mm One click Cleaner
FB-1688	Fiber cleaver
CP-376TR	4P/6P/8P Telecom Crimping Tool
CP-FB01	FTTH Drop Cable Stripper
8PK-326	Fiber Optical Stripper
1PK-067DS	Dual Color Side Cutting Plier (165mm / 6.5")
9SD-207B	Pro-Soft Screwdriver (+ #2x100mm)
9SD-201A	Pro-Soft Screwdriver (- 6.0x75mm)
DK-2043	Fiber Optic Kevlar Cutter
DK-2060	Auto Stop Measuring Tape
MS-018	Leak proof dispenser pump bottle
FL-528	1W LED Head Light
PD-2612	8 OZ Curved Claw Hammer
SB-1592	Component Storage Box
MS-153A	Bulb Blower (Ø42mm)
8PK-C002	Foam Swabs Cleaning Kit
5MT-7601-LC	Fiber Optical Power Meter LC Adaptor
9PK-153	Brush

### 1 MT-7602 4 in 1 fiber optic power multimeter

- Fiber optic power meter
- Visual fault locator
- Cable tester
- LED flashlight



### 2 FB-C008 / FB-C009 1.25/2.5mm One click cleaner

#### 800 cleans for FC/PC, ST, SC or LC Connectors

- Easy pushing motion
- 180° rotates cleaning system
- Extendable nozzle
- Indication Window



### 3 FB-1688 Fiber cleaver

#### 16 cutting location for each blade.

#### Blade life up to 48000 times



- Body: Zinc alloy anodic treatment
- Blade: Tungsten
- Blade dimension: Φ20×t2.0mm
- Dimensions: 62x60x56mm
- Cladding Diameter: 125 μm
- Cleave length: 10~20 mm
- Cleave angle: ≤ 0.8°

### 4 CP-376TR 4P/6P/8P Telecom Crimping Tool

- Body: S45C
- Handle: Black:T.P.R Green:PP
- Application: 8P8C/RJ45, 6P2C/6P4C/6P6C RJ11/RJ12
- modular plugs, RJ22 4P2C/4P4C handset modular plugs

### 5 CP-FB01 FTTH Drop Cable Stripper



- Body: Zinc alloy steel
- Blade: CR12
- for 3.1x2.0mm drop cable


### 6 8PK-326 Fiber Optical Stripper

- Strips 125 micron glass fiber with 250 micron buffer coating
- Material : S50C



## Diamond Lapping Film

The diamond lapping film consists of precision graded diamond particles resin bonded to a uniform mylar film.

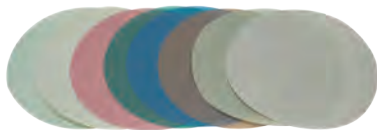

Model No.	Specifications	color	Individual packing
FB-6008-0.5D	Diamond Lapping Film, 0.5μM, Ø5" disk, 100pcs/pack	white	poly bag
FB-6008-1D	Diamond Lapping Film, 1μM, Ø5" disk, 100pcs/pack	gray	poly bag
FB-6008-3D	Diamond Lapping Film, 3μM, Ø5" disk, 100pcs/pack	purple	poly bag
FB-6008-6D	Diamond Lapping Film, 6μM, Ø5" disk, 100pcs/pack	brown	poly bag
FB-6008-9D	Diamond Lapping Film, 9μM, Ø5" disk, 100pcs/pack	blue	poly bag
FB-6008-30D	Diamond Lapping Film, 30μM, Ø5" disk, 100pcs/pack	green	poly bag
FB-6008-15SIC	Silicon Carbide Lapping Film, 15μM, Ø5" PSA polis disc, 100pcs/pack	olive green	poly bag
FB-6008-30SIC	Silicon Carbide Lapping Film, 30μM, Ø5" PSA polis disc, 100pcs/pack	olive green	poly bag

## ST-3216 Multi-Function Business Backpack

• Decompress • Ventilate • Comfortable • Large capacity

- Airflow back design provides extra soft comfort back cushion, good ventilation and maximum back support.
- Perfect ergonomic shoulder strap provides comfort, ventilation and maximum back support.



### Large Capacity

The central multi components, interior pocket organizer provides extensive capacity for laptop, pad, smartphones, pens, CDs, tools and more. The mesh side pockets are perfect for water bottles, coffee mugs or other side pockets items.




Material	Dimensions(mm/inch)	Individual packing
600D polyester	310×160×470/ 12.2x6.3x19.0	Plastic bag+Hanging card

## ST-5208 Tool Pouch

- Various styles for multiple tool usage
- Different size compartments designed for easy tools classify and storage
- Made of lightweight and durable polyester provides extra strength and carrying comfort
- Use your own belt or use our ST-5504 belt



Water repellent

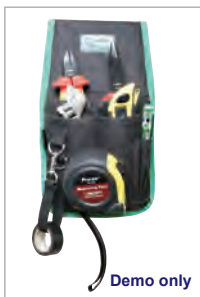

Demo only



Material	Loading capacity	Dimension (mm/inch)	Individual packing
600DX600D Polyester	4kg	169x290x50/6.7x11.4x2.0	Poly bag + Hanger

## ST-5504 Tool Belt with Safety Lock

- High quality, heavy duty 600 denier polyester for durability
- Lightweight design with all stress point strengthen by high density webbing
- Adjustable to meet different users' demands.
- Use with our ST-5208 pouch



Extra lock design, prevent belt loosening



Material	Loading capacity	Dimension (mm/inch)	Individual packing
Polypropylene	15kg	Width: 50mm/2.0" Length: 1600mm/63"	Poly bag + Hanger

## 902-497 Compartment Storage Box

- Adjustable compartments for multiple uses



Material	Dimension(LxWxH)	Individual packing
PP	35.8x23.5x6 (mm) 1.4x0.9x0.2(inch)	Shrink packing

### MS-153C Bulb Blower



Material	Nozzle material	Nozzle size (mm/inch)	Air valve material	Pump capacity	OAL. (mm/inch)	Individual packing
PVC	ABS	Ø 5.0x30mm/ Ø 0.2"x1.2"	copper with chrome plating	110 ml	Ø 56x110mm / Ø 2.2"x5.5"	Blister card

### 902-461 Triple Thread Chaser Set

- Comes with high speed steel blade and PVC handle.
- Quickly forms new threads, re-forms burred threads, and cleans out plaster obstruction.
- Taps three hole sizes and each tap size rethreads to next larger size if threads are stripped
- Applicable to iron, aluminum, zinc alloy, copper, fiber PCB, bakelite, plastic.



Material		Hardness	Torque	Tap sizes
blade	Handle			
High speed steel (H.S.S.)	PVC	HRC 64±2*	≥23kg-cm, ≥70kg-cm	6-32, 8-32, 10-32, 10-24, 12-24, 1/4-20
Handle size		Blade size	OAL. (mm/inch)	Individual packing
Ø20x80mm		Ø4.8x45mm/ Ø6.3x45mm	125 / 5	Blister card

### MS-161 Heavy-Duty Suction Cup

MS-161 comes with ABS handle and TPR suction cap, features comfortable grip and high suction capacity up to 11kgs. Easy to remove the glass-sheathed displays.



- Size: Ø 58mm x 72mm
- Max. Load: 11kgs (24.3lbs)

Material		Suction Capability	Dimension(mm/inch)	Individual packing
Handle	suction cup			
ABS	TPR	11kgs (24.3lbs)	Ø 58mm x 72mm/ Ø 2.3" x 2.8"	Blister card

### MS-3209 3-in-1 F-Type Install/Remove Tool

MS-3209 is a useful 3 way tool for extracting and insertion the F connector convenient in hard to reach area and flaring the braid to make cable insertion onto the connector easier. Ideal for CATV, SATV installation and removing job.



Material		OAL. (mm/inch)	Individual packing
Body	Handle		
Carbon steel with nickel plated	PVC	188 / 7.4	Blister card

### MS-018 Leak Proof Dispenser Pump Bottle

- Portable leak proof construction.
- Bottle scale indication.
- Anti dumping of cone design.
- No chemical reaction Polypropylene material.
- Perfect for fiber cleaning, nail treatment and more.



Material	Capacity	Individual packing
Polypropylene	180ml	Poly bag

### 902-529 Anti-Static Liquid Dispenser Bottle

- High Density Polyethylene (HDPE) durAstatic bottles are ESD Safe
- Long lasting dissipative properties - Rtt: 10E4 to < 1 x 10E11 ohms tested
- Stainless steel bottle cap with a transparent pad



Description	Capacity	Individual packing
High Density Polyethylene (HDPE)	180ml (6oz)	Poly bag

### 902-511 Storage Strap

- Industrial strength & weather resistant
- Holds up to 150 lbs.
- Width and length 3x23 inch.



Demo only (Hose not included)

Material	Individual packing
Nylon	Hanger

## MS-C002 Mini Vacuum & Blowing Cleaner



High speed 25000 rpm and easy-to-use handy vacuum cleaner with attachments for vacuuming / blowing / brushing off dirt and dust.

Speed	Torque	Output	Power	Size(mm/inch)	Individual packing
25,000 rpm	26 g-cm	5.15W/1.83A	DC 6.0V (AA 1.5V×4 pcs)	Ø 45×130×90 / Ø 18.0×5.1×3.5	color box



Vacuum cleaner



Blowing cleaner



Sweeping brush

## PD-160 16" Digital LCD Angle Level

- Easily readable LCD Display shows the exact angle at once.
- Automatically shuts off after 5 minutes.
- Comes with backlight allowing use even in dark area.
- Data hold function helps user record the reading .
- Mechanical locking function.



Material	Measuring angle range	Digital accuracy	Measuring precision	Auto shut off
Aluminum Alloy steel	0 to 225 degrees	0.1 degree	±0.5 degree	5 min
Backlight	Dual spirit (bubble) level indicators	Size of the LCD display	Battery Type	Length (mm/inch)
Yes	Vertical / Horizontal	50x19mm	DC 9V (6F22) (not included)	400/15.6
				Individual packing
				Color box



## PK-5011 CATV/CCTV Basic Tool Kit



This is a complete tool bundle along with F connectors to install or remove existing or additional cable TV, satellite outlets or cable modems. It includes adjustable waterproof compression tool, coaxial cable stripper/cutter and 4pcs F connectors to make your work smart and easy.



### Contents

CP-316 Adjustable Compression Tool (as page 10)
CP-507 Coaxial Cable Stripper/Cutter (as page 13)
CN-710FCA2-BU 4pcs F connectors for RG6 quad coaxial
903-003 Carry case (160×120×45 mm / 6.3×4.7×1.8 inch)
Individual packing Blister card

## PK-2006 LAN Basic Tool Kit



This is a complete tool bundle to make RJ45 or RJ11/RJ12 patch cords for phone and computer. It includes 6P/8P parallel action modular crimper and stripper to make your job well done.



### Contents

CP-333 Modular crimping tool (as page 10)
6PK-501 Wire stripping tool
903-003 Carry case (160×120×45 mm / 6.3×4.7×1.8 inch)
Individual packing Blister card

**PK-9112 Pro Tech Tool Kit**



The P2/P5/P6 pentalobe tips are special for Apple products.

The TS3.5/TS4.5 Torx Plus® sockets are for Nintendo, SONY, SEGA products.

Ideal for opening of tablets, notebooks, electronic device cases and most branded video games such as Apple, HTC, Samsung, Sony, Microsoft, Nintendo, Sega and more.

Contents	
Opening and prying tools	Prying Paddle (30.5x30.5x30.5mm / 1.2x1.2x1.2")
	Opening Lever(POM)(88.7mm / 3.5")
	Opening Lever(POM)(84.4mm / 3.3")
	Suction Cup Ø36mm
	Point-Blade Solder Aid Tools (155mm/6.1")
	Spudger Solder Aid Tools (140mm/5.5")
	Fork-Blade Solder Aid Tools (173mm/6.8")
Tweezers	Double-end Metal Spudger (185mm/7.3")
	Metal spudger tool (123x12mm/4.8x0.5")
	super fine tip straight (120.5 mm/4.7")
	super fine tip curved (120.5 mm/4.7")
Static protection tools	super fine tip straight (120.5 mm/4.7")
	Wrist Strap 10FT, to avoid sensitive electronic components, from electrostatic damage.
	Ruler 6", Precision Knife, SD-9828 58pcs Driver Kit
Tool bag (233x150x55 mm/9.2x6.0x2.2")	

Individual packing: Color Box

**902-516 8 PC Apprentice's Tool Set**



902-516 Includes 6 essential premium hand tools (plus pouch & belt) to make your job easy and efficient

- Pliers & Screwdrivers exceeds ASME/ANSI specifications for maximum performance.
- Three pcs pliers: Precision machined and forged from steel. Hardened cutting edges offer greater durability and strength.
- Two pcs screwdrivers: Precision machined tips for optimal fastener contact, high grade rust resistant chrome plating, black phosphate coated tips to prevent surface shipping.
- One pc AWG 20-10 Wire Stripper: Machined stripping stations with positive stop for precise applications

Contents	
8" Long Nosed Pliers	8" Diagonal Cutting Pliers
9" Heavy Duty Lineman's Pliers	AWG 20-10 Wire Stripper
1/4" x 4" Slotted Screwdriver	#2 x 4" Phillips Screwdriver
Tool Pouch	Tool Belt with Safety Lock

Individual packing: Blister card

**500-038 14 PC Electrician's Tool Pouch Kit**



500-038 includes heavy duty, high quality tools, perfect for the professional or apprentice electrician

Contents	
Long-Nosed Pliers w/side Cutter	
Heavy Duty Lineman's Plier	
9.5" Crimper Plier	
Electrician's Knife	
25' Tape Measure	
Groove Joint Plier	
Screwdrivers x 4	
⊕ 1/4"x4", 1/4"x8"	⊕ #2x4", #2x8"
AWG 16,14,12,10,8 Precision Wire Stripper	
3/16" x 7.8" Cable Ties (100pcs)	
Receptacle Tester- GFCI outlets	
19mm x 5M Electrical Tape	
Durable Black Pouch & Belt	

Individual packing: Blister card



## PK-2811M 15 PC 1000V Insulated Single Open End Wrench Set




Model No.	Material	Width across flats(mm)	Head width Max. (mm)	Head thickness Max.(mm)	OAL. ±2(mm)
HW-V106B	50CrV	6	23	7.2	90
HW-V107B		7	25	7.2	90
HW-V108B		8	27	7.7	100
HW-V109B		9	29	7.7	100
HW-V110B		10	31	8.2	110
HW-V111B		11	34	8.7	110
HW-V112B		12	36	8.7	130
HW-V113B		13	39	10.5	135
HW-V114B		14	40	10.5	145
HW-V115B		15	42	11.5	150
HW-V116B		16	43	11.5	160
HW-V117B		17	47	12.5	160
HW-V119B		19	53	14.0	175
HW-V122B		22	58	14.0	195
HW-V124B		24	62	16.5	225

Individual packing: Color Sleeve



600D tool roll bag:  
305x635 mm / 12x25"

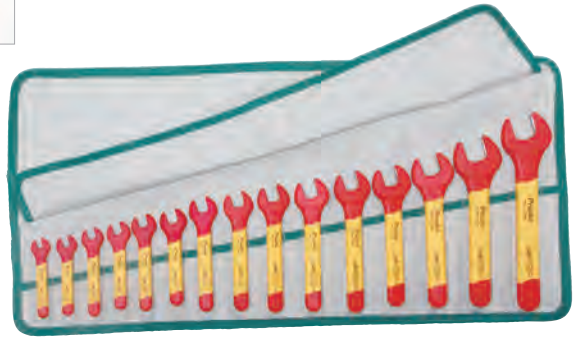

## PK-2812M 15 PC 1000V Insulated Single Box End Wrench Set




Model No.	Material	Width across flats (mm)	Head width Max. (mm)	Head thickness Max. (mm)	Depth of crank (mm)	OAL. ±2 (mm)
HW-V206B	50CrV	6	16.0	6.8	25	150
HW-V207B		7	18.0	7.0	25	150
HW-V208B		8	19.0	7.4	27	155
HW-V209B		9	20.0	8.3	27	155
HW-V210B		10	21.0	8.8	30	170
HW-V211B		11	22.5	8.9	30	170
HW-V212B		12	22.5	9.8	32	190
HW-V213B		13	26.5	10.0	32	190
HW-V214B		14	28.0	11.0	34	205
HW-V215B		15	29.0	11.1	34	205
HW-V216B		16	31.0	11.5	36	215
HW-V217B		17	32.0	12.3	36	215
HW-V218B		18	35.0	12.7	37	230
HW-V219B		19	36.0	13.2	37	230
HW-V221B		21	39.0	13.9	41	245
HW-V222B	22	41.0	13.9	41	245	
HW-V224B	24	44.0	16.0	42	265	
HW-V227B	27	48.0	16.4	42	290	
HW-V230B	30	52.0	16.8	45	310	
HW-V232B	32	55.0	17.5	45	310	

Individual packing: Color Sleeve



600D tool roll bag:  
330x780 mm / 13x30"

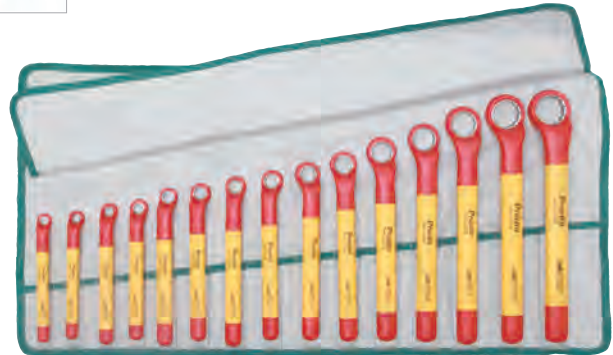

## PK-2813M 15 PC 1000V Insulated Metric Roll Tool Kit



Ideal for power plant, HVAC, automotive, military, aircraft field applications and more.



600D tool roll bag:  
368x743 mm/14.5x29.2"

Contents	
PM-911	Insulated combination plier (195mm/7.7")
PM-917	Insulated side cutter(165mm/6.5")
PM-910	Insulated wire stripping plier (160mm / 6.3")
PM-918	Insulated long nose plier(200mm/7.9")
SR-V206	Insulated cable cutter 150mm (22mm <sup>2</sup> )
HW-V110B	Insulated single open end wrench 10mm
HW-V113B	Insulated single open end wrench 13mm
HW-V114B	Insulated single open end wrench 14mm
HW-V117B	Insulated single open end wrench 17mm
HW-V119B	Insulated single open end wrench 19mm
SD-800-S2.5	Insulated screwdriver(-2.5x75)
SD-800-S4.0	Insulated screwdriver (-4.0x100)
SD-800-S5.5	Insulated screwdriver (-5.5x125)
SD-800-S6.5	Insulated screwdriver (-6.5x150)
PD-V003A	Insulated straight blade cable knife (50x180mm/2.0x7.1")
9Z-PK2813	Tool roll bag(368x743mm/15.1x29.2")

Individual packing: Color Sleeve



## PK-2809M 1000V Insulated Standard Tool Kit



PK-2809M tool kit is equipped with a range of 26pcs 1000V insulated single open end wrenches, screwdrivers, pliers and cutters, T handle and 1/2" sockets in a durable tool box. Ideal for power plant, HVAC, automotive, military, aircraft field applications and more

Contents	
PM-911	Insulated combination plier (195mm/7.7")
PM-917	Insulated side cutter(165mm/6.5")
HW-V110B	Insulated single open end wrench 10mm
HW-V111B	Insulated single open end wrench 11mm
HW-V112B	Insulated single open end wrench 12mm
HW-V113B	Insulated single open end wrench 13mm
HW-V114B	Insulated single open end wrench 14mm
HW-V117B	Insulated single open end wrench 17mm
HW-V119B	Insulated single open end wrench 19mm
SD-800-S2.5	⊖ Insulated screwdriver(-2.5x75)
SD-800-S3.0	⊖ Insulated screwdriver(-3.0x100)
SD-800-S4.0	⊖ Insulated screwdriver(-4.0x100)
SD-800-S5.5	⊖ Insulated screwdriver (-5.5x125)
SD-800-P0	⊕ Insulated screwdriver (#0x60)
SD-800-P1	⊕ Insulated screwdriver (#1x80)
SD-800-P2	⊕ Insulated screwdriver (#2x100)
SK-V752	Insulated 1/2" drive T handle (200mm/7.9")
SK-V410B	Insulated 1/2" drive socket 10mm
SK-V411B	Insulated 1/2" drive socket 11mm
SK-V412B	Insulated 1/2" drive socket 12mm
SK-V413B	Insulated 1/2" drive socket 13mm
SK-V414B	Insulated 1/2" drive socket 14mm
SK-V417B	Insulated 1/2" drive socket 17mm
SK-V419B	Insulated 1/2" drive socket 19mm
PD-V003A	Insulated straight blade cable knife (50x180mm/2.0x7.1")
PD-V003B	Insulated hook blade cable knife (28x155mm/1.1x6.1")
9SB-3935	Plastic tool box (390x350x90mm/15.3x13.8x3.5")

Individual packing: Color Sleeve

## PK-2836M 1000V Insulated Universal Tool Kit



PK-2836M tool kit is equipped with a range of 41pcs 1000V insulated single open end wrenches, single box end wrenches, adjustable wrenches, screwdrivers, knife, pliers and cutters, T handle, 1/2" sockets and type in a durable aluminum frame tool case. Ideal for power plant, HVAC, automotive, military, aircraft field applications and more.

Contents	
PM-911	Insulated combination plier (195mm/7.7")
PM-917	Insulated side cutter(165mm/6.5")
PM-910	Insulated wire stripping plier (160mm / 6.3")
SR-V210	Insulated cable cutter 250mm (80mm <sup>2</sup> )
HW-V110B	Insulated single open end wrench 10mm
HW-V113B	Insulated single open end wrench 13mm
HW-V114B	Insulated single open end wrench 14mm
HW-V117B	Insulated single open end wrench 17mm
HW-V119B	Insulated single open end wrench 19mm
HW-V122B	Insulated single open end wrench 22mm
HW-V210B	Insulated single box end wrench 10mm
HW-V213B	Insulated single box end wrench 13mm
HW-V214B	Insulated single box end wrench 14mm
HW-V217B	Insulated single box end wrench 17mm
HW-V219B	Insulated single box end wrench 19mm
HW-V222B	Insulated single box end wrench 22mm
SD-800-S2.5	⊖ Insulated screwdriver(-2.5x75)
SD-800-S4.0	⊖ Insulated screwdriver (-4.0x100)
SD-800-S5.5	⊖ Insulated screwdriver (-5.5x125)
SD-800-S6.5	⊖ Insulated screwdriver (-6.5x150)
SD-800-P1	⊕ Insulated screwdriver (#1x80)
SD-800-P2	⊕ Insulated screwdriver (#2x100)
SK-V752	Insulated 1/2" drive T handle (200mm/7.9")
HW-V710	Insulated 1/2" drive reverse flat ratchet handle (200mm/7.9")
SK-V851	Insulated 1/2" drive extension bar (125mm/5")
SK-V852	Insulated 1/2" drive extension bar (250mm/9.8")
SK-V410B	Insulated 1/2" drive socket 10mm
SK-V411B	Insulated 1/2" drive socket 11mm
SK-V412B	Insulated 1/2" drive socket 12mm
SK-V413B	Insulated 1/2" drive socket 13mm
SK-V414B	Insulated 1/2" drive socket 14mm
SK-V416B	Insulated 1/2" drive socket 16mm
SK-V417B	Insulated 1/2" drive socket 17mm
SK-V418B	Insulated 1/2" drive socket 18mm
SK-V419B	Insulated 1/2" drive socket 19mm
SK-V422B	Insulated 1/2" drive socket 22mm
SK-V424B	Insulated 1/2" drive socket 24mm
PD-V003A	Insulated straight blade cable knife (50x180mm/2.0x7.1")
SR-V336	Insulated electricians scissors (160mm/6.3")
MS-V001	Insulated tape( 20mmx10M / 0.8"x32.8')
HW-V610	Insulated 10" adjustable wrench
TC-736	Expert & Elegant aluminum frame tool case (486x325x159mm / 19.1x12.8x6.3")
9PK-2836M-TP	Top pallet for PK-2836M
9PK-2836M-P	Pallet for PK-2836M

Individual packing: Plain box+color label

Model .No	Page	Model .No	Page	Model .No	Page	Model .No	Page
500-036	23	902-491-BLADE	12	CP-521	13	MT-7501	25
500-038	30	902-492	21	DP-366J	14	MT-7505	25
5FB-C010-RPM	25	902-493	21	FB-6008-0.5D	26	MT-7601	24
5MT-7601-LC	24	902-494	22	FB-6008-15SIC	26	MT-7602	24
5MT-7601-LC	24	902-495	22	FB-6008-1D	26	NT-8540	6
6PK-301N	9	902-496	22	FB-6008-30D	26	NT-8560	6
800-093	18	902-497	27	FB-6008-30SIC	26	NT-8580	6
800-094	18	902-498	9	FB-6008-3D	26	PD-160	29
800-095	18	902-499	12	FB-6008-6D	26	PK-2006	29
800-096	18	902-500	23	FB-6008-9D	26	PK-2809M	32
800-097	18	902-501	23	FB-C008	25	PK-2811M	31
800-098	18	902-502	23	FB-C009	25	PK-2812M	31
800-099	18	902-503	23	FB-C010	25	PK-2813M	31
800-100	18	902-504	23	GS-23K	14	PK-2836M	32
800-101	18	902-505	23	HW-T21-40200	19	PK-5011	29
800-102	18	902-506	23	HW-T21-60340	19	PK-9112	30
800-103	18	902-507	23	HW-T41-315	19	PK-9458	26
800-104	18	902-508	23	HW-T41-525	19	PM-396K	8
800-105	18	902-509	23	HW-T716-3	19	PM-760	7
800-106	18	902-510	23	HW-T83-20100	19	PM-761	7
800-107	18	902-511	28	MA-023	20	PM-763	7
800-108	18	902-512	14	MA-1004A	20	PM-764	7
800-109	18	902-513	14	MA-1006A	20	PM-765	7
800-110	18	902-514	8	MA-1601A	20	PM-771	7
800-111	18	902-515	8	MS-018	28	PM-773	7
800-112	18	902-516	30	MS-153C	28	PM-774	7
800-113	18	902-519	9	MS-161	28	PM-808	8
800-152	18	902-520	9	MS-3176	17	PT-5202A	22
800-153	18	902-529	28	MS-3209	28	SD-3502	17
800-154	18	CP-148	12	MS-C002	29	SD-9817	16
8PK-CT016	11	CP-151B	11	MT-1508	1	SD-9828	17
902-231	18	CP-316	10	MT-4611	5	SD-T635-0112	16
902-232	18	CP-319	12	MT-4612	5	SD-T635-16	16
902-233	18	CP-333	10	MT-4615	5	SD-T635-510	16
902-234	18	CP-353	11	MT-4616	4	SD-T636	15
902-235	18	CP-386	11	MT-4617	4	SD-T860	15
902-236	18	CP-418	10	MT-4618	4	ST-3216	27
902-237	18	CP-507	13	MT-5211	1	ST-5208	27
902-461	28	CP-509	13	MT-7028	3	ST-5504	27
902-491	12	CP-512	13	MT-7071	2		



**eclipse**<sup>SM</sup>

**Eclipse Enterprises, Inc.**

13302 Chula Road, Amelia Court House, VA 23002

Phone:804-561-2610

Fax:804-561-2642

<http://www.eclipsetools.com>

<http://www.proskit.com>

