



STRIPPERS


Pro'sKit® Strippers

All Pro'sKit® precision strippers pass strict quality control using precision instruments and ensuring accurate stripping with much less effort against injury and long service life.

Pro'sKit® offers a complete range of strippers, including precision wire strippers, automatic wire strippers, coaxial cable strippers, round cable slitting & ringing tools, for most applications, such as electrical wire, hook-up wire, multi-conductor cable, flat telephone cable, twisted pair round cables, coaxial cables, fiber optics cables...etc.

Gripping

Mainly used in holding, pulling and bending wires.

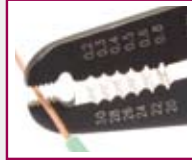

Cutting wires



With cutting edge for soft wires from Ø0.25 to Ø1.2mm(AWG 30 to 16), not for hard or thick objects.

Wire spring




Stripping flat telephone cables

For stripping electronic flat cable, wire width up to 12mm.



Stripping wires

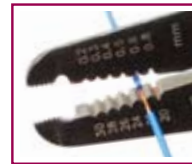

Pro'sKit® precision strippers are processed by CNC lathe to guarantee the accurate size of notches for accurate stripping, without damage.



Pro'sKit® end-action wire stripper comes with V type design and screw adjustment to preset wire size up to 3.9mm.



Pro'sKit® automatic wire stripper requires much less effort to strip wires quickly. The notch size could be custom made upon special request.

The spring design is very important! It allows handles to self-open to make work faster with much less effort.



2 blade stripping coaxial cables

2 blade coaxial cable stripper usually used in stripping braided shields coaxial cables




3 blade stripping coaxial cables

3 blade coaxial cable stripper usually used for stripping foil/braided shields coaxial cables

Pro'sKit® coaxial cable strippers and twisted pair round cable strippers are designed with lever action that requires much less force for operating as effectively as possible. Blades made from special grade steel provide sharp and durable edges. Some of Pro'sKit strippers come with adjustable wire size function to preset wire size to meet applications requirement.

Cutting wires

Coaxial & twisted pair round cable strippers With cutting edge for cutting soft wires from Ø0.25 to Ø1.0mm(AWG 30 to 18), not for hard or thick objects.

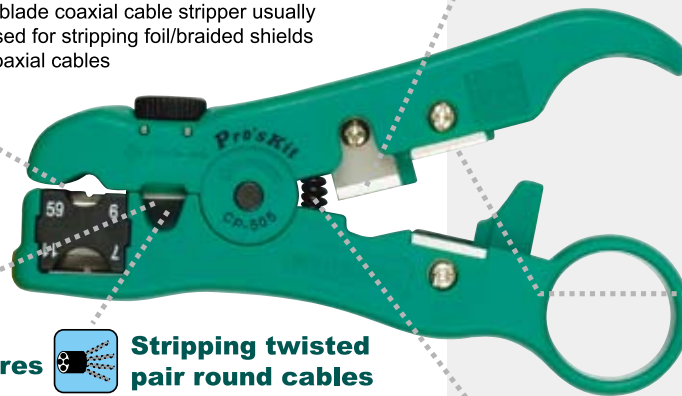

Stripping wires

For stripping electrical wires

Stripping twisted pair round cables


For stripping twisted pair round cables.

Wire spring



Stripping flat telephone cables

For stripping flat telephone cables

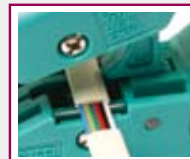

Safety Caution



- Blades are very sharp, please use carefully and keep them out of reach of children.
- Blades are consumables, please replace when worn or damaged.

TESTERS
PRECISION PLIERS & CUTTERS
ELECTRICAL PLIERS & CUTTERS
KNIVES & SCISSORS & SAW
CRIMPERS
STRIPPERS
PUNCHDOWN TOOLS
SOLDERING / ASSEMBLY
SCREWDRIVERS/ BITS
HEX KEY/ WRENCHES
TWEZERS

200-007/ 200-007W Adjustable Cutter with spring/ Stripper without spring



CP-301G Precision Wire Stripper



Heat-treated sharp angle w/fine laser marking



Safety lock design

Material: S50C

Material: PVC



200-085 Wire Stripper-Cutter W/Spring



CP-302G Precision Wire Stripper



Heat-treated sharp angle w/fine laser marking



Safety lock design

Material: S50C

Material: PVC



902-247 Adjustable Stripper



- For removing insulation from electrical wire.
- Rotating dial allows effortless changes between wire sizes.
- Hardened steel cutting jaws for clean wire cuts.
- Spring-opening jaws for repetitive stripping and cutting.
- Jaw lock protects cutting edges when tool is not in use.
- Vinyl cushion handles.



902-090 Precision Wire Stripper



- Plier nose
- Cutter jaws
- Soft handles
- Spring return



Model No.	Material	Hardness	Handle	Application	O.A.L (mm/inch)	Individual packing
200-007	S45C	45°±2°	PVC	Stripping wire From10~30 AWG/4~0.5mm (with spring)	127/5.0	Blister card
200-007W	S45C	45°±2°	PVC	Stripping wire From10~30 AWG/4~0.5mm (without spring)	127/5.0	Blister card
200-085	S45C	45°±3°	PVC	For cutting and stripping AWG.24-10	132/5.2	Blister card
902-247	S45C	45°±3°	PVC	For stripping AWG.26-12	140/5.5	Blister card
CP-301G	S50C	45°±3°	PVC	30,28,26,24,22,20 AWG / 0.2,0.3,0.4,0.5,0.6,0.8 mm	165/8.1	Blister card
CP-302G	S50C	45°±3°	PVC	20,18,16,14,12,10 AWG / 0.8,1.0,1.3,1.6,2.0,2.6 mm	165/8.5	Blister card
902-090	SK7	50°±3°	PP	For cutting and stripping AWG 16, 14, 12, 10, 8	156/6.1	Blister card

▶ 200-047 Fiber Optic Stripper



▶ CP-367A Self-Adjusting Insulation Stripper



Cutting under Ø2.0mm(0.08")



Stripping AWG 24~10 (0.2~6.0mm²)



Model No.	Material	Application	O.A.L (mm/inch)	Individual packing
200-047	Blade:S50C	Strips 125 micron glass fiber with 250 micron buffer coating without scratching or nicking glass fiber.	148/5.8	Blister card
CP-367A	Blade: SK5 Body: Nylon	Stripping: AWG 24~10/0.2~6.0mm ² ,Cutter: under Ø 2.0mm(0.08")	115/4.5	Blister card

▶ 200-091 Wire Stripping Tool



 
Ideal for flat cable stripping



Cutting



▶ 200-003 Wire Stripping Tool



▶ 200-072 Automatic Wire Stripper & Crimper



Stripping



Crimping



Stripping



Cutting



The EASY STRIPPER cutters are made by precision machines for long life use. 15N 88°~90° (HRC55°~60°) blade cuts wire fast and smoothly. Plastic insulated handles keep your work safe.

▶ 200-070 Automatic Wire Stripper & Crimper



Micro adjuster knob & wire stopper



Crimping



Stripping



Cutting



- Micro adjusting the swivel knob to strip electrical wire gauge smaller than AWG24 (0.2mm²)
- Adjustable stopper is swiveled if user does not use this function.

Model No.	Material			Blade HRC	Application	O.A.L (mm/inch)	Individual packing
	Body	Blade	Handle				
200-091	ABS & low carbon steel	65Mn	-	45°~55°	Stripping flexible cable from 0.2~4mm ² (AWG 24-12)	172/6.8	Blister card
200-003	Zinc alloy	S45C	PVC	45°~55°	Stranded/Solid wire: AWG 22, 18-20, 14-16, 12, 10, 8 Stripper range: AWG 24-10 (0.2~6.0mm ²) For insulated terminals AWG 22-10 (0.5-6.0mm ²) For non-insulated terminals AWG 22-10 (0.5-6.0mm ²) For auto ignition terminals 7-8mm	170/6.7	Blister card
200-072	SS 41	Alloy steel	PVC	52°~57°	Stripper range: AWG 10-24 (0.2~6.0mm ²) For insulated terminals AWG 22-10(0.5-6.0mm ²) For non-insulated terminals AWG 22-10(0.5-6.0mm ²) For auto ignition terminals 7-8mm	210/8.3	Blister card
200-070	SS 41	Alloy steel	ABS+TPR	52°~57°	Stripping range: AWG 10-24 (0.2~6.0mm ²) For insulated terminals AWG 22-10(0.5-6.0mm ²) For non-insulated terminals AWG 22-10(0.5-6.0mm ²) For auto ignition terminals 7-8mm	210/8.3	Blister card

TESTERS
PRECISION PLIERS & CUTTERS
ELECTRICAL PLIERS & CUTTERS
KNIVES & SCISSORS & SAW
CRIMPERS
STRIPPERS
PUNCHDOWN TOOLS
SOLDERING / ASSEMBLY
SCREWDRIVERS/ BITS
HEX KEY/ WRENCHES
TWEEZERS

▶ CP-511A Universal Stripping Tool



Stripping low volt cable Ø8~13mm



Stripping regular cable AWG 20~10(0.5~6mm²) and RG59, RG6 Coaxial Cable



▶ 200-009/200-048 Rotary Cable Slitter



Cable slitting and stripping




Replacement blade: 200-036


▶ 200-016 Wire Stripper Tool



Replacement blade: 900-117(6 pcs/pack)

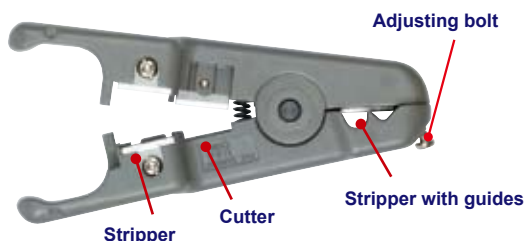

▶ 200-090 Coax Stripper

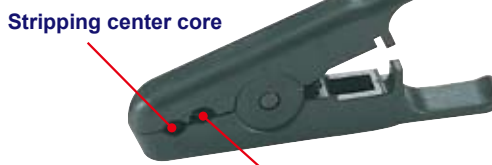

- Strips cables in 2 easy steps.

Model No.	Material		Application	Replacement blade	O.A.L. (mm/inch)	Individual packing
	Blade	Body				
CP-511A	SK5	ABS+TPR	Regular cable AWG 20/18/16/14/12/10(0.5/1.0/2.5/4.0/6.0 mm ² , RG59/RG6 coaxial cable, Ø8~13mm low-volt cable	-	125/4.9	Blister card
200-009	Blade: SWP spring steel Blade holder: Metal	Nylon+Fiber	Range 0.18"~1.0" diameter	200-036	140/5.5	Blister card
200-048	Blade: SWP spring steel Blade holder: Metal	Nylon+Fiber	Range 1.0"~1.4" diameter	200-036	140/5.5	Blister card
200-016	-	ABS	Wire(UTP/STP) or wire & multiconductor cable from Ø3.2-9mm(0.13"~0.35") max.	900-117(6 pcs/pack)	112/4.4	Blister card
200-090	-	ABS	RG-58,59,62,6	-	100/4	Blister card

▶ 200-084 Coax Stripper



- Clothespin design
- Strip configuration for RG6, 58 and 59
- Adjustable blades

Model No.	Material		O.A.L. (mm/inch)	Individual packing
	Blade	Body		
200-084	SK5	ABS	120/4.7	Blister card
902-323	SK5	ABS	120/4.7	Blister card

▶ 902-323 Coax Cable Stripper




Optional replacement cassettes: 902-324, 902-325, 902-326



- For stripping RG-58, RG-59, RG6 coaxial cable


Model No.	Cassette color	Application
902-324	Red	3 Step strips for dual crimp N series connectors Strips braid 0.236 in. (6mm) and Dielectric 0.236 in. (6 mm);
902-325	Green	2 Step strips for twinax and UHF connectors Strips braid 0.480 in. (12mm);
902-326	Blue	2 Step strips for F-type and single crimp BNC/TNC connectors Strips braid 0.250 in. (6.35mm);

▶ **200-064 Multi-Function Wire Stripper**

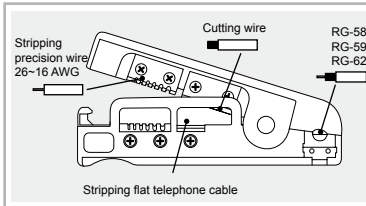


- Compact and lightweight design for easy operation.
- Provide multifunction for cutting and stripping RG-58/59/62 coaxial cable, flat telephone cable, 26-16 AWG precision wire.
- Blades are made for precision stripping and are quality built with carbon steel and finished with black oxide to prevent corrosion.

▶ **200-005/200-081 Rotary Coaxial Cable Stripper**

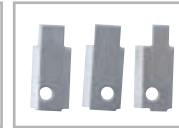


Replacement blade: 900-027

 ▶ **200-050 Rotary Coaxial Stripper**



• 2-Blade Model

 ▶ **200-051 Rotary Coaxial Stripper**



• 3-Blade model RG-59/62/6

▶ **902-334 Rotary Coaxial Stripper**



- Compact and lightweight design for stripping RG-174 coaxial cable easily.
- Made of ABS handle with SK5 blade.
- Rotary stripping, one-squeeze cutting action.
- Includes a small hex wrench in handle for blade depth adjustment.



▶ **200-004 Rotary Coaxial Cable Stripper**



Used for removing the outer sheath from PVC and Plenum types of coaxial cable. 2 Blade design.

Model No.	Material	Application	Replacement blade	O.A.L (mm/inch)	Individual packing
200-064	ABS	Stripping: RG-58/59/62 coaxial cable, 26-16 AWG(0.13~1.3mm ²) precision wire, flat telephone cable, cutting: 3.5~9mm(12-8 AWG)	-	125/4.9	Blister card
200-005	ABS	RG-58/59/62/3C/4C	900-027(6 pcs/pack)	107/4.2	Blister card
200-081	ABS	For big cable O.D. around 10.5mm such as RG213	900-027(6 pcs/pack)	105/4.1	Blister card
200-050	ABS	RG-59/62/6	900-027(6 pcs/pack)	105/4.1	Blister card
200-051	ABS	3-Blade model RG-59/62/6	900-027(6 pcs/pack)	105/4.1	Blister card
902-334	ABS	Stripping RG-174 coaxial cable	902-334-BLADES	98.5/3.9	Blister card
200-004	ABS	RG-58/59/62/6/3C2V/4C/5C	900-026(6 pcs/pack)	98.5/3.9	Blister card


 
TESTERS
PRECISION PLIERS & CUTTERS
ELECTRICAL PLIERS & CUTTERS
KNIVES & SCISSORS & SAW
CRIMPERS
STRIPPERS
PUNCHDOWN TOOLS
SOLDERING / ASSEMBLY
SCREWDRIVERS/ BITS
HEX KEY/ WRENCHES
TWEEZERS

200-065 Rotary Coaxial Cable Stripper



New design for stripping ethernet, thinnet RG-62/58/59/6 coax cable and other cable size. Each tool does 2 or 3 step strips without any adjustment.


902-229 Universal Stripping Tool

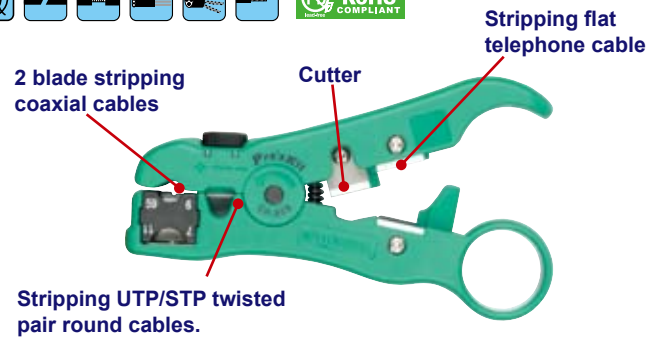

200-042 Economy UTP Stripper



 - A simple tool for UTP/STP cable.
- Rotate stripper just three times to extract the jacket of cable.
- Also a function for 110 punch down tool.



200-042-100 Economy UTP Stripper (100pcs/jug)



MS-3207 Advanced 3 in 1 Connector Tool



One end of this tool is for flaring the braid and the other for screwing on a twist-on F-Connector to the cable.

- Length: 4.3x2.4x0.4" (110x60x9.5mm)
- Material: 12L14
- Finish: Nickel Plating
- Users can use one end to enlarge space between shield and insulation for RG59, another end for RG6 and the other end locks F connector into tool socket and twists it onto a stripped cable end.



Model No.	Material	Application	Replacement	O.A.L.(mm/inch)	Individual packing
200-065	ABS	Thinnet RG-62/58/59/6 coax cable and other cable size	-	108/4.3	Blister card
902-229	ABS	Stripping UTP/STP twisted pair round cable, flat telephone cable, RG-59/11/7/6 coaxial cable	Blade: 902-269 Cassette: 902-268	125/4.9	Blister card
200-042	Poly-Resin	Stripping UTP/STP cable & 110 punch down	-	94/3.7	Blister card
200-042-100	Poly-Resin	Stripping UTP/STP cable & 110 punch down	-	94/3.7	Color Label
MS-3207	PP	RG59, RG6, F connectors	-	100/3.9	Blister card