



PUNCH DOWN TOOLS



www.eclipsetools.com

Punchdown Tool

- Spring loaded impact
- Hi-Lo settings
- Spare blade storage in handle
- Blades/Handle inter-changeable with Harris Dracon and Fluke 814 tool and other industry standard tools




Description	Part No.
Handle Only(no blades)	700-007
Handle w/110 & 66 Blades	700-010
Handle w/110 Blade	700-011
Handle w/66 Blade	700-012
Type 66 Blade	700-008
Type 110 Blade	700-009
Type KRONE Blade	700-015
Type BIX Blade	700-017

Impact Punchdown Tool



4 or 5-Pair 110 Punchdown Tool

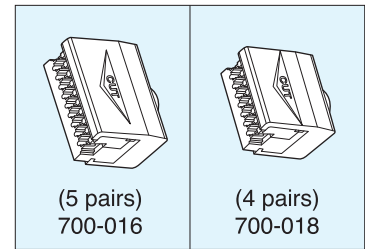

- A built-in combination hook / spudger for tracing and removing wires.
- Twist-lock style holder provides quick, easy blade changes and prevents pullout.
- An additional safe storage for one more spare blade

- Punches and cuts 10 wires at one time

Description	Part No.
Impact Punchdown Tool (Handle only, no blades)	700-020
Handle w/110 & 66 Blades	700-021
Handle w/110 Blade	700-022
Handle w/66 Blade	700-023

Description	Part No.
5-pair 110 Punchdown Tool	700-014
4-pair 110 Punchdown Tool	700-029
Replacement 5-pair head	700-016
Optional 4-pair head	700-018

Mini Punchdown Tool



Display Jug for
Distributor's
Counter



- Lid flips to allow storage for protective.
- Holds 25 pcs for retail display.

Description	Part No.
Mini Punchdown Tool (66 Blade Type)	700-025
Mini Punchdown Tool (66 Blade Type in display jug shown at right)	700-025-25
Mini Punchdown Tool (110 Blade Type)	700-024
Mini Punchdown Tool (110 Blade Type in display jug shown at right)	700-024-025

Punchdown Tool-Locking Collar

- 2 Stage impact (Hi-Low)
- Unique locking mechanism. Pull back collar, insert blade, release collar to lock blade in place.
- Material: Blade: SAE 4140



Item #: 700-027

Item #: 700-026



Item #: 700-028

Description	Application	Part No.
Type 110 Replacement Blade		700-026
Punch Down Tool With 110 Blade	Hi-Low adjust pressure (33lbs~11lbs±4lbs)	700-027
Type 66 Replacement Blade		700-028

Punchdown Tool



Impact
Item #: 700-001

- Impact handle, spring loaded
- Adjustable impact force
- High: 33 lbs. +/- 4 lbs
- Low: 22 lbs. +/- 4 lbs
- Spare blade storage compartment (only for #700-001)



Non-Impact
Item #: 700-013

Description	Part No.
Impact Punchdown Tool (no Blade) Orange	700-001
Non-Impact Punchdown Tool (no Blade) Gray	700-013
110 Type Replacement Blade for 700-001 & 700-013	700-002
66 Type Replacement Blade for 700-001 & 700-013	700-003
66 & 110 Type Replacement Blade for 700-001 & 700-013	700-004
630A Type Replacement Blade for 700-001 & 700-013	700-005
KRONE Type Replacement Blade for 700-001 & 700-013	700-006



SCREWDRIERS/BITS



www.eclipsetools.com

Screwdriver-Rubber Grip

- These Cushion-Grip screwdrivers offer excellent comfort and durability. Our grips are designed to allow repetitive use with little or no fatigue.
- The Cushion-Grip is fitted onto a hard plastic core for strength. The rubberized outer grip feels good in the hand, yet still transfers torque effectively.
- The screwdriver blade portion that is inside the hard plastic core has protruding tabs formed on it to maintain a secure fit to the handle and superior torque performance.

Flat Blade




Description	Part No.
Screwdriver - Rubber Grip (13/64" x 3")	800-097
Screwdriver - Rubber Grip (13/64" x 4")	800-099
Screwdriver - Rubber Grip (13/64" x 6")	800-095
Screwdriver - Rubber Grip (1/4" x 1-1/2")	800-101
Screwdriver - Rubber Grip (1/4" x 4")	800-093

Phillips



Description	Part No.
Screwdriver - Rubber Grip (#1 x 3")	800-098
Screwdriver - Rubber Grip (#1 x 4")	800-100
Screwdriver - Rubber Grip (#2 x 1-1/2")	800-102
Screwdriver - Rubber Grip (#2 x 4")	800-094
Screwdriver - Rubber Grip (#2 x 6")	800-103
Screwdriver - Rubber Grip (#2 x 8")	800-096
Screwdriver - Rubber Grip (#2 x 10")	800-104

Screwdriver-Rubber Grip-Offset Speed Driver

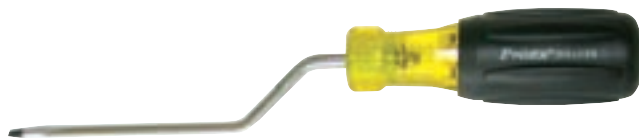

Description	Part No.
Offset Screwdriver (Phillips: #1) W/Cushion Grip	800-089
Offset Screwdriver (Slotted: 13/64") W/Cushion Grip	800-090

Eclipse Tools

Robertson (Square) Tip



Description	Part No.
Screwdriver - Rubber Grip (S0 x 4")	800-105
Screwdriver - Rubber Grip (S1 x 4")	800-106
Screwdriver - Rubber Grip (S2 x 4")	800-107
Screwdriver - Rubber Grip (S3 x 4")	800-108

Screwdriver-Rubber Grip Star Tip




Description	Part No.
Star Screwdriver - Rubber Grip (T15) Star Tip	800-109
Star Screwdriver - Rubber Grip (T20) Star Tip	800-110
Star Screwdriver - Rubber Grip (T25) Star Tip	800-111
Star Screwdriver - Rubber Grip (T27) Star Tip	800-112
Star Screwdriver - Rubber Grip (T30) Star Tip	800-113

Hollow Shaft Nutdrivers



Precision-machined socket

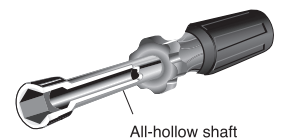


All-hollow shaft

Now available separately

Description	Part No.
7 Pc Set with Roll-up Pouch	800-088
Hollow-Shaft Nutdriver (3/16")	902-231
Hollow-Shaft Nutdriver (1/4")	902-232
Hollow-Shaft Nutdriver (5/16")	902-233
Hollow-Shaft Nutdriver (11/32")	902-234
Hollow-Shaft Nutdriver (3/8")	902-235
Hollow-Shaft Nutdriver (7/16")	902-236
Hollow-Shaft Nutdriver (1/2")	902-237

Screwdriver

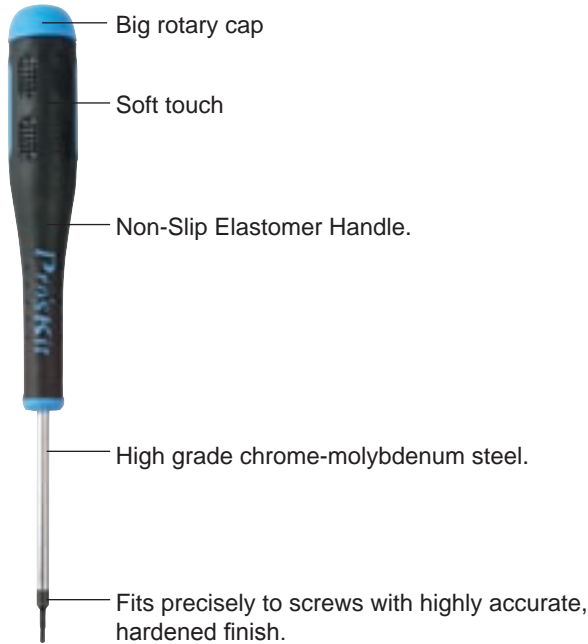

Screwdriver



Description	Tip	Working length	Part No.
Screwdriver	T10H	2"	800-140
Screwdriver	T3	2"	800-141
Screwdriver	T4	2"	800-142
Screwdriver	T5H	2"	800-143
Screwdriver	T6H	2"	800-144
Screwdriver	T7H	2"	800-145
Screwdriver	T8H	2"	800-146
Screwdriver	T9H	2"	800-147

Screwdriver set



- 2.0 x .8"
- 2.4 x .8"
- 3.0 x .8"
- #00 x .8"
- #0 x .8"
- #1 x .8"

Description	Part No.
Screwdriver set	800-149

Screwdriver set



- T5H x .8"
- T6H x .8"
- T7H x .8"
- T10H x .8"
- T15H x .8"
- T20H x .8"

Description	Part No.
Screwdriver set	800-150



Screwdriver



Description	Tip	Working length	Part No.
Screwdriver	# 000	2"	800-131
Screwdriver	# 00	2"	800-132
Screwdriver	# 0	3"	800-133
Screwdriver	# 1	6"	800-134




Screwdriver



Description	Tip	Working length	Part No.
Screwdriver	1.0	2"	800-135
Screwdriver	1.6	2"	800-136
Screwdriver	2.0	2"	800-137
Screwdriver	2.4	3"	800-138
Screwdriver	3.0	4"	800-139

Eclipse Tools

Ceramic Driver

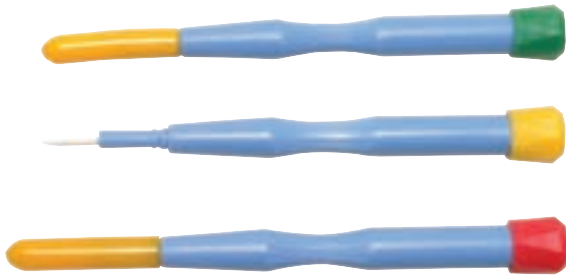


Description	Part No.
⊖ 0.015" x 0.035" (0.4x0.9mm)	800-114
⊖ 0.015" x 0.047" (0.4x1.2mm)	800-115
⊖ 0.015" x 0.055" (0.4x1.4mm)	800-116
⊖ 0.015" x 0.070" (0.4x1.8mm)	800-117
⊖ 0.015" x 0.078" (0.4x2.0mm)	800-118
⊖ 0.015" x 0.094" (0.4x2.4mm)	800-119
⊖ 0.027" x 0.094" (0.7x2.4mm)	800-120
⊕ PH0	800-121
⊕ PH1.7	800-122

ESD Precision Screwdriver



Strong chrome-molybdenum vanadium steel blade

ESD-Safe for maximum protection of static electricity sensitive components.

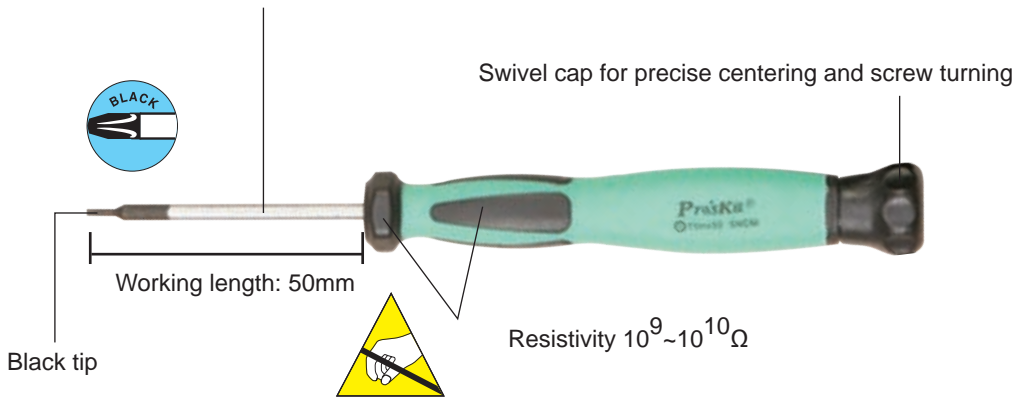

Model No.	Spec.
SD-083-P2	⊕ #00
SD-083-P3	⊕ #0
SD-083-P4	⊕ #1
SD-083-S3	⊖ 2.0
SD-083-S4	⊖ 2.4
SD-083-S5	⊖ 3.0
SD-083-T4	⊕ T4
SD-083-5H	⊕ T5H
SD-083-T6H	⊕ T6H

Soft-Handled Screwdrivers

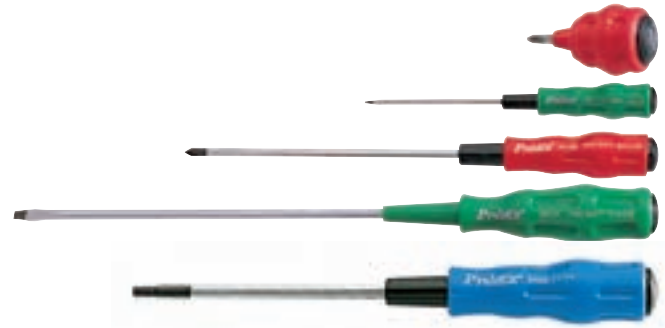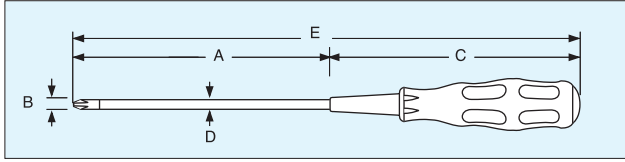

- Rubber grip
- Ergonomic design
- Chrome vanadium blades
- Hardened, tempered, Black-oxide tip

Display Stand (Distributors only)



- For distributors
- Each size holds 50 screwdrivers
- Great for displaying our product

Description	Part No.
Small Stand	900-031
Large Stand	900-014

11 Pc Star Screwdriver Set



- T6 thru T40
- Same handle as our popular screwdriver line
- Convenient plastic carrying case

Description	Part No.
11 PC Star Screwdriver Set	800-030

Description (Inch)						Part No.
A	Tip	B	C	D	E	
3	⊖	1/8	3.3	1/8	6.3	800-001
3	⊕	#0	3.3	1/8	6.3	800-002
4	⊖	1/8	3.3	1/8	7.3	800-010
4	⊕	#0	3.3	1/8	7.3	800-011
6	⊖	1/8	3.3	1/8	9.3	800-012
6	⊕	#0	3.3	1/8	9.3	800-013
3	⊖	3/16	4.3	3/16	7.3	800-003
3	⊕	#1	4.3	3/16	7.3	800-004
4	⊖	3/16	4.3	3/16	8.3	800-014
4	⊕	#1	4.3	3/16	8.3	800-015
6	⊖	3/16	4.3	3/16	10.3	800-016
6	⊕	#1	4.3	3/16	10.3	800-017
8	⊖	3/16	4.3	3/16	12.3	800-018
8	⊕	#1	4.3	3/16	12.3	800-019
10	⊖	3/16	4.3	3/16	14.3	800-020
10	⊕	#1	4.3	3/16	14.3	800-021
4	⊖	1/4	4.3	1/4	8.3	800-005
4	⊕	#2	4.3	1/4	8.3	800-006
6	⊖	1/4	4.3	1/4	10.3	800-022
6	⊕	#2	4.3	1/4	10.3	800-023
8	⊖	1/4	4.3	1/4	12.3	800-024
8	⊕	#2	4.3	1/4	12.3	800-025
10	⊖	1/4	4.3	1/4	14.3	800-026
10	⊕	#2	4.3	1/4	14.3	800-027
Stubby	⊖	1/4	0.7	1/4	3	800-028
Stubby	⊕	#2	0.7	1/4	3	800-029
2	⊕	T05	3.3	5/32	5.3	800-032
2	⊕	T06	3.3	5/32	5.3	800-033
2	⊕	T07	3.3	5/32	5.3	800-034
3	⊕	T08	3.3	5/32	6.3	800-035
3	⊕	T09	3.3	5/32	6.3	800-036
3	⊕	T10	3.3	5/32	6.3	800-037
3	⊕	T15	3.3	5/32	6.3	800-038
2	⊕	T07	3.3	5/32	5.3	800-043
3	⊕	T08	3.3	5/32	6.3	800-044
3	⊕	T09	3.3	5/32	6.3	800-045
3	⊕	T10	3.3	5/32	6.3	800-046
3	⊕	T15	3.3	5/32	6.3	800-047
2	⊕	TR1	3.3	1	5.3	800-123

Eclipse Tools

2-in-1 Ceramic Drivers



Description			Part No.
Material	Type(inch)	OAL(inch)	
Bit: Zirconia Body: ABS ABS (fireproof)	A 0.4 X 0.035	5.39	902-191
	B 0.4 X 0.07		
	A 0.4 X 0.047		902-192
	B 0.4 X 0.078		
	A 0.4 X 0.047		902-194
	B 0.4 X 0.094		
	A 0.4 X 0.047		902-195
	B PH1.7		
	A 0.4 X 0.035		902-196
	B PHO		

5 Pc Reversible Ceramic Driver Set

- Contains: 5 pen style drivers with 2 reversible tips in each
- Straight and phillips tips of various sizes


Description	Part No.
5 Pc Reversible Ceramic Driver Set	800-062



Pro-soft Screwdriver Set



- 3.2x2-15/16"
- #0x2-15/16"
- 5x2-15/16"
- #1x2-15/16"
- 6x3-15/16"
- #2x3-15/16"

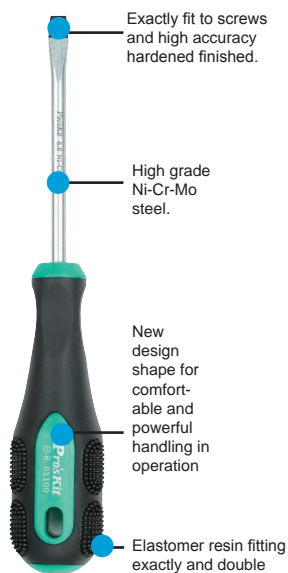


Description	Part No.
Pro-soft Screwdriver Set Eclipse Tools	902-096

Pro-soft Screwdriver Set



- T5Hx1-15/16"
- T9Hx1-15/16"
- T6Hx1-15/16"
- T10Hx1-15/16"
- T7Hx1-15/16"
- T15Hx2-15/16"
- T8Hx1-15/16"

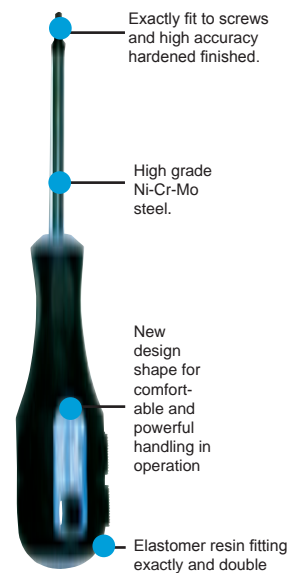

Description	Part No.
Pro-soft Screwdriver Set	902-097


6 Pc Precision Screwdriver Set



- #0 X 3", #1 X 4", #1 X 6" Phillips
- .10x3", .12 x 4", .15x6" Flat Blade

Description	Part No.
6 Pc Precision Screwdriver Set	800-007


6 Pc Electronic Screwdriver Set

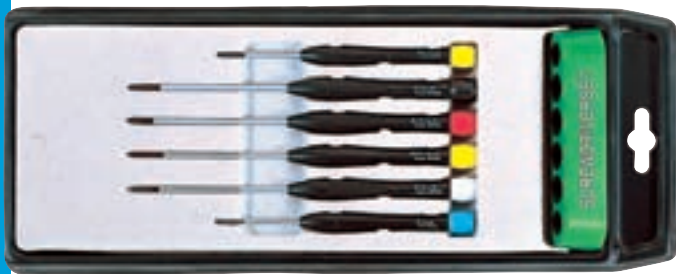

- Includes standup rack
- #0-3 x 1.6", #0-2 x 3", #0 x 3" phillips
- .08 x 1.6", .10 x 3", .12 x 3" straight blade

Description	Part No.
6 Pc Electronic Screwdriver Set	800-009

6 Pc Precision Screwdriver Set with Cutter

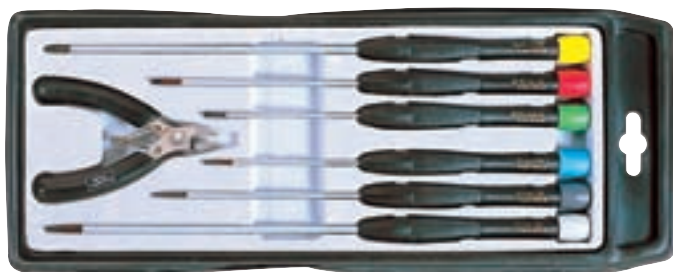

- Micro cutter, spring loaded
- 6 pc Swivel cap Screwdrivers
- .10x3", .12x4", .16x6" Flat
- #00x3", #0x4", #1x6" Phillips

Description	Part No.
6 Pc Precision Screwdriver Set with Cutter	800-077

7 Pc Precision Screwdriver

- 2" blade length
- Cupped Swivel cap
- 4 Flat blade- 1.6, 2.0, 2.4, 3.0mm
- 3 Phillips-#00, #0, #1



Description	Part No.
7 Pc Precision Screwdriver	800-075

15 Pc Precision Screwdriver Set

- Color coded handles for different types
- 4 pc Yellow Hex - 1.5, 2.0, 2.5 & 3.0 mm
- 4 pc Green Slotted - 1.0, 2.0, 3.0 & 3.5 mm
- 4 pc Blue Star Tip - T6, T8, T10 & T15
- 3 Pc Red Phillips - #000, #00 and #0
- Molded Case with fitted pockets for storage



Description	Part No.
15 Pc Precision Screwdriver Set	800-073


20 Pc Precision Electronic Screwdriver Set

- One handle with interchangeable bits
- #00 and #0 Phillips, 2.0, 2.5, 3.0, 4.0 mm straight blades
- T-6, 7, 8, 9 & 10 star bit, 1.5, 2.0, 2.5 mm hex
- Pozidrive #0 and #00



Description	Part No.
20 Pc Precision Electronic Screwdriver Set	800-060

Folding Security Star Tip

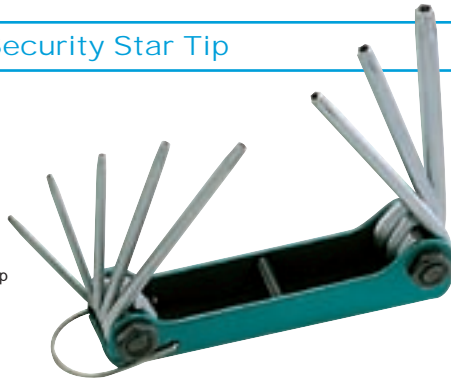

- T9 - T40 security Star Tip
- Chrome plated keys
- Green lacquered case


Description	Part No.
Folding Security Star Tip	800-052

7 Pc Folding Hex Set



Description	Part No.
7 Pc Folding Hex Set (1/16", 5/64", 3/32", 1/8", 5/32", 3/16" & 1/4")	800-066
7 Pc Folding Hex-Metric (1.5, 2, 2.5, 3, 4, 5, 6mm)	800-124

9 Pc Ball Point Hex Wrench Set

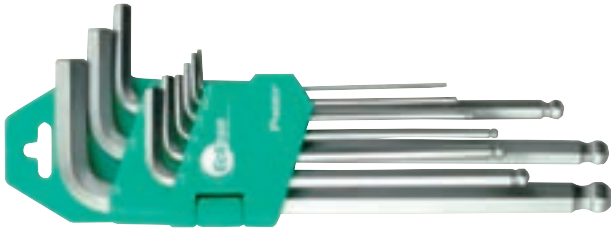

- 1/16", 5/64", 3/32", 1/8", 5/32", 3/16", 1/4", 5/16" & 3/8"
- Mirror polished
- Long arm type
- Ball point allows for slightly indirect operation

Description	Part No.
9 Pc Ball Point Hex Wrench Set	800-065
9 Pc Long Arm Hex - Metric	800-125

30 Pc Hex Key Set



- Inch side .028 to 3/8"
- Metric side 0.9 to 10mm
- 15-Pc inch size
- 15-Pc metric size
- Handy plastic

Description	Part No.
30 Pc Hex Key Set	900-038

Folding Key Set




- Material: SAE6150 Chrome vanadium steel
- Case: T.P.R. Anti-slip
- Key: Satin finish

Description	Part No.
8 PC Folding Security Star Key Set(T9H, T10H, T15H, T20H, T25H,T27H, T30H, T40H)	902-100
9 PC Folding Hex Key Set(3/16",7/32",1/4",5/32",9/64",1/8,7/64,3/32,5/64)	902-226

16 Pc Hex Key Wrench Set

 Pocket size designed for various uses.



Part No.	Tip size	S	L
902-101(inch)	1/16"	14	46
	5/64"	17	48
	3/32"	17	52
	1/8"	20	58
	5/32"	22	65
	3/16"	25	72
	7/32"	28	77
	1/4"	29	86

Allen key reference table

Hex wrench (mm)	0.71	0.89	1.27	1.5	1.6	2	2.4	2.5	3	3.2	4	5	6	8	10	12
Hexagonal head bolts			M1.4	M1.6/M2	M2	M2.5	M3	M3	M4	M4	M5	M6	M8	M10	M12	M14
Hexagonal head set screws	M1.6/M1.7	M2	M2.5	M3		M4	M5	M6		M8	M10	M12	M16	M20	M22	

Description	Part No.
16 PC Hex Key Wrench Set	902-101


Double-ended Screwdriver



- Pocket clip
- Straight blade on long end
- Phillips on short end

Description	Part No.
Double-ended Screwdriver	800-040

Pocket Clip Screwdriver

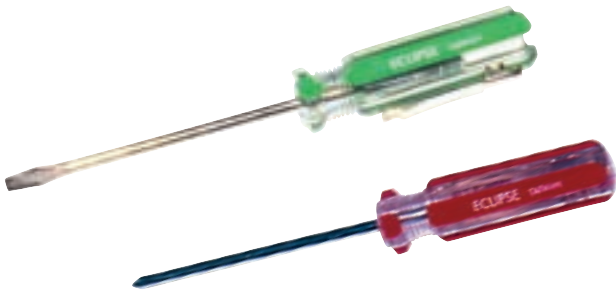

Description	Part No.
1/8" Straight blade	800-041
#0 Phillips blade	800-042


4-in-1 Screwdriver

- Two Double-Ended, Reversible Tips



Description	Part No.
4-in-1 Screwdriver-Pen Style	800-092
4-in-1 Screwdriver-Pen Style (50 pc Display Box)	800-092-50

6-In-1 Magnetic Quick Change Screwdriver

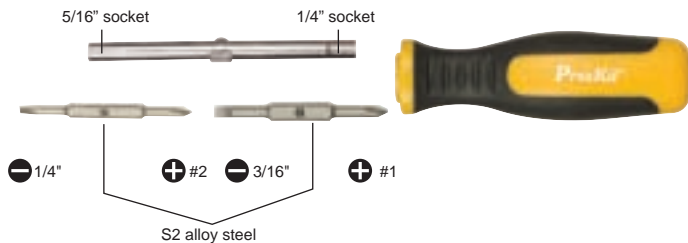

- Industrial quality with maximum versatility. Shock proof acetate handle and S2 alloy steel bit.
- OAL: 7"

Description	Part No.
6-In-1 Magnetic Quick Change Screwdriver	800-080

Magnetizer/Demagnetizer



- High-impact casing
- Magnetize/demagnetize screwdrivers/tweezers and other small tools

Description	Part No.
Magnetizer/Demagnetizer	800-070

Can Wrench



- Popular Telecom tool
- 3/8" and 7/16" hex ends
- Insulated body

Description	Part No.
Can Wrench	900-055


CATV Install/Extract Tool



- Installs and removes F-Type connectors in hard to reach places
- Handle contains male F-Type holder

Description	Part No.
CATV Install/Extract Tool 12" (shown)	800-072
CATV Install/Extract Tool 6"	800-079


BNC Connector Insertion / Removal Tool

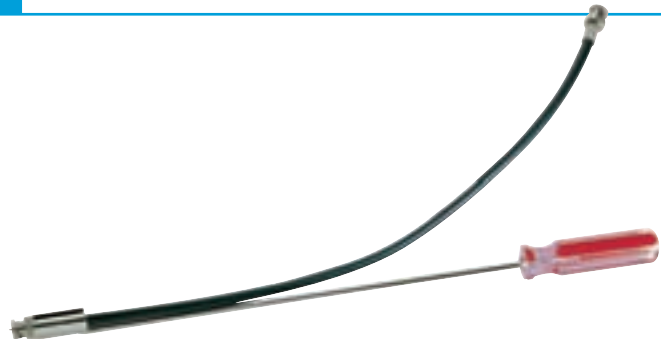

- Provides easy access to difficult to reach, high density connectors

Description	Part No.
12 inch (shown)	800-050
8 inch	800-049

Double-end Reversible Screwdriver

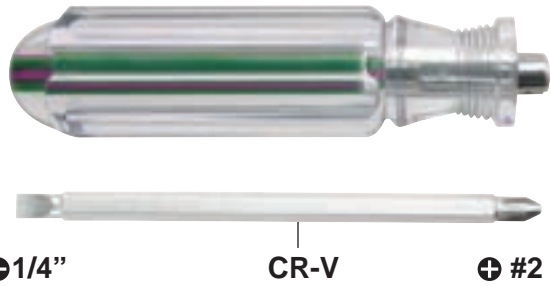

Description	Part No.
Double-end Reversible Screwdriver	800-148

1/2" T-handle Hex Hey



Description	Part No.
1/2" T-handle Hex Hey	HW-928

10 Pc T-Handle Hex Key Set

- 3/32", 7/64", 1/8", 9/64", 5/32", 3/16", 7/32", 1/4", 5/16", 3/8"



Description	Part No.
10 PC T-Handle Hex Key Set	800-067

7 Pc T-Handle Hex Hey Set

- Long reach design with T-handle for greater torque and ease of use
- Hardened S2 steel alloy
- Set comes in a durable blow-molded case
- 3/32", 1/8", 5/32", 3/16", 1/4", 5/16" and 3/8"



Description	Part No.
7 PC T-Handle Hex Hey Set	800-091

Screwholding Screwdriver Set



- Contents:
 - ⊖ 0.2 x 6.1, 0.2x 5.1, 0.1 x 5.1
 - ⊕ #1 0.2 x 5.1 , #2 0.2x7.1

Description	Part No.
Screwholding Screwdriver - Set	800-151

3 Pc Anti-Static Alignment Set



- For protection of sensitive components
- Duplex, trimmer and square/hex tool
- Conductive nylon-avoid high voltage

Description	Part No.
3 PC Anti-Static Alignment Set	800-130

Eclipse Tools

Bit Set



Item #: 800-128

Item #: 800-127

Description	Part No.
18 Pc Bit Set (Clips to belt)	800-127
20 Pc Bit Set (Clips to belt)	800-128

20-in-1 Telescoping, Magnetic Screwdriver



- Self contained Bits and Sockets
- Magnetic telescoping tip to hold bits and screws
- 13 piece bits
- 5 piece sockets

Description	Part No.
20-in-1 Telescoping, Magnetic Screwdriver	800-039

Star Wrench Driver Set

T-8 to T-30 have tamper proof holes for preventing tampering for cordless telephones and wireless equipment.



Design with tips at both ends for horizontal and vertical use.



Description	Part No.
Star Wrench Driver Set	902-069

Flexible, Ratcheted Screwdriver Set



- 7.5" flexible shaft
- Good for getting into hard to reach areas
- 10 pc Bit set

Description	Part No.
Flexible, Ratcheted Screwdriver Set	800-076

Twin Wrench/Driver Set



- Tips at both ends for vertical or horizontal use
- T10, T15, T20 Star Tip bits
- 3 Flat blade screwdriver bits
- 4 Phillips screwdriver bits

Description	Part No.
Twin Wrench/Driver Set	800-068

17 Pc Offset Ratchet & Socket Driver Set



- Offset ratchet handle, reversible
- 6 pc socket set, 1/4" hex drive
- 10 pc 1/4" hex screwdriver bits

Description	Part No.
17 PC Offset Ratchet & Socket Driver Set	800-078

33 Pc Security Bit Pack



- Security bit assortment
- 8 piece security hex
- 12 piece security Torx
- 4 piece security spanner
- 4 piece tri-wing
- 4 piece phillips
- 1/4" magnetic bit holder
- Honeycomb plastic case

Description	Part No.
33 PC Security Bit Pack (S2 grade steel) Superior grade	800-048
33 PC Security Bit Pack (SAE 6150 CR-V steel) Economy grade	800-048E

22 Pc 1/4" Drive Socket Set



- 1/4" Ratchet
- 9 pc Inch 3/16" to 1/2"
- 9 pc metric 4mm to 12mm
- 3" and 6" extensions
- Nutdriver handle

Description	Part No.
22 Pc 1/4" Drive Socket Set	900-194

Ratcheted Screwdriver Handle



- Ratcheting
- Swiveling
- Reversible
- Heavy-duty rubber grip
- Your bits can be stored in handle holder

Description	Part No.
Ratcheted Screwdriver Handle	800-074

All-In-One Tool Set




- Contains: 9 SAE sockets, 9 metric sockets, 21 screwdriver bits, 5 drill bits, needle-nosed pliers, 6" adjustable wrench, reversible ratchet screwdriver handle, flexible extension, magnetic bit holder, socket adaptor

Description	Part No.
All-In-One Tool Set	800-061

58-piece Precision Electronic Screwdriver Set

Features:

- Material: Chrome-Molybdenum Vanadium Steel Bits 56 pcs, Length: 1.1 inch
- Ergonomic, double molded structure. Non-slip.
- Light weight designed (10 ounces)

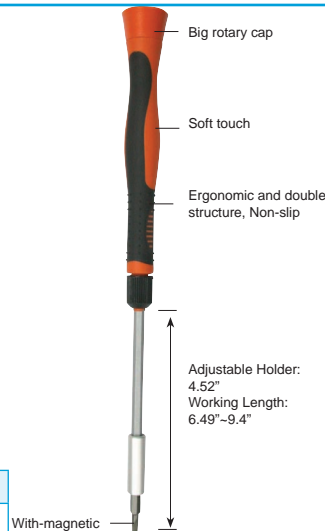

Contents	
+	#000, #00, #0, #1
⊖	1.0mm, 1.5mm, 2.0mm, 2.5mm, 3.0mm, 3.5mm, 4.0mm
⊕	T5H, T6H, T7H, T8H, T9H, T10H, T15H, T20H
⊗	T3, T4, T5, T6, T7, T8, T9, T10, T15,
⊙	0.7mm, 0.9mm, 1.3mm, 1.5mm, 2mm, 2.5mm, 3mm, 4mm
⊚	0.028", 0.035", 0.05", 1/16", 5/64", 3/32"
⊛	1.5mm, 2mm, 2.5mm, 3mm, 1/16", 5/65", 3/32"
⊜	2mm, 2.3mm, 2.5mm
⊝	#0, #1
⊞	TR1
⊟	2mm

Description	Part No.
58-piece Precision Electronic Screwdriver Set	902-219

Eclipse Tools


Ratcheted Screwdriver Set of 10 bits(double ended)

- ⊖ 4 ⊖ 3
- ⊖ 5 ⊖ 7
- ⊕ PH.0 ⊕ PH.3
- ⊕ PZ.0 ⊕ PZ.3
- ⊕ PZ.1 ⊕ PZ.2
- ⊕ PH.2 ⊕ PH.1
- ⊕ T-10 ⊕ T-15
- ⊕ T-20 ⊕ T-25
- ⊖ 2 ⊖ 3
- ⊖ 4 ⊖ 5



Description	Part No.
Ratcheted Screwdriver Set of 10 bits (double ended)	800-051

14 Pc Ratchet Precision Screwdriver Set

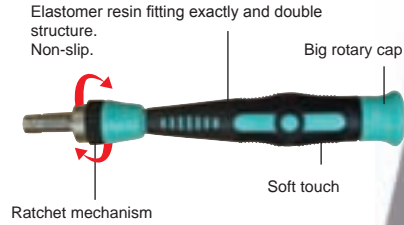

- Bits Contents:
- ⊕ #00, #0, #1 ⊖ 1.0, 1.5, 2.5
 - ⊖ 4.0, 5.0 ⊕ T5,T6,T7,T8
- Extension blade: 4.7" ratchet handle



Description	Part No.
14 PC Ratchet Precision Screwdriver Set	SD-9312

11 Pc Cellular Phone Maintenance Tool Kit

Supplied with T-Grip holder, slotted tip 0.5mm X 2.0mm, T5, T6, T8, Phillips #1, pressing blade, panel pry bar, spanner 5mm, and antenna repair tool. It's ideal for the repair and maintenance of cellular phones.



Description	Part No.
11 PC Cellular Phone Maintenance Tool Kit	902-222


33 Pc Screwdriver Set w/Bits

- Bits Contents:
- ⊕ PH000x1.1 ⊕ T8x1.1
 - ⊕ PH00x1.1 ⊕ T9x1.1
 - ⊕ PH0x1.1 ⊕ T10x1.1
 - ⊕ PH1x1.1 ⊕ T15x1.1
 - ⊖ SL1.0x1.1 ⊕ T20x1.1
 - ⊖ SL1.5x1.1 ⊕ H0.7x1.1
 - ⊖ SL2.0x1.1 ⊕ H0.9x1.1
 - ⊖ SL2.5x1.1 ⊕ H1.3x1.1
 - ⊖ SL3.0x1.1 ⊕ H1.5x1.1
 - ⊖ SL3.5x1.1 ⊕ H2.0x1.1
 - ⊖ SL4.0x1.1 ⊕ H2.5x1.1
 - ⊕ T4x28 ⊕ H3.0x1.1
 - ⊕ T5x28 ⊕ H4.0x1.1
 - ⊕ T6x28 ⊕ PZ1x1.1
 - ⊕ T7x28 ⊕ PZ0x1.1
- Socket:
- ⊖ M5
 - ⊖ M6
- Shaft:
- ⊖ M4



Description	Part No.
33 PC Screwdriver Set w/Bits	800-129

Pro-soft Spanner Security Screwdriver Set

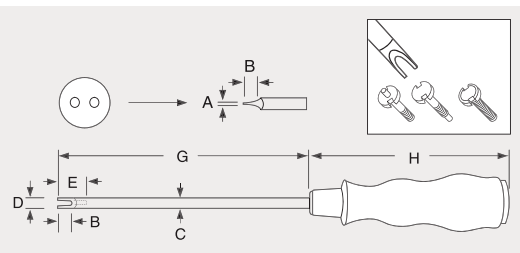

Unit: inch

Description	Pro-soft Spanner Security Screwdriver Set						
Part No.	A	B	C	D	E	G	H
902-098	.02	.02	.16	.08	.39	3.15	3.35
	.04	.02	.20	.08	.39	3.15	4.33
	.04	.02	.20	.09	.39	3.15	4.33
	.05	.02	.21	.10	.39	3.15	4.33
Contents	M1.7, M2.0, M2.3, M2.6						



6 Pc Insulated Precision Screwdriver Set

- Provides Shock Protection to 1000V AC
- Meet VDE Standards for safety to 1000V AC
- Both sets come complete with a plastic storage case
- Material (Blade): Cr-Mo
- OAL: 6-4/16 inches



- ⊖ 0.4x2.0x2-9/16" ⊖ 0.4x2.5x2-9/16"
- ⊖ 0.23x1.5x2-9/16" ⊕ PH0x2-9/16"
- ⊕ PH00x2-9/16" ⊕ PH1x2-9/16"



Description	Part No.
6 PC Insulated Precision Screwdriver Set	902-099

30-Piece Do-It-All Kit

This comprehensive kit will work with almost every type of fastener.



New

Contents	
■	SQ1, SQ2
—	PH0, PH1, PH2, PH3
✱	PZ0, PZ1, PZ2, PZ3
+	SL3.5, 4.5, 5.5, 6, 8
●	HX2, 2.5, 3, 4, 5, 6, 8
⊙	T5, T6, T7, T8, T10, T15, T20, T35

Description	Part No.
30-Piece Do-It-All Kit	SD-2313

5-in-1 Screwdriver with LED Flashlight

#0 + 1/8" #00 + 1/16"



New



50 pcs display pack

Description	Part No.
5-in-1 Screwdriver with LED Flashlight (50 Pcs display pack)	SD-804
5-in-1 LED Screwdriver Single pc Eclipse Tools	SD-804-1

12 Pc Pro-Soft Screwdriver Set



New

Contents	
—	2.0x50
—	3.0x75
—	5.0x75
—	6.0x40
—	6.0x100
—	6.0x200
+	#00x50
+	#0x75
+	#1x75
+	#2x40
+	#2x100
+	#2x200

Exactly fit to screws and high accuracy hardened finished.

High grade Ni-Cr-Mo steel.

New design shape for comfortable and powerful handling in operation

Elastomer resin fitting exactly and double structure. Non-slip.

Comes in a plastic molded tray!

Description	Part No.
12 Pc Pro-Soft Screwdriver Set	SD-2312

10 Pc Pro-Soft Screwdriver Set

Mobile telephone, communication equipment, radio and precision equipment.



New

Exactly fit to screws and high accuracy hardened finished.

High grade chrome-molybdenum steel.

Working length: 50mm

Elastomer resin fitting exactly and double structure. Non-slip.

Soft touch

Rotary cap




Spec.	
#000	+
#00	+
1.0	—
1.6	—
2.0	—
T3	⊙
T4	⊙
T5H	⊙
T6H	⊙
T7H	⊙

Description	Part No.
10 Pc Pro-Soft Screwdriver Set	SD-9810


62 Pc Security Bit Set

- Contents:
- M5, M6, M8
- C1, C2, C3
- 1/8", 3/16"
- 2mm x 2mm x 2mm
- S0, S1, S2, S3
- 1, 2, 3, 4, 5
- 0, 1, 2
- Wing nut driver
- 6, 8, 10
- PZ0, PZ1, PZ2
- 4, 6, 8, 10, 12
- T-5, T-6, T-7, T-8, T-10, T-15, T-20, T-25, T-27, T-30, T-40
- 2mm, 2.5mm, 3mm, 4mm, 5mm, 6mm, 8mm, 5/64", 3/32", 7/64", 1/8", 9/64", 5/32"
- 1 Pc 1/4" x 60mm magnetic bits holder
- 1 Pc bits holder socket
- 1 Pc socket adapter
- 1 Pc ratchet screwdriver

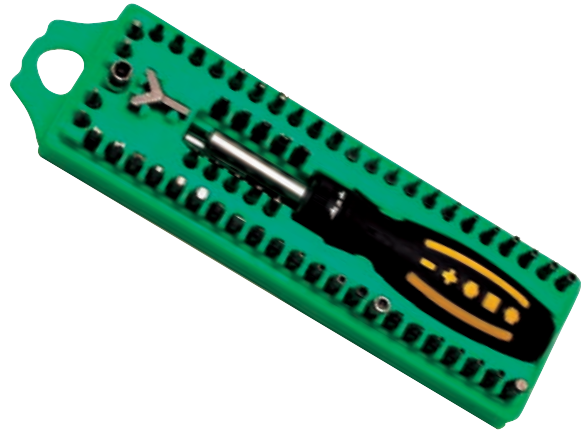

Description	Part No.
62 Pc Security Bit Set	800-081

21 Pc 1/4" & 3/8" Dual Function Ratchet Handle Sockets Set

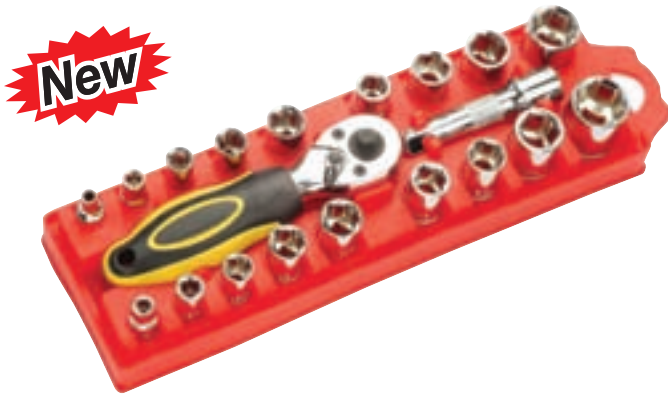

- Handy, all-in-one 21-piece ratchet set!
- Chrome vanadium steel bits.
- Includes a custom storage case.
- Light weight design, 1063g per set.
- 18 bits with one stubby ratchet handle, and two extension bars.

Description	Part No.
21 Pc 1/4" & 3/8" Dual Function Ratchet Handle Sockets Set	SD-2306M

Contents
1 pc 1/4" DR & 3/8" DR stubby ratchet handle
1 pc extension bar 1/4" DR x2"
1 pc extension bar 3/8" DR x3"
8 pc 3/8" DR socket: 10mm, 11mm, 12mm, 13mm, 14mm, 15mm, 17mm, 19mm
10 pc 1/4" DR socket: 4mm, 5mm, 6mm, 7mm, 8mm, 9mm, 10mm, 11mm, 12mm, 13mm

35 Pc 1/4" Drive Socket & Screwdriver



- Featuring ratchet lock function, and two unique handles for more flexible work.
- Handy, all-in-one 35-piece ratchet set!
- Chrome vanadium steel bits.
- Includes a custom storage case.
- Light weight design, 679g per set.

Description	Part No.
35 Pc 1/4" DR Socket & Screwdriver	SD-2307M

Contents
11 pc 1/4" DR sockets: 4mm, 5mm, 5.5mm, 6mm, 7mm, 8mm, 9mm, 10mm, 11mm, 12mm, 13mm
20 pc bits: PH0, PH1, PH2, PH3 T10, T15, T20, T25, T30, T40 3mm, 5mm, 7mm PZ2 2.5mm, 3mm, 4mm, 5mm, 6mm, 8mm
1 pc ratchet handle 1/4" DR
1 pc bit holder
1 pc handle driver
1 pc 1/4" x 2" ext bar

35 Pc 1/4" Drive Socket & Screwdriver W/Long Nosed Plier Set

- Featuring ratchet lock function, universal joint, and adjustable T-bar.
- Chrome vanadium steel bits.
- Light weight design, 908g per set.
- Handy, all-in-one 35-piece variety of tools!
- Includes a patented reversible storage case.

New



Double-sided design reversible storage case.


Contents	
11 pc 1/4" DR sockets: 4mm, 5mm, 5.5mm, 6mm, 7mm, 8mm, 9mm, 10mm, 11mm, 12mm, 13mm	
12 pc bits: ⊕ PH1, PH2, PH3 ⊗ T10, T15, T20, T25, T30 ⊖ 3mm, 4mm, 5mm, 6mm	
4 pc 50mm bit ⊕ PH2, PH3 ⊖ 6mm, 7mm	
2 pc ext bar 1/4"x3" ,1/4"x6"	1 pc long nose plier (135mm)
1 pc ratchet handle	1 pc 1/4" DR adjustable T-bar
1 pc bit holder	1 pc handle driver
1 pc 1/4" x 1/4" universal joint	

Description	Part No.
35 Pc 1/4" DR Socket & Screwdriver W/Long Nose Plier Set	SD-2308M

40 Pc Reversible Ratchet Screwdriver W/Bits & Sockets Set

- Handy, all-in-one 40-piece ratchet set!
- Featuring dual-color rotatable ratchet handle.
- Chrome vanadium steel bits.
- Includes a custom storage case.
- Light weight design, 733g per set.

New

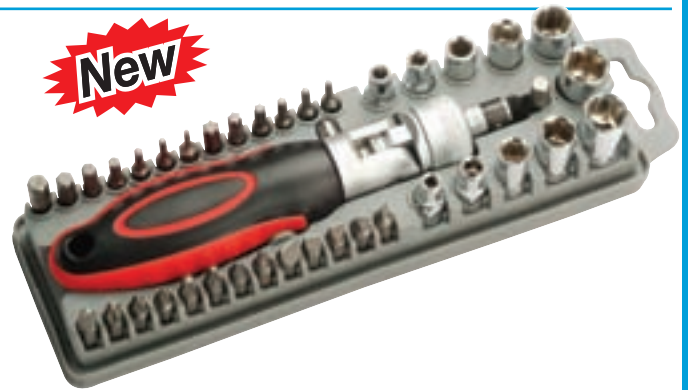


Contents	
11 pc 1/4" DR sockets: 4mm, 5mm, 5.5mm, 6mm, 7mm, 8mm, 9mm, 10mm, 11mm, 12mm, 13mm	
26 pc bits: ⊕ PH0, PH1, PH2, PH3 ⊗ T10, T15, T20, T25, T30, T40 ⊖ 3mm, 4mm, 5mm, 6mm, 8mm ⊕ PZ0, PZ1, PZ2, PZ3 ● 2mm, 2.5mm, 3mm, 4mm, 5mm, 6mm, 7mm	
1 pc adapter	
1 pc magnetic bit holder 100mm	
1 pc 3-position reversible ratchet screwdriver	

Description	Part No.
40 Pc Reversible Ratchet Screwdriver W/Bits & Sockets Set	SD-2309

100 Pc Assorted Power Bits Set

- Handy, all-in-one 100-piece ratchet set!
- Includes a custom storage case.
- Chrome vanadium steel bits.
- Light weight design, 669g per set.

New

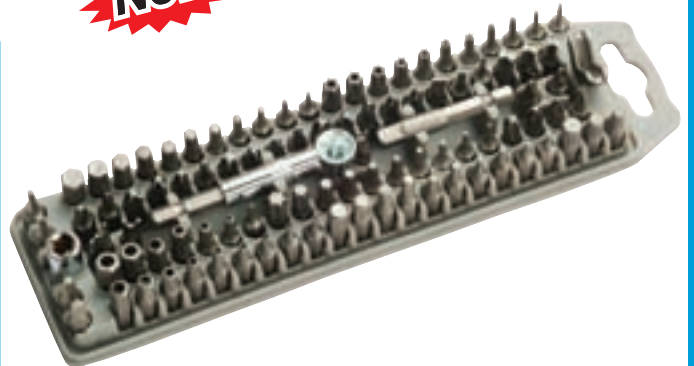

Contents	
96 pc bits: ⊕ PH1, PH2 ⊕ S2: PH0, PH1, PH2, PH3 ⊖ C1, C2, C3 ⊕ S0, S1, S2, S3 ⊖ 1, 2, 3, 4, 5 ⊕ 6, 8, 10 ⊕ PZ0, PZ1, PZ2, PZ3 ⊕ 2mm x 2mm x 2mm ● M5, M6, M8 ⊖ 2mm, 3mm, 5mm ⊕ 4, 6, 8, 10, 12 ⊕ Wing nut driver ● 1.5mm, 2mm, 2.5mm, 3mm, 4mm, 4.5mm, 5mm, 5.5mm, 6mm, 7mm, 8mm, 1/16", 5/64", 3/32", 7/64", 1/8", 9/64", 5/32", 3/16", 7/32", 1/4" ● 2mm, 3mm, 4mm, 5mm, 6mm, 7mm, 8mm, 5/64", 3/32", 7/64", 1/8", 9/64", 5/32", 3/16", 7/32", 1/4" ● T5H, T6H, T8H, T10H, T15H, T20H, T25H, T27H, T30H, T35H, T40H ● T5, T6, T8, T10, T15, T20, T25, T27, T30, T40	
1 pc sockets adapter	1 pc dry wall stopper
1 pc Eclipse Tools	1 pc magnetic bit holder

Description	Part No.
100 Pc Assorted Power Bits Set	SD-2310



SOLDERING/ASSEMBLY



www.eclipsetools.com

Mini-Soldering Station



- Precision temperature control: ~330°C (~626°F)
- Super slim, pen-like style for greater control and visibility
- Specially designed for repairs to cell phones and PC boards
- Conductive soldering stand
- Dual voltage AC 110/220V

Description	Part No.
Mini-Soldering Station, 4-14 Watt Variable	900-259
Replacement Tip	900-245

50W Soldering Station



- Temperature range = 470°F-900°F
- 3 Pin power plug
- Quick start allows rapid heating
- Anti- bacteria silicone handle
- Ceramic heater

Description	Part No.
50W Soldering Station	900-066N
Replacement Tip (Pencil Type)	900-073N
Replacement Tip (Chisel Type)	900-074N

20W-40W Soldering Station

- 20W-40W switchable solder station
- UL approved
- Comes with pencil tip



Description	Part No.
20W-40W Soldering Station	900-035
Replacement Tip (Chisel Type)	900-036
Replacement Tip (Pencil Type)	900-146

Lead-Free Soldering Station

- Three power consumption options (50W/65W/90W)
- Rapid heat-up and temperature stability
- Touch preheating and sensor in tip
- temperature stability
- Separate tip and heater design to reduce replacement cost
- Heavy duty soldering station
- Auto shut-off function
- ESD safe



• Replacement Heater:	
	902-056
• Replacement Tip:	
	902-057
	902-058
	902-059
	902-060
	902-061

unit:inch



Part No.	902-055
Input Voltage/Frequency	AC100-120V, 50/60Hz
Output Voltage/Frequency	AC24V 2-3.5A 60Hz
Temperature Range	200-500
Temperature Stability (no Load)	±2°C (±36°F)
Power Consumption (optional)	50/65/90W
Temperature Rise Time	43/38/30sec (50/65/90W) 25-350°C
Temperature Drop	25 °C (77°F)
Heating Mode	CPU
Auto Power Off	Yes (Not in use for 30 minutes) Yes (abnormal operation for 80 seconds)
Temperature Display	LED
ESD Housing	ABS & PC
Outer Dimensions	165X125X85mm
Weight	1.5Kg
Standard Plug	E
Power Consumption	90W AC24V
Heater and Tips	Separate
Touch Sensor for Preheating	Yes (3-5°C in 3 sec.)
Heating Theory	Resistor
Tip to Ground Resistance	Under 2Ω
Tip to Ground Potential	Under 2mV
Total Length (W/O cord)	189mm
Cord (with Soldering Iron)	1.5M
Weight (W/O cord)	42g
Weight	420g
Replacement Heater	902-056

 
Soldering Station

• Replacement Heater:



902-173


• Replacement Tip:



902-127
Sales unit: 5pcs/Bag



 
902-130
Sales unit: 5pcs/Bag



902-128
Sales unit: 5pcs/Bag



 902-131
Sales unit: 5pcs/Bag



902-129(Standard)
Sales unit: 5pcs/Bag

unit:inch



LED display

Economic Type



902-091

Digital display

Economic Type



902-092

Description	Voltage (v)	Consumption	Temperature	Replacement Heater	Station Size	Weight (g)	Part No.
Soldering Station	110~120	48 (W)	150~420°C	902-173	170(L)	2000	902-091
			160~480°C		116(W)		96(H)

Temperature Controlled Soldering Station


Description	Voltage (v)	Consumption	Temperature	Replacement Heater	Station Size	Weight (g)	Part No.
Temperature Controlled Soldering Station	110~120	50 (W)	250~480°C	902-174	175(L) 103(W) 90(H)	1100	902-093

• Replacement Heater:




902-174

 
• Replacement Tip:




900-073N

 


902-134

 


902-132
(Standard)

 

902-135

 

902-133

 

900-074N

unit:inch



Cordless Soldering Iron



- Heats and cools very rapidly.
- 3 "AA" Batteries not included.

Description	Part No.
Cordless Soldering Iron	902-047N
Replacement Tip	902-047TN

Eclipse Tools

15W Soldering Iron



Description	Part No.
15 Watt	900-044
Replacement Tip (Pencil Type)	900-050

30W Soldering Iron



- 3-Way iron
- Cap screws on tip to allow hot storage
- Pencil/Pistol styles with cap placement

Description	Part No.
30 Watt	900-018N
Replacement Tip (Pencil Type)	900-020N

Butane Torch



- Dose not contain Butane
- Can be refilled by standard butane can
- Uses a standard type lighter refill

Description	Part No.
Butane Torch	900-227

Soldering Gun



Allows soldering in seconds without long wait for tip to heat. Use low heat when working near sensitive parts and to lengthen tip life. High heat is instantly available when needed. Trigger switch turns gun on and off. 140/100Watt 120V AC

Description	Part No.
Soldering Gun	900-207
Replacement Tips	900-241

Flux Bottle



- i.d=0.6mm o.d=0.9mm

Description	Part No.
Flux Bottle (2 pack)	900-230

Digital Ultrasonic Cleaner

- Tightened lid design for effective noise reduction
- Improved products durability and safety by water resistance capability enhancement
- Cleans discs such as CDs, VCDs, DVDs, etc.
- Use only plain tap water to clean
- Remove dirt effectively; results can be seen with bare eyes!
- Clean articles to shine just like new



Item Number	902-187	Power Supply	AC 110-120V 50/60Hz
Dimensions	8.3x6.2x4.9 inch	Power	35W (110V)
Tank Size	750ml	Timer Setting	5 CYCLES: 180s, 280s, 380s, 480s, 90s
Standard Plug	Eclipse Tools	Weight	2.2 lbs

Liquid Dispenser Bottles



Item #: 900-253 Item #: 900-252 Item #: 900-251

- Polyethylene bottles are not chemically reactive
- Purity pump to prevent backwash of contaminants into container

Description	Part No.
Bottle - 4oz/114ml	900-251
Bottle - 6oz/170ml	900-252
Bottle - 8oz/227ml	900-253

Blow Brush



• Ideal for blowing out hard-to-reach areas.


Description	Part No.
Blow Brush	900-254

Solder Aid Tools



Description	Part No.
Solder Aid Tools	900-250

6 PC Soldering Aid Set

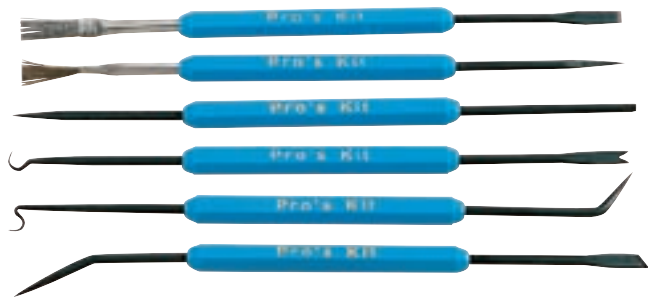

• 6 Double-ended picks and brushes

Description	Part No.
6 PC Soldering Aid Set	900-100

Eclipse Tools

Desoldering Tools



Item #: 900-001N
Desoldering Pump
 • Larger design
 • High suction force
 • Exposed plunger



Item #: 900-006N



Item #: 900-003
Mini Desolder Pump
 • Smaller design
 • Protective shield around plunger



Item #: 900-007



Item #: 900-004
ESD Mini-desolder Pump
 • Smaller design
 • Metallic, ESD protective
 • Conductive tip



Item #: 900-008



Item #: 900-161
Mini Desolder Pump
 • Compact version of our popular 900-001N
 • Replacement tips available




Item #: 900-175

Description	Part No.
Desoldering Pump	900-001N
Mini Desolder Pump	900-003
Mini Desolder Pump	900-004
Mini Desolder Pump	900-161
Replacement Tip for 900-001	900-006N
Replacement Tip for 900-003	900-007
Replacement Tip for 900-004	900-008
Replacement Tip for 900-161	900-175

Vacuum Pick-up Tool

Function:

 - The hand-held SMD vacuum pick up tool is ideal for picking up and moving large or small electronic components.
- Lightweight, portable and suitable for picking and placing small components with weight to up 50 grams and having a flat surface, dilly packages and surface mount components, etc. And its new high-power probes have longer holding action.



Description	Part No.
Vacuum Pick-up Tool	902-115

Vacuum Pick-Up Tool



- Ideal for picking and placing surface mount devices (SMD's)

Description	Part No.
Vacuum Pick-Up Tool	900-238

Mini Soldering Stand (2PCS/PACK)



- 2 position iron holder stand
- Built-in sponge tray

Description	Part No.
Mini Soldering Stand (2PCS/PACK)	902-095

Helping Hands Octopus Clamp Kit



Description	Part No.
Helping Hands Octopus Clamp Kit	902-227

Eclipse Tools

5"/6" Straight and Curved Forceps



- Hemostat locking design
- Serrated jaws
- Insulated handles

Description	Part No.
5" Straight Forceps (insulated)	900-058
5" Curved Forceps (insulated)	900-059
6" Straight Forceps (insulated)	900-181
6" Curved Forceps (insulated)	900-222

Ionized Air Blowers (AC 110V/60HZ)

Features:

- Compact, lightweight, and quiet; ideal for field use.
- Adjustable airflow output for greater worker comfort.
- True laminar flow reducing ion recombination and emitter contamination.
- Easy cleaning and replaceable blower.

Voltage	AC 110V 60 HZ
Current	≤0.25Amp(AC110V)
Air Volume output	Fan speed Flow 20~110CFM
Air Flow characteristics	16"x24" Area Coverage
Operating Temperature	32°F(0°C)~122°F(50°C)
Enclosure	Stainless steel
Finish	Powder Coat
Size	10"x7"x4"
Ion Balance (offset voltage)	0V+/-10V
Weight (lbs)	1.56
Individual Packing	Color Box



Description	Part No.
Ionized Air Blowers (AC 110V/60HZ)	902-107

Solder Tip Cleaner



- Made of low abrasive brass shavings.
- No water necessary.
- No temperature drop as in conventional sponges.
- Cleans better than conventional sponges.
- Anti-slip pad.

Description	Part No.
Solder Tip Cleaner	900-242
Solder Tip Cleaner- 5 pk refill	900-243


Helping Hands

- The practical helper for soldering work for electronics and model-making.
- Holding clamps adjustable in many ways, complete with magnifying glass 3.5"(90mm) dia:2X.
- Sturdy stand.



Description	Magnification	Part No.
Helping Hands	2X	902-094

Soldering Stand w/Solder Reel Holder

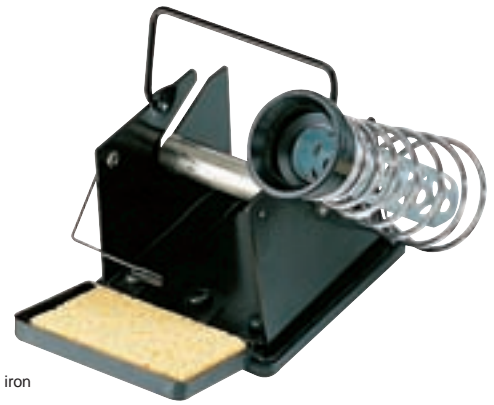

- Holds standard soldering iron
- Sponge for cleaning tip
- Holds roll of solder for easy, one-handed dispensing
- Heavy weighted base keeps unit stable

Description	Part No.
Soldering Stand w/Solder Reel Holder	900-099

Helping Hands Soldering Aid



- Magnifying Lens
- Soldering Iron Holder
- Sponge

Description	Part No.
Helping Hands Soldering Aid	900-206


Soldering Tool Stand



- Holds up to two soldering irons
- All holders adjustable for maximum comfort

Description	Part No.
Soldering Tool Stand	900-101

Solder Iron Stand

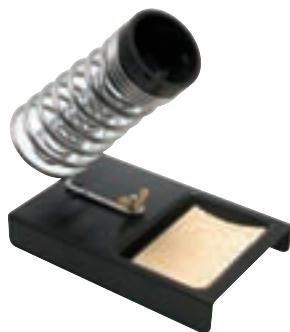

- Small stand for holding soldering iron
- Comes with a sponge

Description	Part No.
Solder Iron Stand	900-016

"Helping Hands" Soldering Aid



- "Helping Hands" Soldering Aid
- Table top, weighted base
- Multi-dimensional adjustment capability
- Alligator style clips for holding subject work

Description	Part No.
Without Magnifier	900-015
With Magnifier	900-037

Eclipse Tools

Mini - Vacuum Cleaner



- 3 "AA" batteries, not included

Description	Part No.
Mini - Vacuum Kit	900-270

Breadboard Accessory



- 70pcs of 22 AWG solid wires
- Variety of colors
- 14 lengths x 5pcs each
- Pre-cut, Pre Stripped and Pre-formed on each end.
- Completely Reusable
- (2,5,7,10,12,15,17,20,22,25,50,75,100 and 125mm)

Description	Part No.
Breadboard Accessory - 70 pcs/set	900-271

Breadboard Accessory



- 350pcs of 22 AWG solid wires
- Variety of colors
- 14 lengths x 25pcs each
- Pre-cut, Pre Stripped and Pre-formed on each end.
- Completely Reusable
- (2,5,7,10,12,15,17,20,22,25,50,75,100 and 125mm)

Description	Part No.
Breadboard Accessory - 350 pcs/set	900-272


Eclipse Tools

Breadboards

Item #: 900-247

840 tie points

- Expandable by combining several boards together to meet your different requirement

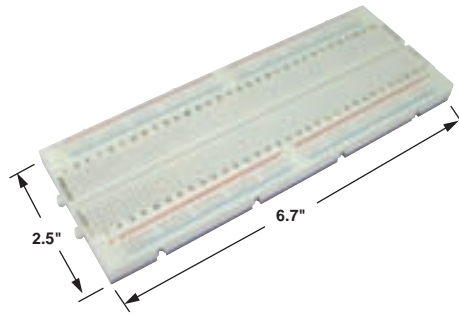


Excellent expandability



Friendly graduations

Item #: 900-248


1580 tie points

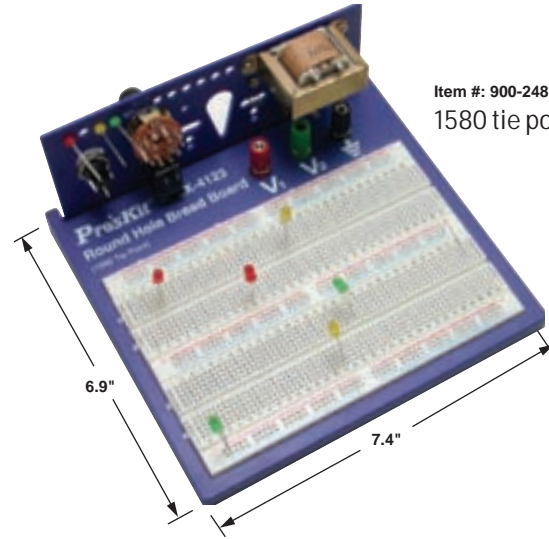

Edge plate can easy fold up

Item #: 900-249

2420 tie points

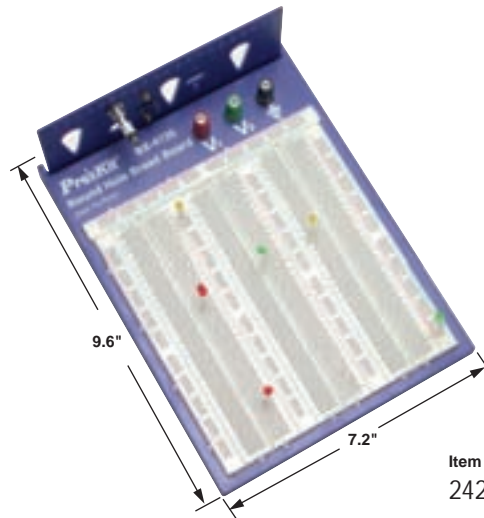

- Round hole designed for easy plug and pull
- Waterproof material made of ABS & phosphor bronze with good flexibility and electric conductivity

Description	Application	Part No.
Round Hole Breadboard	840 tie points	900-247
Round Hole Breadboard	1580 tie points	900-248
Round Hole Breadboard	2420 tie points	900-249



TESTERS



www.eclipsetools.com

Butt Set

- Amplified speaker for both Talk and Monitor Modes (battery operated)
- 12 memory positions
- Last number redial function
- Moisture and dust-resistant housing
- Profile of design allows test set to be easily held (hands-free) between shoulder and head
- Lightweight, compact design
- 9V battery included
- Dimension: 11.2" x 2.8" x 2.8"

Best Value – compare to TS22A™
"Data Safe Monitor Mode"




Description	Part No.
Butt-Set	400-042


Telecom Mini-Test Set

Data Safe ADSL Mode

- LCD display for dialing number, Caller ID, Clock and other information
- Indicator for determine the Net service and speed
- Headset & neck strap provide convenient hand-free function
- Smart power saving, estimate battery life
- 62 Caller ID memories, each memory up to 16 digits
- 16 dialing number memories, each number up to 16 digits
- Support 2 dialing modes: Tone (DTMF) and pulse
- Up to 16 digits phone number memory for speed dialing key
- Pre-dialing and last number redial function
- PBX pause key, insert a PBX pause in stored numbers
- Cable continuity & Tel. line polarity indicator
- RJ-45 port for extension change cord
- Standard alligator clip
- Auto Busy Redial

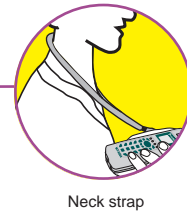

New

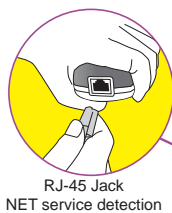

Accessories

Description	Part No.
Telecom Test Set	MT-8002

Test Lead (Professional Clip Style)




New

- Professional grade "Bed of Nails" insulation piercing clips within the jaws
- Ultra-durable nylon braided jacket
- Guarantee ruggedness and flexibility
- Non-insulated ring terminals
- Connect directly to 400-042 butt set
- Length: 60 inch
- Materials: Nylon, Copper
- Color: Red/Black

Description	Part No.
Test Lead (Professional Clip Style)	902-267

Eclipse Tools

In-Line Modular Adapters

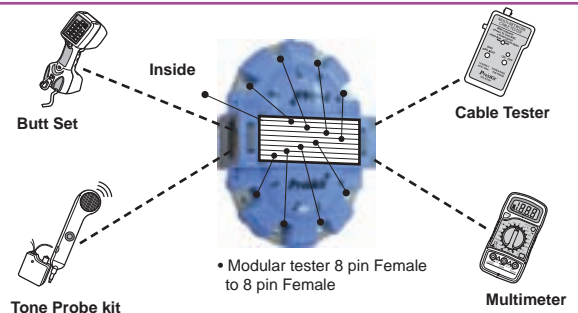

Description	Part No.
In-Line Modular Adapters	900-244

Economy Multimeter



- AC/DC voltage up to 600V
- DC current up to 10A
- Resistance 200-2M ohms
- hFE: 1-1000
- Diode test
- Data hold
- 9V power



Description	Part No.
Economy Multimeter	400-014

Digital Multimeter

- Display: 3999 counts, Digit is 25mm high.
- Data hold
- Continuity checking with buzzer
- Diode test
- Relative measurement
- hFE: 1-1000
- DC Voltage: 400mV±0.5%, 4/40/400/1000V ±0.8%
- AC Voltage: 200mV±1.2%, 2/20/200/750V±1.5%
- DC Current: 400µ/4m/40m/400mA±1.0%, 10A±2.0%
- AC Current: 400µ/4m/40m/400mA±1.5%, 10A±2.5%

- Resistance: 400Ω±1.2%, 4K/40K/400K/4MΩ±1.0%, 40MΩ±2.0%
- Capacitance: 4nF±5%, 40nF±2.0%, 400nF±0.5%, 4µF±1.0% 40µF±1.5%
- Frequency: 10/100/1K/10K/100K/1M/10MHZ±0.5%
- Auto power-off
- Power: AA(1.5V)x2
- Dimension: 6-1/4" x 3-1/4" x 1-3/4" (Without soft protection rubber case)
- Battery included



Description	Part No.
Digital Multimeter	400-043

3-IN-1 Auto-Detector

Detects Studs, Metal and Voltage



Description	Part No.
3-IN-1 Auto-Detector	400-032

20AMP Digital Multimeter



This meter is one of a series of portable, professional measuring instruments capable of performing the following functions:

- DC and AC voltage measurement
- DC and AC current measurement
- Resistance measurement
- Capacitance measurement
- Diode and Transistor test
- Audible continuity test
- Temperature measurement
- Frequency measurement

There are different functions and 32 ranges provided. A rotary switch is used to select functions as well as ranges.

GENERAL:

- Maximum voltage between terminals and earth ground 1000V dc or 700V rms ac (sine)
- Fuse protection mA: F 200mA/250V (A: unfused)
- Power Supply 9V battery
- Display LCD, 1999 counts, updates 2-3/sec
- Measuring method Dual-slope integration A/D converter
- Overrange indication "1" figure only on the display
- Polarity indication "-" displayed for negative polarity
- Operating temperature 0°C to 40°C (32°F to 104°F)
- Storage temperature -10°C to 50°C (10°F to 122°F)
- Low battery indication "BAT" appears on the display



Protective Function Analog Multimeter

- Durable reliable vibration-proof and patented protection circuit
- Double-sided glass epoxy through hole resist finish
- Protective function preventing mixed measurements
- Resistance, current and low-range voltage.
- DCV: 0.1/0.5/2.5/10/50/250/1000V (DC 20KΩ/V)
- DCA: 50µ/2.5m/25m/250m/10A
- ACV: 10/50/250/1000V (AC 9KΩ/V)
- Resistance: 1/10/1K/10KΩ
- Capacitance: C1(Rx1K): 2000µF,
- Battery: 1.5Vx@2+9Vx@1
- Continuity checking with buzzer



Description	Part No.
20AMP Digital Multimeter	400-047

Eclipse Tools

Description	Part No.
Protective Function Analog Multimeter	902-136

Auto-Ranging Professional Digital Multimeters

- 3 3/4 digit Display(4,000 counts), Large LCD Display, LCD window size: 45x25 mm.
- Auto-ranging functions.
- Touch Switch buttons respectively for Relative Test(REL), Data Hold-on(Data-H) except for Frequency Range, Back-lighting(BLCTR) and Function select (Func) for AC/DC Inter-change, Buzzer/Diode inter-change .
- High sensitivity of 100 μ V.
- Impedance: 10M Ω on all DCV&ACV ranges.
- Double-injection Plastics case(ABS + TPE).
- Good Protection by PTC, Two Fuses & Diode on the ranges of Current, Resistance, Voltage.
- Power-saving design to keep battery long life.
- Auto Power-Off once no operating after 20 minutes.
- Continuity Test, Transistor Test, Diode test, LED checky, Auto-zeroing.
- DC Voltage: 400m~1000V(\pm 1.0% of rdg+2 Digits).
- AC Voltage: 4~750V(\pm 1.5% of rdg+5 Digits).
- DC Current: 400 μ ~400mA(\pm 1.2% of rdg+2 Digits), 10A(\pm 2.0% of rdg+3 Digits).
- AC Current: 400 μ ~400mA(\pm 1.5% of rdg+3 Digits), 10A(\pm 2.5% of rdg+5 Digits).
- Resistance: 400~4M Ω (\pm 1.0% of rdg+2 Digits), 40M Ω (\pm 2.0% of rdg+4 Digits).
- Capacitance: 4nF(\pm 5.0% of rdg+25 Digits), 40nF(\pm 2.5% of rdg+10 Digits), 400nF (\pm 0.8% of rdg+3 Digits) 4 μ F(\pm 1.5% of rdg+2 Digits), 100 μ F(\pm 2.0% of rdg+2 Digits).
- Frequency: 10~2MHz(\pm 0.5% of rdg+2 Digits), 2M~20MHz(\pm 2.5% of rdg+2 Digits).
- Temperature: -20~1000°C(\pm 2.0% of rdg+2 Digits), 0~1800°F(\pm 2.5% of rdg+2 Digits).
- Power: 6F22 9V battery 1pc.
- Size: 147 x 75 x 40 mm.
- Weight: 270g with battery.
- This instrument complies with insulation category (over voltage category), CAT II1000V.
- Pollution degree 2 in accordance with IEC-664.



Description	Part No.
Auto-Ranging Professional Digital Multimeters	902-243

Professional 3 1/2 Digital Multimeters

- 3 1/2 digit Display (1,999 Counts), Large LCD Display, LCD window size: 45x25 mm
- Back Light for LCD with button and automatically turn-off after 10 sec.
- Push-type Switch buttons respectively for Data Hold-on(HOLD), Back-lighting (BLCTR) and AC/DC Inter-change.
- High sensitivity of 100 μ V.
- Impedance: 10M Ω on all DCV&ACV ranges.
- Double-injection Plastics case(ABS + TPE).
- Good Protection by PTC, Two Fuses & Diode on the ranges of Current, Resistance, Voltage.
- Continuity Test, Transistor Test, Diode test, LED check, Automatic low battery, Auto-zeroing.
- DC Voltage: 200mV(\pm 0.5% of rdg+1 Digit), 2/20/200V(\pm 1.0% of rdg+2 Digits), 1000V(\pm 1.5% of rdg+2 Digits).
- AC Voltage: 200mV(\pm 1.0% of rdg+3 Digits), 2/20/200V(\pm 1.5% of rdg+3 Digits), 750V(\pm 2.5% of rdg+4 Digits).
- DC Current: 200 μ /2m/20m/200mA(\pm 1.2% of rdg+2 Digit), 10A(\pm 2.0% of rdg+5 Digits).
- AC Current: 200 μ /2m/20m/200mA(\pm 1.5% of rdg+3 Digits), 10A(\pm 2.5% of rdg+5 Digits).
- Resistance: 200 Ω (\pm 1.2% of rdg+2 Digits), 2K/20K/200K/2M Ω (\pm 1.0% of rdg+2 Digits), 20M Ω (\pm 2.5% of rdg+4 Digits).
- Power: 6F22 9V battery 1pc.
- Size: 147 x 75 x 40 mm.
- Weight: 260g with battery.
- This instrument complies with insulation category (over voltage category), CAT II 1000V.
- Pollution degree 2 in accordance with IEC-664.



Description	Part No.
Professional 3 1/2 Digital Multimeters	902-248

Digital Earth Resistance Tester

- Capable of measuring earth voltage (Vac.)
- 2mA measuring current permits earth resistance to test without tripping earth leakage current breakers in the circuit.
- Battery operated.
- Auto power off function.
- Data hold function.
- Small and light weight.



IEC 1010 CAT.III



Description	Part No.
Eclipse Tools Digital Earth Resistance Tester	8PK-ST1520

Specifications

Measurement ranges	Earth resistance 0-20 Ω /0-200 Ω /0-2000 Ω Earth voltage 0-200V AC (40-50Hz)
Accuracy	Earth Resistance \pm (2% rdg+2dgt) Earth Voltage \pm (1% rdg+2dgt)
Earth resistance resolution	0-20 Ω (0.01 Ω) 0-200 Ω (0.1 Ω) 0-2000 Ω (1 Ω)
Measurement system	Earth resistance by constant current inverter 820Hz APPROX. 2mA.
Low battery indication	"B" symbol appears on the display
Data hold indication	"DH" symbol appears on the display
Over range indication	"1" (MSD)
Open circuit indication	LED will be unlit
Display LCD	3-1/2 digit (2000 counts)
Power source	1.5V(SUM-3) x 6. Type AA.
Dimensions (mm)	163(L) x 100(W) x 50(D)
Weight	480g approx.(battery included)
Accessories	Test leads (red 15m yellow-10m green-5m), Auxiliary earth bars. Heavy-duty case, Instruction manual

Multi-Modular Cable Tester



- Auto scans twisted pairs for shorts/opens/mis-wiring
- USOC4/6/8 testing
- RJ45/RJ12/RJ11 connector capability
- Designed to test intentionally crossed pairs or straight through pairs
- Remote terminator allows testing of already installed cables

Description	Part No.
Multi-Modular Cable Tester	400-004

Lan Cable Tester

3PK-NT040C LAN cable testers are intelligent continuity testers for LAN cables which save time on the job. Their intuitive operation keep you from wasting time working through complex menus.

• Comes with 8 identifier remotes and carrying case



New

Description	Part No.
Lan Cable Tester	3PK-NT040C

Cable Sniffer with Remote


- Tests RJ45 CAT5, USB, and BNC
- 5 LED's
- Performs tests of Shorts and Opens
- 9V Battery powered (not included)



Description	Part No.
Cable Sniffer with Remote	400-019

Eclipse Tools

Receptacle Tester

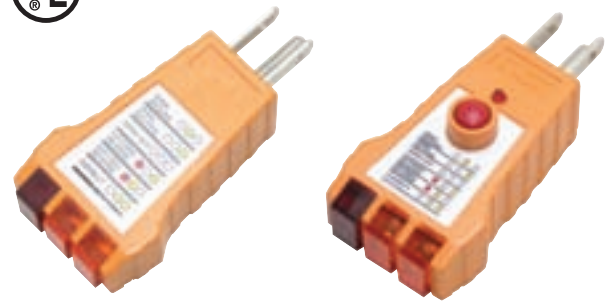

Description	Part No.
Receptacle Tester-Standard	400-029
Receptacle Tester-GFCI Outlets	400-030

Circuit Breaker Identifier

- Quickly identifies and locates 110 ~ 125 VAC circuit breakers and fuses.
- Not necessary to interrupt power.
- Audible tone generated when matching breaker is located
- An easy way to identify location of circuit breaker on the circuit breaker panel box which is connected to a specific outlet



Description	Part No.
Circuit Breaker Identifier	400-031

Mini-LAN Tester

- This Mini-LAN Tester is a small, hand-held tool for verifying, troubleshooting and quickly diagnosing problems during a LAN installation.
- This tester offers easy operation.
- Simply push the "TEST" button and the LEDs quickly give a clear indication of the LAN status.



Description	Part No.
Mini-LAN Tester	400-018

Economy LAN Cable Tester w/Remote


- Check in Loopback or Installed/Remote mode
- Tests Shielded and Unshielded twisted pair cable (STP/UTP)
- 9V Battery not included



Description	Part No.
Economy LAN Cable Tester w/Remote	400-021

LAN/LINK Identifier

- Link status
- 10/100mbps
- Full/Half duplex
- Receive data
- HUB/Switch/NIC blink
- No Link or Fault
- Battery low indicator to ensure accurate results
- Hub & NIC Status

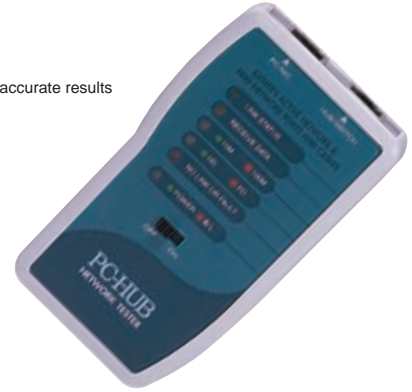

Description	Part No.
LAN -Tester	400-040

LAN Cable Tester with Remote



Description	Part No.
Standard configuration, RJ45/BNC Cables	400-001

Multi-Modular Cable Tester



- Tests RJ45, 10 Base-T, Token Ring, RJ11/12 USOC and Coaxial Cables
- Checks continuity, shorted/open and crossed wire pairs
- Coaxial cable tested for shorted or open shield as well as center conductor breaks
- LED's on both units allow for one person testing
- 9V Battery not included

Description	Part No.
Multi-Modular Cable Tester	400-026

PC Cable Tester



- Tests most common PC and network related cables for opens, shorts and pin-to-pin connections
- Automatic / Variable speed scan mode
- USB(A) & USB(B) & Firewire connectors, (400-007 only)
- Operates on external 9V positive center pin adaptor, (not included)
- Enhanced LED glow for shorted printer cable test
- Connector types include:
 - 36 pin Centronics
 - 9, 15 & 25 pin D-Subminiature
 - 15 pin High Density D-Sub
 - BNC
 - 8P8C RJ45 Modular Jack (shielded)
 - USB(A) & USB (B) and 1394 Connectors (model 400-007 only)

Description	Part No.
PC Cable Tester With USB Connectors (as shown)	400-007

Current Probe

- SMT Application
- Display: Digital and analog display. 3999 counts and 42 segments bar graph.
- Digit is 9mm high
- DC Voltage: 400V/600V ±1.0%
- AC Voltage: 400V/600V ±1.5%
- AC Current : 40A/400A ±2.0%
- Max. Diameter for conductor: ø1.1"
- Resistance : 400Ω±1.0%
- Data hold
- Continuity Test
- Autorange and manual range
- Back Light
- Power: AAA (1.5V) x 2



Description	Part No.
Current Probe	400-022

Hand Held Digital Clamp Meter

- LCD size : 0.6" x 1.9" display:1999 counts
- Max. Diameter for conductor: ø60mm
- DC Voltage : 1000V±0.8%
- AC Voltage : 600V±1.2%
- AC Current : 200-600A±2%, 600-1000A±3%
- Resistance : 200Ω / 20KΩ±1%
- Continuity check : Built in buzzer will sound.
- Data hold : Provided
- Power: 9V Battery



Description	Part No.
Hand Held Digital Clamp Meter	902-074

Oscilloscope Probe Kit

- Switchable X1/X10 attenuation with reference switch positions.
- Break-resistant center conductor & wide compensation range.
- Flatter response, sharper leading edges.
- Faster rise time and replaceable cable probe head tip and ground lead.
- Max. input voltage: 600V (DC-peak AC).
- Includes BNC adapter, IC tip, insulating tip & trimming tool.



Switchable series							
Model No.	Attn.	Readout	Input impedance	Band width	Resetime	Max input V	Compensation range
6HP-9060	x1	No	1MΩ 90PF	6MHz	58ns	600VDC	NA
	x10		10MΩ 18PF	60MHz	5.8ns		10-35PF
6HP-9100	x1	No	1MΩ 47PF	6MHz	58ns	600VDC	NA
	x10		10MΩ 16PF	100MHz	3.5ns		10-35PF
6HP-9150	x1	No	1MΩ 47PF	6MHz	58ns	600VDC	NA
	x10		10MΩ 15PF	150MHz	2.3ns		10-35PF
6HP-9250	x1	No	1MΩ 47PF	6MHz	58ns	600VDC	NA
	x10		10MΩ 14PF	250MHz	1.4ns		10-35PF

Dual Telephone Line Tester

- Tester two lines in Same RJ11 jack
- Protects modem (Digital systems provide high-current phone lines that can damage most computer modems. Since both safe analog lines and dangerous digital lines use the same type of connectors, it is impossible to visually determine if a phone line is safe. Use Voltage Valet's Digital Phone Line Tester before you plug in to detect high-current digital telephone lines that can damage your computer modem.)



Description	Part No.
Dual Telephone Line Tester	400-028

Telecom Tester

- Inexpensireand effective
- The tele-check
- Inscr the plug



Description	Part No.
Telecom Tester	400-017

All-in One Toner & Probe Kit

Best Value

Features:

- Locates cables quickly and easily
- Locates hidden cables
- Isolates the right cable or pair fast
- Overcome noise and save time
- Tone on live networks safely and effectively
- Verify conductor continuity with cable map
- Identify and troubleshoot cable services RJ45/RJ11/USB and Coax

Applications:


- Copper cabling media, including shielded (STP) and UTP cable.
- 75 or 50 Ohm coaxial cable
- 10 Base-T or 10/100 Base-T datacom net works
- Two conductor control, security, generic cabling
- POTS telecom service
- Testing range: 1500 meters



4 Testers in One

Description	Part No.
All-in One Toner & Probe Kit	902-228

Tone Generator and Probe Set

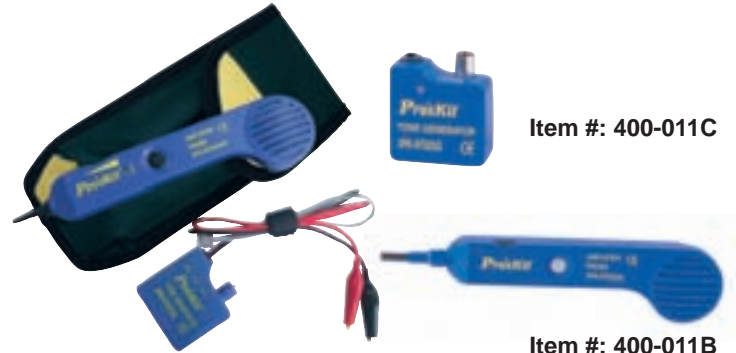

Item #: 400-011C

Item #: 400-011B

- Comes with a canvas carrying pouch and belt loop for convenient portability

Description	Part No.
Tone Generator and Probe Set	400-011
Pouch from 400-011	400-011A
Probe from 400-011	400-011B
Tone generator from 400-011	400-011C

Non-Contact AC Detector

Ideal for electrical troubleshooting detecting a live AC source and locating a burned-out bulb in a series. Detects AC voltage without connection into the wire circuit. Very bright LED and buzzer alarm informs you that voltage is present. Pen-shaped design for easy carrying and storage.

- Test Volt: 90-240V AC 50-60Hz
- Instant Indication: Bright LED on end Beeper sound intermittently
- Contents : AC voltage detector, Precision screwdriver and 2 "AAA" batteries



New

Description	Part No.
Non-Contact AC Detector	NT-303

8-Way Coaxial Cable Mapper

New

The 8 way coaxial cable mapper is designed to find and identify multiple coax cables. It is a hand-held device for CATV and security system installers who test multi-run coax systems terminated with F-connectors, or those who wish to map runs to a central bundle. It can be used to put a tone signal on a coax cable. With eight individual remote terminators, it's ideal for mapping coax installations.



8 Serial-number Terminators



Description	Part No.
8-Way Coaxial Cable Mapper	NT-301

Mini-Pocket Tester

The cable test detects DC continuity or shorts using a loud audible tone and an easy to read LED. The system has a DC generator/short detector and a removable tone detector that screws into the base.



New

Description	Part No.
Cable Tester Eclipse Tools	NT-302

Mini-Pocket Tester Kit with adaptors

NT-302 cable tester supports coaxial cable with F-connectors. With the addition of a wide range of optional adaptors, you can test telephone, LAN, audio, security, or virtually any other type of wire or cable easily.

KITS includes:

- NT-302 cable tester
- F-81 F double female adapter
- 2 F double male adapter
- 2 F push-on male to female adapters
- 2 RCA male to F-female adapters
- 2 RCA female to F-male adapters
- 2 BNC male to F female adapters
- 2 BNC female to F-female adapters
- 2 RJ-11 adapters
- 2 RJ-45 adapters
- 5 F Female to PAL Female



New

Description	Part No.
8 Way Coaxial Cable Mapper W/8 Serial Number Terminator	NT-3200



TOOL CASES



www.eclipsetools.com

Economy Tool Case

- Dark green canvas exterior
- 18 tool holding straps inside
- Zipper allows to fold open
- Carrying/hanging strap
- Size = 11.9"x8.7"x1.9"

Description	Part No.
Economy Tool Case	900-051



Deluxe Tool Bag



- Size: 15.4"x9.6"x9.8"

Description	Part No.
Deluxe Tool Bag (tools not included)	900-106

Economy Tool Bag



- Size: 16.5"x6.7"x9.8"

Description	Part No.
Economy Tool Bag (tools not included)	900-107

Black Tool Pouch

- Large capacity, general purpose pouch with Tape Measure clip, Butt-Set hook, and Tape Roll holder.
- Made from durable fabric.



Description	Part No.
Black Tool Pouch	902-254

Soft Sided Tool Pouch



Description	Part No.
Soft Sided Tool Pouch	900-246

Heavy Duty Zipper Bag



- Material : PVC leather
- Size: 17"x12.8"x3.5"

Description	Part No.
Heavy Duty Zipper Bag	900-052

Double-Sided Tool/Computer Case



- Several zippered pouches
- Bottom compartment for laptop
- Top compartment has tool holding straps
- Size: 14.2"x11"x4.7"

Description	Part No.
Double-Sided Tool/Computer Case	900-054

Mechanic's Tool Bag



(Tools not included)

- Size: 12"x6"x6.5"

Description	Part No.
Mechanic's Tool Bag	MTB-1

Blow Molded Case With Pre-Cut Soft Foam




- Size: 17.4"x11"x3.5"
- Material: H.D.P.E

Demo only

Description	Part No.
Blow Molded Case With Pre-Cut Soft Foam	900-225

Ruggedized Tool Case w/1 Pallet


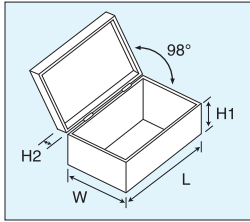


• L x W x H1 : 18.3"x12.7"x 3.93"
H2 : 2.75"



Description	Part No.
Ruggedized Tool Case w/1 Pallet	900-199

Aluminum Frame Tool Case

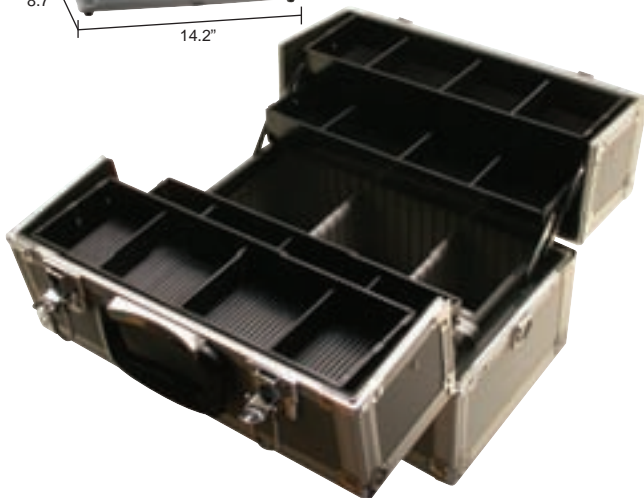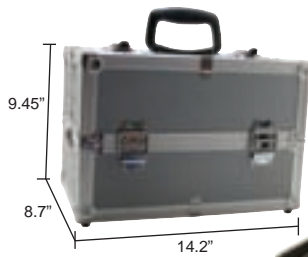

• Size : 9.45"X8.7"X14.2"

Description	Part No.
Aluminum Frame Tool Case	900-203

Eclipse Tools


Aluminum Frame Tool Case



- Ruggedized tool case
- Moveable partitions
- Carrying straps
- Removable pallet with tool pockets
- Size: 18"X13"X5.9"

Description	Part No.
Aluminum Frame Tool Case	900-048
Second Pallet	900-045

Zipper Bag w/2 Pallet

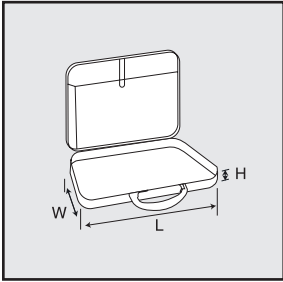


- L x W x H : 15-3/8" x 10-1/4" x 2-3/4"
- Material: 600D Polyester



Description	Part No.
Zipper Bag w/2 Pallet	902-118

Tool Bag

- Material: 600D polyester
- Intensive structure for strap, zipper and handle designed to enhance the durability.
- High capacity and affordable price make it the best mate for students.

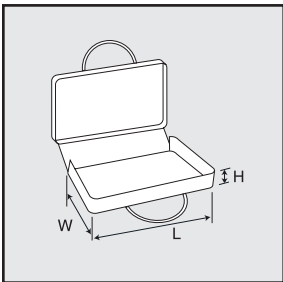

- L x W x H : 15-3/8" x 10-1/4" x 2-3/4"



Description	Part No.
Tool Bag	902-119



Eclipse Tools



(Tools not included)

Wheeled Case



- Material: Denim-like Polyester with water-repellent treatment
- Multi function bag with 4 inner layers, ideal for storing tools, books, personal computers etc.
- 2 pcs removable tool pallets
- Recessed rubber wheels and telescoping handle for convenient transportation
- Carry your tools, laptop and business material in one convenient case.
- Size: 17.3"x12.2"x7.9"

Description	Part No.
Wheeled Case	900-261

Eclipse Tools

Soft-sided Tool Bag



- Material: Denim-like Polyester
- Multi function bag with 4 inner layers ideally for storing tools, books, mobile computers, clothes, etc.
- Intensive structure for strap, zipper and handle designed to enhance the durability.
- Size: 15.7"x10.8"x3.5"

Description	Part No.
Soft-Sided Tool Bag	900-260

Aluminum Frame Tool Case



- Ruggedized tool case
- Moveable partitions
- Carrying straps
- Removable pallet with tool pockets
- Size: 18"x13"x5.9"

Description	Part No.
Aluminum Frame Tool Case	900-011
Second Pallet	900-045

ABS Tool Case



- Ruggedized tool case
- Carrying straps
- Removable pallet with tool pockets
- Size: 17-1/2"x13-1/2"x5-3/4"

Description	Part No.
ABS Tool Case	900-141

Wheeled Hard case

- Heavy-duty black scuff resistant molded ABS thermoplastic forms the tough shell of this case. Extruded aluminum rim, drawbolt key locks and strong molded handle.
- Size: 18.3"x13.2"x7.5"



Description	Part No.
Wheeled Hard case	900-262

Eclipse Tools



WIRING INSTALLATION



www.eclipsetools.com

Steel Fish Tapes



Item #: 900-147



Item #: 900-148



Item #: 900-149



Item #: 902-197

- 1/8" wide tape, 0.06" thick
- Rugged, enclosed design
- Looped end to prevent snags or tearouts
- Steel tape
- Compact, easy to use.

Description	Part No.
50 Feet	900-147
100 Feet	900-148
200 Feet	900-149
Fiberglass Fish Tape (150 feet)	902-197

100 FT Fish Tape Refills



Item #: 900-148FT




Item #: 900-148T

Description	Part No.
100 FT Fish Tape Refills (wide: 1/8"x thick: 0.06")	900-148T
100 FT Fish Tape Refills (fiber glass)	900-148FT

Eclipse Tools

Fiberglass Push/Pull Rod Set

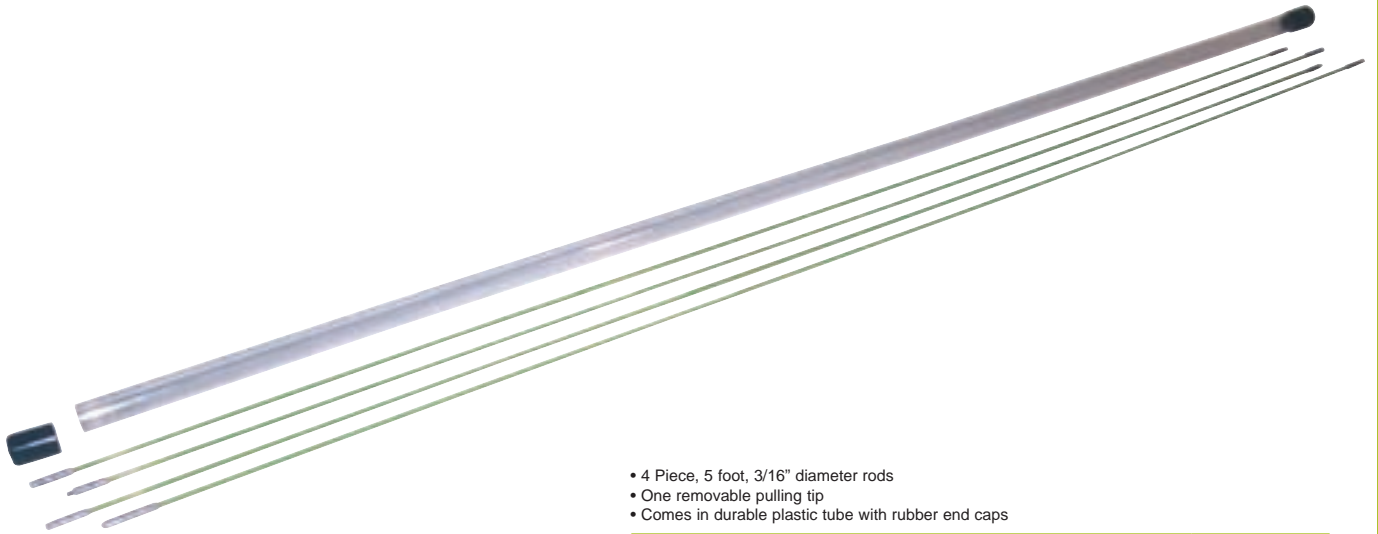

- 4 Piece, 5 foot, 3/16" diameter rods
- One removable pulling tip
- Comes in durable plastic tube with rubber end caps

Description	Part No.
Fiberglass Push/Pull Rod Set	900-170
Magnet Tip	900-171
Hook Tip	900-172
Whisk Tip	900-173
Replacement Tip	900-174

Conduit Benders




Description	Part No.
1/2 Inch	900-154
3/4 Inch	900-155
1 Inch	900-156
Handle for 1/2" & 3/4" Conduit Benders -3/4"x38"	900-154H
Handle for 1" Conduit Benders -1"x44"	900-156H

Eclipse Tools


- Rugged design
- Marked for determining bend angles
- Three sizes
- Die Cast Aluminum

Jab Saw

 
Best Value



Wood

 

Non-Ferrous

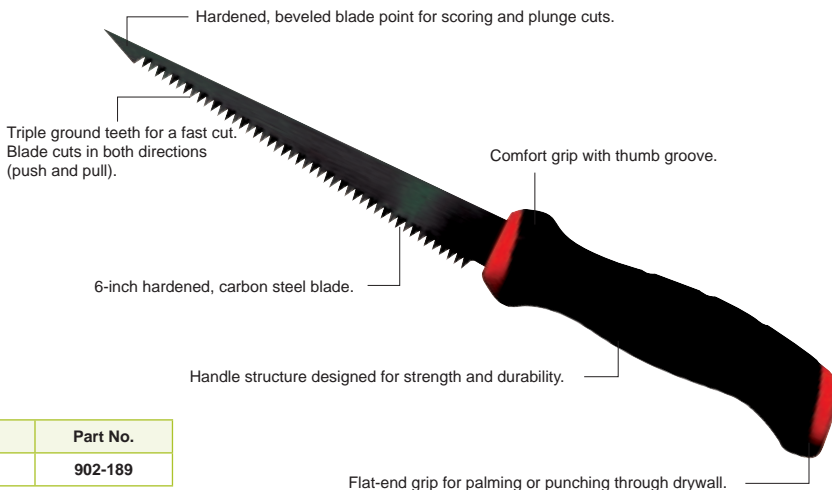

Description	Part No.
Jab Saw	902-189

Dualgrip Wallboard Saw

Professional Grade - comes with Sheath



Description	Part No.
Dualgrip Wallboard Saw	900-229

BI-Metal Hole Saw Kit

- Hole Saw Contents: 7/8", 1-1/8", 1-3/8", 1-1/2", 1-3/4", 2", 2-1/2", 3", 3-5/8", 4-1/8", 4-1/2"
- Arbour:
 - Triangular shank 1/4" fits hole saws 7/8", 1-1/8"
 - Triangular shank 7/16" fits hole saws 1-3/8", 1-1/2", 1-3/4", 2", 2-1/2", 3", 3-5/8", 4-1/8", 4-1/2"
 - SDS plus shank fits hole saws 7/8", 1-1/8"
- Extension Bar: 12" length fits hex shank 7/16" arbour
- Hex Key: 4mm

Blades and Arbors Now Available Individually

Description	Part No.
BI-Metal Hole Saw Kit	500-036
7/8" Hole Saw	902-175
1-1/8" Hole Saw	902-176
1-3/8" Hole Saw	902-177
1-1/2" Hole Saw	902-178
1-3/4" Hole Saw	902-179
2" Hole Saw	902-180
2-1/2" Hole Saw	902-181
3" Hole Saw	902-182
3-5/8" Hole Saw	902-183
4-1/8" Hole Saw	902-184
4-1/2" Hole Saw	902-185
Arbors	902-272 New
1/4" Arbors	902-273 New
7/16" Arbors	902-271 New



Kit 500-036



CABLE TIES



www.eclipsetools.com

Heavy Duty Cable Tie Tool

- Cuts up to .350 inch size cable ties
- Tension tool



Description	Part No.
Heavy Duty Cable Tie Tool	900-062

Cable Tie Gun

- Cable tie width from 3/32" - 11/32"
- Neatly cuts end of cable tie off
- Adjustable tension control



Description	Part No.
Cable Tie Gun	900-005

Cable Tie Fasten Tool

For Stainless Steel Ties

New



- Fasten and automatic cut ties, with adjustable bundling pressure
- Thickness up to 0.3mm
- Width up to 7.9mm

Description	Part No.
Cable Tie Fasten Tool	CP-384

Cable Tie Gun

New



- Thickness up to 1.3mm
- Width up to 4.6mm
- Nylon and Vinyl Ties Only – not for Steel

Description	Part No.
Cable Tie Gun	CP-383

Hook and Loop Cable Tie Material-Bulk Roll (50 feet long-1/2 inch wide)



New



New

Description	Part No.
Hook and Loop Cable Ties Material-Bulk Roll-Black	902-035
Hook and Loop Cable Ties Material-Bulk Roll-white	MS-V350-WH
Hook and Loop Cable Ties Material-Bulk Roll-Blue	MS-V350-BL

Eclipse Tools

Hook and Loop Cable Ties




Description	Part No.
Hook And Loop Cable Ties-8" Black (25pc pack)	900-098-BK
Hook And Loop Cable Ties-8" Blue (25pc pack)	900-098-BU
Hook And Loop Cable Ties-8" Green (25pc pack)	900-098-GN
Hook And Loop Cable Ties-8" Orange (25pc pack)	900-098-OR
Hook And Loop Cable Ties-8" Red (25pc pack)	900-098-RD
Hook And Loop Cable Ties-8" White (25pc pack)	900-098-WH
Hook And Loop Cable Ties-8" Yellow (25pc pack)	900-098-YL

Hook and Loop Cable Ties (Assortment Pack)



The hook and loop cable ties are made by Nylon/P.P. material and offered 5 colors combination pack (Black, Blue, Green, Red, and Yellow). They are good for use in binding the cables and patch cables and won't even affect the transmittance performance because of over tight binding. Reusable, the back-to-back design provides instant installation without using tools.

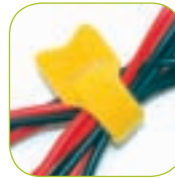


Description	Part No.
Hook and Loop Cable Ties 7-4/5" 3 of each color (15 pcs/pack)	MS-V308

Cable Ties



Description	Part No.
Cable Tie 4" X 3/32" Neutral (100pc pack)	902-012
Cable Tie 7-7/8" X 3/32" Neutral (100pc pack)	902-015
Cable Tie 5-1/2" X 9/64" Neutral (100pc pack)	902-013
Cable Tie 7-7/8" X 9/64" Neutral (100pc pack)	902-016
Cable Tie 7-1/2" X 3/16" Neutral (100pc pack)	902-014
Cable Tie 11-3/4" X 3/16" Neutral (100pc pack)	902-017
Cable Tie 14-1/2" X 3/16" Neutral (100pc pack)	902-018
Cable Tie 4" X 3/32" Black (100pc pack)	902-019
Cable Tie 7-7/8" X 3/32" Black (100pc pack)	902-022
Cable Tie 5-1/2" X 9/64" Black (100pc pack)	902-020
Cable Tie 7-7/8" X 9/64" Black (100pc pack)	902-023
Cable Tie 7-12" X 3/16" Black (100pc pack)	902-021
Cable Tie 11-3/4" X 3/16" Black (100pc pack)	902-024
Cable Tie 14-1/2" X 3/16" Black (100pc pack)	902-025

Eclipse Tools

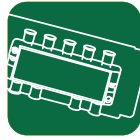

HOME NETWORKING SYSTEM



www.eclipsetools.com

14 Inch /28 Inch Box With Lid

Description	Part No.
14 Inch Box With Lid	902-001
28 Inch Box With Lid	902-046



Power Supply



Description	Part No.
Power Supply Eclipse Tools	902-005

Telephone 8 Port Module



Description	Part No.
Telephone 8 Port Module	902-002

Push Button Fasteners



Description	Part No.
Push Button Fasteners	902-007

Grommets




Description	Part No.
Grommets	902-008

Installation Kit



Description	Part No.
Installation Kit	902-006

Network 8 Port Module

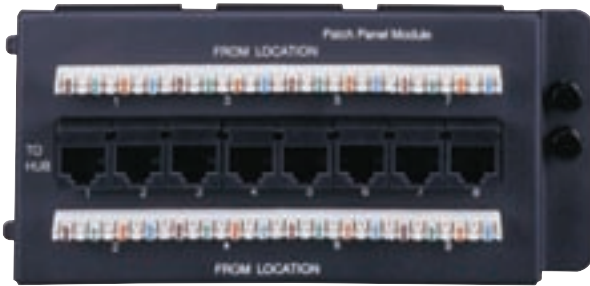

Description	Part No.
Network 8 Port Module	902-003

Telephone Module with built-in DSL Filters



Description	Part No.
Telephone Module with built-in DSL Filters	902-009

Television 8 Port Module



Description	Part No.
Television 8 Port Module Eclipse Tools	902-004

8 Port 10/100 Base T Ethernet Hub



Description	Part No.
8 Port 10/100 Base T Ethernet Hub	902-010