

Approvals



Life expectancy




L-10 LIFE AT 40°C:
80 000 hours

Brushless DC Motor

Electrical protection: impedance protected
Housing material: plastic UL 94 VO
Impeller material: plastic UL 94 VO
Weight: 180 g

Available with:

- speed sensor
- open collector alarm

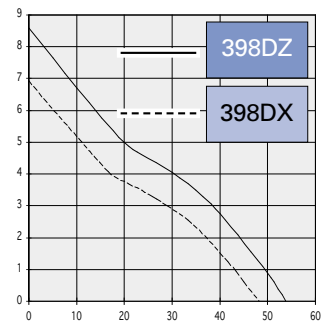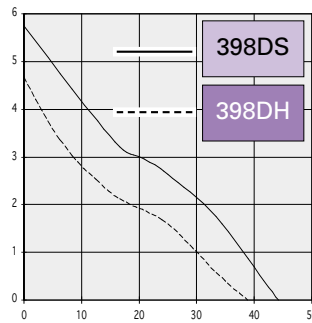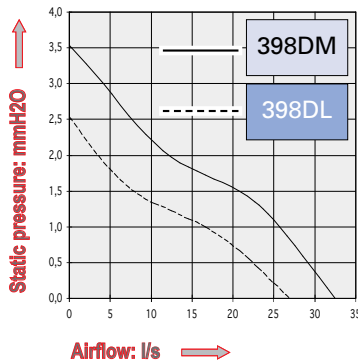

Part number	Nominal voltage	Airflow	Noise level	Nominal speed	Input power	Voltage range	Bearing system		Connection type		Operating temperature	
	V						l/s	dB(A)	RPM	W	V	Ball
398DL1LP11000	12	27,0	31	1950	1,7	(7-13,8)	X		X		- 10	60
398DL2LP11000	24	27,0	31	1950	1,7	(14-27,6)	X		X		- 10	60
398DL4LP11000	48	27,0	31	1950	1,9	(28-56)	X		X		- 10	60
398DM1LP11000	12	32,5	34	2300	2,0	(7-13,8)	X		X		- 10	60
398DM2LP11000	24	32,5	34	2300	2,2	(14-27,6)	X		X		- 10	60
398DM4LP11000	48	32,5	34	2300	2,4	(28-56)	X		X		- 10	60
398DH1LP11000	12	38,8	39	2670	3,2	(7-13,8)	X		X		- 10	60
398DH2LP11000	24	38,8	39	2670	3,4	(14-27,6)	X		X		- 10	60
398DH4LP11000	48	38,8	39	2670	3,4	(28-56)	X		X		- 10	60
398DS1LP11000	12	44,2	42,5	3000	3,6	(7-13,8)	X		X		- 10	60
398DS2LP11000	24	44,2	42,5	3000	3,6	(14-27,6)	X		X		- 10	60
398DS4LP11000	48	44,2	42,5	3000	3,8	(28-56)	X		X		- 10	60
398DX1LP11000	12	48,2	45,5	3300	4,8	(7-13,8)	X		X		- 10	60
398DX2LP11000	24	48,2	45,5	3300	4,8	(14-27,6)	X		X		- 10	60
398DZ1LP11000	12	53,8	48,5	3700	6,0	(7-13,8)	X		X		- 10	60
398DZ2LP11000	24	53,8	48,5	3700	6,0	(14-27,6)	X		X		- 10	60

Accessories:

- Plastic finger guards P/N : PFG-120 & 121-53
- Metal finger guard P/N : 9601-43
- Rubber mounts P/N : AM-10
- Plastic filters P/N : F120/T102 & 120V
- Metal filters 96-152 96-302
- Metal mesh filter P/N : 120-G