


CHARACTERISTICS

Weight: 0,8 Kg / 1,77 Lb
 Housing in ZAMAK
 Turbine in plastic UL 94 V-0
 L-10 life expectancy at 40°C: 80.000 hours
 Operating temperature range: -10 / +70 °C
 Storage temperature: -40 / +70°C
 Connection: Terminals
 Impedance Protected

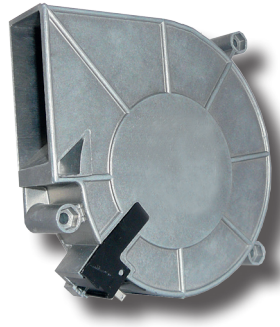

OPTIONS

Other IP levels
 Flying leads connection
 Salt spray protection
 Shocks and vibrations protection
 Marine application
 Other voltages

Part Number	Voltage V	Frequency Hz	Nb Phases	Airflow		Pressure		Nominal speed RPM	Noise level LP dBA	Nominal current	Starting current mA	power W	Capacitor µF
				l/s	CFM	mm H ₂ O	inch H ₂ O						
583CBA0092000	115	50	1	13,5	28,62	9,5	0,37	2550	49	270	400	21	
92	115	60	1	13,2	27,98	13,5	0,53	2500	51	250	350	20	
91	220	50	1	13,5	28,62	9,5	0,37	2550	49	140	210	21	
91	220	60	1	13,2	27,98	13,5	0,53	2500	51	130	185	20	

