


Datasheet

Item No. 73.335.4035.0

Bottom BAS GUT GC 40HM32 50 A0

revos BASIC 500V size 16H closed-bottom base with cable gland M32, left, high design, double locking lever

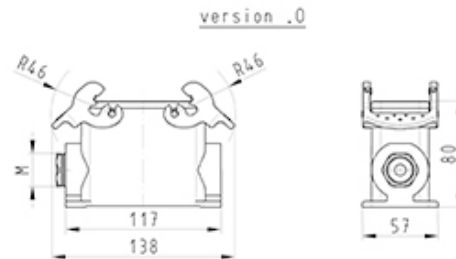

Item No.	73.335.4035.0
EAN	4015573623330
order unit	1 Piece(s)

Approvals



Technical data

General

Nominal voltage	500
Housing material	Aluminium
Colour	Grey
Surface	With powder coating
Degree of protection (IP)	IP54
UV resistant	Yes
Inflammability class of insulation material acc. with UL94	Other
Operating temperature range min.	-40 °C
Operating temperature range max.	120 °C

Model

DIN-size	16H
Model	Surface mounting (base)
Locking mechanism	Double locking levers
Cable entry	Sideways
Type of cable	Gland nut
With cable screw gland	Yes
Thread size M	32
Hinged lid	No
EMC-version	No

Drawings

Ausführung .1  
version .1

Weitere Daten siehe Katalog  
further data see catalog

Teile-Nr. part-no.	Typ type
73.335.4035.0	BAS GUT GC 40HM32 50 A0
73.335.4035.1	BAS GUT GC 40HM32 50 A1

Kabelver- schraubung M32 cable gland M32		Gewinde M32 thread M32	
Ausführung .0 version .0		Ausführung .1 version .1	

Fertigung nach DIN 7167/Envelope system etc. to DIN 7167. This DIN standard describes the envelope principle. According to the envelope principle the deviations of form and parallelism are limited by the size tolerances.	2005 05.02. Schnitt 1. 1:1	Werkstoff/Material 2005 05.02. Schnitt 1. 1:1	Zeichnung Nr./Drawing No. 73.335.4035.0 01K
GEHAUSEUNTERTEIL Größe 40 M 32 1x links / size 40 M32 Closed housing with one cable gland on left side		73.335.4035.0 01K 00-PEB-05/91	