
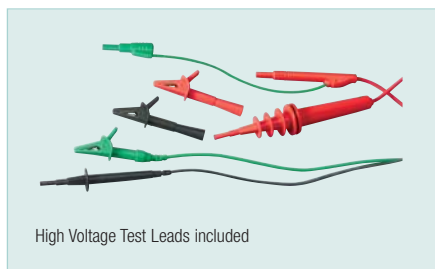


Digital High Voltage Insulation Tester

6kV digital tester
With real time voltage bargraph

Features:

- Four DC test voltages
0.5kV, 1kV, 2.5kV, 5kV
- Measure Insulation Resistance to 250G
- Large LCD with real-time bargraph display of test voltage and voltage decay during discharge
- Microprocessor based with advanced safety features
- Test duration (up to 99.9s) is displayed
- Live circuit display warning and beeper
- Enersave™ feature to extend battery life
- Autoranging and Auto power off functions
- Complete with built-in carrying case with cover, 8 x AA batteries, and test leads

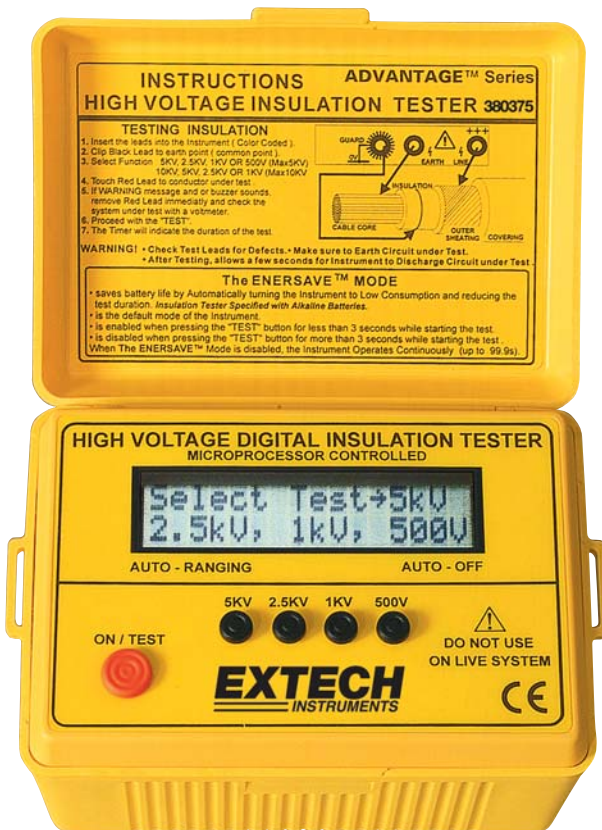

High Voltage Test Leads included

Specifications	Range
Test Voltage (Resolution)	0.5/ 1.0/ 2.5/ 5.0 kV (1k)
Insulation Resistance	25/ 50/ 125/ 250 G
Accuracy	±3.0%
Power	8 AA batteries
Dimensions	4.7 x 6.7 x 3.7" (120 x 170 x 95mm)
Weight	22oz (625g)

Ordering Information:

380375.....Digital High Voltage Insulation Tester

