

MultiView™ Series Digital MultiMeter


Manual Ranging Digital MultiMeter
With Adjustable Viewing Angle Display

Features:

- Large 1" LCD display adjusts for better viewing angle
- 2000 count (3-1/2 digits)
- Basic DCV accuracy of 0.5%
- Battery check for 9V and 1.5V batteries
- 50Hz square wave output
- Auto power off
- Shock resistant case with protective rubber holster
- Improper test lead position alarm alerts user if position does not match function selected
- Measurement functions include AC/DC Voltage and Current, Resistance, Diode, Continuity and Transistor
- Complete with 9V battery, test leads and protective holster

Applications:

- Tilt display adjusts 0° to 80° for best viewing angle
- Industrial electrical installation and troubleshooting
- Electronic testing and repair

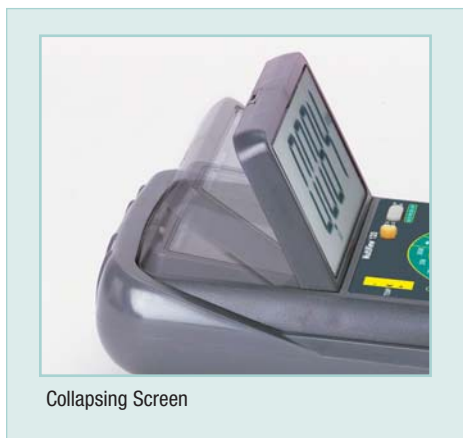

Specifications	Range	Max. Resolution	Basic Accuracy (%rdg+digits)
AC Voltage	200mV, 2V, 20V, 200V, 750V	100µV	±(1.2% + 3d)
DC Voltage	200mV, 2V, 20V, 200V, 1000V	100µV	±(0.5% + 1d)
AC/DC Current	20µA, 200µA, 2mA, 20mA, 200mA, 2A, 10A	10nA	±(0.8% + 1d) DC ±(1.8% + 3d) AC
Resistance (Ω)	200, 2k, 20k, 200k, 2M, 20M, 200M	0.1Ω	±(0.8% + 3d)
Dimensions/ Weight	3.5 x 7.5 x 1.4" (88 x 191 x 36mm) / 11oz (312g)		

Ordering Information:

- MV110MultiView™ Digital MultiMeter
 MV110-NISTMultiView™ Digital MultiMeter with NIST Certificate
 CA899Vinyl Pouch Carrying Case
 TL805Spare set of CAT. III-1000V Test Leads
 TL807Set of Alligator Clips (2pk) for TL805

