

TOOLS



STATIC DISSIPATIVE TWEEZERS



Fig. 1



Fig. 2



Fig. 3

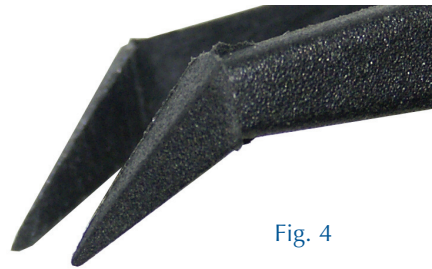


Fig. 4



Fig. 5

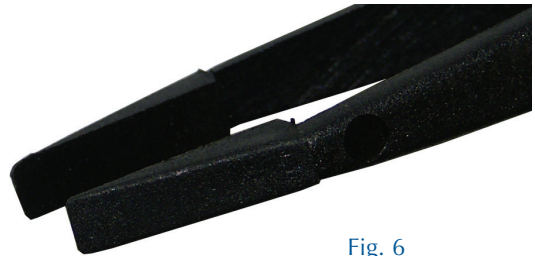


Fig. 6



Fig. 7



Tweezers (Full View)

Static Dissipative Tweezers

Retail Part No.	Bulk Part No.	Figure No.	Description	Length (Inches)
12-9511		1	Static Dissipative, Non-metallic, Acid Resistant Plastic Tweezers with Straight, Flat, Rounded Tip .	4-1/2
12-9514		2	Static Dissipative, Non-metallic, Acid Resistant Plastic Tweezers with Curved, Rounded Tip.	4-1/2
12-9517		3	Static Dissipative, Non-metallic, Acid Resistant Plastic Tweezers with Very Fine, Straight Tip.	4-1/2
12-9520		4	Static Dissipative, Non-metallic, Acid Resistant Plastic Tweezers with Very Fine, Angular Tip.	4-1/2
12-9523		5	Static Dissipative, Non-metallic, Acid Resistant Plastic Tweezers with Very Fine, Curved Tip.	4-1/2
12-9526		6	Static Dissipative, Non-metallic, Acid Resistant Plastic Tweezers with Straight, Flat Tip.	4-1/2
12-9529		7	Static Dissipative, Non-metallic, Acid Resistant Plastic Tweezers with Straight, Broad Flat Tip.	4-1/2

For the latest information—www.gcelectronics.com
 All quantities are single; BU's are packages of 10 Unless otherwise noted.

