


COMPONENT SPEAKER WIRE (Cont.)

2 Conductor Parallel Zip Cord

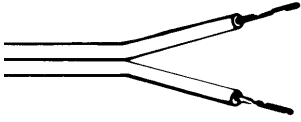

Two conductor Parallel Zip Cord Wire for loudspeaker connection and other low voltage applications such as alarm, signal and telephone circuits. Temperature range:-20° to+60°. White Identification polarity stripe.

24 Gauge (2-Conductor)

Specifications:
 Oxygen Free Copper
 Conductor AWG: 24 gauge
 Stranding: 7/32
 Insulation Nominal Wall Thickness: .016"
 Voltage: 300V
 Temperature Rating: -20°C to + 60°C
 Construction: Bare Copper Conductors; Clear PVC;
 1 Conductor Identified for Polarity
 Nominal O.D.: .055" x .110"

Applications:
 Automotive Speaker Wire, Juke Boxes,
 Stereo Speaker Wire

Part No.	Color	Length	Packaging
14-224-2B13	Clear	25 ft.	Spool
14-224-2B23	Clear	50 ft.	Spool
14-224-2B43	Clear	100 ft.	Spool
14-224-2B63	Clear	500 ft.	Spool
14-224-2B83	Clear	1000 ft.	Spool
30-586	Clear	50 ft.	Hank
30-588	Clear	100 ft.	Hank

22 Gauge (2-Conductor)

Specifications:
 Oxygen Free Copper
 Conductor AWG: 22 gauge
 Stranding: 7/30
 Insulation Nominal Wall Thickness: .020"
 Voltage: 300V
 Temperature Rating: -20°C to + 60°C
 Construction: Bare Copper Conductors; Clear PVC;
 1 Conductor Identified for Polarity
 Nominal O.D.: .070" x .140"

Applications:
 Automotive Speaker Wire, Juke Boxes,
 Stereo Speaker Wire

Part No.	Color	Length	Packaging
14-222-2C13	Clear	25 ft.	Spool
14-222-2C23	Clear	50 ft.	Spool
14-222-2C43	Clear	100 ft.	Spool
14-222-2C63	Clear	500 ft.	Spool
14-222-2C83	Clear	1000 ft.	Spool

20 Gauge (2-Conductor)

Specifications:
 Oxygen Free Copper
 Conductor AWG: 20 gauge
 Stranding: 7/28
 Insulation Nominal Wall Thickness: .025"
 Voltage: 300V
 Temperature Rating: -20°C to + 60°C
 Construction: Bare Copper Conductors; Clear PVC;
 1 Conductor Identified for Polarity
 Nominal O.D.: .085" x .170"

Applications:
 Automotive Speaker Wire, Juke Boxes,
 Stereo Speaker Wire

Part No.	Color	Length	Packaging
14-220-2D13	Clear	25 ft.	Spool
14-220-2D23	Clear	50 ft.	Spool
14-220-2D63	Clear	500 ft.	Spool
14-220-2D83	Clear	1000 ft.	Spool
30-553	Clear	50 ft.	Hank

18 Gauge (2-Conductor)

Specifications:
 Oxygen Free Copper
 Conductor AWG: 18 gauge
 Stranding: 16/30
 Insulation Nominal Wall Thickness: .025"
 Voltage: 300V
 Temperature Rating: -20°C to + 60°C
 Construction: Bare Copper Conductors; Clear PVC;
 1 Conductor Identified for Polarity
 Nominal O.D.: .100" x .200"

Applications:
 Automotive Speaker Wire, Juke Boxes,
 Stereo Speaker Wire

Part No.	Color	Length	Packaging
14-218-2E13	Clear	25 ft.	Spool
14-218-2E23	Clear	50 ft.	Spool
14-218-2E43	Clear	100 ft.	Spool
14-218-2E53	Clear	250 ft.	Spool
14-218-2E63	Clear	500 ft.	Spool
14-218-2E83	Clear	1000 ft.	Spool
30-584	Clear	50 ft.	Hank
30-554	Clear	100 ft.	Hank

16 Gauge (2-Conductor)

Specifications:
 Oxygen Free Copper
 Conductor AWG: 16 gauge
 Stranding: 19/29
 Insulation Nominal Wall Thickness: .025"
 Voltage: 300V
 Temperature Rating: -20°C to + 60°C
 Construction: Bare Copper Conductors; Clear PVC;
 1 Conductor Identified for Polarity
 Nominal O.D.: .105" x .205"

Applications:
 Automotive Speaker Wire, Juke Boxes,
 Stereo Speaker Wire

Part No.	Color	Length	Packaging
14-216-2F13	Clear	25 ft.	Spool
14-216-2F23	Clear	50 ft.	Spool
14-216-2F43	Clear	100 ft.	Spool
14-216-2F53	Clear	250 ft.	Spool
14-216-2F63	Clear	500 ft.	Spool
14-216-2F83	Clear	1000 ft.	Spool

14 Gauge (2-Conductor)

Specifications:
 Oxygen Free Copper
 Conductor AWG: 14 gauge
 Stranding: 19/27
 Insulation Nominal Wall Thickness: .025"
 Voltage: 300V
 Temperature Rating: -20°C to + 60°C
 Construction: Bare Copper Conductors; Clear PVC;
 1 Conductor Identified for Polarity
 Nominal O.D.: .120" x .240"

Applications:
 Automotive Speaker Wire, Juke Boxes,
 Stereo Speaker Wire

Part No.	Color	Length	Packaging
14-214-2Q23	Clear	50 ft.	Spool
14-214-2Q43	Clear	100 ft.	Spool
14-214-2Q63	Clear	500 ft.	Spool