

PRECISION ELECTRONIC SCREWDRIVERS (Cont.)



Fig. 1

Precision Electronic Screwdrivers (Cont.)

Retail Part No.	Bulk Part No.	Figure No.	Description	Blade Size	Shaft Diameter	Shaft Length	Handle Length	Overall Length
12-6414		1	Phillips Head Screwdriver	1.4 mm	2.0 mm	40 mm	S-80 mm	120 mm
12-6424		1	Phillips Head Screwdriver	2.4 mm	2.4 mm	40 mm	S-80 mm	120 mm
12-6520		1	Phillips Head Screwdriver	2.0 mm	2.0 mm	75 mm	M-95 mm	170 mm
12-6524		1	Phillips Head Screwdriver	2.4 mm	2.4 mm	75 mm	M-95 mm	170 mm
12-6525		1	Phillips Head Screwdriver	2.4 mm	2.4 mm	100 mm	M-95 mm	195 mm
12-6630		1	Phillips Head Screwdriver	3.0 mm	3.0 mm	100 mm	L-105 mm	205 mm
12-6640		1	Phillips Head Screwdriver	4.0 mm	4.0 mm	100 mm	L-105 mm	205 mm
12-6641		1	Phillips Head Screwdriver	4.0 mm	4.0 mm	150 mm	L-105 mm	255 mm

PRECISION ELECTRONIC SCREWDRIVER SETS



Fig. 2

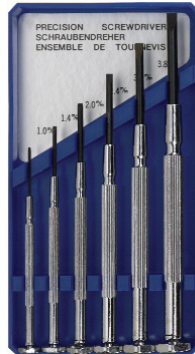


Fig. 3

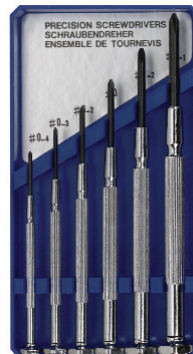



Fig. 4



Fig. 5



Fig. 6

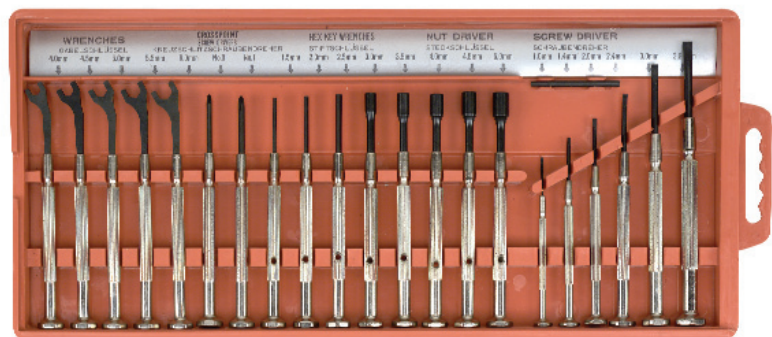

~~Fig. 7~~

Precision Electronic Screwdriver Sets

Retail Part No.	Figure No.	Flat Heads	Phillips Heads	Set Also Includes	No. of Pieces
12-043	2	0.9mm, 1.2mm, 1.8mm, 2.4mm, 3.0mm, 3.5mm			6
12-063	3	1.0mm, 1.4mm, 2.0mm, 2.4mm, 3.0mm, 3.8mm			6
12-064	4		1.6mm, 2.0mm, 2.4mm, 3.0mm, 3.5mm, 4.0mm		6
12-065	5	1.4mm, 2.0mm, 2.4mm, 3.0mm	3.0mm, 4.0mm		6
12-066	6	1.0mm, 1.2mm, 1.4mm, 1.8mm, 2.4mm, 3.0mm	2.4mm, 3.0mm, 4.0mm	Magnetic Tip, AWL	11
12-068	7	1.0mm, 1.4mm, 2.0mm, 2.4mm, 3.0mm, 3.8mm	3.0mm, 4.0mm	(*See Note Below)	21

*Includes Open Wrenches: 4.0mm, 4.5mm, 5.0mm, 5.5mm, 6.0mm; Hex Key Wrenches: 1.5mm, 2.0mm, 2.5mm; Nutdrivers: 3.0mm, 3.5mm, 4.0mm, 4.5mm, 5.0mm