


TOOLS


9000 SERIES PROFESSIONAL RATCHETING CRIMP TOOLS

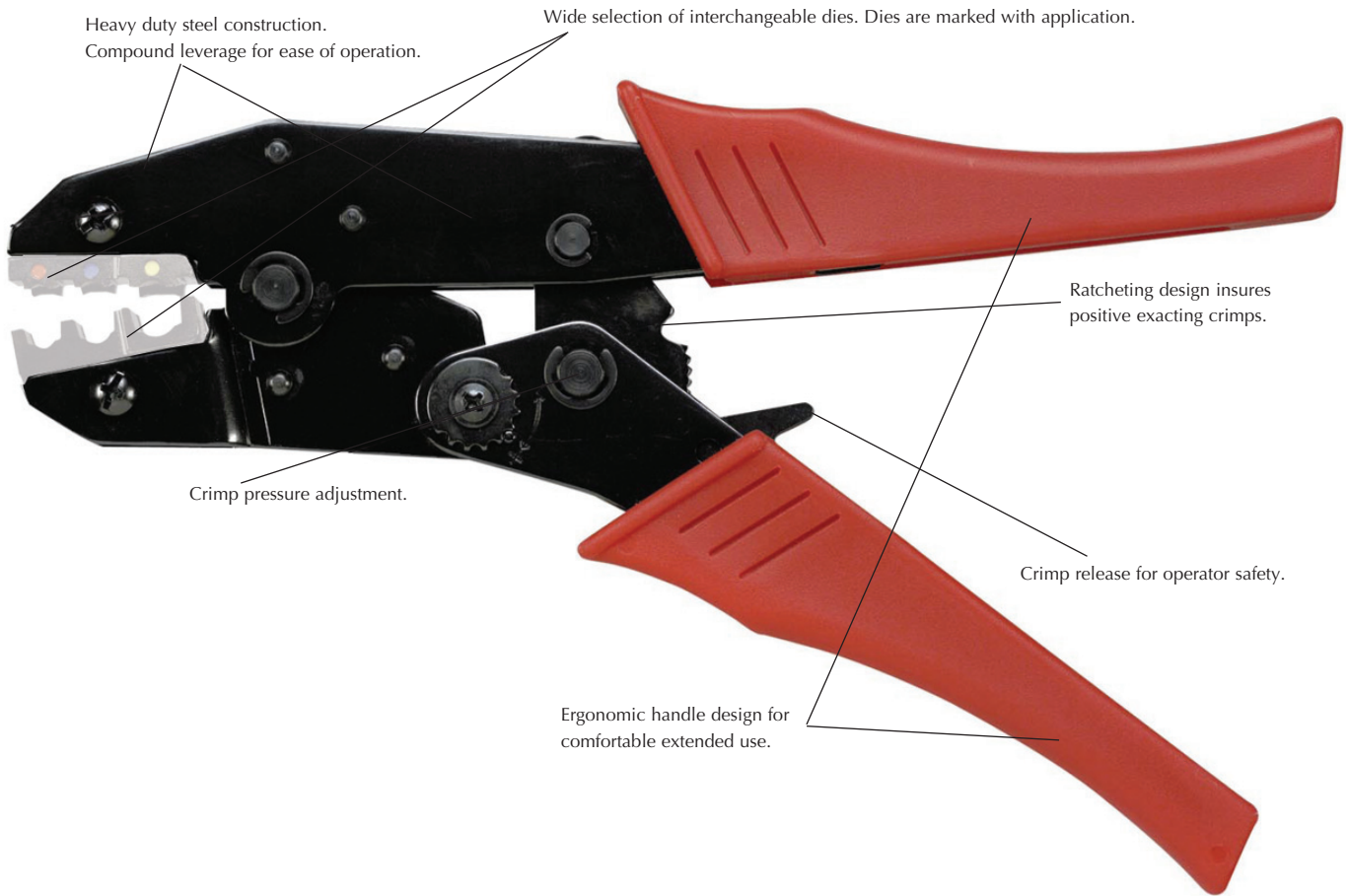


9000 Series Professional Ratcheting Crimp Tools and Die Sets

Retail Part No.	Bulk Part No.	Description	Replacement Die Set
12-9000		Heavy Duty Crimping Tool, Frame Only	All Die Sets Below
12-9001		10-22 AWG Insulated Terminals, Color Coded Nests	12-9101
12-9002		10-22 AWG Non-insulated Terminals	12-9102
12-9003		10-22 AWG Full Insulated Quick Disconnect Terminals with Thinner Wire Barrels	12-9103
12-9004		RG-58, 59/62 BNC/TNC Coaxial Connectors	12-9104
12-9005		Cambridge CP-88, CP-89, RG-58, 59/62 BNC/TNC	12-9105
12-9006		8-22 AWG Non-insulated Terminals	12-9106
12-9007		16-26 AWG Mini Insulated Rings, Spade and Butt Splices	12-9107
12-9008		Fiber Optic SMA, SMB, SFR Connectors	12-9108
12-9009		AMP Fiber Optic SMA or SFR Type Connectors	12-9109
12-9010		RG-58/174 and Belden 8218, 50 and 75 Ohm Cables	12-9110
12-9011		RG-59, RG-6, 8281 50 and 75 Ohm Cables	12-9111
12-9012		N-series RG-8/11 Connectors	12-9112
12-9013		RG-174, Mini 59 BNC/TNC Connectors	12-9113
12-9014		RG-6, RG-174, 8281 Cable	12-9114
12-9015		Twinax (Hex)	12-9115
12-9016		Plenum and Non-plenum, Thinwire also PTFE	12-9116
12-9017		AMP Thinwire Dual Crimp BNC Coaxial Connectors	12-9117
12-9018		AMP RG-58 Dual Crimp BNC/TNC Coaxial Connectors	12-9118
12-9019		AMP RG-59/62 Dual Crimp BNC/TNC Coaxial Connectors	12-9119
12-9020		Mini UHF and BNC/TNC 5 Cavity	12-9120
12-9021		RG-59, RG-6, RG-6 Quad Shield F-type CATV Connectors	12-9121
12-9022		Modular Plug RJ-45 8 Position Keyed or Non-keyed	12-9122
12-9023		Modular Plug RJ-11 2, 4, and 6 Position	12-9123
12-9024		Modular Plug DEC MMJ 6 Position with an Offset Release Tab	12-9124
12-9025		Modular Plug AMP RJ-45 8 Position/Primary Strain Relief is Located Further Back on Die	12-9125
12-9026		Modular Plug RJ-22 2 and 4 Position	12-9126

  Tools





TOOLS



9000 SERIES PROFESSIONAL RATCHETING CRIMP TOOL (Cont.)

Replacement Die Sets


Retail Part No.	Complete Tool Part	Die	Examples
12-9101	12-9001		
12-9102	12-9002		
12-9103	12-9003		
12-9104	12-9004		
12-9105	12-9005		
12-9106	12-9006		
12-9107	12-9007		
12-9108	12-9008		
12-9109	12-9009		
12-9110	12-9010		
12-9111	12-9011		
12-9112	12-9012		
12-9113	12-9013		


Replacement Die Sets (Cont.)

Retail Part No.	Complete Tool Part	Die	Examples
12-9114	12-9014		
12-9115	12-9015		
12-9116	12-9016		
12-9117	12-9017		
12-9118	12-9018		
12-9119	12-9019		
12-9120	12-9020		
12-9121	12-9021		
12-9122	12-9022		
12-9123	12-9023		
12-9124	12-9024		
12-9125	12-9025		
12-9126	12-9026		

Tools

  For the latest information—www.gcelectronics.com
 All quantities are single; BU's are packages of 10 Unless otherwise noted.





TOOLS

INSTALLER CRIMP TOOLS

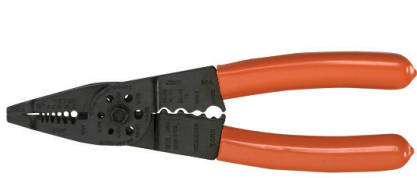


Fig. 1

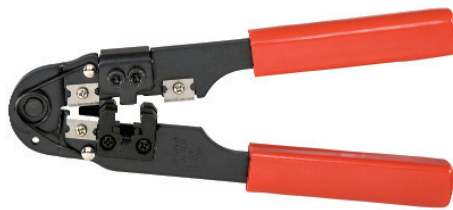


Fig. 2



Fig. 3

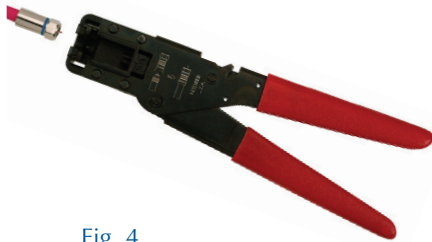


Fig. 4

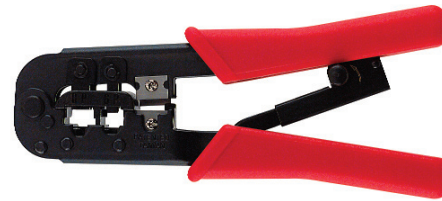


Fig. 5

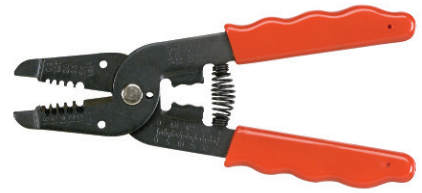


Fig. 6



Fig. 7



Fig. 8



Fig. 9



Fig. 10

 



Fig. 11

Tools

Installer Crimping Tools

Retail Part No.	Bulk Part No.	Figure No.	Description	Crimps Connector	Cable Size
8175		1	5-in-1 Crimping Tool	Solderless Terminals	Strips Wire 10-22 Gauge
12-001		2	Telco® Crimping Tools	8 Contact Professional	Telco®/Telephone Wire
12-004		2	Telco® Crimping Tools	4 & 6 Contact Professional	Telco®/Telephone Wire
12-005		2	Telco® Crimping Tools	Modular Hand Set 4 Contact	Telco®/Telephone Wire
30-9955		2	Telco® Crimping Tools	10 Contact Professional	Telco®/Telephone Wire
12-002		3	Dura Crimp	4 & 6 Contact Modular/4 Position Hand Set	
12-088		4	Standard Ratcheting Compression Tool		
12-2475		5	Dual Cut & Crimp Tool	8P8C/RJ-45, 6P4C/RJ-11 & 6P2C	
12-400		6	Crimping Tool & Terminal Asst.	Solderless Terminals	Strips 10-22 Gauge
12-450		7	Coaxial Crimp Tool	Coaxial	RG-59, RG-6, RG-11
12-454		8	Modular Crimp Tool	RJ-11, RJ-45, Modular 6 & 8 Way	Modular Line Cord
12-455		9	Crimping Tool	"F" Type & BNC	RG-58, RG-59, RG-62
12-456		10	Ratcheting Crimp Tool	Coaxial	RG-58, RG-59, RG-62, RG-6
12-459		11	Coaxial Tool Kit	Coaxial	RG-58, RG-59, RG-62, RG-6



 

TOOLS



INSTALLER CRIMP TOOLS (Cont.)



Fig. 1



Fig. 2

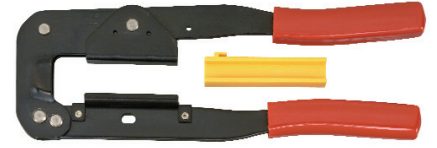


Fig. 3

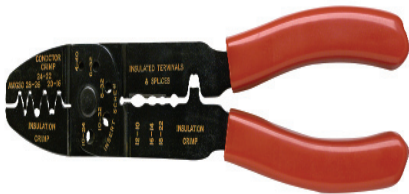


Fig. 4



Fig. 5



Fig. 6



Fig. 7



Fig. 8



Fig. 9

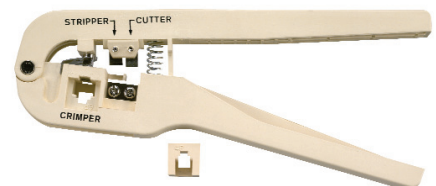


Fig. 10

Installer Crimping Tools

Retail Part No.	Bulk Part No.	Figure No.	Description	Crimps Connector	Cable Size
12-460		1	Crimping Tool	10-22 AWG & D-subminiature Contacts	
12-461		2	Coaxial Center Conductor Cutter	Dual Crimp Coaxial	
12-463		3	IDC Crimp Tool	IDC	Flat (Ribbons)
12-464		4	D-Sub/Double-D Service Tool	D-sub & Double-D High Density	
12-466		5	4-way Indent Crimper	20-26 AWG D-subminiature Contacts	
12-556		6	Compression Crimp Tool	SD-446-BU	RG-6
12-7403		7	Static Dissipative Grip Shears		Cuts Wire Up to .04"
12-7404		8	Small Blade Copper Wire Shears		Cuts Between SMD Leads
12-8800		9	Professional Quality Compression Tool	Male "F" Compression	RG-59 & RG-6
30-9951	30-9951-BU	10	Modular Crimp Tool	4 Conductor Modular & Handset	Modular Line Cord

For the latest information—www.gcelectronics.com
 All quantities are single; BU's are packages of 10 Unless otherwise noted.

