


## WIRE ACCESSORIES

### Wire & Cable Markers

Letters or numbers for identification of wiring and component location. Permanent, legible, foolproof. Made of durable, vinyl cloth markers with plastic coating. Adhesion to steel. Resistant to oil, water, abrasions. Service Temperature Rating: 40°F to 250°F. Precut to exact size. Self-adhesive backed.

Retail Part No.	Description
12-2210	Numbers 1-33
12-2211	Numbers 34-66
12-2212	Numbers 67-99
12-2213	Letters A-Z
12-9229	Kit: 3 Strips of 33, Numbers 1-99

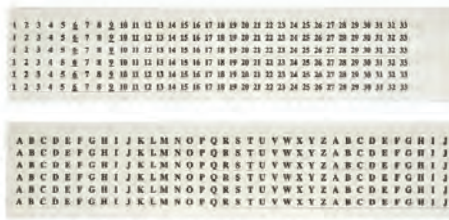

### Heat Gun

UL Listed, 115V AC

A dual range heat gun for use in heating shrink tube and drying coatings, adhesives, etc. Low temperature range setting produces a nominal 700°F (2,000 BTU's), high range 975°F (4,000 BTU's). Maximum setting draws 10 Amps, low heat draws 5 Amps. A light weight design that is easy to handle. Designed so that it may be put down to cool without a special holder.



Retail Part No.	Description
12-997	Dual range heat gun

### Flexible Heat Shrink PVC Tubing

Three Thin Wall PVC assortments of black, clear and black and clear tubing in a variety of inside diameters. The shrink ratio on this tubing is 2 to 1, it is fungus resistant and non-corrosive. It is recommended for tightly sealing connectors, tool handles and weather proofing wire splices in insulated wire or cable. It may be shrunk with heat guns, oven, etc. Refills for these assortments listed under the assortment. This tubing meets UL requirements, ASTM D-922, MIL-1-631 Grade C and MIL-1-23053, Grade 5b.

Retail Part No.	Quantity in Assortment	Retail Part No.	Quantity in Refill	Description
12-1080	23			Assortment of Thin Wall HST, as below
	4	12-1040	35	1/16 DIA X 6", Black, Thin Wall HST
	3	12-1042	32	3/32 DIA X 6", Black, Thin Wall HST
	3	12-1044	30	1/8 DIA X 6", Black, Thin Wall HST
	3	12-1046	27	3/16 DIA X 6", Black, Thin Wall HST
	2	12-1048	23	1/4 DIA X 6", Black, Thin Wall HST
	2	12-1050	30	9/32 DIA X 6", Black, Thin Wall HST
	2	12-1052	19	3/8 DIA X 6", Black, Thin Wall HST
	2	12-1054	15	1/2 DIA X 6", Black, Thin Wall HST
	1	12-1056	15	3/4 DIA X 6", Black, Thin Wall HST
	1	12-1058	10	1 DIA X 6", Black Thin Wall HST



Retail Part No.	Quantity in Assortment	Retail Part No.	Quantity in Refill	Description
12-1082	21			Assortment of Thin Wall HST, as below
	5	12-1060	30	1/16 DIA X 6", Clear, Thin Wall HST
	4	12-1062	27	3/32 DIA X 6", Clear, Thin Wall HST
	3	12-1064	25	1/4 DIA X 6", Clear, Thin Wall HST
	4	12-1066	25	5/16 DIA X 6", Clear, Thin Wall HST
	2	12-1068	20	3/8 DIA X 6", Clear, Thin Wall HST
	2	12-1070	15	5/8 DIA X 6" Clear, Thin Wall HST
	1	12-1072	10	3/4 DIA X 6" Clear, Thin Wall HST

### Heat Shrinkable Tubing Assortment

Shrinks to half its original size when heated. Use it for insulating terminals, connectors, tool handles and wire splices. Use heat gun, oven or barrel of soldering iron. Assorted sizes and colors. 6" lengths.

Retail Part No.	Quantity in Assortment	Refill Part No.	Quantity in Refill	Description
H3-462	7			Assortment of Thin Wall HST, as below
	1	12-1040	35	1/16 DIA X 6", Black, Thin Wall HST
	1	12-1052	19	3/8 DIA X 6", Black, Thin Wall HST
	1	12-1058	12	1 DIA X 6", Black, Thin Wall HST
	2	12-1062	27	1/8ID X 6", Clear, Thin Wall HST
	2	12-1064	25	1/4ID X 6", Clear, Thin Wall HST

