




# GUARDIAN Electric Manufacturing

ISO 9001 / AS9100 Certified Company

Woodstock, IL 60098 Ph. (815)334-3600 Fax (815)337-0377

Or visit us at our website [www.guardian-electric.com](http://www.guardian-electric.com)

## Model TP8 x 9 Push-Type DC Tubular Solenoid

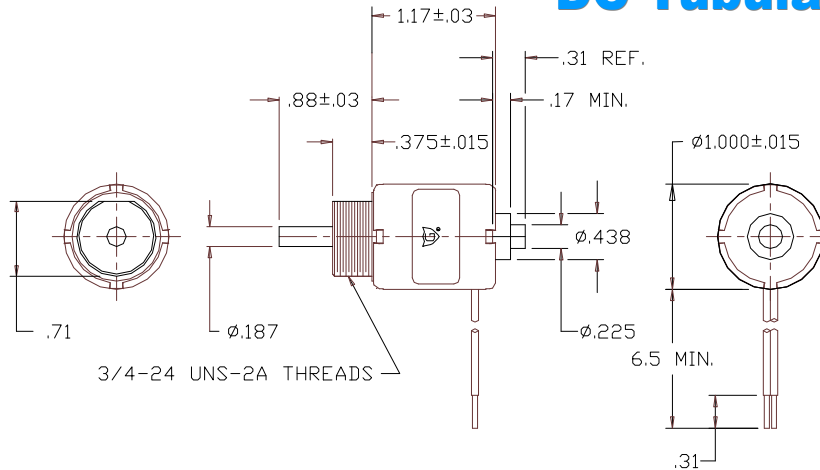

Solenoid shown energized and fully seated.

Supplied with mounting bracket, hex nut and lockwasher (not shown).

Spring kits are available (consult factory).

Total Weight: 3.46 oz.

Plunger Weight: 2.20 oz.


Model No.	Part No.	Duty Cycle	Voltage	Resistance (Ω)	Power (W)	Current
TP8x9-I-12	A420-066673-00	Intermittent	12VDC	10.9	13.9	1.1 A
TP8x9-C-12	A420-066672-00	Continuous	12VDC	35.5	4.3	338 mA
TP8x9-I-24	A420-066675-00	Intermittent	24VDC	44	13.7	545 mA
TP8x9-C-24	A420-066674-00	Continuous	24VDC	135	4.5	178 mA

When ordering, please refer to Part No., as listed above.

Consult factory for custom configurations.

Stroke (in.)	Push Force (oz.)								Holding Force (oz.)
	0.050	0.125	0.250	0.375	0.500	0.625	0.750	1.000	-
Continuous Duty	16	8	3	0.8	N/A	N/A	N/A	N/A	76
Intermittent Duty	34	24	15	5	0.8	N/A	N/A	N/A	123

### UL Recognition

Recognized under the  Component Recognition Program of **Underwriters Laboratories, Inc.**

### Continuous Duty

100% 'On' Time

### Intermittent Duty

25% 'On' Time, (100 Seconds 'On' Max. Followed By 300 Seconds 'Off' Min.)

### RoHS

These parts comply with **RoHS** Directive 2002/95/EC