

1554

Watertight Plastic - Flat Lid



Key Features

- Ideally suited for mounting printed circuit boards or DIN rail mounted components (see photo features below for details).
- ABS Versions are molded from general purpose material which carries a flammability rating of UL94-HB. For indoor use.
- Polycarbonate versions are UV stabilized for outdoor use. Gray polycarb carries a UL94-5VA rating, while clear and smoked lids carry a UL94V-0 rating.
- Polycarbonate versions are UL 508 listed (File # E65324).
- Enclosure color is a light gray (RAL 7035).
- Gasketed lid with two piece "tongue & groove" construction provides protection against access of oil, dust and water.
- Gasket is one piece made from high temperature, U.L. listed silicone.
- Designed to meet IP 66 & NEMA 4, 4X, 12 & 13 ratings.
- Lid is secured with included M4 stainless steel machine screws which are threaded into integral stainless steel bushings for repetitive assembly & disassembly. All hardware is stainless steel to avoid corrosion caused by dissimilar metals.
- Lid screws are self captivated (lid holes are threaded with the first installation of lid screws).
- Internal features are maximized for mounting options and vary with size:
 - » Internal DIN rail mounting tabs molded into most models, except sizes "C" and "D".
 - » Threaded (M3) integral brass inserts and/or standoffs (#6 self tapping screws) for P.C. board or inner panel mounting in all but the smallest size ("B").
 - » Vertical P.C. card guides (for 1.5 mm thick P.C. boards) are molded in all but the smallest size ("B").



Accessories

Inner Panels



Foot Kit



www.hammondmfg.com

USA

(716) 630-7030

Canada

(519) 822-2960

Quebec

(450) 975-1884

Europe (UK)

01256 812812

Australia

+61-8-8240-2244

1554



Watertight Plastic - Flat Lid

Available with clear or smoked lids.






Shown here with galvanized steel inner panel installed



Feet kit can be installed and locked in place either vertically or horizontally



Wall or shelf-mount through holes in the back of the enclosure (outside the gasket perimeter).

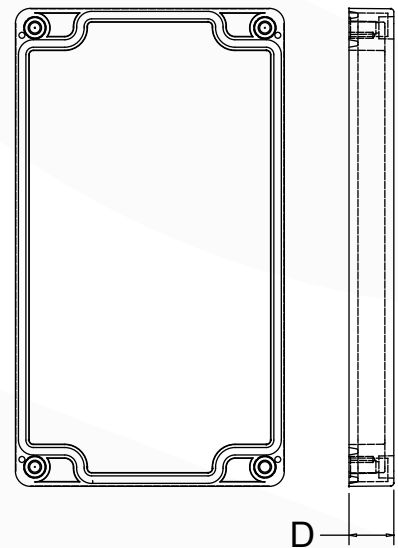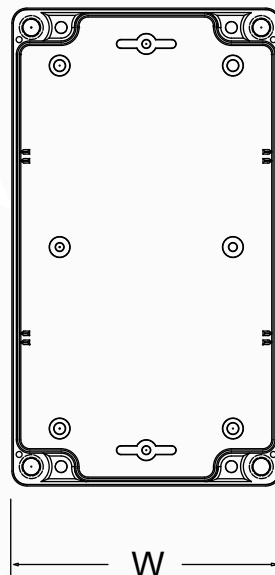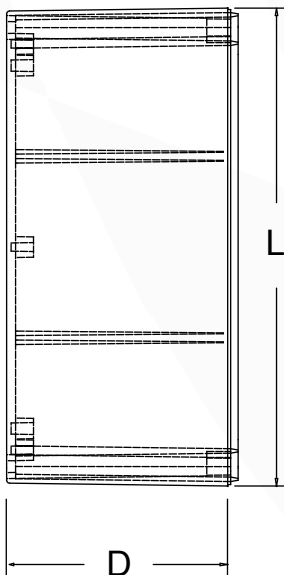

www.hammondmfg.com

USA

(716) 630-7030

Canada

(519) 822-2960

Quebec

(450) 975-1884

Europe (UK)

01256 812812

Australia

+61-8-8240-2244

1554



IP 66



Watertight Plastic - Flat Lid

ABS With Gray Lid	Polycarbonate With Gray Lid	Polycarbonate With Clear Lid	Polycarbonate With Smoked Lid	Lid Screws	Units	Length (L)	Width (W)	Total Height (D+D)	Inner Panel	Foot Kit	Replacement Gasket
1554BGY	1554B2GY	1554B2GYCL	1554B2GYSL	4	in mm	2.6 65	2.6 65	1.6 40	1554BPL	1554FT	1554BGASKET
1554EGY	1554E2GY	1554E2GYCL	1554E2GYSL	4	in mm	3.5 90	3.5 90	2.4 60	1554EPL	1554FT	1554EGASKET
1554EEGY	1554EE2GY	1554EE2GYCL	1554EE2GYSL	4	in mm	3.5 90	3.5 90	90.5 3.56	1554EPL	1554FT	1554EGASKET
1554CGY	1554C2GY	1554C2GYCL	1554C2GYSL	4	in mm	4.7 120	2.6 65	1.6 40	1554CPL	1554FT	1554CGASKET
1554DGY	1554D2GY	1554D2GYCL	1554D2GYSL	4	in mm	4.7 120	2.6 65	2.4 60	1554CPL	1554FT	1554CGASKET
1554FGY	1554F2GY	1554F2GYCL	1554F2GYSL	4	in mm	4.7 120	3.5 90	2.4 60	1554FPL	1554FT	1554FGASKET
1554GGY	1554G2GY	1554G2GYCL	1554G2GYSL	4	in mm	4.7 120	3.5 90	3.15 80	1554FPL	1554FT	1554FGASKET
1554NGY	1554N2GY	1554N2GYCL	1554N2GYSL	4	in mm	4.7 120	4.7 120	2.4 60	1554NPL	1554FT	1554NGASKET
1554PGY	1554P2GY	1554P2GYCL	1554P2GYSL	4	in mm	4.7 120	4.7 120	3.15 80	1554NPL	1554FT	1554NGASKET
1554JGY	1554J2GY	1554J2GYCL	1554J2GYSL	4	in mm	6.3 160	3.5 90	2.4 60	1554JPL	1554FT	1554JGASKET
1554KGY	1554K2GY	1554K2GYCL	1554K2GYSL	4	in mm	6.3 160	3.5 90	3.5 90	1554JPL	1554FT	1554JGASKET
1554RGY	1554R2GY	1554R2GYCL	1554R2GYSL	4	in mm	6.3 160	6.3 160	2.4 60	1554RPL	1554FT	1554RGASKET
1554SGY	1554S2GY	1554S2GYCL	1554S2GYSL	4	in mm	6.3 160	6.3 160	3.5 90	1554RPL	1554FT	1554RGASKET
1554HGY	1554H2GY	1554H2GYCL	1554H2GYSL	4	in mm	7.1 180	4.7 120	2.4 60	1554HPL	1554FT	1554HGASKET
1554TGY	1554T2GY	1554T2GYCL	1554T2GYSL	4	in mm	7.1 180	4.7 120	3.5 90	1554HPL	1554FT	1554HGASKET
1554UGY	1554U2GY	1554U2GYCL	1554U2GYSL	4	in mm	7.9 200	4.7 120	3.5 90	1554UPL	1554FT	1554UGASKET
1554VGY	1554V2GY	1554V2GYCL	1554V2GYSL	4	in mm	9.4 240	6.3 160	3.5 90	1554VPL	1554FT	1554VGASKET
1554VAGY	1554VA2GY	1554VA2GYCL	1554VA2GYSL	6	in mm	9.4 240	6.3 160	3.5 90	1554VAPL	1554FT	1554VAGASKET
1554VBGY	1554VB2GY	1554VB2GYCL	1554VB2GYSL	6	in mm	9.4 240	6.3 160	4.7 120	1554VAPL	1554FT	1554VAGASKET
1554XGY	1554X2GY	1554X2GYCL	1554X2GYSL	6	in mm	11.81 300	7.87 200	3.54 90	1554XPL	1554FT	1554XGASKET
1554XAGY	1554XA2GY	1554XA2GYCL	1554XA2GYSL	6	in mm	11.81 300	7.87 200	4.72 120	1554XPL	1554FT	1554XGASKET
1554YGY	1554Y2GY	1554Y2GYCL	1554Y2GYSL	6	in mm	11.81 300	9.45 240	3.74 95	1554YPL	1554FT	1554YGASKET
1554YAGY	1554YA2GY	1554YA2GYCL	1554YA2GYSL	6	in mm	11.81 300	9.45 240	4.72 120	1554YPL	1554FT	1554YGASKET



www.hammondmfg.com

USA

(716) 630-7030

Canada

(519) 822-2960

Quebec

(450) 975-1884

Europe (UK)

01256 812812

Australia

+61-8-8240-2244