


Four Post Fixed Depth Shelf

Features

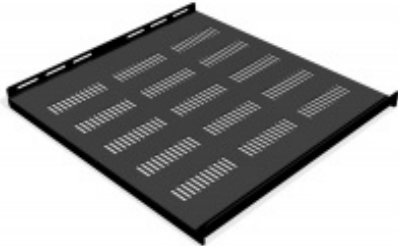

- Constructed of heavy duty 14 gauge steel.
- Front & rear lip folded for extra strength.
- Versatile design can be used upside down (front & rear lip become equipment retainers).
- Sides folded up for easy hardware installation from above.
- Sides are slotted for easy adjustment with most rail depth locations.
- Rugged textured powder paint finish.
- Tested to nearly double the suggested load rating of 350 lbs.
- Includes all mounting hardware.
- Manufactured in North America.

Please note that to mount this product you need to have two (2) pairs of [combination rails](#) within your cabinet. This product does not mount to the front and back of the rails like traditional rack mounting shelves. If used with our [CPR square hole rails](#) you will need to order [CPRSA rail adaptor](#) for each shelf ordered.

Solid Part No.	Vented Part No.	Shelf Depth
RFUS1918BK1	RFVS1918BK1	18.00
RFUS1921BK1	RFVS1921BK1	21.00
RFUS1926BK1	RFVS1926BK1	26.00
RFUS1931BK1	RFVS1931BK1	31.00

Data subject to change without notice.