

## Type 3R Mild Steel Metering Cabinets *C3RMC Series*

Hinge Door with Handle



### Application

- Designed for outdoor housing of metering transformers.

### Standards

- CSA Approved, Type 3R
- Complies with
  - NEMA Type 3R
  - IEC 60529, IP24

### Construction

- Formed and seam welded from 14 or 16 gauge steel.
- Smooth, continuously welded seams ground smooth.
- Formed lip on enclosure to exclude flowing liquids and contaminants.
- Padlockable "L" style handle.
- Oil resistant gaskets are permanently secured.
- Removable inner panel included.
- Collar studs provided for mounting inner panel.
- Doors may be easily removed for modifications and are interchangeable.
- Bonding stud provided on door and grounding stud installed in enclosure.
- Hinges are constructed from 304 stainless steel.
- Hinge pins are stainless steel.


### Finish

- Cover and enclosure are phosphatized and finished with a recoatable ANSI 61 smooth Gray powder inside and out.
- Removable inner panel is finished in white powder coating.


### Accessories

- Door Stop Kit
- Mounting Foot Kit
- Drip Shield Kit


# Single Door

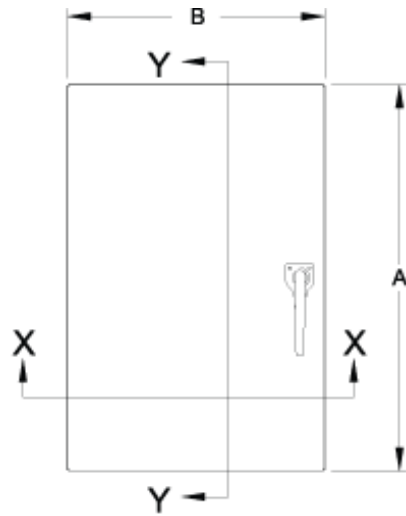

**Front View**

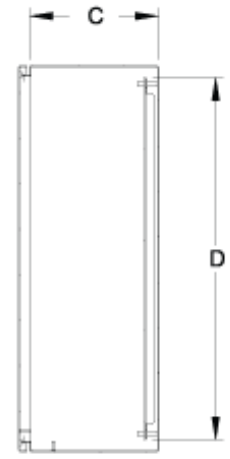


**Section Y-Y**

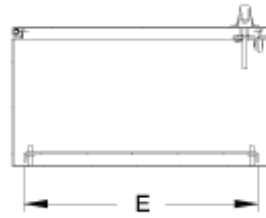

**Section X-X**


# Double Door

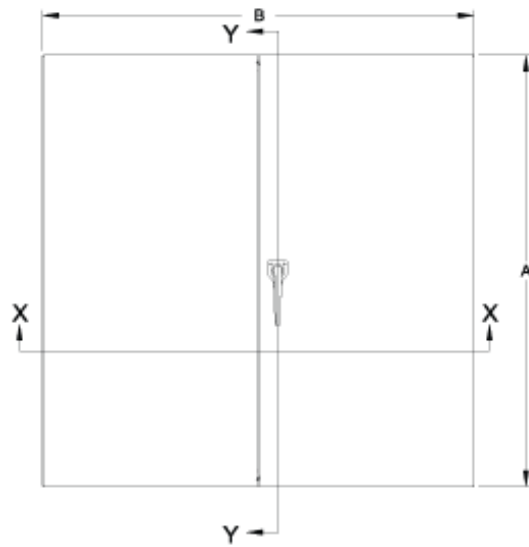

**Front View**



**Section Y-Y**

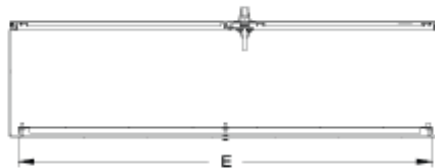

**Section X-X**

Part No.	Overall Dimensions			Panel Dimensions		Type of Door	Ship Wt. Lbs
	A	B	C	D	E		
C3RMC202010	20.00	20.00	10.00	18.17	18.17	Single	42

Part No.	Overall Dimensions			Panel Dimensions		Type of Door	Ship Wt. Lbs
	A	B	C	D	E		
<b>C3RMC271310</b>	27.00	13.00	10.00	25.17	11.17	Single	38
<b>C3RMC302010</b>	30.00	20.00	10.00	28.17	18.17	Single	69
<b>C3RMC303010</b>	30.00	30.00	10.00	28.17	28.17	Double	92
<b>C3RMC363612</b>	36.00	36.00	12.00	34.17	34.17	Double	131
<b>C3RMC484812</b>	48.00	48.00	12.00	46.17	46.17	Double	210

*Data subject to change without notice*

© 2015. Hammond Manufacturing Ltd. All rights reserved.