



Quality Products. Service Excellence.

Type 12 Modular Dust-Tight Equipment Cabinet C3 Series

Note: This product line has been discontinued as a stocked series. Information is for reference only. For alternative solution assistance, please **contact Hammond here** or call: USA (716) 630-7030, Canada and International (519) 822-2960.




Features

- NEMA 12 rated - ideal for use in harsh factory floor situations.
- Oil resistant gaskets are permanently secured on all openings.
- Sides and doors (link provided below) are easily removable for easy internal access.
- Choice of two depths.
- Unit is shipped as a welded frame only with four (4) leveling feet.
- Heavy duty 14 gauge welded steel frame.
- Frame ships with reinforced lifting eyes.
- Finished in a rugged, beige textured powder paint.
- Tested to nearly double the suggested load rating of 1,500 lbs.
- RoHS Compliant.
- Manufactured in North America.



Gallery

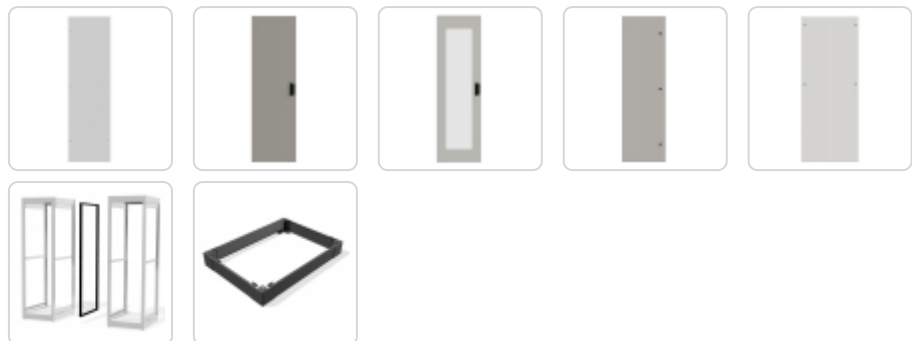

Accessories

- Side Panel Locking Kit
- Adjustable Depth 4-Post Rack Mount Shelf
- Sliding Keyboard Shelf
- Outlet Strips
- Horizontal Ring Cable Manager
- Horizontal Lacing Strip
- Cable Management Arm
- Vertical Cable Tray
- Grounding
- Climate Control
- Universal Rack Shelf
- Rack Mount Locking Storage Drawer
- Four Post Mounting Sliding Shelf
- Rack Unit Label
- Adjustable Depth Cable Manager
- Horizontal Hinged Cable Manager
- Horizontal Steel Finger Cable Manager
- Mounting Hardware
- Rack Panels



C3 Frames

Part No.	Overall Dimensions			Usable Mounting Dimensions		Side Panel Rack (Pair)		Tapped 10-32 Comination Rail	Square Hole L-Panel Rail
	Height	Width	Depth	Height	Depth	Units	Part No.	Part No.	Part No.
C3F196323CG1	70.31	23.00	23.63	63.06	21.63	36U	C3SP6323CG1	CCR63TZPL	CPR63SZPL
C3F197023CG1	77.31	23.00	23.63	70.06	21.63	40U	C3SP7023CG1	CCR70TZPL	CPR70SZPL
C3F197823CG1	86.06	23.00	23.63	78.81	21.63	45U	C3SP7823CG1	CCR78TZPL	CPR78SZPL
C3F196331CG1	70.31	23.00	31.50	63.06	29.50	36U	C3SP6331CG1	CCR63TZPL	CPR63SZPL
C3F197031CG1	77.31	23.00	31.50	70.06	29.50	40U	C3SP7031CG1	CCR70TZPL	CPR70SZPL
C3F197831CG1	86.06	23.00	31.50	78.81	29.50	45U	C3SP7831CG1	CCR78TZPL	CPR78SZPL

C3 Doors

Solid Door With Handle	Solid Door With Quarter Turn	Window Door	Solid Cover	Use with Cabinet Frame	
Part No.	Part No.	Part No.	Part No.	Rack Units	Height
C3DS1963HCG1	C3DS1963QCG1	C3DS1963PCG1	C3CS1963SCG1	36U	63.00
C3DS1970HCG1	C3DS1970QCG1	C3DS1970PCG1	C3CS1970SCG1	40U	70.00
C3DS1978HCG1	C3DS1978QCG1	C3DS1978PCG1	C3CS1978SCG1	45U	78.75

C3 Accessories

Baying Kit Beige	Bottom Plinth Black	Bottom Plinth Beige	Caster Kit	Use with Cabinet Frame		
Part No.	Part No.	Part No.	Part No.	Rack Units	Height	Depth
C3JK6323	CPL19423BK1	CPL19423CG1	C3CRS19	36U	63.00	23.63
C3JK7023	CPL19423BK1	CPL19423CG1	C3CRS19	40U	70.00	23.63
C3JK7823	CPL19423BK1	CPL19423CG1	C3CRS19	45U	78.75	23.63
C3JK6331	CPL19431BK1	CPL19431CG1	C3CRS19	36U	63.00	31.50
C3JK7031	CPL19431BK1	CPL19431CG1	C3CRS19	40U	70.00	31.50
C3JK7831	CPL19431BK1	CPL19431CG1	C3CRS19	45U	78.75	31.50

Data subject to change without notice

© 2019. Hammond Manufacturing Ltd. All rights reserved.