

ABBATRON

Premier Supplier of Electronic Hardware

HH Smith

Custom Capabilities | Test Accessories | Plugs, Jacks, Posts | Connectors | Hardware | Spacers/Standoffs

- [Home](#)
- [About](#)
- [Abbatron](#)
- [Products](#)
- [Locate](#)
- [Distributor](#)
- [or](#)
- [Representative](#)
- [Contact Us](#)
- [Request](#)
- [Information](#)
- [Site Map](#)

Insulated Binding Posts

- Post head is molded Lexan Polycarbonate, hex or fluted. Captivated to prevent loss.
- Body is brass with gold or tin plating as indicated.
- Insulated washers are molded polycarbonate and completely insulate post from panel. Keyed to panel and body to prevent rotation.
- Body mounts in 3/8" or 1/2" round or "D" hole for rotation.
- Connects with .080" phone tip plug, 1/4" spade lug, standard banana plug, alligator clip or wire. To connect circuit wrap wire around solder turret or attach to solder lug between nuts.
- All posts shown here are available in standard red(-102) or black(-103) Other colors are available from factory. Please add color to part number as suffix.

[More information on binding posts](#)



Inventory Search


Cross Reference

UPS Tracking

632 Arch Street, POB
726 Meadville, PA
16335 USA 814-724-
6440

[Contact Webmaster](#)

© June 6, 2005

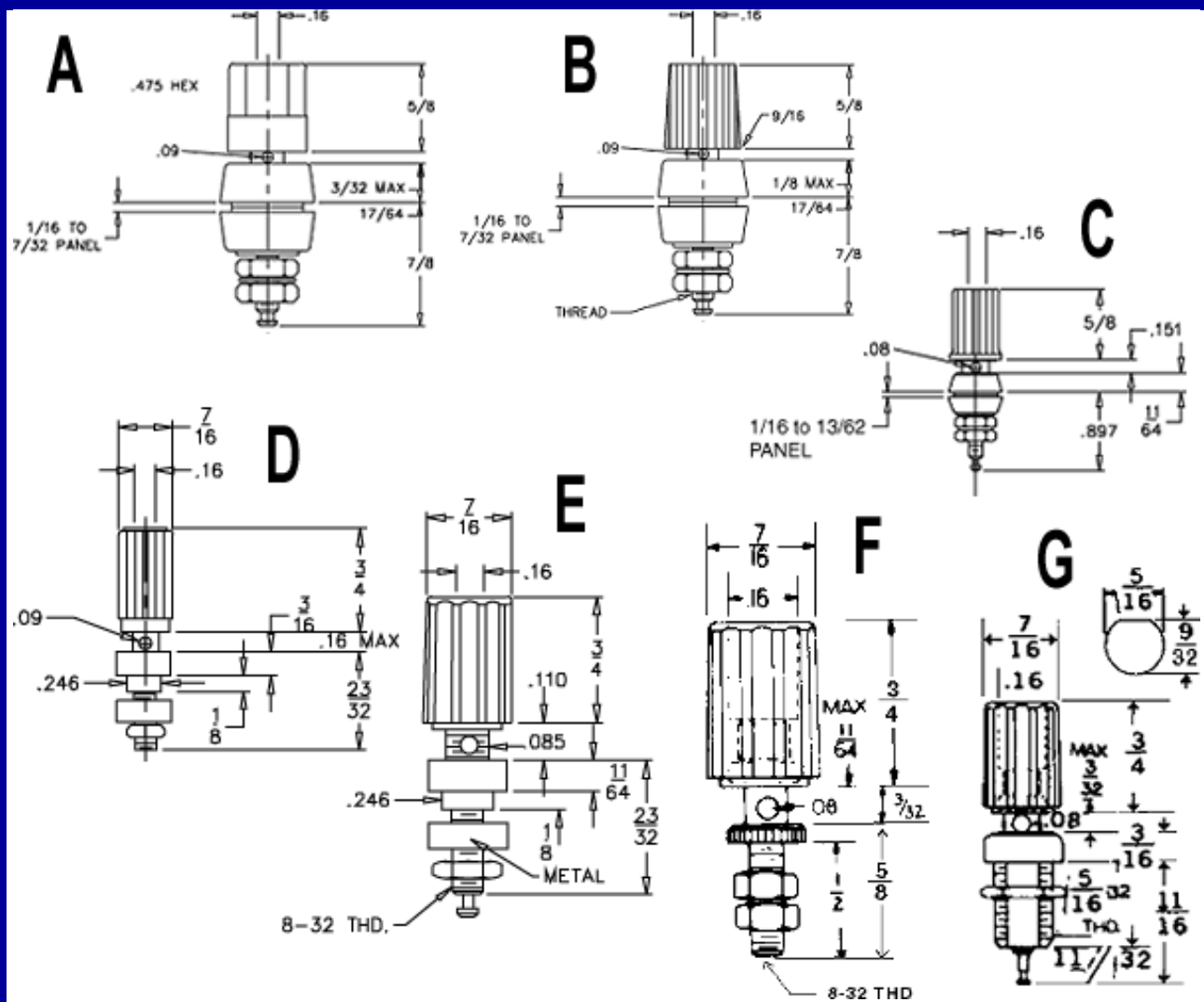

PART NO.	FIG.	HEAD SHAPE	POST THREAD	PLATING
257	A	Hex	10-32	Gold
257N			8-32	
899			10-32	Tin
899N			8-32	
459	B	Fluted	10-32	Gold
459N			8-32	
799			10-32	Tin
799N			8-32	
1275	C	Fluted	6-32	Tin
1275N			8-32	
1517			6-32	Gold
1514			8-32	

PART NO.	FIG.	MNTG HOLE	POST THREAD	WASHER	PLATING
1480	A	1/4	8-32	Insulating	Nickel
1481	B			Grounding	
1482	C			None	
1463	D	5/16	8-32	Insulating	Tin
1464	D	5/16 "D"	8-32		