




SwivelLok®
Multi-Position
Liquidtight Connector

HUBBELL

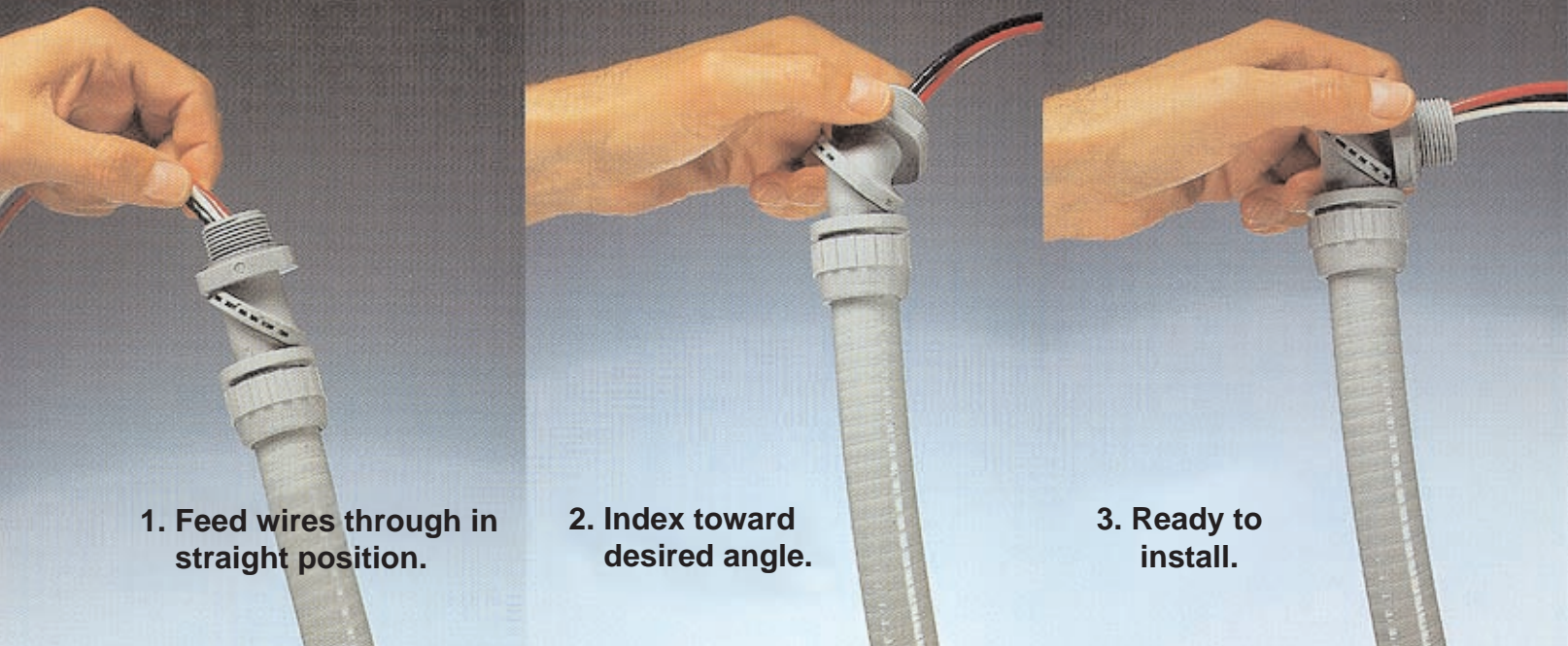

1. Feed wires through in straight position.

2. Index toward desired angle.

3. Ready to install.

With the introduction of a 3/8" version, enhanced SwivelLok® multi-position liquidtight connectors are now available in 3/8", 1/2", 3/4" and 1" sizes in both gray and black nylon. When teamed with PolyTuff® I flexible liquidtight nonmetallic conduit or PolyTuff® II flexible liquidtight nonmetallic tubing, it becomes the *SwivelLok® system*. Now there's **one** connector that can handle any angle from 0° to 90°. Easily feed the conductors through

the SwivelLok® connector in the straight position and then simply swivel it to the desired angle. No need to spend time forcing wires through 45° and 90° connectors, one SwivelLok® connector can handle all your liquidtight applications. SwivelLok® connectors—innovation, quality and performance in one liquidtight connector system engineered to save time and installed cost.

Features

- Swivels into any position between straight and 90 degrees.
- Indexes every 15 degrees when twisted.
- Smooth ferrule.
- Multiple position capability.
- Meets same UL and CSA performance standards as all Hubbell liquidtight fittings.


Benefits

- Saves time by feeding wires through straight, then twisting to desired position. No more fishing wires through 90 degree connectors. Same fitting may be used in any desired position.
- Easy position selection.
- Eliminates threading on at installation. Saves time. Provides superior conduit pull-out retention.
- Less inventory and broader application capacity.
- High reliability.



Ordering Information			Dimensional Chart							
Catalog Number	Size	Color	Catalog Number	Trade Size	A	B	C	D	E	F
PS0389NGY	3/8"	GRAY	PS0389NGY				A/C*	A/F*		
PS0509NGY	1/2"	GRAY	PS0389NBK	3/8"	3.268	.569	1.406	1.298	1.300	1.426 1.998
PS0759NGY	3/4"	GRAY	PS0509NGY							
PS1009NGY	1"	GRAY	PS0509NBK	1/2"	3.268	.569	1.406	1.298	1.300	1.426 1.998
PS0389NBK	3/8"	BLACK	PS0759NGY							
PS0509NBK	1/2"	BLACK	PS0759NBK	3/4"	3.659	.581	1.650	1.525	1.525	1.593 2.229
PS0759NBK	3/4"	BLACK	PS1000NGY							
PS1009NBK	1"	BLACK	PS1009NBK	1"	3.996	.718	1.937	1.798	1.798	1.838 2.296

A/C = Across corners, A/F = Across flats

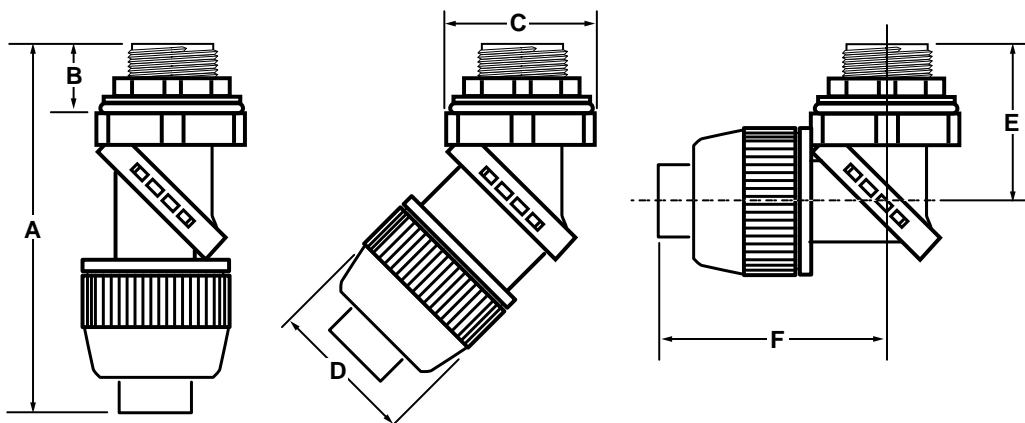

SwivelLok Connectors...Make it a System

When teamed with PolyTuff I flexible liquidtight nonmetallic conduit or PolyTuff II flexible liquidtight nonmetallic tubing, it becomes the *SwivelLok System*. Add straight, 90 degree or SwivelLok connectors where applicable to make PolyTuff nonmetallic conduit or tubing the choice for any job. PolyTuff liquidtight systems: the system you want to connect with.

Systems Ordering Information

Trade Size	Polytuff I Gray Conduit	Straight Gray Connectors	90° Gray Connectors	PolyTuff II Black Tubing	Straight Black Connectors	90° Black Connectors
1/4"	-	-	-	B2025	F2025	F20259
3/8"	G1038	P038NGYA	PS0389NGY*	B2038	P038NBKA	PS0389NBK*
1/2"	G1050	P050NGYA	PS0509NGY*	B2050	P050NBKA	PS0509NBK*
3/4"	G1075	P075NGYA	PS0759NGY*	B2075	P075NBKA	PS0759NBK*
1"	G1100	P100NGYA	PS1009NGY*	B2100	P100NBKA	PS1009NBK*
1 1/4"	G1125	P125NGY	P1259NGY	B2125	P125NBK	P1259NBK
1 1/2"	G1150	P150NGY	-	B150NBK	B150NBK	-
2"	G1200	P200NGY	-	B2200	P200NBK	-

*SwivelLok Connector



Wiring Device - Kellems

Hubbell Incorporated (Delaware) • 185 Plains Road • Milford, CT 06460-2420 • (203) 882-4800 • FAX (800) 255-1031
World Wide Web URL: <http://www.hubbell-wiring.com>

Worldwide Locations

Hubbell Canada (905) 839-1138, Fax (905) 839-9108
Hubbell Ltd. England (441) 234-85444, Fax (441) 234-854008
Hubbell-Taian Co., Ltd., (886) 2 567-5995, Fax (886) 2 567-4853
Hubbell Int'l. Inc., Korea Branch (82) 2 607-1362, Fax (82) 2 603-7386

Hubbell de Mexico, S.A. de C.V. (52) 5 575-2022, Fax (52) 5 559-8626
Caribe Sales Agencies, Puerto Rico (809) 720-7185, Fax (809) 789-2796
Hubbell S.E. Asia Pte., Ltd., (65) 382-1600, Fax (65) 382-3727
Hubbell Inc. Middle East (971) 4 369-763, Fax (971) 4 360-541