


# SECTION L



## Table of Contents




### HBL® Extra Heavy Duty Industrial Series

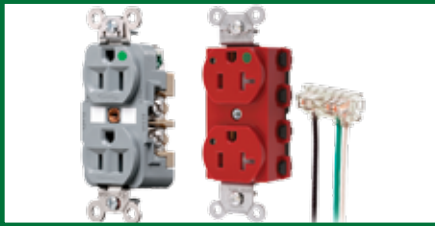

### Industrial and Commercial Series GFCIs



### Surge Protection Devices

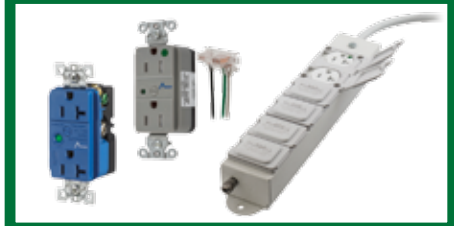

Product	Page
HBL® Extra Heavy Duty Hospital Grade Duplex Receptacles	
Products at a Glance	L-2
Features and Benefits	L-3
Duplex and Style Line® Decorator	L-4
SNAPConnect® Receptacles	L-5
Hubbell-PRO Receptacles	L-8
USB Charger Receptacles	L-10
Single and 4-PLEX® Receptacles	L-10
Hospital Grade Plugs, Connector Bodies and Receptacles	
15 and 20A, 125V	L-11
15 and 20A, 250V	L-11

Product	Page
Extra Heavy Duty Industrial GFCI Receptacles	L-12
Commercial GFCI Receptacles	
Tamper-Resistant	L-13
Tamper-Resistant and Weather Resistant	L-14
Standard	L-15
Hospital Grade Surge Protection Devices	L-16
Hubbelock® Plugs, Connectors and Receptacles	L-17
Hubbelock® Mobile X-Ray Devices	L-18



## Products at a Glance



### HBL® Extra Heavy Duty Hospital Grade

- Hospital Grade with green dot symbol
- One-piece nickel-plated integral ground strap
- ID marking surface for quick circuit identification
- Square head, 10-thread bronze center rivet
- Deep nylon body design increases impact and chemical resistance



### Extra Heavy Duty SNAPConnect®

- Hospital and Specification Grade
- Tamper-Resistant, NOT Plug Resistant™
- Power indicating LED
- Steel mounting strap, self-grounding
- Compact size requires minimal space



### Hubbell-PRO Heavy Duty

- Hospital and Specification Grade
- Tamper-Resistant, NOT Plug Resistant™
- Power LED feature
- Circuit ID marking area
- Steel mounting strap, self-grounding
- Assembled in USA



### USB Charger Receptacles

- Two Type-C, Type A&C and Type A port configurations, high power 5 Amp, 5 Volt USB output
- Heavy duty stainless steel USB ports; rated for 10,000 cord insertions and removals
- Patented Hubbell Tamper-Resistant technology uses cam action shutters. The friction-free design of the mechanism's doors requires much less force
- Available in SNAPConnect®



### 4-PLEX Receptacles

- Hospital Grade and Surge
- Mounts directly to 4-inch square box
- "A" and "B" circuit ID molded into face
- Removable knockouts for mounting to octagon concrete ring or box
- Heavy duty, triple wipe, brass power and ground contacts



### SpikeShield® Surge Suppression Plug Strips

- UL2930 HCOA's
- UL1449 SPD's available
- 15A and 20A versions
- 6 foot or 15 foot cords available
- USB versions in several models



### Hubbellock® Devices

- Nylon cover, thermoset interior
- Armored, epoxy filled, rubber cord grip
- Black, back wired
- Mobile X-Ray devices



## Features and Benefits

### Hubbell “Hospital Grade” Devices

UL requirements for Hospital Grade devices is more stringent than those for standard devices. Hubbell receptacles are designed to meet and exceed the standards.

- Exclusive nickel-plated bypass contact design increases contact pressure, lowering the operating temperature.
- Four point grounding system provides redundant grounding for low resistance ground continuity in high abuse areas.
- High tech reinforced thermoplastic polyester (RTP) back is tough and heat resistant.

Because of these features and others, the benefit is performance, reliability, and value for any health care facility.



**HBL8200GY**




#### Housing Design

- Reinforced thermoplastic base provides superior thermal, electrical and mechanical properties
- Providing contact stability, this high performance material will reduce heat buildup giving you long lasting performance
- Deep body design increases impact and chemical resistance




#### Terminals

- External wiring clamps allow for visual inspection of the terminals
- Unique strand containment feature on the terminal “bundles” the wire, ensuring 100% clamping of wire strands and reducing heat from the termination

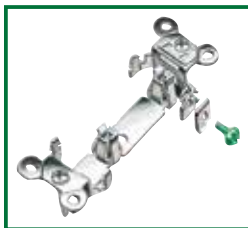

#### One-Piece Mounting Strap

- Back wired ground terminal allows faster, easier installation
- One-piece nickel-plated brass integral ground strap for greater corrosion resistance
- Patented ground contact provides redundant grounding

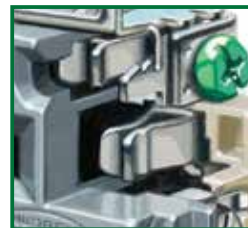

#### Contacts

- Exclusive bypass contacts are made of nickel-plated brass alloy, increasing blade retention, insuring reliable uninterrupted flow of power
- Barbed assembly arms reduce possibility of face/base separation




#### Identification

- I.D. marking surface provides quick, sure circuit identification
- All Hospital Grade devices are marked with the green dot symbol, required by UL




#### Center Rivet


- Square head, 10-thread bronze center rivet won't rotate, reduces stripping and resists corrosion

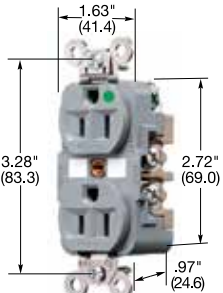


**HBL8200GY**

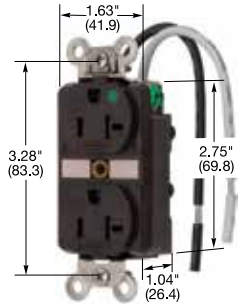


**HBL8300SGA**

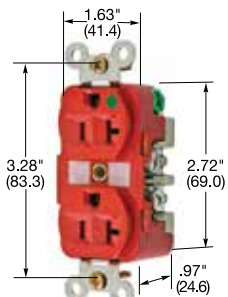

**HBL8300RMRI**

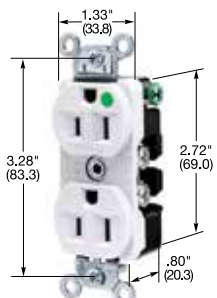

**HBL8200ILW**

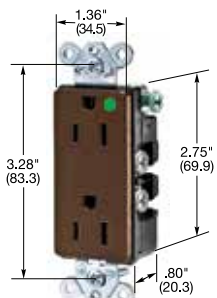

**HBL2172**

Dimensions in Inches (mm)

**IP20**  
SUITABILITY



**15A 125V**  
NEMA 5-15R  
UL CSA  
0.5 HP



**20A 125V**  
NEMA 5-20R  
UL CSA  
1 HP

## HBL® Extra Heavy Duty Hospital Grade Receptacles

### Duplex

Description	Color	Catalog Number	
Flush, thermoplastic polyester face, back and side wired.	Black	<b>HBL8200BK</b>	-
	Blue	-	<b>HBL8300BL</b>
	Brown	<b>HBL8200</b>	<b>HBL8300</b>
	Gray	<b>HBL8200GY</b>	<b>HBL8300GY</b>
	Ivory	<b>HBL8200I</b>	<b>HBL8300I</b>
	Light Almond	<b>HBL8200LA</b>	<b>HBL8300LA</b>
	Red	<b>HBL8200RED</b>	<b>HBL8300RED</b>
	White	<b>HBL8200W</b>	<b>HBL8300W</b>
Flush, LED illuminated face, back and side wired.	Gray	<b>HBL8200ILGY</b>	<b>HBL8300ILGY</b>
	Ivory	<b>HBL8200ILI</b>	<b>HBL8300ILI</b>
	Red	<b>HBL8200ILR</b>	<b>HBL8300ILR</b>
	White	<b>HBL8200ILW</b>	<b>HBL8300ILW</b>
Tamper-Resistant receptacle with wire leads. Complies with requirements of NEC® article 517-18(c).	Brown	<b>HBL8200SGA</b>	<b>HBL8300SGA</b>
	Gray	<b>HBL8200SGGYA</b>	<b>HBL8300SGGYA</b>
	Ivory	<b>HBL8200SGIA</b>	<b>HBL8300SGIA</b>
	Light Almond	<b>HBL8200SGLA</b>	<b>HBL8300SGLA</b>
	Red	<b>HBL8200SGRA</b>	<b>HBL8300SGRA</b>
	White	<b>HBL8200SGWA</b>	<b>HBL8300SGWA</b>
Isolated ground <sup>A</sup> .	Orange	<b>IG8200</b>	<b>IG8300</b>
	Red	<b>IG8200R</b>	<b>IG8300R</b>

### MRI Receptacle, Duplex

Description	Color	Catalog Number	
MRI receptacle, flush, thermoplastic polyester face, back and side wired.	Ivory	<b>HBL8200IMRI</b>	<b>HBL8300IMRI</b>
	Light Almond	<b>HBL8200LAMRI</b>	<b>HBL8300LAMRI</b>
	Red	<b>HBL8200RMRI</b>	<b>HBL8300RMRI</b>
	White	<b>HBL8200WMRI</b>	<b>HBL8300WMRI</b>

### Slender/Compact, Duplex

Description	Color	Catalog Number	
Flush, thermoplastic polyester face, back, and side wired. Fed. Spec. verified.	Brown	<b>HBL8200H</b>	<b>HBL8300H</b>
	Gray	<b>HBL8200HG</b>	<b>HBL8300HG</b>
	Green	-	<b>HBL8300HGN</b>
	Ivory	<b>HBL8200HI</b>	<b>HBL8300HI</b>
	Light Almond	<b>HBL8200HLA</b>	<b>HBL8300HLA</b>
	Red	<b>HBL8200HRED</b>	<b>HBL8300HRED</b>
	White	<b>HBL8200HW</b>	<b>HBL8300HW</b>

### Style Line® Decorator\*

Description	Color	Catalog Number	
Flush, nylon face, back and side wired.	Brown	<b>HBL2172</b>	<b>HBL2182</b>
	Gray	<b>HBL2172GY</b>	<b>HBL2182GY</b>
	Ivory	<b>HBL2172I</b>	<b>HBL2182I</b>
	Office White	-	<b>HBL2182OW</b>
	Red	<b>HBL2172R</b>	<b>HBL2182R</b>
	White	<b>HBL2172WA</b>	<b>HBL2182WA</b>
Isolated ground <sup>A</sup> .	Ivory	-	<b>IG2182I</b>
	Orange	-	<b>IG2182</b>
	White	-	<b>IG2182WA</b>

Note: <sup>A</sup>See section M for additional information on isolated ground devices.

\*Not Fed. Spec. Listed.

See pages A-48 and A-49 for accessories.

See page Tech-10 for Tamper-Resistant description.

See section N for wallplates.

NEC® is a registered trademark of the National Fire Protection Association (NFPA).



**IP20**  
SUITABILITY



**15A 125V**  
NEMA 5-15R  
UL CSA  
0.5 HP




**20A 125V**  
NEMA 5-20R  
UL CSA  
1 HP


## Extra Heavy Duty Hospital Grade ● SNAPConnect®

### Duplex


Description	Color	Catalog Number	Catalog Number
Hospital grade, finder groove, nylon face, modular receptacle which requires pigtailed connector below.	Black	<b>SNAP8200BKA</b>	<b>SNAP8300BKA</b>
	Brown	<b>SNAP8200A</b>	<b>SNAP8300A</b>
	Gray	<b>SNAP8200GYA</b>	<b>SNAP8300GYA</b>
	Ivory	<b>SNAP8200IA</b>	<b>SNAP8300IA</b>
	Light Almond	<b>SNAP8200LAA</b>	<b>SNAP8300LAA</b>
	Red	<b>SNAP8200RA</b>	<b>SNAP8300RA</b>
White	<b>SNAP8200WA</b>	<b>SNAP8300WA</b>	
Hospital grade, smooth nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Black	<b>SNAP8200BKNA</b>	<b>SNAP8300BKNA</b>
	Brown	<b>SNAP8200NA</b>	<b>SNAP8300NA</b>
	Gray	<b>SNAP8200GYNA</b>	<b>SNAP8300GYNA</b>
	Ivory	<b>SNAP8200INA</b>	<b>SNAP8300INA</b>
	Light Almond	<b>SNAP8200LANA</b>	<b>SNAP8300LANA</b>
	Red	<b>SNAP8200RNA</b>	<b>SNAP8300RNA</b>
White	<b>SNAP8200WNA</b>	<b>SNAP8300WNA</b>	
Hospital grade, Tamper-Resistant, smooth nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Black	<b>SNAP8200BKTRA</b>	<b>SNAP8300BKTRA</b>
	Brown	<b>SNAP8200TRA</b>	<b>SNAP8300TRA</b>
	Gray	<b>SNAP8200GYTRA</b>	<b>SNAP8300GYTRA</b>
	Ivory	<b>SNAP8200ITRA</b>	<b>SNAP8300ITRA</b>
	Light Almond	<b>SNAP8200LATRA</b>	<b>SNAP8300LATRA</b>
	Red	<b>SNAP8200RTRA</b>	<b>SNAP8300RTRA</b>
White	<b>SNAP8200WTRA</b>	<b>SNAP8300WTRA</b>	
Hospital grade, Tamper-Resistant, Split Circuit, smooth nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Black	<b>SNAP8200BKSCTRA</b>	<b>SNAP8300BKSCTRA</b>
	Brown	<b>SNAP8200SCTRA</b>	<b>SNAP8300SCTRA</b>
	Gray	<b>SNAP8200GYSCTRA</b>	<b>SNAP8300GYSCTRA</b>
	Ivory	<b>SNAP8200ISCTRA</b>	<b>SNAP8300ISCTRA</b>
	Light Almond	<b>SNAP8200LASCTRA</b>	<b>SNAP8300LASCTRA</b>
	Red	<b>SNAP8200RSCTRA</b>	<b>SNAP8300RSCTRA</b>
White	<b>SNAP8200WSCTRA</b>	<b>SNAP8300WSCTRA</b>	
Isolated ground <sup>A</sup> , Hospital grade, Tamper-Resistant.	Orange	<b>SNAP8200IGTRA</b>	<b>SNAP8300IGTRA</b>
Red	<b>SNAP8200RIGTRA</b>	<b>SNAP8300RIGTRA</b>	
Hospital grade, with Power Indicating LED, smooth nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Black	<b>SNAP8200BKL</b>	<b>SNAP8300BKL</b>
	Brown	<b>SNAP8200L</b>	<b>SNAP8300L</b>
	Gray	<b>SNAP8200GYL</b>	<b>SNAP8300GYL</b>
	Ivory	<b>SNAP8200IL</b>	<b>SNAP8300IL</b>
	Light Almond	<b>SNAP8200LAL</b>	<b>SNAP8300LAL</b>
	Red	<b>SNAP8200RL</b>	<b>SNAP8300RL</b>
White	<b>SNAP8200WL</b>	<b>SNAP8300WL</b>	
Isolated ground <sup>A</sup> , Hospital grade, with Power Indicating LED.	Orange	<b>SNAP8200IGL</b>	<b>SNAP8300IGL</b>
Red	<b>SNAP8200RIGL</b>	<b>SNAP8300RIGL</b>	
Hospital grade, Tamper-Resistant, with Power Indicating LED, smooth nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Black	<b>SNAP8200BKLTRA</b>	<b>SNAP8300BKLTRA</b>
	Brown	<b>SNAP8200LTRA</b>	<b>SNAP8300LTRA</b>
	Gray	<b>SNAP8200GYLTRA</b>	<b>SNAP8300GYLTRA</b>
	Ivory	<b>SNAP8200ILTRA</b>	<b>SNAP8300ILTRA</b>
	Light Almond	<b>SNAP8200LALTRA</b>	<b>SNAP8300LALTRA</b>
	Red	<b>SNAP8200RLTRA</b>	<b>SNAP8300RLTRA</b>
White	<b>SNAP8200WLTRA</b>	<b>SNAP8300WLTRA</b>	
Isolated ground <sup>A</sup> , Hospital grade, TR with Power Indicating LED.	Orange	<b>SNAP8200IGLTRA</b>	<b>SNAP8300IGLTRA</b>
	Red	<b>SNAP8200RIGLTRA</b>	<b>SNAP8300RIGLTRA</b>

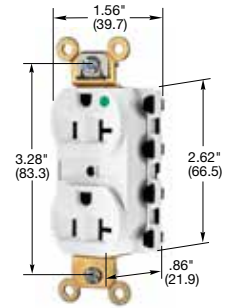


**SNAP8300WA**

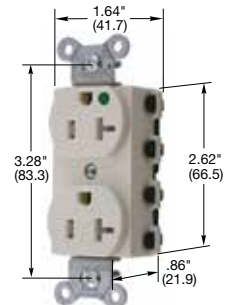


**SNAP8300LATR**

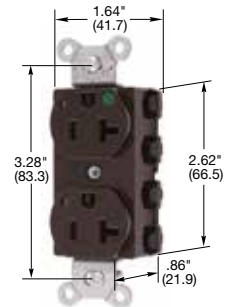

**SNAP8300L**

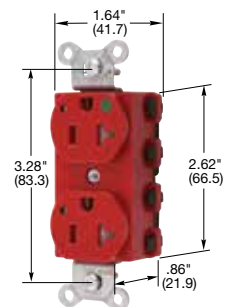

**SNAP8300RLTR**

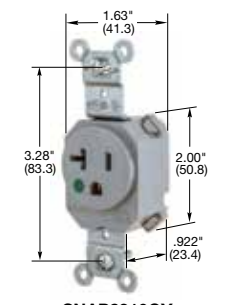

**SNAP8310GY**

Dimensions in Inches (mm)

### SNAPConnect® Extra Heavy Duty Hospital Grade Single Receptacles

Color	Hospital Grade ●		Hospital Grade ● Tamper-Resistant	
	15A 125V	20A 125V	15A 125V	20A 125V
Almond	<b>SNAP8210AL</b>	<b>SNAP8310AL</b>	<b>SNAP8210ALTR</b>	<b>SNAP8310ALTR</b>
Black	<b>SNAP8210BK</b>	<b>SNAP8310BK</b>	<b>SNAP8210BKTR</b>	<b>SNAP8310BKTR</b>
Blue	<b>SNAP8210BL</b>	<b>SNAP8310BL</b>	<b>SNAP8210BLTR</b>	<b>SNAP8310BLTR</b>
Brown	<b>SNAP8210</b>	<b>SNAP8310</b>	<b>SNAP8210TR</b>	<b>SNAP8310TR</b>
Gray	<b>SNAP8210GY</b>	<b>SNAP8310GY</b>	<b>SNAP8210GYTR</b>	<b>SNAP8310GYTR</b>
Ivory	<b>SNAP8210I</b>	<b>SNAP8310I</b>	<b>SNAP8210ITR</b>	<b>SNAP8310ITR</b>
Light Almond	<b>SNAP8210LA</b>	<b>SNAP8310LA</b>	<b>SNAP8210LATR</b>	<b>SNAP8310LATR</b>
Red	<b>SNAP8210R</b>	<b>SNAP8310R</b>	<b>SNAP8210RTR</b>	<b>SNAP8310RTR</b>
White	<b>SNAP8210W</b>	<b>SNAP8310W</b>	<b>SNAP8210WTR</b>	<b>SNAP8310WTR</b>

**IP20**  
SUITABILITY




**15A 125V**  
NEMA 5-15R  
UL CSA  
0.5 HP




**20A 125V**  
NEMA 5-20R  
UL CSA  
1 HP

## Extra Heavy Duty Hospital Grade SNAPConnect®


### Style Line® Decorator

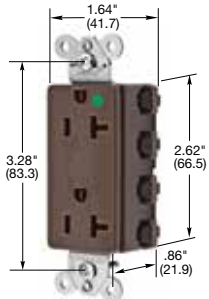


SNAP2182A

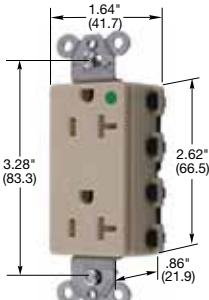


SNAP2182I TR

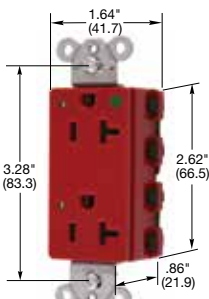


SNAP2182RL

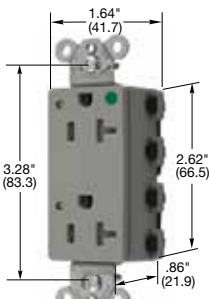

SNAP2182GYLTR

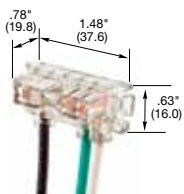

SNAP1RA

Description	Color	Catalog Number	
Hospital grade, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below.	Black	<b>SNAP2172BKA</b>	<b>SNAP2182BKA</b>
	Brown	<b>SNAP2172A</b>	<b>SNAP2182A</b>
	Gray	<b>SNAP2172GYA</b>	<b>SNAP2182GYA</b>
	Ivory	<b>SNAP2172IA</b>	<b>SNAP2182IA</b>
	Light Almond	<b>SNAP2172LAA</b>	<b>SNAP2182LAA</b>
	Red	<b>SNAP2172RA</b>	<b>SNAP2182RA</b>
	White	<b>SNAP2172WA</b>	<b>SNAP2182WA</b>
Hospital grade, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Black	<b>SNAP2172BKNA</b>	<b>SNAP2182BKNA</b>
	Brown	<b>SNAP2172NA</b>	<b>SNAP2182NA</b>
	Gray	<b>SNAP2172GYNA</b>	<b>SNAP2182GYNA</b>
	Ivory	<b>SNAP2172INA</b>	<b>SNAP2182INA</b>
	Light Almond	<b>SNAP2172LANA</b>	<b>SNAP2182LANA</b>
	Red	<b>SNAP2172RNA</b>	<b>SNAP2182RNA</b>
	White	<b>SNAP2172WNA</b>	<b>SNAP2182WNA</b>
 Hospital grade, Tamper-Resistant, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Black	<b>SNAP2172BKTRA</b>	<b>SNAP2182BKTRA</b>
	Brown	<b>SNAP2172TRA</b>	<b>SNAP2182TRA</b>
	Gray	<b>SNAP2172GYTRA</b>	<b>SNAP2182GYTRA</b>
	Ivory	<b>SNAP2172ITRA</b>	<b>SNAP2182ITRA</b>
	Light Almond	<b>SNAP2172LATRA</b>	<b>SNAP2182LATRA</b>
	Red	<b>SNAP2172RTRA</b>	<b>SNAP2182RTRA</b>
	White	<b>SNAP2172WTRA</b>	<b>SNAP2182WTRA</b>
 Hospital grade, Tamper-Resistant, Split Circuit, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Black	<b>SNAP2172BKSCTRA</b>	<b>SNAP2182BKSCTRA</b>
	Brown	<b>SNAP2172SCTRA</b>	<b>SNAP2182SCTRA</b>
	Gray	<b>SNAP2172GYSCTRA</b>	<b>SNAP2182GYSCTRA</b>
	Ivory	<b>SNAP2172ISCTRA</b>	<b>SNAP2182ISCTRA</b>
	Light Almond	<b>SNAP2172LASCTRA</b>	<b>SNAP2182LASCTRA</b>
	Red	<b>SNAP2172RSCTRA</b>	<b>SNAP2182RSCTRA</b>
	White	<b>SNAP2172WSCTRA</b>	<b>SNAP2182WSCTRA</b>
Isolated ground <sup>A</sup> , Hospital grade, Tamper-Resistant.	Orange	<b>SNAP2172IGTRA</b>	<b>SNAP2182IGTRA</b>
	Red	<b>SNAP2172RIGTRA</b>	<b>SNAP2182RIGTRA</b>
 Hospital grade, with Power Indicating LED, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Black	<b>SNAP2172BKL</b>	<b>SNAP2182BKL</b>
	Brown	<b>SNAP2172L</b>	<b>SNAP2182L</b>
	Gray	<b>SNAP2172GYL</b>	<b>SNAP2182GYL</b>
	Ivory	<b>SNAP2172IL</b>	<b>SNAP2182IL</b>
	Light Almond	<b>SNAP2172LAL</b>	<b>SNAP2182LAL</b>
	Red	<b>SNAP2172RL</b>	<b>SNAP2182RL</b>
	White	<b>SNAP2172WL</b>	<b>SNAP2182WL</b>
Isolated ground <sup>A</sup> , Hospital grade, with Power Indicating LED.	Orange	<b>SNAP2172IGL</b>	<b>SNAP2182IGL</b>
	Red	<b>SNAP2172RIGL</b>	<b>SNAP2182RIGL</b>
 Hospital grade, Tamper-Resistant, with Power Indicating LED, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Black	<b>SNAP2172BKLTR</b>	<b>SNAP2182BKLTR</b>
	Brown	<b>SNAP2172LTR</b>	<b>SNAP2182LTR</b>
	Gray	<b>SNAP2172GYLTR</b>	<b>SNAP2182GYLTR</b>
	Ivory	<b>SNAP2172ILTR</b>	<b>SNAP2182ILTR</b>
	Light Almond	<b>SNAP2172LALTR</b>	<b>SNAP2182LALTR</b>
	Red	<b>SNAP2172RLTR</b>	<b>SNAP2182RLTR</b>
	White	<b>SNAP2172WLTR</b>	<b>SNAP2182WLTR</b>
Isolated ground <sup>A</sup> , Hospital grade, TR with Power Indicating LED.	Orange	<b>SNAP2172IGLTR</b>	<b>SNAP2182IGLTR</b>
	Red	<b>SNAP2172RIGLTR</b>	<b>SNAP2182RIGLTR</b>

Note: <sup>A</sup>See section M additional information on isolated ground devices.  
See page A-16 for additional information on SNAPConnect® features.  
See page Tech-10 for Tamper-Resistant and LED Power Indicators description.  
See pages A-50 and A-51 for accessories.  
See section N for wallplates.

### SNAPConnect® Right Angle Pigtailed Connector

Description	Wire Type	General Use	Assembled in USA
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2; Polycarbonate housing material	Solid	<b>SNAP1RA</b>	<b>SNAP1RNA</b>
	Stranded	<b>SNAP2RA</b>	<b>SNAP2RNA</b>

Note: For Assembled in USA products, must order connector with NA suffix.

Dimensions in Inches (mm)



## SNAPConnect® GFCI LED Hospital Grade ●, Assembled in USA

Description	Rating	Color	Catalog Number			
Hospital Grade SNAPConnect GFCI LED, self-grounding staple, requires connector below, sold separately.	15 and 20A 125V AC	Almond	<b>GFRST82SNAPAL</b>	<b>GFRST83SNAPAL</b>		
		Black	<b>GFRST82SNAPBK</b>	<b>GFRST83SNAPBK</b>		
		Brown	<b>GFRST82SNAP</b>	<b>GFRST83SNAP</b>		
		Gray	<b>GFRST82SNAPGY</b>	<b>GFRST83SNAPGY</b>		
		Ivory	<b>GFRST82SNAPI</b>	<b>GFRST83SNAPI</b>		
		Light Almond	<b>GFRST82SNAPLA</b>	<b>GFRST83SNAPLA</b>		
		Red	<b>GFRST82SNAPR</b>	<b>GFRST83SNAPR</b>		
		White	<b>GFRST82SNAPW</b>	<b>GFRST83SNAPW</b>		




15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP



20A 125V  
NEMA 5-20R  
UL CSA  
1 HP




Meets UL  
Standard 943  
Class A GFCI

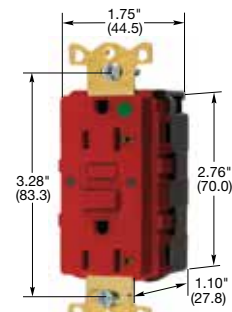

**GFRST83SNAPR**

## SNAPConnect® GFCI LED Hospital Grade ●, Tamper and Weather Resistant, Assembled in USA

Description	Rating	Color	Catalog Number			
Hospital Grade SNAPConnect GFCI TR/WR, self-grounding staple, requires connector below, sold separately.	15 and 20A 125V AC	Almond	<b>GFTWRST82SNAPAL</b>	<b>GFTWRST83SNAPAL</b>		
		Black	<b>GFTWRST82SNAPBK</b>	<b>GFTWRST83SNAPBK</b>		
		Brown	<b>GFTWRST82SNAP</b>	<b>GFTWRST83SNAP</b>		
		Gray	<b>GFTWRST82SNAPGY</b>	<b>GFTWRST83SNAPGY</b>		
		Ivory	<b>GFTWRST82SNAPI</b>	<b>GFTWRST83SNAPI</b>		
		Light Almond	<b>GFTWRST82SNAPLA</b>	<b>GFTWRST83SNAPLA</b>		
		Red	<b>GFTWRST82SNAPR</b>	<b>GFTWRST83SNAPR</b>		
		White	<b>GFTWRST82SNAPW</b>	<b>GFTWRST83SNAPW</b>		

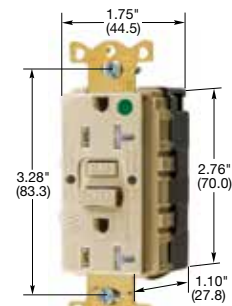

**GFTWRST83SNAPI**

## SNAPConnect® USB Charger Hospital Grade ●, Duplex Receptacles

Description	Color	Catalog Number	
Hospital Grade SNAPConnect USB Charger, Tamper-Resistant Style Line® decorator duplex receptacle, two USB type 2.0 ports 3 Amp, 5 Volt DC, 15 or 20 Amp, 125 Volt AC.	Black	<b>SNAP8200USBBK</b>	<b>SNAP8300USBBK</b>
	Brown	<b>SNAP8200USB</b>	<b>SNAP8300USB</b>
	Gray	<b>SNAP8200USBGY</b>	<b>SNAP8300USBGY</b>
	Ivory	<b>SNAP8200USBI</b>	<b>SNAP8300USBI</b>
	Light Almond	<b>SNAP8200USBLA</b>	<b>SNAP8300USBLA</b>
	Red	<b>SNAP8200USBR</b>	<b>SNAP8300USBR</b>
	White	<b>SNAP8200USBW</b>	<b>SNAP8300USBW</b>



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP



20A 125V  
NEMA 5-20R  
UL CSA  
1 HP



**SNAP8300USBW**

## SNAPConnect® Surge Protection Hospital Grade ●, Tamper-Resistant Receptacle with Power Indicating LED


Description	Color	Catalog Number	
Hospital Grade SNAPConnect Surge suppression, Tamper-Resistant, smooth face, duplex receptacle.	Blue	<b>SNAP8262S</b>	<b>SNAP8362S</b>
	Gray	<b>SNAP8262GYS</b>	<b>SNAP8362GYS</b>
	Ivory	<b>SNAP8262IS</b>	<b>SNAP8362IS</b>
	Light Almond	<b>SNAP8262LAS</b>	<b>SNAP8362LAS</b>
	Red	<b>SNAP8262RS</b>	<b>SNAP8362RS</b>
	White	<b>SNAP8262WS</b>	<b>SNAP8362WS</b>



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP




20A 125V  
NEMA 5-20R  
UL CSA  
1 HP

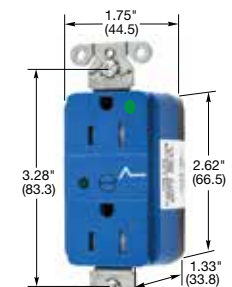

**SNAP8262S**

## SNAPConnect® Right Angle Pigtailed Terminal

 Description	Wire Type	General Use	Assembled in USA
Clear right angle terminal with 6 inch leads, 600V, #12 AWG THHN/THWN-2, Polycarbonate housing material.	Solid	<b>SNAP1RA</b>	<b>SNAP1RNA</b>
	Stranded	<b>SNAP2RA</b>	<b>SNAP2RNA</b>



**SNAP1RA**

Note: See page Tech-10 for Tamper-Resistant and Weather Resistant descriptions.

Dimensions in Inches (mm)

## Features and Benefits

### Hubbell-PRO Heavy Duty Receptacles

- Automatic self-grounding staple
- Combination Tamper-Resistant and LED for pediatric emergency circuits
- Nylon face and base construction
- Circuit ID marking area
- Back and side wiring
- Tri drive screws
- Steel mounting strap



8200REDLTRA




15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP




20A 125V  
NEMA 5-20R  
UL CSA  
1 HP



8200LA

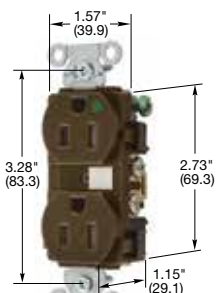

8200TRA

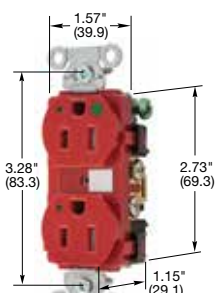

8200REDLTRA

Dimensions in Inches (mm)

### Hubbell-PRO Heavy Duty Hospital Grade Receptacles

#### Duplex

Description	Color	Catalog Number	
Hospital grade, smooth nylon face, back and side wired. Assembled in USA.	Black	8200BK	8300BK
	Brown	8200	8300
	Gray	8200GY	8300GY
	Ivory	8200IV	8300IV
	Light Almond	8200LA	8300LA
	Red	8200RED	8300RED
Hospital grade, Tamper-Resistant, smooth nylon face, back and side wired. Assembled in USA.	White	8200WHI	8300WHI
	Black	8200BKTRA	8300BKTRA
	Brown	8200TRA	8300TRA
	Gray	8200GYTRA	8300GYTRA
	Ivory	8200IVTRA	8300IVTRA
	Light Almond	8200LATRA	8300LATRA
Hospital grade, with Power Indicating LED, smooth nylon face, back and side wired. Assembled in USA.	Red	8200REDTRA	8300REDTRA
	White	8200WTRA	8300WTRA
	Black	8200BKL	8300BKL
	Brown	8200L	8300L
	Gray	8200GYL	8300GYL
	Ivory	8200IVL	8300IVL
Hospital grade, Tamper-Resistant, with Power Indicating LED, smooth nylon face, back and side wired. Assembled in USA.	Light Almond	8200LAL	8300LALM
	Red	8200REDL	8300REDL
	White	8200WL	8300WL
	Black	8200BKLTRA	8300BKLTRA
	Brown	8200LTRA	8300LTRA
	Gray	8200GYLTRA	8300GYLTRA
	Ivory	8200IVLTRA	8300IVLTRA
	Light Almond	8200LALTRA	8300LALTRA
	Red	8200REDLTRA	8300REDLTRA
	White	8200WLTRA	8300WLTRA

Note: See pages A-48 and A-49 for accessories.

See page Tech-10 for Tamper-Resistant and LED Power Indicators description.

See section N for wallplates.

**The products listed on this page are Assembled in USA, and many are Buy American Compliant. Please contact Hubbell with any certification requirements.**



## Features and Benefits

### Hubbell-PRO Heavy Duty Receptacles

- Automatic self-grounding staple
- Combination Tamper-Resistant and LED for pediatric emergency circuits
- Nylon face and base construction
- Circuit ID marking area
- Back and side wiring
- Tri drive screws
- Steel mounting strap



2182IVLTRA



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP




20A 125V  
NEMA 5-20R  
UL CSA  
1 HP


### Hubbell-PRO Heavy Duty Hospital Grade Receptacles

#### Style Line® Decorator


Description	Color	Catalog Number	
Hospital grade, Style Line® decorator, flush, nylon face, back and side wired. Assembled in USA.	Black	2172BK	2182BK
	Brown	2172	2182
	Gray	2172GY	2182GY
	Ivory	2172IV	2182IV
	Light Almond	2172LA	2182LA
	Red	2172RED	2182RED
	White	2172W	2182W
Hospital grade, Tamper-Resistant, Style Line® decorator, flush, nylon face, back and side wired. Assembled in USA.	Black	2172BKTRA	2182BKTRA
	Brown	2172TRA	2182TRA
	Gray	2172GYTRA	2182GYTRA
	Ivory	2172IVTRA	2182IVTRA
	Light Almond	2172LATRA	2182LATRA
	Red	2172REDTRA	2182REDTRA
	White	2172WTRA	2182WTRA
Hospital grade, with Power Indicating LED, Style Line® decorator, flush, nylon face, back and side wired. Assembled in USA.	Black	2172BKL	2182BKL
	Brown	2172L	2182L
	Gray	2172GYL	2182GYL
	Ivory	2172IVL	2182IVL
	Light Almond	2172LAL	2182LAL
	Red	2172REDL	2182REDL
	White	2172WL	2182WL
Hospital grade, Tamper-Resistant, with Power Indicating LED, Style Line® decorator, flush, nylon face, back and side wired. Assembled in USA.	Black	2172BKLTRA	2182BKLTRA
	Brown	2172LTRA	2182LTRA
	Gray	2172GYLTRA	2182GYLTRA
	Ivory	2172IVLTRA	2182IVLTRA
	Light Almond	2172LALTRA	2182LALTRA
	Red	2172REDLTRA	2182REDLTRA
	White	2172WLTRA	2182WLTRA

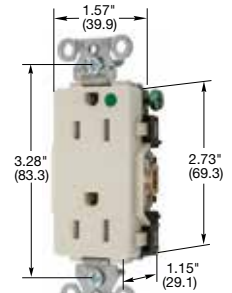

2172LATRA

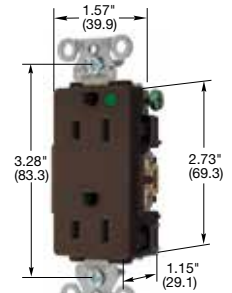

2172L

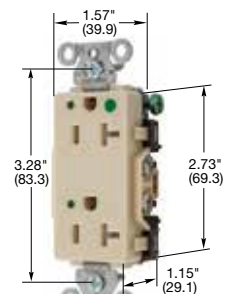

2182IVLTRA

Note: See pages A-48 and A-49 for accessories.  
See page Tech-10 for Tamper-Resistant and LED Power Indicators description.  
See section N for wallplates.

**The products listed on this page are Assembled in USA, and many are Buy American Compliant. Please contact Hubbell with any certification requirements.**


Dimensions in Inches (mm)




15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP




20A 125V  
NEMA 5-20R  
UL CSA  
1 HP

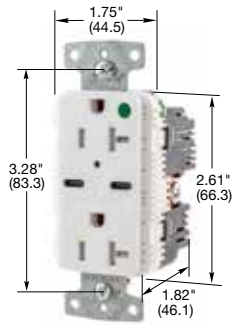


**USB8300C5W**

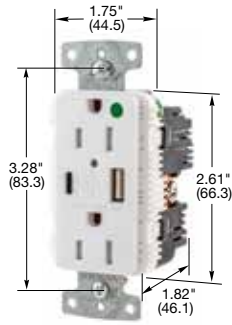


**USB8200AC5W**

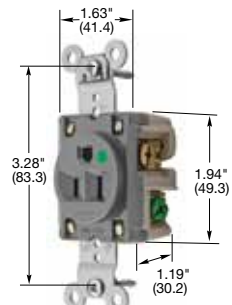

**HBL8210GY**

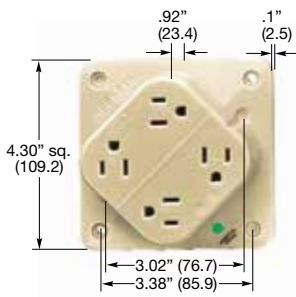

**HBL415HI**

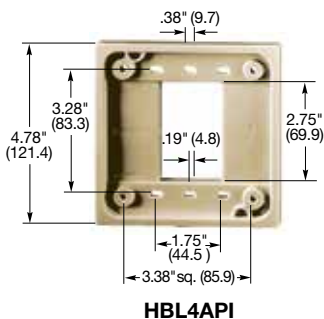

**HBL4API**

Dimensions in Inches (mm)

## Hospital Grade ● USB Charger Type-C, Type A&C and Type A

Description	Color	Catalog Number	
Hospital Grade USB Charger Outlet: two Type-C port configurations, high power 5 Amp, 5 Volt USB output, Tamper-Resistant duplex receptacle, USB ports rated 10,000 cycles.	Black	<b>USB8200C5BK</b>	<b>USB8300C5BK</b>
	Brown	<b>USB8200C5</b>	<b>USB8300C5</b>
	Gray	<b>USB8200C5GY</b>	<b>USB8300C5GY</b>
	Ivory	<b>USB8200C5I</b>	<b>USB8300C5I</b>
	Light Almond	<b>USB8200C5LA</b>	<b>USB8300C5LA</b>
	Red	<b>USB8200C5R</b>	<b>USB8300C5R</b>
	White	<b>USB8200C5W</b>	<b>USB8300C5W</b>
Hospital Grade USB Charger Outlet: one Type A and one Type-C port configurations, high power 5 Amp, 5 Volt USB output, Tamper-Resistant duplex receptacle, USB ports rated 10,000 cycles.	Black	<b>USB8200AC5BK</b>	<b>USB8300AC5BK</b>
	Brown	<b>USB8200AC5</b>	<b>USB8300AC5</b>
	Gray	<b>USB8200AC5GY</b>	<b>USB8300AC5GY</b>
	Ivory	<b>USB8200AC5I</b>	<b>USB8300AC5I</b>
	Light Almond	<b>USB8200AC5LA</b>	<b>USB8300AC5LA</b>
	Red	<b>USB8200AC5R</b>	<b>USB8300AC5R</b>
	White	<b>USB8200AC5W</b>	<b>USB8300AC5W</b>
Hospital Grade USB Charger Outlet: two Type A port configurations, high power 5 Amp, 5 Volt USB output, Tamper-Resistant duplex receptacle, USB ports rated 10,000 cycles.	Black	<b>USB8200A5BK</b>	<b>USB8300A5BK</b>
	Brown	<b>USB8200A5</b>	<b>USB8300A5</b>
	Gray	<b>USB8200A5GY</b>	<b>USB8300A5GY</b>
	Ivory	<b>USB8200A5I</b>	<b>USB8300A5I</b>
	Light Almond	<b>USB8200A5LA</b>	<b>USB8300A5LA</b>
	Red	<b>USB8200A5R</b>	<b>USB8300A5R</b>
	White	<b>USB8200A5W</b>	<b>USB8300A5W</b>

## HBL® Extra Heavy Duty Hospital Grade ● Single Receptacles

**IP20**  
SUITABILITY



Description	Color	Catalog Number	
Flush, nylon face, back and side wired, Fed. Spec. verified.	Almond	-	<b>HBL8310AL</b>
	Brown	<b>HBL8210</b>	<b>HBL8310</b>
	Gray	<b>HBL8210GY</b>	<b>HBL8310GY</b>
	Ivory	<b>HBL8210I</b>	<b>HBL8310I</b>
	Red	<b>HBL8210R</b>	<b>HBL8310R</b>
	White	<b>HBL8210W</b>	<b>HBL8310W</b>
Panel mount on 1.94 in. (49.2) centers.	Brown	<b>HBL8284</b>	-
	Ivory	<b>HBL8284I</b>	<b>HBL8384I</b>
Isolated ground <sup>A</sup> .	Orange	<b>IG8210</b>	<b>IG8310</b>

Note: <sup>A</sup>See section M for additional information on isolated ground devices.

## 4-PLEX® Hospital Grade ● Receptacles



Description	Color	Catalog Number	
4 outlet high impact resistant Polycarbonate construction. Mount to 4 in. square box.	Brown	<b>HBL415H</b>	<b>HBL420H</b>
	Gray	-	<b>HBL420HGY</b>
	Ivory	<b>HBL415HI</b>	<b>HBL420HI</b>
	Red	<b>HBL415HR</b>	<b>HBL420HR</b>
	White	<b>HBL415HW</b>	<b>HBL420HW</b>

## 4-PLEX® Accessories

Description	Color	Catalog Number	
4-PLEX adapter plates for 1- and 2-gang, device boxes.	Brown	<b>HBL4AP</b>	<b>HBL4AP</b>
	Gray	<b>HBL4APGY</b>	<b>HBL4APGY</b>
	Ivory	<b>HBL4API</b>	<b>HBL4API</b>
	Red	<b>HBL4APR</b>	<b>HBL4APR</b>
	White	<b>HBL4APW</b>	<b>HBL4APW</b>

Note: See page A-25 for additional information on 4-PLEX devices.

**IP20**  
SUITABILITY



**15A 125V**  
NEMA 5-15P  
UL CSA



**20A 125V**  
NEMA 5-20P  
UL CSA

## Hospital Grade Plugs

### Insulgrip®

Description	Cord Diameter	Catalog Number	
Black and white nylon.	.230"-.720" (5.8-18.3)	<b>HBL8215C</b>	<b>HBL8315C</b>
Transparent housing.	.230"-.720" (5.8-18.3)	<b>HBL8215CT</b>	<b>HBL8315CT</b>
8 position angle plug, transparent housing.	.250"-.655" (6.4-16.6)	<b>HBL8215CAT*</b>	<b>HBL8315CAT*</b>

### Valise®

Description	Cord Diameter	Catalog Number	
White nylon.	.300"-.660" (7.6-16.8)	<b>HBL8115V</b>	<b>HBL8364V</b>
Insulation displacement, white nylon.	.300"-.360" (7.6-9.1)	<b>HBL8013V*</b>	-

Note: \*Not Fed. Spec. Listed.  
See page A-49 for accessories

**IP20**  
SUITABILITY



**15A 250V**  
NEMA 6-15P  
UL CSA  
1.5 HP



**20A 250V**  
NEMA 6-20P  
UL CSA  
2 HP

## Hospital Grade Plugs

### Valise®

Description	Cord Diameter	Catalog Number	
Valise plug, white nylon.	.300"-.660" (7.6-16.8)	<b>HBL8666V</b>	<b>HBL8464V</b>

Note: HP ratings listed above are based on 208 to 240V AC only.

**IP20**  
SUITABILITY



**15A 125V**  
NEMA 5-15R  
UL CSA  
0.5 HP



**20A 125V**  
NEMA 5-20R  
UL CSA  
1 HP

## Hospital Grade Connector Bodies

### Insulgrip®

Description	Cord Diameter	Catalog Number	
Black and white nylon.	.230"-.720" (5.8-18.3)	<b>HBL8219C</b>	<b>HBL8319C</b>
Transparent housing.	.230"-.720" (5.8-18.3)	<b>HBL8219CT</b>	<b>HBL8319CT</b>

### Valise®

Description	Cord Diameter	Catalog Number	
White nylon.	.300"-.660" (7.6-16.8)	<b>HBL8119V</b>	-

Note: See page A-49 for accessories.

**IP20**  
SUITABILITY



**15A 250V**  
NEMA 6-15R  
UL CSA  
1.5 HP



**20A 250V**  
NEMA 6-20R  
UL CSA  
2 HP

## Hospital Grade Connector Bodies

### Valise®

Description	Cord Diameter	Catalog Number	
White nylon.	.300"-.660" (7.6-16.8)	-	<b>HBL8469V</b>

## HBL® Extra Heavy Duty Hospital Grade Receptacles


### Duplex

Description	Color	Catalog Number	
Flush, thermoplastic polyester face, back and side wired, multiple drive screws.	Brown Ivory	<b>HBL8600</b> <b>HBL8600I</b>	<b>HBL8400</b> <b>HBL8400I</b>


Note: See page A-48 for accessories.  
See section N for wallplates.



**HBL8215C**

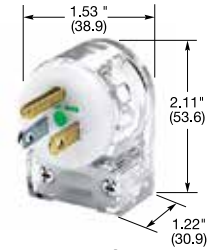


**HBL8215CAT**

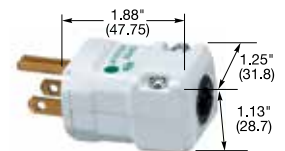


**HBL8115V**




**HBL8219C**

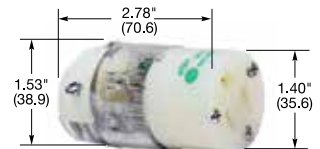

**HBL8219CT**

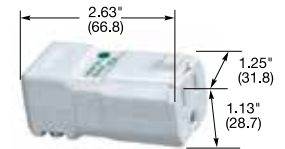

**HBL8119V**

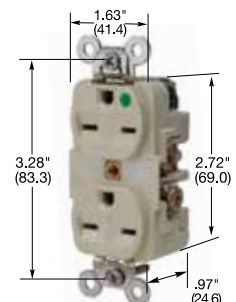

**HBL8600I**

Dimensions in Inches (mm)

## Features and Benefits

### Extra Heavy Duty Hospital Grade ● GFCI Receptacles Tamper-Resistant and Weather Resistant

#### 10kA Short Circuit Current Rating

Limits improper access to energized contacts

- Exclusive patented tamper-resistant protection through switching technology
- Continually tests and monitors for people protection automatically
- Patented self test diagnostics

Power indication

- Steady "ON" GREEN LED provides indication of power

Ground fault indicator

- Steady "ON" RED LED provides visual indication of a ground fault condition; flashing red indicates device has lost capability to provide protection

No power at face if reverse wired

- Open circuit condition eliminates false assumption of protection at face

Durable face with V-0 flammability rating

- Polyester face cover



GFR8300SGI





15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP



20A 125V  
NEMA 5-20R  
UL CSA  
1 HP

### AUTOGUARD® Self Test GFCI Receptacles Tamper-Resistant and Weather Resistant

Description	Rating	Color	Catalog Number	
  Flush, polyester face, back and side wired, multiple drive screws.	15 and 20A 125V AC	Black	<b>GFR8200SGBK</b>	<b>GFR8300SGBK</b>
		Brown	<b>GFR8200SG</b>	<b>GFR8300SG</b>
		Gray	<b>GFR8200SGGY</b>	<b>GFR8300SGGY</b>
		Ivory	<b>GFR8200SGI</b>	<b>GFR8300SGI</b>
		Red	<b>GFR8200SGR</b>	<b>GFR8300SGR</b>
		White	<b>GFR8200SGW</b>	<b>GFR8300SGW</b>

*Note: GFCI type receptacles should not be used in critical care patient areas or for electrical life support equipment applications because of the possibility of power interruption. All GFCI receptacles listed above are furnished with both a matching color nylon wallplate, and a SS26 302/304 super stainless steel wallplate. 20 amp feed-through capability. See page Tech-10 for Tamper-Resistant and Weather Resistant descriptions.*



GFR8300SGW

### GFCI Receptacle Specifications per GFCI Products Listed (Pages L-12 to L-15)

Trip Level	4 to 6 mA.
Trip Time	.025 second nominal.
Frequency	60 Hz.
Voltage	120V AC +10% - 15% (102V to 132V).
Amperage	15A/20A, 20A Feed Thru.
Maximum Interrupting Capacity	10,000A.
Operating Temperature	-35°C to 66°C or -30°F to 150°F.
Maximum Humidity	95%.
Listings and Standards	Meets UL498 for receptacles, UL943 Class A for GFCIs UL File E41978. CSA Certified.
Codes	Meets all NEC® and CEC requirements. NEMA WD-6 ANSI 73.

NEC® is a registered trademark of the National Fire Protection Association (NFPA).



## Features and Benefits


### Commercial Tamper-Resistant GFCI Receptacles

- Patented shutter design for tamper-resistant protection
- Compliant with NEC® 406.12 and NEC® 517-18(c)
- Patented AUTOGUARD® self test technology includes disconnecting power to the receptacle if critical components are damaged and GFCI protection is lost
- Alarm version provides audible notification of a trip condition



GFTRST83B
 
### Hospital Grade ● Tamper-Resistant



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP



20A 125V  
NEMA 5-20R  
UL CSA  
1 HP

Description	Rating	Color	Catalog Number			
Night Light Two LED Night Lights, Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple.	15 and 20A 125V AC	Almond	<b>GFTRST82ALNL</b>	<b>GFTRST83ALNL</b>		
		Black	<b>GFTRST82BKNL</b>	<b>GFTRST83BKNL</b>		
		Brown	<b>GFTRST82NL</b>	<b>GFTRST83NL</b>		
		Gray	<b>GFTRST82GYNL</b>	<b>GFTRST83GYNL</b>		
		Ivory	<b>GFTRST82INL</b>	<b>GFTRST83INL</b>		
		Light Almond	<b>GFTRST82LANL</b>	<b>GFTRST83LANL</b>		
		Red	<b>GFTRST82RNL</b>	<b>GFTRST83RNL</b>		
		White	<b>GFTRST82WNL</b>	<b>GFTRST83WNL</b>		
		Alarm, Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple.	15 and 20A 125V AC	Almond	<b>GFTRST82ALB</b>	<b>GFTRST83ALB</b>
				Black	<b>GFTRST82BKB</b>	<b>GFTRST83BKB</b>
Brown	<b>GFTRST82B</b>			<b>GFTRST83B</b>		
Gray	<b>GFTRST82GYB</b>			<b>GFTRST83GYB</b>		
Ivory	<b>GFTRST82IB</b>			<b>GFTRST83IB</b>		
Light Almond	<b>GFTRST82LAB</b>			<b>GFTRST83LAB</b>		
Red	<b>GFTRST82RB</b>			<b>GFTRST83RB</b>		
White	<b>GFTRST82WB</b>			<b>GFTRST83WB</b>		




GFTRST83WNL



GFTRST83GYB

### Product Dimensions Inches (mm)

GFCI Receptacle	
A	3.27 (83.1)
B	2.75 (69.8)
C	1.75 (44.5)
D	1.47 (37.4)
E	1.10 (27.9)

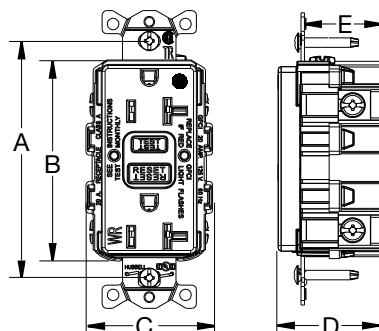

Dimensions in Inches (mm)

## Features and Benefits

### Commercial Tamper and Weather Resistant GFCI Receptacles

- Patented shutter design for tamper-resistant protection
- Meets NEC® requirements for TR (517-18c) and WR (406.9), UV and corrosion resistance for harsh and damp applications
- Patented AUTOGUARD® self test technology
- Protects against line and load reversal, no power to the face or downstream if device is miswired



GFTWRST83WIG



### Hospital Grade • Tamper-Resistant Weather Resistant



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP



20A 125V  
NEMA 5-20R  
UL CSA  
1 HP



GFTWRST82AL



GFTWRST83GYU



GFTWRST82BKIG



GFTWRST83SNAPI

Description	Rating	Color	Catalog Number	Catalog Number
Standard, Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple.	15 and 20A 125V AC	Almond	<b>GFTWRST82AL</b>	<b>GFTWRST83AL</b>
		Black	<b>GFTWRST82BK</b>	<b>GFTWRST83BK</b>
		Brown	<b>GFTWRST82</b>	<b>GFTWRST83</b>
		Gray	<b>GFTWRST82GY</b>	<b>GFTWRST83GY</b>
		Ivory	<b>GFTWRST82I</b>	<b>GFTWRST83I</b>
		Light Almond	<b>GFTWRST82LA</b>	<b>GFTWRST83LA</b>
		Red	<b>GFTWRST82R</b>	<b>GFTWRST83R</b>
Assembled in USA, Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple.	15 and 20A 125V AC	White	<b>GFTWRST82W</b>	<b>GFTWRST83W</b>
		Almond	<b>GFTWRST82ALU</b>	<b>GFTWRST83ALU</b>
		Black	<b>GFTWRST82BKU</b>	<b>GFTWRST83BKU</b>
		Brown	<b>GFTWRST82U</b>	<b>GFTWRST83U</b>
		Gray	<b>GFTWRST82GYU</b>	<b>GFTWRST83GYU</b>
		Ivory	<b>GFTWRST82IU</b>	<b>GFTWRST83IU</b>
		Light Almond	<b>GFTWRST82LAU</b>	<b>GFTWRST83LAU</b>
Isolated Ground, Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple.	15 and 20A 125V AC	Red	<b>GFTWRST82RU</b>	<b>GFTWRST83RU</b>
		White	<b>GFTWRST82WU</b>	<b>GFTWRST83WU</b>
		Almond	<b>GFTWRST82ALIG</b>	<b>GFTWRST83ALIG</b>
		Black	<b>GFTWRST82BKIG</b>	<b>GFTWRST83BKIG</b>
		Brown	<b>GFTWRST82IG</b>	<b>GFTWRST83IG</b>
		Gray	<b>GFTWRST82GYIG</b>	<b>GFTWRST83GYIG</b>
		Ivory	<b>GFTWRST82IIG</b>	<b>GFTWRST83IIG</b>
SNAPConnect®, Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple.	15 and 20A 125V AC	Light Almond	<b>GFTWRST82LAIG</b>	<b>GFTWRST83LAIG</b>
		Red	<b>GFTWRST82RIG</b>	<b>GFTWRST83RIG</b>
		White	<b>GFTWRST82WIG</b>	<b>GFTWRST83WIG</b>
		Almond	<b>GFTWRST82SNAPAL</b>	<b>GFTWRST83SNAPAL</b>
		Black	<b>GFTWRST82SNAPBK</b>	<b>GFTWRST83SNAPBK</b>
		Brown	<b>GFTWRST82SNAP</b>	<b>GFTWRST83SNAP</b>
		Gray	<b>GFTWRST82SNAPGY</b>	<b>GFTWRST83SNAPGY</b>
Ivory	<b>GFTWRST82SNAPI</b>	<b>GFTWRST83SNAPI</b>		
Light Almond	<b>GFTWRST82SNAPLA</b>	<b>GFTWRST83SNAPLA</b>		
	Red	<b>GFTWRST82SNAPR</b>	<b>GFTWRST83SNAPR</b>	
	White	<b>GFTWRST82SNAPW</b>	<b>GFTWRST83SNAPW</b>	

### SNAPConnect® Right Angle Pigtailed Terminal

Description	Wire Type	General Use Catalog Number	Assembled in USA Catalog Number
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2; Polycarbonate housing material.	Solid	<b>SNAP1RA</b>	<b>SNAP1RNA</b>
	Stranded	<b>SNAP2RA</b>	<b>SNAP2RNA</b>



SNAP1RA

## Features and Benefits

### Commercial Standard Hospital Grade • GFCI Receptacles

- Fed. Spec UL Listed, Hospital Grade
- Green power indicator and red trip indicator
- Patented AUTOGUARD® self test technology
- Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP



20A 125V  
NEMA 5-20R  
UL CSA  
1 HP

### Hospital Grade • GFCI Receptacles

Rating	Rating	Color	Catalog Number			
Standard, Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple.	15 and 20A 125V AC	Almond	<b>GFRST82AL</b>	<b>GFRST83AL</b>		
		Black	<b>GFRST82BK</b>	<b>GFRST83BK</b>		
		Brown	<b>GFRST82</b>	<b>GFRST83</b>		
		Gray	<b>GFRST82GY</b>	<b>GFRST83GY</b>		
		Ivory	<b>GFRST82I</b>	<b>GFRST83I</b>		
		Light Almond	<b>GFRST82LA</b>	<b>GFRST83LA</b>		
		Red	<b>GFRST82R</b>	<b>GFRST83R</b>		
		White	<b>GFRST82W</b>	<b>GFRST83W</b>		
		Assembled in USA, Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple.	15 and 20A 125V AC	Almond	<b>GFRST82ALU</b>	<b>GFRST83ALU</b>
				Black	<b>GFRST82BKU</b>	<b>GFRST83BKU</b>
Brown	<b>GFRST82U</b>			<b>GFRST83U</b>		
Gray	<b>GFRST82GYU</b>			<b>GFRST83GYU</b>		
Ivory	<b>GFRST82IU</b>			<b>GFRST83IU</b>		
Light Almond	<b>GFRST82LAU</b>			<b>GFRST83LAU</b>		
Red	<b>GFRST82RU</b>			<b>GFRST83RU</b>		
White	<b>GFRST82WU</b>			<b>GFRST83WU</b>		
Night Light Two LED Night Lights, Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple.	15 and 20A 125V AC			Almond	<b>GFRST82ALNL</b>	<b>GFRST83ALNL</b>
				Black	<b>GFRST82BKNL</b>	<b>GFRST83BKNL</b>
		Brown	<b>GFRST82NL</b>	<b>GFRST83NL</b>		
		Gray	<b>GFRST82GYNL</b>	<b>GFRST83GYNL</b>		
		Ivory	<b>GFRST82INL</b>	<b>GFRST83INL</b>		
		Light Almond	<b>GFRST82LANL</b>	<b>GFRST83LANL</b>		
		Red	<b>GFRST82RNL</b>	<b>GFRST83RNL</b>		
		White	<b>GFRST82WNL</b>	<b>GFRST83WNL</b>		
		Alarm, Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple.	15 and 20A 125V AC	Almond	<b>GFRST82ALB</b>	<b>GFRST83ALB</b>
				Black	<b>GFRST82BKB</b>	<b>GFRST83BKB</b>
Brown	<b>GFRST82B</b>			<b>GFRST83B</b>		
Gray	<b>GFRST82GYB</b>			<b>GFRST83GYB</b>		
Ivory	<b>GFRST82IB</b>			<b>GFRST83IB</b>		
Light Almond	<b>GFRST82LAB</b>			<b>GFRST83LAB</b>		
Red	<b>GFRST82RB</b>			<b>GFRST83RB</b>		
White	<b>GFRST82WB</b>			<b>GFRST83WB</b>		
SNAPConnect®, Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple.	15 and 20A 125V AC			Almond	<b>GFRST82SNAPAL</b>	<b>GFRST83SNAPAL</b>
				Black	<b>GFRST82SNAPBK</b>	<b>GFRST83SNAPBK</b>
		Brown	<b>GFRST82SNAP</b>	<b>GFRST83SNAP</b>		
		Gray	<b>GFRST82SNAPGY</b>	<b>GFRST83SNAPGY</b>		
		Ivory	<b>GFRST82SNAPI</b>	<b>GFRST83SNAPI</b>		
		Light Almond	<b>GFRST82SNAPLA</b>	<b>GFRST83SNAPLA</b>		
		Red	<b>GFRST82SNAPR</b>	<b>GFRST83SNAPR</b>		
		White	<b>GFRST82SNAPW</b>	<b>GFRST83SNAPW</b>		



GFRST82WNL



GFRST82R



GFRST83INL



GFRST83BKB



GFRST83SNAPGY

### SNAPConnect® Right Angle Pigtailed Terminal

Description	Wire Type	General Use Catalog Number	Assembled in USA Catalog Number
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2; Polycarbonate housing material.	Solid Stranded	<b>SNAP1RA</b> <b>SNAP2RA</b>	<b>SNAP1RNA</b> <b>SNAP2RNA</b>



## Surge Protection Devices





15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP




20A 125V  
NEMA 5-20R  
UL CSA  
1 HP


### Hospital Grade • Circuit Guard® Receptacles

Description	Color	Catalog Number	
  SNAPConnect® Tamper-Resistant, surge suppression receptacle, smooth face, duplex. Requires connector on page L-15, sold separately.	Blue	<b>SNAP8262S</b>	<b>SNAP8362S</b>
	Gray	<b>SNAP8262GYS</b>	<b>SNAP8362GYS</b>
	Ivory	<b>SNAP8262IS</b>	<b>SNAP8362IS</b>
	Light Almond	<b>SNAP8262LAS</b>	<b>SNAP8362LAS</b>
	Red	<b>SNAP8262RS</b>	<b>SNAP8362RS</b>
	White	<b>SNAP8262WS</b>	<b>SNAP8362WS</b>
Surge suppression receptacles with light and alarm, 240 joules/15000A per mode.	Almond	<b>HBL8262ALSA</b>	<b>HBL8362ALSA</b>
	Blue	<b>HBL8262SA</b>	<b>HBL8362SA</b>
	Gray	<b>HBL8262GYSA</b>	<b>HBL8362GYSA</b>
	Ivory	<b>HBL8262ISA</b>	<b>HBL8362ISA</b>
	Red	<b>HBL8262RSA</b>	<b>HBL8362RSA</b>
	White	<b>HBL8262WSA</b>	<b>HBL8362WSA</b>
Isolated ground, surge suppression receptacles with light and alarm, 240 joules/15000A per mode.	Blue	<b>IG8262SA</b>	<b>IG8362SA</b>
	Gray	<b>IG8262GYSA</b>	<b>IG8362GYSA</b>
	Ivory	<b>IG8262ISA</b>	<b>IG8362ISA</b>
	Orange	<b>IG8262OSA</b>	<b>IG8362OSA</b>
	Red	<b>IG8262RSA</b>	<b>IG8362RSA</b>
	White	<b>IG8262WSA</b>	<b>IG8362WSA</b>
4-PLEX® surge suppression receptacles with lights, 80 joules/6500A per mode.	Blue	-	<b>HBL420HS</b>
	Ivory	-	<b>HBL420HIS</b>
	Red	-	<b>HBL420HRS</b>


Note: See page Tech-10 for Tamper-Resistant and LED Power Indicators descriptions.

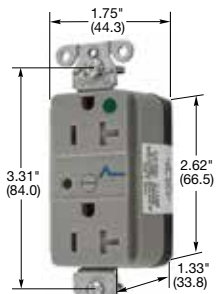

SNAP8362GYS

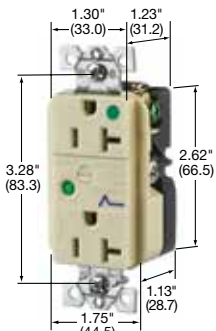

HBL8362ISA

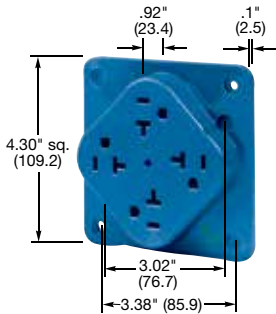

HBL420HS

### 4-PLEX® Accessories

Description	Color	Catalog Number
4-PLEX Adapter Plates for 1- and 2-gang, and 4 in. (101.6) square device boxes.	Blue	<b>HBL4APBL</b>
	Ivory	<b>HBL4API</b>
	Red	<b>HBL4APR</b>
4-PLEX Portable Box. Portable 4 in. (101.6) square box with cord grip. Accepts up to .66 in. (16.8) diameter cord.	Ivory	<b>HBL4PBI</b>

Note: 4-PLEX Box is not UL Listed.

UL2930 Listed



### UL2930 Health Care Outlet Assembly (HCOA)

Description	# of Outlets	Cord Length	Color	15 Amp	20 Amp
UL 2930 HCOA with L-N Surge Protection	6	6'	White	<b>HBL6MG6</b>	<b>HBL6MG620</b>
	6	15'	White	<b>HBL6MG15</b>	<b>HBL6MG1520</b>
UL 2930 HCOA Relocatable Power Tap (RPT)	6	6'	White	<b>HBL6MGRPT6</b>	<b>HBL6MGRPT620</b>
	6	15'	White	<b>HBL6MGRPT15</b>	<b>HBL6MGRPT1520</b>



HBL6MGRPT620

Listed to UL1449



### SpikeShield® Surge Protective Devices (SPD) with Tamper-Resistant Receptacles and Heavy Duty Plug

Description	# of Outlets	Cord Length	Color	15 Amp	20 Amp
Type 3 SPD, Heavy Duty Metal Housing	6	6'	White	<b>HBL6HG6</b>	<b>HBL6HG620</b>
	6	15'	White	<b>HBL6HG15</b>	<b>HBL6HG1520</b>
UL Type 3 SPD, Heavy Duty Metal Housing with 2-port USB	4	6'	White	<b>HBL6HGUSB6</b>	-



HBL6HGUSB6

Dimensions in Inches (mm)





## Hubbellok® Plugs, Connector Bodies and Receptacles

For Hospital Use Only



### Hubbellok® Plugs and Connector Bodies

Description	Plugs	Connector Bodies
Nylon cover, thermoset interior.	<b>HBL23014HGB</b>	<b>HBL23001HGB</b>
Armored, epoxy filled, rubber cord grip.	<b>HBL23004HG</b>	-

Note: Cord clamp range for plug and connector .300" to .660" (7.6 to 16.8).



20A 125V AC



20A 125V AC



**HBL23014HGB**

### Receptacles

Description	Catalog Number
Black, back wired.	- <b>HBL23000HG</b>



**HBL23001HGB**


### Wallplates

Description	Catalog Number
Stainless steel 302/304, single-gang.	<b>HBL23901HG</b>
Stainless steel 302/304, three-gang for two receptacles.	<b>HBL23909HG</b>

Note: Suffix HG or HGB type for hospital use only.



 
**IP30**  
SUITABILITY



20A 125V AC

### Explosion Proof Plug

Description	Catalog Number
Plug, with, epoxy kit, accepts #12 or #14 type SO cable.	<b>HBL24312</b>

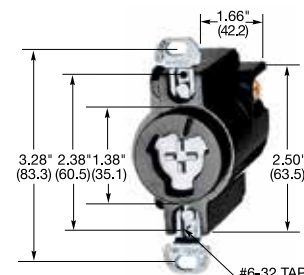


**HBL23000HG**


### Hazardous to Non-hazardous Location Receptacle Conversion Kits

Conversion kits for replacement of explosion proof receptacles listed above, with non-explosion proof receptacles, in the hospital areas formerly classified as hazardous locations and now classified non-hazardous locations due to the change from flammable anesthetizing gases to nonflammable anesthetizing gases.

For Conversion To:	Catalog Number
20A, 125V, duplex receptacle (Hubbell HBL830 Series). Includes adapter ring and stainless steel wall plate for duplex receptacle (receptacle not included).	<b>HBL24300RKD</b>
20A, 125V, Hospital Hubbellok receptacle (Hubbell HBL23000HG) or 20A, 125V, straight blade single receptacle (Hubbell HBL8310 series). Includes adapter ring and stainless wall plate for single receptacle (receptacle not included).	<b>HBL24300RKS</b>

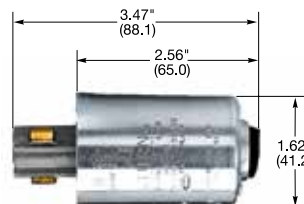

**HBL24312**

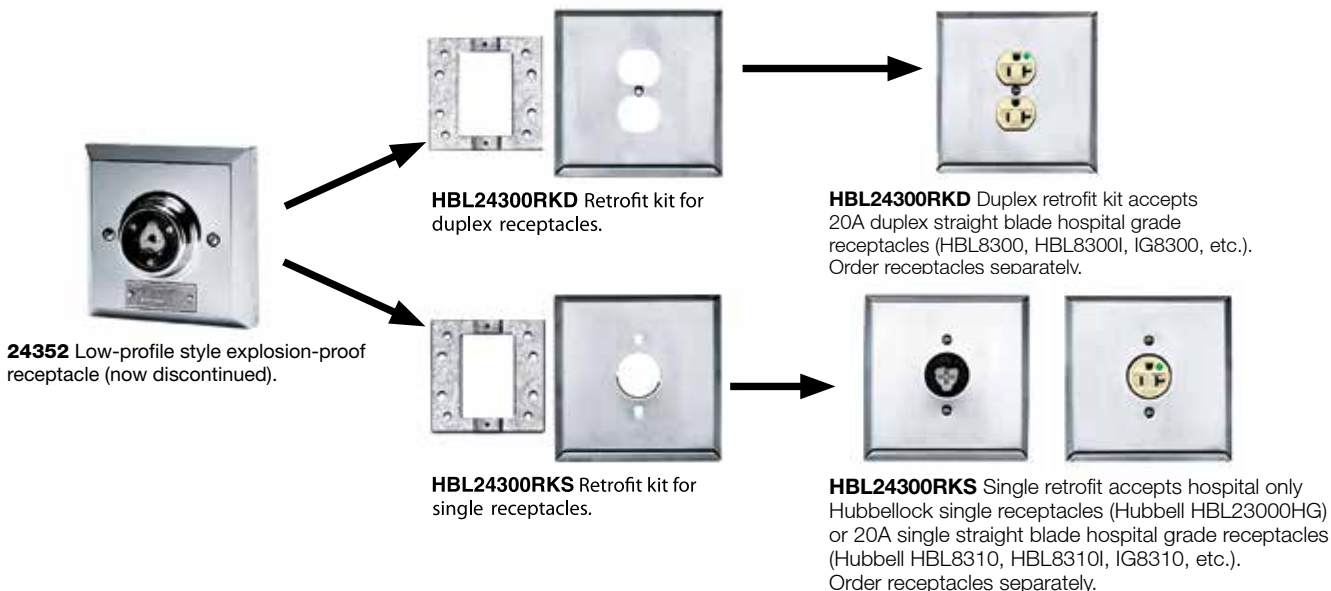

Dimensions in Inches (mm)




## Hubbellock® Mobile X-Ray Devices




**HBL25515**




**HBL25615**

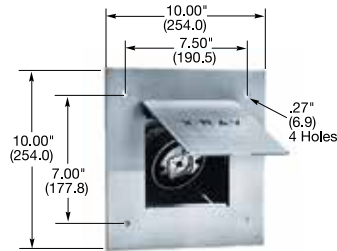

**HBL25605**

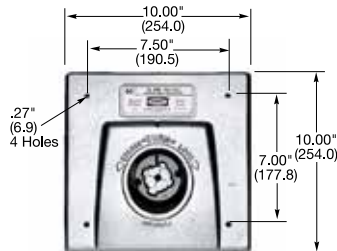


**HBL25603**

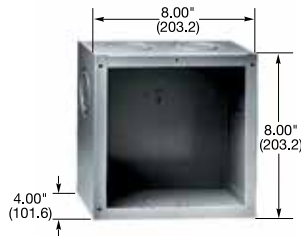


**HBL25509**

 **IP30**  
SUITABILITY



**50A 250V AC**

 

**60A 250V AC**

### Mobile X-Ray Plugs

Description	Catalog Number	
Plug, with epoxy kit, less cord clamp.	<b>HBL25515</b>	<b>HBL25615</b>
Plug, with cord clamp, less epoxy kit.	<b>HBL25525</b>	<b>HBL25625</b>

Note: Cord clamp range of plugs with cord clamps .830" to 1.3" (21.1 to 33.0).  
50A plugs fit 50A or 60A receptacles.

### Mobile X-Ray Receptacles

Description	Catalog Number	
Receptacle with stainless steel plate assembly.	<b>HBL25505</b>	<b>HBL25605</b>
Receptacle with cast aluminum plate assembly.	<b>HBL25503</b>	<b>HBL25603</b>
Replacement receptacle interior.	-	<b>IN16494</b>

### Accessory

Description	Catalog Number
Box stamped steel 8" x 8" x 4" (203.2 x 203.2 x 101.6), accommodates 50A and 60A mobile X-ray receptacles. Knockout sizes 1¼", 1½" and 2".	<b>HBL25509</b>

Dimensions in Inches (mm)