 


Midget Twist-Lock® Devices
 15A, 125V, 2 Pole, 2 Wire Non-Grounding
 Valise® Plug

HUBBELL

Features

- Fully insulated, abuse resistant nylon housing
- Insulation displacement terminals reduce wiring time
- Insulation displacement terminal
- Powerful, cord-gripping jaws
- Totally insulated body adds extra measure of safety



15A 125V
 NEMA ML-1R



Ordering Information


| Description | Cord Diameter | UPC | Catalog Number |
|---------------------|--------------------------|--------------|----------------|
| Black Valise® plug. | .220"-.385" (5.6-9.8) | 783585237282 | HBL7465V |

Listings

Listed to UL 498
 Certified to CSA C22.2 No.42
 Fed Spec W-C-596

Specifications

| | |
|---------------------|---|
| Housing | Nylon |
| Blades | Brass |
| Terminal Screws | #6 - 32 Steel (Philips / Slotted / Robertson) |
| Terminal Clamps | Steel - Nickel plated |
| Body Holding Screws | Steel - Zinc plated |

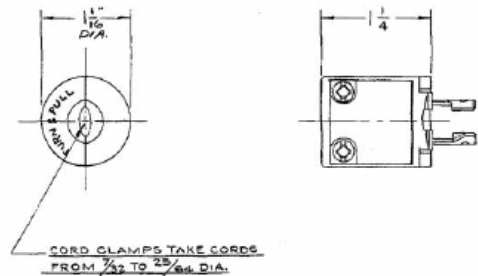

Performance

| Electrical | |
|-------------------------|--|
| Current Interrupting | Certified for current interrupting at full rated current |
| Dielectric Voltage | Withstands 2,000V minimum |
| Mechanical | |
| Terminal Accomodation | #18 AWG - #14 AWG stranded copper wire only. |
| Terminal Identification | Terminals identified in accordance with UL 498 |
| Environmental | |
| Flammability | HB or better per UL94/CSA 22.2 No.0.17 |
| Moisture Resistance | IP20 Suitability |
| Operating Temperatures | Maximum Continuous 75°C Minimum -40°C (w/o impact) |

Accessories

| | |
|--------------------|----------|
| Valise® Connector | HBL7464V |
| Flanged Receptacle | HBL7468 |
| Weatherproof Boot | HBL7490V |

Resources

| | |
|----------------------|--|
| Customer Use Drawing | |
| eCatalog | |

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

