

# Section K Wallplates



## Index

Product	Page
Features and Benefits . . . . .	K-2
Toggle Snap-On Wallplates . . . . .	K-4
Decorator Snap-On Wallplates . . . . .	K-5
Toggle Switch Wallplates . . . . .	K-6
Duplex and Single Receptacle Wallplates . . . . .	K-7
Single Receptacle Wallplates . . . . .	K-8
Blank Wallplates . . . . .	K-9
347 Volt Wallplates . . . . .	K-10
Decorator Wallplates . . . . .	K-11
Combination Wallplates, 2-Gang . . . . .	K-12
Combination Wallplates, 3-Gang . . . . .	K-14
Combination Wallplates, 4- and 5-Gang . . . . .	K-15
Telephone and Coaxial Outlet Plates . . . . .	K-16
Jumbo, Metal Wallplates . . . . .	K-17
Pre-Marked "EMERGENCY" and Barrel Key Switch Wallplates . . . . .	K-18
Pre-marked "ISOLATED GROUND" or "COMPUTER ONLY" Wallplates . . . . .	K-19
Security Wallplates . . . . .	K-20
Accessories and Selection Charts . . . . .	K-21
Weatherproof Plates for Receptacles . . . . .	K-22
Weatherproof Plates for Receptacles and Switches . . . . .	K-23
Weatherproof Covers for Flanged Devices . . . . .	K-24
Weatherproof Switch Plates, Covers and Locking Covers . . . . .	K-25
Heavy Duty Weatherproof Covers . . . . .	K-26
Weatherproof Covers . . . . .	K-27
While-In-Use Weatherproof Covers . . . . .	K-28
Screws and Accessories . . . . .	K-30
Technical Information . . . . .	K-31
Wallplate Dimensions . . . . .	K-32
Custom Metal Wallplates . . . . .	K-33



Features and Benefits



Nylon Wallplates



Metal Wallplates



Weatherproof Covers



## Wallplates

### Nylon Wallplates

Features and Benefits



Hubbell offers a wide variety of configurations, sizes, and finishes in both metal and nylon wallplates for use in industrial, institutional, commercial, and residential applications. We offer finishes in nylon, aluminum, brass, brass plated, chrome, and stainless steel.

We have totally redesigned and expanded our line of nylon wallplates featuring larger standard sized wallplates to give extra coverage to hide rough box opening, improved aesthetics, greater strength, impact resistance, along with excellent cleanability in all different types of environments.

- Standard size is  $\frac{1}{8}$  inch larger to give you extra coverage to hide rough box openings. Also available in mid-size and pre-marked.
- Curved corners for improved aesthetics, for use in any application.
- Reinforcement ribs for extra strength.
- Captive screw feature holds mounting screw in place for quick and easy installation.
- High-impact, self-extinguishing nylon material, which is virtually unbreakable.
- Smooth, easy to clean finish is highly resistant to solvents and cleaning solutions, providing long life in the harshest environments.
- Non-conductive material.

Nylon wallplates are designed for durability and easy cleaning. Hubbell's standard sized wallplates are  $\frac{1}{8}$  inch larger to give you that extra coverage to hide rough box openings. The depth is  $\frac{1}{4}$  inch so that it will comfortably fit over the device even on imperfect installations or on retrofit work.

#### Nylon Wallplates



#### Nylon Pre-Marked Wallplates





# Wallplates Metal Wallplates

Features and Benefits



Protective film helps to prevent scratches and damage.

### Stainless Steel

Provide solutions for a variety of industrial and commercial applications; with environments subjected to heavy abuse.

- The 302/304 type stainless steel wallplates are ideal for highly corrosive environments such as food processing, hospitals, static free requirements and more.

Non-magnetic:

18.0% Chromium

8.0% Nickel

- The 430 type stainless steel wallplates are aesthetically identical to the 302/304 type stainless steel wallplates and are best suited for environments where corrosion resistance is less critical.

Magnetic:

17.0% Chromium

Less than 0.5% Nickel

### Smooth Solid Brass

- Provides a plush appearance with the durability of metal.
- Finish is lacquer coated to inhibit oxidation.

### Anodized Aluminum

- Non-magnetic and corrosion resistance for a wide range of applications.
- Finish is lacquer coated to inhibit oxidation.

### Metallic Plated Steel

- Available in either chrome or brass finishes.

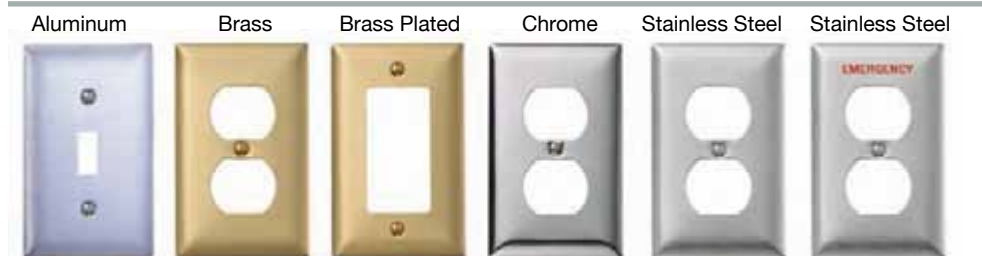


### Custom Metal Wallplates

Hubbell offers 40 custom configurations from 2-gang to 8-gang, in five different metal finishes. These custom openings can be configured in any combination to meet your specific requirements.

### Metal Wallplates


### Pre-Marked





# Wallplates
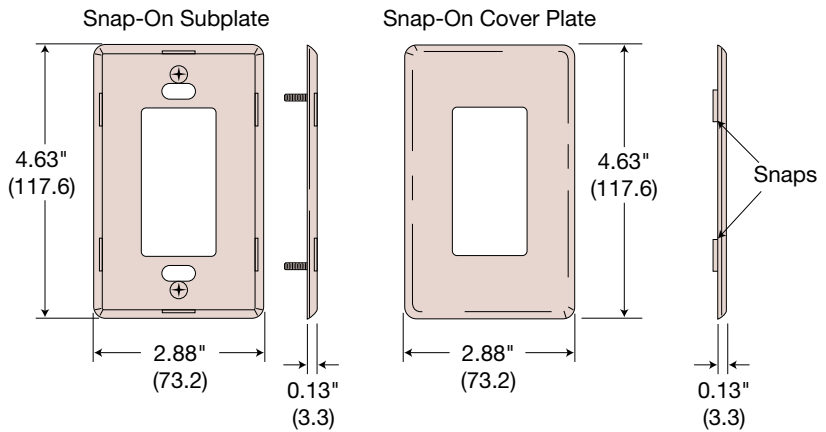
## Snap-On Wallplates



### Toggle Snap-On Wallplates

 
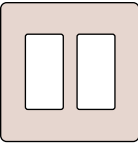
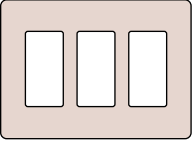
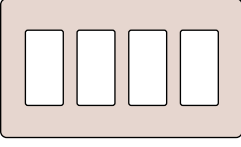
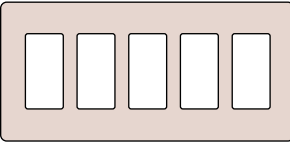
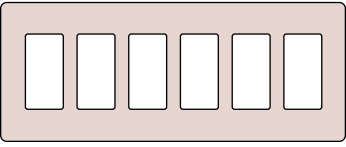
Description	Color	Catalog Number
Snap-On Wallplate, 1-Gang, 1-Toggle Style	Ivory White	<b>RFW1I</b> <b>RFW1W</b>
		
Snap-On Wallplate, 2-Gang, 2-Toggle Style	Ivory White	<b>RFW2I</b> <b>RFW2W</b>
		
Snap-On Wallplate, 3-Gang, 3-Toggle Style	Ivory White	<b>RFW3I</b> <b>RFW3W</b>
		



# Wallplates

## Decorator Snap-On Wallplates

### Decorator Snap-On Wallplates

Description	Color	Catalog Number
Snap-On Wallplate, 1-Gang, 1-Decorator 	Almond Ivory Light Almond White	RCW1AL RCW1I RCW1LA RCW1W
Snap-On Wallplate, 2-Gang, 2-Decorator 	Almond Ivory Light Almond White	RCW2AL RCW2I RCW2LA RCW2W
Snap-On Wallplate, 3-Gang, 3-Decorator 	Almond Ivory Light Almond White	RCW3AL RCW3I RCW3LA RCW3W
Snap-On Wallplate, 4-Gang, 4-Decorator 	Almond Ivory Light Almond White	RCW4AL RCW4I RCW4LA RCW4W
Snap-On Wallplate, 5-Gang, 5-Decorator 	Almond Ivory Light Almond White	RCW5AL RCW5I RCW5LA RCW5W
Snap-On Wallplate, 6-Gang, 6-Decorator 	Almond Ivory Light Almond White	RCW6AL RCW6I RCW6LA RCW6W

 
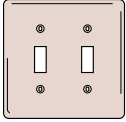
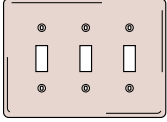
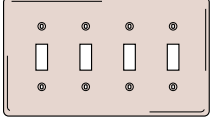
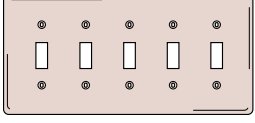
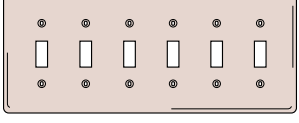

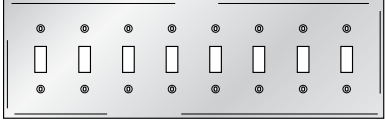
 




# Wallplates

## Toggle Switch Wallplates

### Toggle Switch Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number	
 1-Gang, 1-Toggle	Almond	NP1AL	NPJ1AL	Aluminum	SA1	
	Black	NP1BK	NPJ1BK	Brass	SB1	
	Brown	NP1	NPJ1	Brass Plated	SBP1	
	Gray	NP1GY	NPJ1GY	Chrome	SCH1	
	Ivory	NP1I	NPJ1I	S/S 302/304	SS1	
	Light Almond	NP1LA	NPJ1LA	S/S 430	SS1L	
	Office White	NP1OW	NPJ1OW	S/S Beveled	97071	
	Red	NP1R	NPJ1R	Steel, Almond*	SP1AL	
	White	NP1W	NPJ1W	Steel, Gray*	SP1G	
	 2-Gang, 2-Toggle	Almond	NP2AL	NPJ2AL	Aluminum	SA2
Black		NP2BK	NPJ2BK	Brass	SB2	
Brown		NP2	NPJ2	Brass Plated	SBP2	
Gray		NP2GY	NPJ2GY	Chrome	SCH2	
Ivory		NP2I	NPJ2I	S/S 302/304	SS2	
Light Almond		NP2LA	NPJ2LA	S/S 430	SS2L	
Office White		NP2OW	NPJ2OW	Steel, Almond*	SP2AL	
Red		NP2R	NPJ2R	Steel, Gray*	SP2G	
White		NP2W	NPJ2W			
 3-Gang, 3-Toggle		Almond	NP3AL	NPJ3AL	Aluminum	①
	Black	NP3BK	NPJ3BK	Brass	SB3	
	Brown	NP3	NPJ3	Brass Plated	SBP3	
	Gray	NP3GY	NPJ3GY	Chrome	SCH3	
	Ivory	NP3I	NPJ3I	S/S 302/304	SS3	
	Light Almond	NP3LA	NPJ3LA	S/S 430	SS3L	
	Office White	NP3OW	NPJ3OW	Steel, Almond*	SP3AL	
	Red	-	NPJ3R			
	White	NP3W	NPJ3W			
	 4-Gang, 4-Toggle	Almond	NP4AL	NPJ4AL	Aluminum	①
Black		NP4BK	NPJ4BK	Brass	SB4	
Brown		NP4	NPJ4	Brass Plated	SBP4	
Gray		NP4GY	NPJ4GY	Chrome	①	
Ivory		NP4I	NPJ4I	S/S 302/304	SS4	
Light Almond		NP4LA	NPJ4LA	S/S 430	SS4L	
Office White		NP4OW	NPJ4OW	Steel, Almond*	SP4AL	
White		NP4W	NPJ4W			
 5-Gang, 5-Toggle		Almond	NP5AL	-	Aluminum	①
		Black	NP5BK	-	Brass	SB5
	Brown	NP5	-	Brass Plated	①	
	Gray	NP5GY	-	Chrome	①	
	Ivory	NP5I	-	S/S 302/304	SS5	
	Light Almond	NP5LA	-	S/S 430	-	
	White	NP5W	-	Steel, Almond*	SP5AL	
	 6-Gang, 6-Toggle	Almond	NP6AL	-	Aluminum	①
		Brown	NP6	-	Brass	SB6
		Gray	NP6GY	-	Brass Plated	①
Ivory		NP6I	-	Chrome	①	
Light Almond		NP6LA	-	S/S 302/304	SS6	
White		NP6W	-	S/S 430	-	
 7-Gang, 7-Toggle		Almond	-	-	Aluminum	①
		Brown	-	-	Brass	①
		Gray	-	-	Brass Plated	①
		Ivory	-	-	Chrome	①
	White	-	-	S/S 302/304	SS607	
	 8-Gang, 8-Toggle	Almond	-	-	Aluminum	①
		Brown	-	-	Brass	①
		Gray	-	-	Brass Plated	①
		Ivory	-	-	Chrome	①
		White	-	-	S/S 302/304	SS608
 2-Gang, 1-Toggle		Almond	-	-	Aluminum	-
		Brown	-	-	Brass	-
		Gray	-	-	Brass Plated	-
		Ivory	-	-	Chrome	-
		White	-	-	S/S 302/304	SS740
				S/S 430	-	

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

① Available as a custom wallplate. See pages K-33 to K-38. Consult custom wallplates section for additional openings and combinations.

 
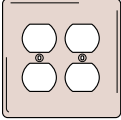
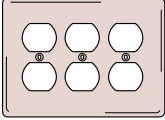
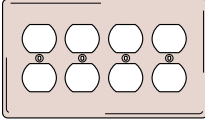
 
\* Powder coat paint finish.








# Wallplates Duplex and Single Receptacle Wallplates

## Duplex Receptacle Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number	
 1-Gang, 1-Duplex	Almond	NP8AL	NPJ8AL	Aluminum	SA8	
	Black	NP8BK	NPJ8BK	Brass	SB8	
	Blue	-	NPJ8BL	Brass Plated	SBP8	
	Brown	NP8	NPJ8	Chrome	SCH8	
	Gray	NP8GY	NPJ8GY	S/S 302/304	SS8	
	Ivory	NP8I	NPJ8I	S/S 430	SS8L	
	Light Almond	NP8LA	NPJ8LA	S/S Beveled	97101	
	Office White	NP8OW	NPJ8OW	Steel, Almond*	SP8AL	
	Orange	NP8OR	-	Steel, Gray*	SP8G	
	Red	NP8R	NPJ8R			
	White	NP8W	NPJ8W			
	 2-Gang, 2-Duplex	Almond	NP82AL	NPJ82AL	Aluminum	SA82
		Black	NP82BK	NPJ82BK	Brass	SB82
Brown		NP82	NPJ82	Brass Plated	SBP82	
Gray		NP82GY	NPJ82GY	Chrome	SCH82	
Ivory		NP82I	NPJ82I	S/S 302/304	SS82	
Light Almond		NP82LA	NPJ82LA	S/S 430	SS82L	
Office White		NP82OW	NPJ82OW	Steel, Almond*	SP82AL	
Orange		NP82OR	-	Steel, Gray*	SP82G	
Red		NP82R	NPJ82R			
White		NP82W	NPJ82W			
 3-Gang, 3-Duplex		Almond	NP83AL	-	Aluminum	①
	Black	NP83BK	-	Brass	①	
	Brown	NP83	-	Brass Plated	①	
	Gray	NP83GY	-	Chrome	①	
	Ivory	NP83I	-	S/S 302/304	SS83	
	White	NP83W	-	S/S 430	-	
 4-Gang, 4-Duplex	Almond	NP84AL	-	Aluminum	①	
	Black	NP84BK	-	Brass	①	
	Brown	NP84	-	Brass Plated	①	
	Gray	NP84GY	-	Chrome	①	
	Ivory	NP84I	-	S/S 302/304	SS84	
	White	NP84W	-	S/S 430	-	
 2-Gang, 1-Duplex	-	-	-	Brass	-	
	-	-	-	Brass Plated	-	
	-	-	-	Chrome	-	
	-	-	-	S/S 302/304	SS748	
	-	-	-	S/S 430	-	
 
## Single 15/20A Straight Blade or 15A Twist-Lock® Receptacle Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
 1-Gang, 1-Single 1.40 in. (35.6) Dia. Hole	Almond	NP7AL	NPJ7AL	Aluminum	SA7
	Black	NP7BK	NPJ7BK	Brass	SB7
	Brown	NP7	NPJ7	Brass Plated	SBP7
	Gray	NP7GY	NPJ7GY	Chrome	SCH7
	Ivory	NP7I	NPJ7I	S/S 302/304	SS7
	Light Almond	NP7LA	NPJ7LA	S/S 430	SS7L
	Office White	NP7OW	NPJ7OW	Steel, Almond*	SP7AL
	Red	NP7R	NPJ7R	Steel, Gray*	SP7G
	White	NP7W	NPJ7W		
	 2-Gang, 1-Single 1.40 in. (35.6) Dia. Hole	-	-	-	Aluminum
-		-	-	Brass	-
-		-	-	Brass Plated	-
-		-	-	Chrome	-
-		-	-	S/S 302/304	SS747
 2-Gang, 2-Single 1.40 in. (35.6) Dia. Hole	-	-	-	Aluminum	①
	-	-	-	Brass	①
	-	-	-	Brass Plated	①
	-	-	-	Chrome	①
	-	-	-	S/S 302/304	SS72
-	-	-	S/S 430	-	

 

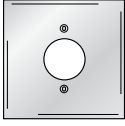
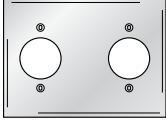
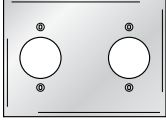
Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.  
 ① Available as a custom wallplate. See pages K-33 to K-38. Consult custom wallplates section for additional openings and combinations.  
 \* Powder coat paint finish.








## Wallplates

### Single Receptacle Wallplates

#### Single 20/30A Twist-Lock® Receptacle Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
 1-Gang, 1-Single 1.60 in. (40.6) Dia. Hole	Almond	NP720AL	-	Aluminum	SA720
	Black	NP720BK	-	Brass	SB720
	Brown	NP720	-	Brass Plated	①
	Gray	NP720GY	-	Chrome	①
	Ivory	NP720I	-	S/S 302/304	SS720
	Office White	NP720OW	-	S/S 430	-
	Red	NP720R	-		
	White	NP720W	-		
 1-Gang, 1-Single 1.70 in. (43.2) Dia. Hole	-	-	-	Aluminum	-
	-	-	-	Brass	-
	-	-	-	Brass Plated	-
	-	-	-	Chrome	-
	-	-	-	S/S 302/304	SS725
	-	-	-	S/S 430	-
 2-Gang, 1-Single 1.60 in. (40.6) Dia. Hole	-	-	-	Aluminum	-
	-	-	-	Brass	-
	-	-	-	Brass Plated	-
	-	-	-	Chrome	-
	-	-	-	S/S 302/304	SS749
	-	-	-	S/S 430	-
 3-Gang, 2-Single 1.60 in. (40.6) Dia. Hole	-	-	-	Aluminum	-
	-	-	-	Brass	-
	-	-	-	Brass Plated	-
	-	-	-	Chrome	-
	-	-	-	S/S 302/304	SS320
	-	-	-	S/S 430	-
 3-Gang, 2-Single 1.70 in. (43.2) Dia. Hole	-	-	-	Aluminum	-
	-	-	-	Brass	-
	-	-	-	Brass Plated	-
	-	-	-	Chrome	-
	-	-	-	S/S 302/304	SS330
	-	-	-	S/S 430	-
 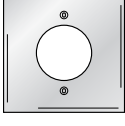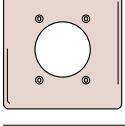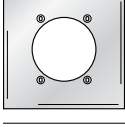 
#### Single Receptacle Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
 1-Gang, 1-Single 2.15 in. (54.6) Dia. Hole	Almond	NP724AL	NPJ724AL	Aluminum	SA723
	Black	NP724BK	NPJ724BK	Brass	①
	Brown	NP724	NPJ724	Brass Plated	①
	Gray	NP724GY	NPJ724GY	Chrome	SCH723
	Ivory	NP724I	NPJ724I	S/S 302/304	SS723
	White	NP724W	NPJ724W	S/S 430	SS723L
 2-Gang, 1-Single 2.15 in. (54.6) Dia. Hole	-	-	-	Aluminum	-
	-	-	-	Brass	-
	-	-	-	Brass Plated	-
	-	-	-	Chrome	SCH702
	-	-	-	S/S 302/304	SS702
	-	-	-	S/S 430	-
 2-Gang, 1-Single 2.15 in. (54.6) Dia. Hole	Almond	NP703AL	NPJ703AL	Aluminum	-
	Black	NP703BK	NPJ703BK	Brass	-
	Brown	NP703	NPJ703	Brass Plated	-
	Gray	NP703GY	NPJ703GY	Chrome	-
	Ivory	NP703I	NPJ703I	S/S 302/304	SS703
	White	NP703W	NPJ703W	S/S 430	SS703L
 2-Gang, 1-Single 2.48 in. (63.0) Dia. Hole	-	-	-	Aluminum	-
	-	-	-	Brass	-
	-	-	-	Brass Plated	-
	-	-	-	Chrome	-
	-	-	-	S/S 302/304	SS701
	-	-	-	S/S 430	-
 2-Gang, 1-Single 2.66 in. (67.6) Dia. Hole	-	-	-	Aluminum	-
	-	-	-	Brass	-
	-	-	-	Brass Plated	-
	-	-	-	Chrome	-
	-	-	-	S/S 302/304	SS716
	-	-	-	S/S 430	-

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

① Available as a custom wallplate. See pages K-33 to K-38. Consult custom wallplates section for additional openings and combinations.


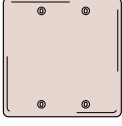
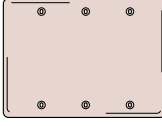
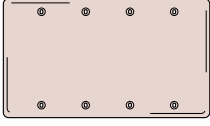
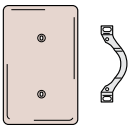
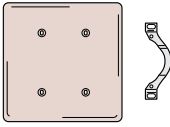
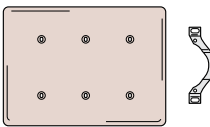
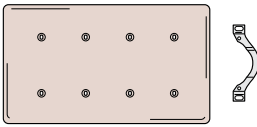




# Wallplates

## Blank Wallplates

### Blank Wallplates, Box Mount and Strap Mount

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
 1-Gang, 1-Blank, Box Mount	Almond	<b>NP13AL</b>	<b>NPJ13AL</b>	Aluminum	<b>SA13A</b>
	Black	<b>NP13BK</b>	<b>NPJ13BK</b>	Brass	<b>SB13</b>
	Brown	<b>NP13</b>	<b>NPJ13</b>	Brass Plated	<b>SBP13</b>
	Gray	<b>NP13GY</b>	<b>NPJ13GY</b>	Chrome	<b>SCH13</b>
	Ivory	<b>NP13I</b>	<b>NPJ13I</b>	S/S 302/304	<b>SS13</b>
	Light Almond	<b>NP13LA</b>	<b>NPJ13LA</b>	S/S 430	<b>SS13L</b>
	Office White	<b>NP13OW</b>	<b>NPJ13OW</b>	Steel, Almond*	<b>SP14BAL</b>
	White	<b>NP13W</b>	<b>NPJ13W</b>	Steel, Gray*	<b>SP14BG</b>
 2-Gang, 2-Blank, Box Mount	Almond	<b>NP23AL</b>	<b>NPJ23AL</b>	Aluminum	<b>SA23</b>
	Black	<b>NP23BK</b>	-	Brass	<b>SB23</b>
	Brown	<b>NP23</b>	<b>NPJ23</b>	Brass Plated	①
	Gray	<b>NP23GY</b>	-	Chrome	<b>SCH23</b>
	Ivory	<b>NP23I</b>	<b>NPJ23I</b>	S/S 302/304	<b>SS23</b>
	Light Almond	<b>NP23LA</b>	<b>NPJ23LA</b>	S/S 430	<b>SS23L</b>
	Office White	<b>NP23OW</b>	<b>NPJ23OW</b>	Steel, Almond*	<b>SP24BAL</b>
	White	<b>NP23W</b>	<b>NPJ23W</b>	Steel, Gray*	<b>SP24BG</b>
 3-Gang, 3-Blank, Box Mount	Almond	<b>NP33AL</b>	-	Aluminum	①
	Brown	<b>NP33</b>	-	Brass	①
	Ivory	<b>NP33I</b>	-	Brass Plated	①
	White	<b>NP33W</b>	-	Chrome	①
					S/S 302/304
 4-Gang, 4-Blank, Box Mount	Almond	<b>NP43AL</b>	-	Aluminum	①
	Brown	<b>NP43</b>	-	Brass	①
	Ivory	<b>NP43I</b>	-	Brass Plated	①
	White	<b>NP43W</b>	-	Chrome	①
					S/S 302/304
 1-Gang, 1-Blank, Strap Mount	Almond	<b>NP14AL</b>	-	Aluminum	①
	Black	<b>NP14BK</b>	-	Brass	<b>SB14</b>
	Brown	<b>NP14</b>	-	Brass Plated	①
	Gray	<b>NP14GY</b>	-	Chrome	①
	Ivory	<b>NP14I</b>	-	S/S 302/304	<b>SS14</b>
	Office White	<b>NP14OW</b>	-	S/S 430	<b>SS14L</b>
	Red	<b>NP14R</b>	-	Steel, Almond*	<b>SP14AL</b>
	White	<b>NP14W</b>	-	Steel, Gray*	<b>SP14G</b>
 2-Gang, 2-Blank, Strap Mount	Almond	<b>NP24AL</b>	-	Aluminum	①
	Black	<b>NP24BK</b>	-	Brass	①
	Brown	<b>NP24</b>	-	Brass Plated	①
	Gray	<b>NP24GY</b>	-	Chrome	①
	Ivory	<b>NP24I</b>	-	S/S 302/304	<b>SS24</b>
	Office White	<b>NP24OW</b>	-	S/S 430	<b>SS24L</b>
	Red	<b>NP24R</b>	-	Steel, Almond*	<b>SP24AL</b>
	White	<b>NP24W</b>	-	Steel, Gray*	<b>SP24G</b>
 3-Gang, 3-Blank, Strap Mount	Almond	<b>NP34AL</b>	-	Aluminum	①
	Brown	<b>NP34</b>	-	Brass	①
	Ivory	<b>NP34I</b>	-	Brass Plated	①
	White	<b>NP34W</b>	-	Chrome	①
					S/S 302/304
 4-Gang, 4-Blank, Strap Mount	Almond	<b>NP44AL</b>	-	Aluminum	①
	Brown	<b>NP44</b>	-	Brass	①
	Ivory	<b>NP44I</b>	-	Brass Plated	①
	White	<b>NP44W</b>	-	Chrome	①
					S/S 302/304
				S/S 430	-


 

 
 

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.  
 ① Available as a custom wallplate. See pages K-33 to K-38. Consult custom wallplates section for additional openings and combinations.  
 \* Powder coat paint finish.






## Wallplates

### 347 Volt Wallplates

#### 347 Volt Toggle Wallplates with 2.25" (57.2) Spacing Between Gangs, Stamped "347V"

Description	Color	Nylon Catalog Number	Material	Metal Catalog Number
1-Gang, 1-Toggle 2.25 in. (57.2) Spacing 	-	-	Aluminum	-
	-	-	Brass	-
	-	-	Brass Plated	-
	-	-	Chrome	-
	-	-	S/S 302/304	<b>SS1C</b>
-	-	-	S/S 430	-
2-Gang, 2-Toggle 2.25 in. (57.2) Spacing 	-	-	Aluminum	-
	-	-	Brass	-
	-	-	Brass Plated	-
	-	-	Chrome	-
	-	-	S/S 302/304	<b>SS2C</b>
-	-	-	S/S 430	-
3-Gang, 3-Toggle 2.25 in. (57.2) Spacing 	-	-	Aluminum	-
	-	-	Brass	-
	-	-	Brass Plated	-
	-	-	Chrome	-
	-	-	S/S 302/304	<b>SS3C</b>
-	-	-	S/S 430	-
4-Gang, 4-Toggle 2.25 in. (57.2) Spacing 	-	-	Aluminum	-
	-	-	Brass	-
	-	-	Brass Plated	-
	-	-	Chrome	-
	-	-	S/S 302/304	<b>SS4C</b>
-	-	-	S/S 430	-
5-Gang, 5-Toggle 2.25 in. (57.2) Spacing 	-	-	Aluminum	-
	-	-	Brass	-
	-	-	Brass Plated	-
	-	-	Chrome	-
	-	-	S/S 302/304	<b>SS5C</b>
-	-	-	S/S 430	-
6-Gang, 6-Toggle 2.25 in. (57.2) Spacing 	-	-	Aluminum	-
	-	-	Brass	-
	-	-	Brass Plated	-
	-	-	Chrome	-
	-	-	S/S 302/304	<b>SS6C</b>
-	-	-	S/S 430	-
   
#### 347 Volt Decorator Wallplates







Description	Color	Nylon Catalog Number	Material	Metal Catalog Number
1-Gang, 1-Decorator 	Black	<b>HPS1347BK</b>	Aluminum	-
	Gray	<b>HPS1347GY</b>	Brass	-
	Ivory	<b>HPS1347I</b>	Brass Plated	-
	White	<b>HPS1347W</b>	Chrome	-
	-	-	S/S 302/304	-
-	-	-	S/S 430	-
2-Gang, 2-Decorator 	Black	<b>HPS2347BK</b>	Aluminum	-
	Gray	<b>HPS2347GY</b>	Brass	-
	Ivory	<b>HPS2347I</b>	Brass Plated	-
	White	<b>HPS2347W</b>	Chrome	-
	-	-	S/S 302/304	-
-	-	-	S/S 430	-
3-Gang, 3-Decorator 	Ivory	<b>HPS3347I</b>	Aluminum	-
	White	<b>HPS3347W</b>	Brass	-
	-	-	Brass Plated	-
	-	-	Chrome	-
	-	-	S/S 302/304	-
-	-	-	S/S 430	-

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.



# Wallplates Decorator Wallplates
      
## GFCI, Surge Receptacles and Style Line® Device Wallplates

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number	
	Almond	<b>NP26AL</b>	<b>NPJ26AL</b>	Aluminum	①	
	Black	<b>NP26BK</b>	<b>NPJ26BK</b>	Brass	<b>SB26</b>	
	Blue	-	<b>NPJ26BL</b>	Brass Plated	<b>SBP26</b>	
	Brown	<b>NP26</b>	<b>NPJ26</b>	Chrome	<b>SCH26</b>	
	Gray	<b>NP26GY</b>	<b>NPJ26GY</b>	S/S 302/304	<b>SS26</b>	
	Ivory	<b>NP26I</b>	<b>NPJ26I</b>	S/S 430	<b>SS26L</b>	
	Light Almond	<b>NP26LA</b>	<b>NPJ26LA</b>	Steel, Almond*	<b>PHPS1AL</b>	
	Office White	<b>NP26OW</b>	<b>NPJ26OW</b>	Steel, Gray*	<b>PHPS1G</b>	
	Red	<b>NP26R</b>	<b>NPJ26R</b>			
	White	<b>NP26W</b>	<b>NPJ26W</b>			
		Almond	<b>NP262AL</b>	<b>NPJ262AL</b>	Aluminum	①
Black		<b>NP262BK</b>	<b>NPJ262BK</b>	Brass	<b>SB262</b>	
Brown		<b>NP262</b>	<b>NPJ262</b>	Brass Plated	<b>SBP262</b>	
Gray		<b>NP262GY</b>	<b>NPJ262GY</b>	Chrome	<b>SCH262</b>	
Ivory		<b>NP262I</b>	<b>NPJ262I</b>	S/S 302/304	<b>SS262</b>	
Light Almond		<b>NP262LA</b>	<b>NPJ262LA</b>	S/S 430	<b>SS262L</b>	
Office White		<b>NP262OW</b>	<b>NPJ262OW</b>	Steel, Almond*	<b>PHPS2AL</b>	
Red		<b>NP262R</b>	<b>NPJ262R</b>	Steel, Gray*	<b>PHPS2G</b>	
White		<b>NP262W</b>	<b>NPJ262W</b>			
		Almond	<b>NP263AL</b>	<b>NPJ263AL</b>	Aluminum	①
		Black	<b>NP263BK</b>	<b>NPJ263BK</b>	Brass	①
	Brown	<b>NP263</b>	<b>NPJ263</b>	Brass Plated	<b>SBP263</b>	
	Gray	<b>NP263GY</b>	<b>NPJ263GY</b>	Chrome	①	
	Ivory	<b>NP263I</b>	<b>NPJ263I</b>	S/S 302/304	<b>SS263</b>	
	Light Almond	<b>NP263LA</b>	<b>NPJ263LA</b>	S/S 430	-	
	Office White	<b>NP263OW</b>	<b>NPJ263OW</b>	Steel, Almond*	<b>PHPS3AL</b>	
	Red	<b>NP263R</b>	<b>NPJ263R</b>			
	White	<b>NP263W</b>	<b>NPJ263W</b>			
		Almond	<b>NP264AL</b>	<b>NPJ264AL</b>	Aluminum	①
		Black	<b>NP264BK</b>	<b>NPJ264BK</b>	Brass	①
Brown		<b>NP264</b>	<b>NPJ264</b>	Brass Plated	①	
Gray		<b>NP264GY</b>	<b>NPJ264GY</b>	Chrome	①	
Ivory		<b>NP264I</b>	<b>NPJ264I</b>	S/S 302/304	<b>SS264</b>	
Light Almond		<b>NP264LA</b>	<b>NPJ264LA</b>	S/S 430	-	
Office White		<b>NP264OW</b>	<b>NPJ264OW</b>	Steel, Almond*	<b>PHPS4AL</b>	
White		<b>NP264W</b>	<b>NPJ264W</b>			
		Almond	<b>NP265AL</b>	-	Aluminum	①
		Black	<b>NP265BK</b>	-	Brass	①
		Brown	<b>NP265</b>	-	Brass Plated	①
	Gray	<b>NP265GY</b>	-	Chrome	①	
	Ivory	<b>NP265I</b>	-	S/S 302/304	<b>SS265</b>	
	Light Almond	<b>NP265LA</b>	-	S/S 430	-	
	White	<b>NP265W</b>	-	Steel, Almond*	<b>PHPS5AL</b>	
		Almond	<b>NP266AL</b>	-	Aluminum	①
Black		<b>NP266BK</b>	-	Brass	①	
Brown		<b>NP266</b>	-	Brass Plated	①	
Gray		<b>NP266GY</b>	-	Chrome	①	
Ivory		<b>NP266I</b>	-	S/S 302/304	<b>SS266</b>	
Light Almond		<b>NP266LA</b>	-	S/S 430	-	
White		<b>NP266W</b>	-	Steel, Almond*	<b>PHPS6AL</b>	

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.  
 ①Available as a custom wallplate. See pages K-33 to K-38. Consult custom wallplates section for additional openings and combinations.  
 \* Powder coat paint finish.













# Wallplates
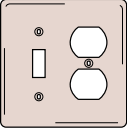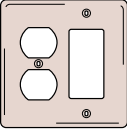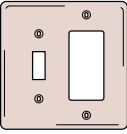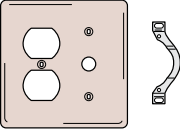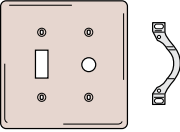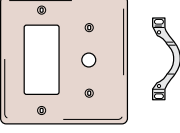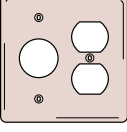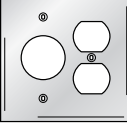
## Combination Wallplates, 2-Gang

### Combination Wallplates, 2-Gang

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number	
2-Gang, 1-Toggle, 1-Duplex 	Almond	<b>NP18AL</b>	<b>NPJ18AL</b>	Aluminum	①	
	Black	<b>NP18BK</b>	<b>NPJ18BK</b>	Brass	①	
	Brown	<b>NP18</b>	<b>NPJ18</b>	Brass Plated	<b>SBP18</b>	
	Gray	<b>NP18GY</b>	<b>NPJ18GY</b>	Chrome	<b>SCH18</b>	
	Ivory	<b>NP18I</b>	<b>NPJ18I</b>	S/S 302/304	<b>SS18</b>	
	Light Almond	<b>NP18LA</b>	<b>NPJ18LA</b>	S/S 430	<b>SS18L</b>	
	Office White	<b>NP18OW</b>	<b>NPJ18OW</b>	Steel, Almond*	<b>SP18AL</b>	
	Red	<b>NP18R</b>	<b>NPJ18R</b>	Steel, Gray*	<b>SP18G</b>	
	White	<b>NP18W</b>	<b>NPJ18W</b>			
	2-Gang, 1-Duplex, 1-Decorator 	Almond	<b>NP826AL</b>	<b>NPJ826AL</b>	Aluminum	①
		Black	<b>NP826BK</b>	<b>NPJ826BK</b>	Brass	<b>SB826</b>
Brown		<b>NP826</b>	<b>NPJ826</b>	Brass Plated	①	
Gray		<b>NP826GY</b>	<b>NPJ826GY</b>	Chrome	①	
Ivory		<b>NP826I</b>	<b>NPJ826I</b>	S/S 302/304	<b>SS826</b>	
Light Almond		<b>NP826LA</b>	<b>NPJ826LA</b>	S/S 430	-	
Office White		<b>NP826OW</b>	<b>NPJ826OW</b>			
White		<b>NP826W</b>	<b>NPJ826W</b>			
2-Gang, 1-Toggle, 1-Decorator 		Almond	<b>NP126AL</b>	<b>NPJ126AL</b>	Aluminum	①
		Black	<b>NP126BK</b>	<b>NPJ126BK</b>	Brass	<b>SB126</b>
		Brown	<b>NP126</b>	<b>NPJ126</b>	Brass Plated	<b>SBP126</b>
	Gray	<b>NP126GY</b>	<b>NPJ126GY</b>	Chrome	①	
	Ivory	<b>NP126I</b>	<b>NPJ126I</b>	S/S 302/304	<b>SS126</b>	
	Light Almond	<b>NP126LA</b>	<b>NPJ126LA</b>	S/S 430	<b>SS126L</b>	
	White	<b>NP126W</b>	<b>NPJ126W</b>	Steel, Almond*	<b>PJS126AL</b>	
				Steel, Gray*	<b>PJS126G</b>	
	2-Gang, 1-Duplex, 1-Telephone .406 in. (10.3) Hole Strap Mount 	Almond	<b>NP128AL</b>	-	Aluminum	-
		Black	<b>NP128BK</b>	-	Brass	-
		Brown	<b>NP128</b>	-	Brass Plated	-
Gray		<b>NP128GY</b>	-	Chrome	-	
Ivory		<b>NP128I</b>	-	S/S 302/304	-	
White		<b>NP128W</b>	-	S/S 430	-	
2-Gang, 1-Toggle, 1-Telephone .406 in. (10.3) Hole Strap Mount 		Almond	<b>NP112AL</b>	-	Aluminum	-
	Black	<b>NP112BK</b>	-	Brass	-	
	Brown	<b>NP112</b>	-	Brass Plated	-	
	Gray	<b>NP112GY</b>	-	Chrome	-	
	Ivory	<b>NP112I</b>	-	S/S 302/304	-	
	Office White	<b>NP112OW</b>	-	S/S 430	-	
	White	<b>NP112W</b>	-			
2-Gang, 1-Decorator, 1-Telephone .406 in. (10.3) Hole Strap Mount 	Almond	<b>NP1226AL</b>	-	Aluminum	-	
	Black	<b>NP1226BK</b>	-	Brass	-	
	Brown	<b>NP1226</b>	-	Brass Plated	-	
	Gray	<b>NP1226GY</b>	-	Chrome	-	
	Ivory	<b>NP1226I</b>	-	S/S 302/304	-	
	White	<b>NP1226W</b>	-	S/S 430	-	
	2-Gang, 1-Single Receptacle 1.40 in. (35.6) Hole, 1-Duplex 	Almond	<b>NP78AL</b>	-	Aluminum	①
Brown		<b>NP78</b>	-	Brass	①	
Gray		<b>NP78GY</b>	-	Brass Plated	①	
Ivory		<b>NP78I</b>	-	Chrome	①	
White		<b>NP78W</b>	-	S/S 302/304	<b>SS78</b>	
				S/S 430	-	
2-Gang, 1-Single Recept. 1.60 in. (40.6) Hole, 1-Duplex 	Almond	-	-	Aluminum	①	
	Brown	-	-	Brass	①	
	Ivory	-	-	Brass Plated	①	
	White	-	-	Chrome	①	
				S/S 302/304	<b>SS8720</b>	
				S/S 430	-	

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

① Available as a custom wallplate. See pages K-33 to K-38. Consult custom wallplates section for additional openings and combinations.









\* Powder coat paint finish.



## Wallplates
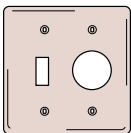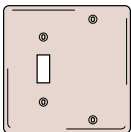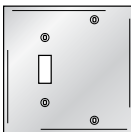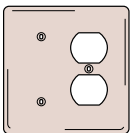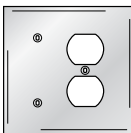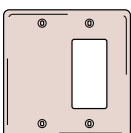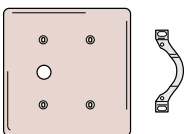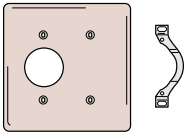
### Combination Wallplates, 2-Gang

#### Combination Wallplates, 2-Gang

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
2-Gang, 1-Toggle, 1-Single Receptacle 1.40 in. (35.6) Hole 	Almond	<b>NP17AL</b>	-	Aluminum	①
	Black	<b>NP17BK</b>	-	Brass	①
	Brown	<b>NP17</b>	-	Brass Plated	①
	Gray	<b>NP17GY</b>	-	Chrome	①
	Ivory	<b>NP17I</b>	-	S/S 302/304	<b>SS17</b>
	White	<b>NP17W</b>	-	S/S 430	-
2-Gang, 1-Toggle, 1-Blank, Box Mount 	Almond	<b>NP113AL</b>	<b>NPJ113AL</b>	Aluminum	①
	Black	<b>NP113BK</b>	-	Brass	①
	Brown	<b>NP113</b>	<b>NPJ113</b>	Brass Plated	①
	Gray	<b>NP113GY</b>	-	Chrome	①
	Ivory	<b>NP113I</b>	<b>NPJ113I</b>	S/S 302/304	<b>SS113</b>
	Light Almond	<b>NP113LA</b>	-	S/S 430	-
	White	<b>NP113W</b>	-		
2-Gang, 1-Toggle, 1-Blank, Strap Mount 	Almond	-	-	Aluminum	①
	Brown	-	-	Brass	①
	Ivory	-	-	Brass Plated	①
	Light Almond	-	-	Chrome	①
	White	-	-	S/S 302/304	<b>SS114</b>
				S/S 430	-
2-Gang, 1-Blank, 1-Duplex, Box Mount 	Almond	<b>NP138AL</b>	<b>NPJ138AL</b>	Aluminum	①
	Black	<b>NP138BK</b>	-	Brass	①
	Brown	<b>NP138</b>	<b>NPJ138</b>	Brass Plated	①
	Gray	<b>NP138GY</b>	-	Chrome	①
	Ivory	<b>NP138I</b>	<b>NPJ138I</b>	S/S 302/304	<b>SS138</b>
	Light Almond	<b>NP138LA</b>	-	S/S 430	-
	White	<b>NP138W</b>	<b>NPJ138W</b>		
2-Gang, 1-Blank, 1-Duplex, Strap Mount 	Almond	-	-	Aluminum	①
	Brown	-	-	Brass	①
	Ivory	-	-	Brass Plated	①
	White	-	-	Chrome	①
				S/S 302/304	<b>SS148</b>
			S/S 430	-	
2-Gang, 1-Blank, 1-Decorator, Box Mount 	Almond	<b>NP1326AL</b>	<b>NPJ1326AL</b>	Aluminum	①
	Black	<b>NP1326BK</b>	<b>NPJ1326BK</b>	Brass	①
	Brown	<b>NP1326</b>	<b>NPJ1326</b>	Brass Plated	①
	Gray	<b>NP1326GY</b>	<b>NPJ1326GY</b>	Chrome	①
	Ivory	<b>NP1326I</b>	<b>NPJ1326I</b>	S/S 302/304	<b>SS1426*</b>
	Light Almond	<b>NP1326LA</b>	<b>NPJ1326LA</b>	S/S 430	-
	White	<b>NP1326W</b>	<b>NPJ1326W</b>		
2-Gang, 1-Telephone, .406 in. (10.3) Hole, 1-Blank, Strap Mount 	Almond	<b>NP1214AL</b>	-	Aluminum	-
	Black	<b>NP1214BK</b>	-	Brass	-
	Brown	<b>NP1214</b>	-	Brass Plated	-
	Gray	<b>NP1214GY</b>	-	Chrome	-
	Ivory	<b>NP1214I</b>	-	S/S 302/304	-
	White	<b>NP1214W</b>	-	S/S 430	-
2-Gang, 1-Single Receptacle 1.40 in. (35.6) Hole 1-Blank, Strap Mount 	Almond	<b>NP147AL</b>	-	Aluminum	-
	Black	<b>NP147BK</b>	-	Brass	-
	Brown	<b>NP147</b>	-	Brass Plated	-
	Gray	<b>NP147GY</b>	-	Chrome	-
	Ivory	<b>NP147I</b>	-	S/S 302/304	-
	White	<b>NP147W</b>	-	S/S 430	-

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

① Available as a custom wallplate. See pages K-33 to K-38. Consult custom wallplates section for additional openings and combinations.








\* Strap Mount.



# Wallplates
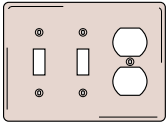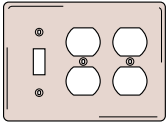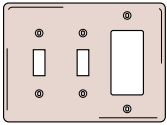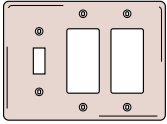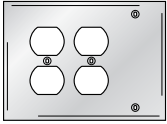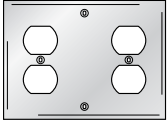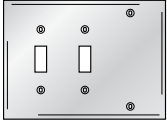
## Combination Wallplates, 3-Gang

### Combination Wallplates, 3-Gang

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
	Almond	<b>NP28AL</b>	<b>NPJ28AL</b>	Aluminum	①
	Black	<b>NP28BK</b>	-	Brass	①
	Brown	<b>NP28</b>	<b>NPJ28</b>	Brass Plated	<b>SBP28</b>
	Gray	<b>NP28GY</b>	-	Chrome	①
	Ivory	<b>NP28I</b>	<b>NPJ28I</b>	S/S 302/304	<b>SS28</b>
	Light Almond	<b>NP28LA</b>	<b>NPJ28LA</b>	S/S 430	-
	Office White	<b>NP28OW</b>	-	Steel, Almond*	<b>SP28AL</b>
	White	<b>NP28W</b>	<b>NPJ28W</b>	Steel, Gray*	<b>SP28G</b>
	Almond	<b>NP182AL</b>	-	Aluminum	①
	Black	<b>NP182BK</b>	-	Brass	①
	Brown	<b>NP182</b>	-	Brass Plated	①
	Gray	<b>NP182GY</b>	-	Chrome	①
	Ivory	<b>NP182I</b>	-	S/S 302/304	<b>SS182</b>
	White	<b>NP182W</b>	-	S/S 430	-
	Almond	<b>NP226AL</b>	<b>NPJ226AL</b>	Aluminum	①
	Black	<b>NP226BK</b>	<b>NPJ226BK</b>	Brass	①
	Brown	<b>NP226</b>	<b>NPJ226</b>	Brass Plated	①
	Gray	<b>NP226GY</b>	<b>NPJ226GY</b>	Chrome	①
	Ivory	<b>NP226I</b>	<b>NPJ226I</b>	S/S 302/304	<b>SS226</b>
	Light Almond	<b>NP226LA</b>	<b>NPJ226LA</b>	S/S 430	-
	White	<b>NP226W</b>	<b>NPJ226W</b>	Steel, Gray*	<b>PJS226G</b>
	Almond	<b>NP1262AL</b>	-	Aluminum	①
	Black	<b>NP1262BK</b>	-	Brass	①
	Brown	<b>NP1262</b>	-	Brass Plated	①
	Gray	<b>NP1262GY</b>	-	Chrome	①
	Ivory	<b>NP1262I</b>	-	S/S 302/304	①
	Light Almond	<b>NP1262LA</b>	-	S/S 430	-
	Almond	-	-	Aluminum	①
	Brown	-	-	Brass	①
	Ivory	-	-	Brass Plated	①
	White	-	-	Chrome	①
					S/S 302/304
				S/S 430	-
	Almond	-	-	Aluminum	①
	Brown	-	-	Brass	①
	Ivory	-	-	Brass Plated	①
	White	-	-	Chrome	①
					S/S 302/304
				S/S 430	-
	Almond	-	-	Aluminum	①
	Brown	-	-	Brass	①
	Ivory	-	-	Brass Plated	①
	White	-	-	Chrome	①
					S/S 302/304
				S/S 430	-

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.

① Available as a custom wallplate. See pages K-33 to K-38. Consult custom wallplates section for additional openings and combinations.





\* Powder coat paint finish.





# Wallplates Combination Wallplates, 4- and 5-Gang
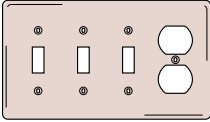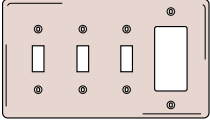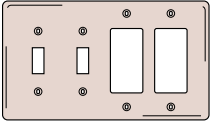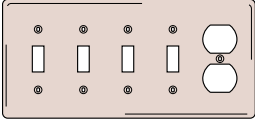
## Combination Plates, 4- and 5-Gang

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
4-Gang, 3-Toggle, 1-Duplex 	Almond	<b>NP38AL</b>	-	Aluminum	①
	Black	<b>NP38BK</b>	-	Brass	①
	Brown	<b>NP38</b>	-	Brass Plated	①
	Gray	<b>NP38GY</b>	-	Chrome	①
	Ivory	<b>NP38I</b>	-	S/S 302/304	<b>SS38</b>
	Light Almond	<b>NP38LA</b>	-	S/S 430	-
	White	<b>NP38W</b>	-		
4-Gang, 3-Toggle, 1-Decorator 	Almond	<b>NP326AL</b>	-	Aluminum	①
	Black	<b>NP326BK</b>	-	Brass	①
	Brown	<b>NP326</b>	-	Brass Plated	①
	Gray	<b>NP326GY</b>	-	Chrome	①
	Ivory	<b>NP326I</b>	-	S/S 302/304	<b>SS326</b>
	Light Almond	<b>NP326LA</b>	-	S/S 430	-
	White	<b>NP326W</b>	-		
4-Gang, 2-Toggle, 2-Decorator 	Almond	<b>NP2262AL</b>	-	Aluminum	①
	Black	<b>NP2262BK</b>	-	Brass	①
	Brown	<b>NP2262</b>	-	Brass Plated	①
	Gray	<b>NP2262GY</b>	-	Chrome	①
	Ivory	<b>NP2262I</b>	-	S/S 302/304	①
	Light Almond	<b>NP2262LA</b>	-	S/S 430	-
	White	<b>NP2262W</b>	-		
5-Gang, 4-Toggle, 1-Duplex 	Almond	<b>NP48AL</b>	-	Aluminum	①
	Brown	<b>NP48</b>	-	Brass	①
	Ivory	<b>NP48I</b>	-	Brass Plated	①
	White	<b>NP48W</b>	-	Chrome	①
				S/S 302/304	①
			S/S 430	-	

 
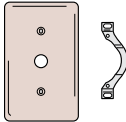
 
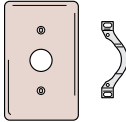

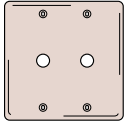
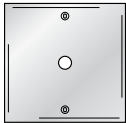
Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.  
 ①Available as a custom wallplate. See pages K-33 to K-38. Consult custom wallplates section for additional openings and combinations.



# Wallplates

## Telephone and Coaxial Outlet Plates

### Telephone and Coaxial Outlet Plates

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
 1-Gang, 1-Tel Nylon .406 in. (10.3) Hole, Metal .640 in. (16.3) Hole, Box Mount	Almond	<b>NP11AL</b>	<b>NPJ11AL</b>	Aluminum	①
	Black	<b>NP11BK</b>	-	Brass	①
	Brown	<b>NP11</b>	<b>NPJ11</b>	Brass Plated	①
	Gray	<b>NP11GY</b>	-	Chrome	①
	Ivory	<b>NP11I</b>	<b>NPJ11I</b>	S/S 302/304	<b>SS11*</b>
	Light Almond	<b>NP11LA</b>	<b>NPJ11LA</b>	S/S 430	<b>SS11L*</b>
	Red	<b>NP11R</b>	-		
	White	<b>NP11W</b>	<b>NPJ11W</b>		
 1-Gang, 1-Tel Nylon .406 in. (10.3) Hole, Metal .640 in. (16.3) Hole, Strap Mount	Almond	<b>NP12AL</b>	-	Aluminum	①
	Black	<b>NP12BK</b>	-	Brass	<b>SB12*</b>
	Brown	<b>NP12</b>	-	Brass Plated	<b>SBP12*</b>
	Gray	<b>NP12GY</b>	-	Chrome	<b>SCH12*</b>
	Ivory	<b>NP12I</b>	-	S/S 302/304	<b>SS12*</b>
	White	<b>NP12W</b>	-	S/S 430	<b>SS12L*</b>
 1-Gang, 1-Tel .625 in. (15.9) Hole, Box Mount	Almond	<b>NP737AL</b>	-	Aluminum	-
	Brown	<b>NP737</b>	-	Brass	-
	Ivory	<b>NP737I</b>	-	Brass Plated	-
	White	<b>NP737W</b>	-	Chrome	-
				S/S 302/304	-
			S/S 430	-	
 1-Gang, 1-Tel .625 in. (15.9) Hole, Strap Mount	Almond	<b>NP730AL</b>	-	Aluminum	-
	Black	<b>NP730BK</b>	-	Brass	-
	Brown	<b>NP730</b>	-	Brass Plated	-
	Gray	<b>NP730GY</b>	-	Chrome	-
	Ivory	<b>NP730I</b>	-	S/S 302/304	-
	White	<b>NP730W</b>	-	S/S 430	-
 1-Gang, 1-Tel .380 in. (9.7) Hole, Box Mount or Strap Mount	Almond	-	-	Aluminum	①
	Brown	-	-	Brass	①
	Ivory	-	-	Brass Plated	①
	White	-	-	Chrome	①
				S/S 302/304	<b>SS739</b>
				S/S 302/304, Strap Mount	<b>SS738</b>
				S/S 430	-
 2-Gang, 2-Tel Nylon .406 in. (10.3) Hole, Metal .640 in. (16.3) Hole, Box Mount	Almond	<b>NP21AL</b>	-	Aluminum	①
	Black	<b>NP21BK</b>	-	Brass	①
	Brown	<b>NP21</b>	-	Brass Plated	①
	Gray	<b>NP21GY</b>	-	Chrome	①
	Ivory	<b>NP21I</b>	-	S/S 302/304, Strap Mount	<b>SS22*</b>
	White	<b>NP21W</b>	-	S/S 430	-
 2-Gang, 1-Tel .640 in. (16.3) Hole, Box Mount	Almond	-	-	Aluminum	-
	Brown	-	-	Brass	-
	Ivory	-	-	Brass Plated	-
	White	-	-	Chrome	-
				S/S 302/304	<b>SS741*</b>
			S/S 430	-	

Note: All standard and mid-size nylon wallplates feature pre-inserted captive screws for faster assembly, up to 6-gang.


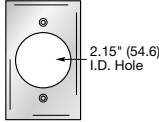


 

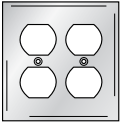
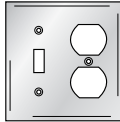

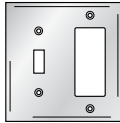
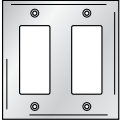
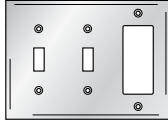
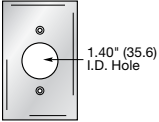
① Available as a custom wallplate. See pages K-33 to K-38. Consult custom wallplates section for additional openings and combinations.

\* .50" (12.7) I.D. nylon bushing provided.




# Wallplates Jumbo, Metal Wallplates
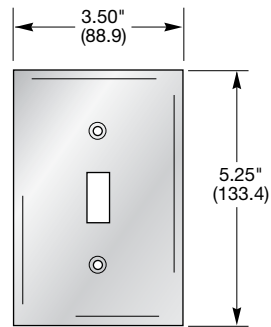
## Jumbo, Smooth, Stainless Steel Type 302/304 Wallplates

Configuration	Catalog Number	Configuration	Catalog Number
1-Gang, 1-Toggle 	<b>SSJ1</b>	1-Gang, 1-Single Receptacle for 2.09–2.13 in. (53.1–54.1) Dia. Face 	<b>SSJ723</b>
2-Gang, 2-Toggle 	<b>SSJ2</b>	1-Gang, 1-Blank, Box Mount 	<b>SSJ13</b>
1-Gang, 1-Duplex 	<b>SSJ8</b>	1-Gang, 1-Telephone Opening, .640 in. (16.3) Box Mount 	<b>SSJ11*</b>
2-Gang, 2-Duplex 	<b>SSJ82</b>	2-Gang, 1-Toggle, 1-Duplex 	<b>SSJ18</b>
1-Gang, 1-Decorator 	<b>SSJ26</b>	2-Gang, 1-Toggle, 1-Decorator 	<b>SSJ126</b>
2-Gang, 2-Decorator 	<b>SSJ262</b>	3-Gang, 2-Toggle, 1-Decorator 	<b>SSJ226</b>
1-Gang, 1-Single Receptacle for 1.36–1.39 in. (34.5–35.3) Dia. Face 	<b>SSJ7</b>		

Note: \*.50 in. (12.7) I.D. nylon bushing provided.  
Specifications are subject to change without notice.

Oversize dimensions (see page K-32 for more details).  
1-Gang, 5.25 in. x 3.50 in. (133.4 x 88.9).  
2-Gang, 5.25 in. x 5.31 in. (133.4 x 134.9).  
3-Gang, 5.25 in. x 7.12 in. (133.4 x 180.8).






**Jumbo Wallplate**



# Wallplates
 
## Pre-Marked "EMERGENCY" and Barrel Key Switch Wallplates

### Pre-Marked "EMERGENCY" Wallplates





Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
1-Gang, 1-Duplex 	Red	-	<b>NPJ8RMEV</b>	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - <b>SS8MEV</b> -
1-Gang, 1-Toggle 	Red	-	<b>NPJ1RME</b>	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - <b>SS1ME</b> -
2-Gang, 2 Duplex 	-	-	-	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - <b>SS82MEV</b> -

Note: Mid-size plate dimensions shown on page K-32.  
All lettering .25 in. (6.3) high.



See page K-30 for security screwdriver and screws ordering information.

### Stainless Steel Barrel Key Switch Wallplates

  Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
1-Gang, with on/off markings 	-	-	-	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - <b>SS12RKL</b> -
1-Gang, with position markings 	-	-	-	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - <b>SS12RKLM</b> -
2-Gang, with on/off markings 	-	-	-	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - <b>SS22RKL</b> -
2-Gang, with position markings 	-	-	-	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - <b>SS22RKLM</b> -





Note: See Section C, page C-8 for barrel key switch selection.






## Wallplates
    
### Pre-Marked Wallplates


#### Pre-Marked "ISOLATED GROUND" Wallplates

Description	Color	Nylon Standard	Nylon No Marking	Material	Metal Catalog Number
1-Gang, 1-Duplex 	Orange	<b>NP8OIG</b>	<b>NP8OR</b>	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -
1-Gang, 1-Decorator 	Orange	<b>NP26OIG</b>	-	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -
1-Gang, 1-Single Recept. 1.40 in. (35.6) Hole for 1.36–1.39 in. (34.5–35.3) Dia. face 	Orange	<b>NP7OIG</b>	-	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -
1-Gang, 1-Single Recept. 1.60 in. (40.6) Hole for 20 and 30A Twist-Lock® with 1.55–1.58 in. (39.4–40.1) Dia. face 	Orange	<b>NP720OIG</b>	-	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -

#### Pre-Marked "COMPUTER ONLY" Wallplates

 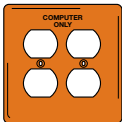 Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
1-Gang, 1-Duplex 	Orange Ivory	- -	<b>NPJ8CO</b> <b>NPJ8C</b>	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -
2-Gang, 2-Duplex 	Orange	-	<b>NPJ82CO</b>	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -
1-Gang, 1-Decorator 	Blue Ivory	- -	<b>NPJ26CBL</b> <b>NPJ26C</b>	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	- - - - - -

#### 1-Gang Louver Plate, Box Mount

Description	Color	Nylon Standard	Nylon Mid-Size	Material	Metal Catalog Number
1-Gang, Vertical Mounted Louver 	-	-	-	Aluminum Brass Brass Plated Chrome S/S 302/304 S/S 430	① <b>SB771</b> <b>SBP771</b> ① <b>SS771</b> -

Note: \* Mid-size plate dimensions shown on page K-32.

① Available as a custom wallplate. See pages K-33 to K-38. Consult custom wallplates section for additional openings and combinations.



## Wallplates

### Security Wallplates



SWP1



SWP8

#### 1-Gang, White

Description	Catalog Number
1-Toggle switch	SWP1
1-Duplex receptacle	SWP8
1-GFCI/Style Line® opening	SWP26
1-Telephone or TV opening .640 in. (16.3)	SWP12
1-Blank	SWP13



SWP82



SWP18

#### 2-Gang, White


Description	Catalog Number
2-Toggle switches	SWP2
2-Duplex receptacles	SWP82
1-Toggle switch, 1-Duplex receptacle	SWP18
2-GFCI/Style Line® openings	SWP262
1-Toggle switch, 1-GFCI/Style Line® opening	SWP126
1-Duplex receptacle, 1-Telephone or TV	SWP812
1-Duplex receptacle, 1-Blank	SWP813
2-Blank	SWP23



SWP28

#### 3-Gang, White

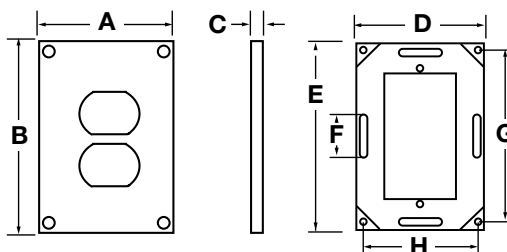Description	Catalog Number
2-Toggle switches, 1-Duplex receptacle	SWP28



#### Dimensions

	A	B	C	D	E	F	G	H
1-Gang	3.77"	5.52"	.55"	3.37"	5.13"	1.00"	4.63"	2.88"
(mm)	(95.8)	(140.2)	(14.0)	(85.6)	(130.3)	(25.4)	(117.6)	(73.2)
2-Gang	5.52"	5.52"	.55"	5.13"	5.13"	1.00"	4.63"	4.63"
(mm)	(140.2)	(140.2)	(14.0)	(130.3)	(130.3)	(25.4)	(117.6)	(117.6)
3-Gang	7.39"	5.52"	.55"	7.00"	5.13"	1.00"	4.63"	6.50"
(mm)	(187.71)	(140.21)	(14.0)	(177.8)	(130.3)	(25.4)	(117.6)	(165.1)

#### Specifications

Tamper resistant wallplate 1-gang duplex receptacle shall be of the following construction:

Cover plate: One piece #14 cold rolled zinc plated steel. Plate shall have a five stage baked white polyester powder enamel finish. Gloss: 85%; reflectance: 93%; hardness minimum: 2H and pass 600 hour salt spray test.

Back plate: #10 cold rolled galvanized steel. Plate assembly shall use four (4) #8-32 X ½ inch stainless steel T-15 TORX® head screws with center pin reject. Plate must be UL listed to UL 514D and comply with the NEC®.

NEC® is a registered trademark of the The National Electrical Code.  
TORX® is a registered trademark of Textron Inc.



## Wallplates Accessories and Selection Charts



### Brass Locking Cover Plate

Description	Catalog Number
Locking cover plate for single 15 and 20A straight blade receptacles and 15A Twist-Lock® receptacles. Straight cylinder type lock. All cylinder locks keyed alike.	<b>HBL96067</b>



**HBL96067**  
shown with receptacle  
(sold separately)



**HBL6187**  
shown with receptacle  
and back box  
(sold separately)

### Weather Shield Plate

Description	Catalog Number
20° angle plate for duplex receptacles.	<b>HBL6187</b>

### Catalog Number of Receptacles in Groups A through E below

Group A		Group B			Group C	Group D		Group E
Boss diameter 1.36" to 1.39" (34.5 to 35.3)		Boss diameter 1.55" to 1.58" (39.4 to 40.1)			Boss diameter 1.68" to 1.72" (42.7 to 43.7)	Boss diameter 2.09" to 2.13" (53.1 to 54.1)		Boss diameter 2.28" to 2.44" (57.9 to 62.0)
HBL23000HG	HBL5661	HBL23CM10	HBL2530	HBL2770	HBL45105	HBL7962	HBL7301A	
HBL23030	HBL6810	HBL2310	HBL26CM10	HBL2810	HBL45205	HBL9350	HBL8330A	
HBL4560	HBL7210B	HBL2320	HBL2610	HBL2820	HBL45305	HBL9308	HBL8350A	
HBL4710	HBL7250	HBL2330	HBL2620	HBL2830	HBL45905	HBL9315	HBL8430A	
HBL4760	HBL7310B	HBL2340	HBL2630	HBL3330		HBL9330	HBL8450A	
HBL5251	HBL7310BG	HBL2410	HBL2640	HBL3330G		HBL9360•	HBL8460A	
HBL52CM61	HBL7535	HBL2420	HBL2650	HBL3430		HBL9365•	HBL9430A	
HBL5261	HBL7582	HBL2430	HBL2710	HBL3430G		HBL9367•	HBL9450A	
HBL53CM61	HBL8210	HBL2440	HBL2720	HBL3520			HBL9460A	
HBL5361	HBL8310	HBL2450	HBL2730	HBL7410B				
HBL5461	HBL8410	HBL2460	HBL2740	HBL7410BG				
HBL5552B	HBL8420	HBL2510	HBL2750					
		HBL2520	HBL2760					

### Wallplates for Single Receptacles

Description	Group A		Group B		Group C		Group D		Group E
	Boss diameter 1.36" to 1.39" (34.5 to 35.3)		Boss diameter 1.55" to 1.58" (39.4 to 40.1)		Boss diameter 1.68" to 1.72" (42.7 to 43.7)		Boss diameter 2.09" to 2.13" (53.1 to 54.1)		Boss diameter 2.28" to 2.44" (57.9 to 62.0)
	1-Gang	2-Gang	1-Gang	2-Gang	1-Gang	2-Gang	1-Gang	2-Gang	2-Gang
Smooth nylon, brown.	NP7*	-	NP720*	-	-	-	NP724*	NP703*	-
Cast aluminum.	HBL7320	-	HBL7320	-	HBL3394	-	HBL9419	-	-
Stainless steel, 302/304, smooth.	SS7**	-	SS720	-	SS725	-	SS723	SS703	SS701

Note: See pages K-7 and K-8 for complete plate descriptions.

\* Catalog number indicated is Brown, add with the following to designate color: "BK" for Black, "I" for Ivory.

\*\* Catalog number indicated is Stainless Steel, replace "SS" with the following prefix to designate material: "SA" for Anodized Aluminum, "SB" for Solid Brass.

### Weatherproof Lift Covers for WDL "Closed" and WDL "Open", Wet Locations, 1-Gang

Description	Group A	Group B	Group C	Group D		
	Boss diameter 1.36" to 1.39" (34.5 to 35.3)	Boss diameter 1.55" to 1.58" (39.4 to 40.1)	Boss diameter 1.68" to 1.72" (42.7 to 43.7)	Boss diameter 2.09" to 2.13" (53.1 to 54.1)	50A Twist-Lock® Receptacles	30A 4W Hubbell® Receptacles
Thermoplastic, with cover "open", gray.	HBL7423WO	HBL7425WOA	HBL7424WO	-	HBL7774WO <sup>▲</sup>	-
Thermoplastic, with cover "open", yellow.	HBL74CM23WO	HBL74CM25WOA	HBL74CM24WO	-	HBL77CM74WO <sup>▲</sup>	-
Cast aluminum, with cover "closed".	HBL7420	HBL7420	HBL3393	HBL9420 HBL9425*	HBL7770	HBL20405 <sup>†</sup> HBL20446 <sup>†</sup>

Note: • 50A 2P 3W.

<sup>▲</sup>The "CS" versions of 50A Twist-Lock® receptacles will only fit these thermoplastic plates.

<sup>†</sup> **HBL20446** plate painted red for use with **HBL20443** only. **HBL20405** plate is for use with **HBL20403** only. See Section B, page B-65 for devices.



# Wallplates

## Weatherproof Covers for Receptacles

For FS/FD Box Mounting

**IP44**  
SUITABILITY



HBL7777A

### For Receptacles with Face Diameters of 2.28–2.44 in. (57.9–62.0)

Description	Catalog Number
Thermoplastic, 2-gang, WET LOCATIONS with cover "closed," gray.	HBL7777A <sup>▲</sup>
Thermoplastic, 2-gang, WET LOCATIONS with cover "closed," yellow.	HBL77CM77A <sup>▲</sup>
Thermoplastic, 2-gang, WET LOCATIONS with cover "closed," gray.	HBL7777 <sup>▽</sup>



HBL7774WO

### For Receptacles with Face Diameters of 2.09–2.13 in. (53.1–54.1)

Description	Catalog Number
Cast aluminum, WET LOCATIONS with cover "closed."	HBL9420
Cast aluminum, no lift cover, NOT weatherproof.	HBL9419

### For 50A Twist-Lock<sup>®</sup> Single Receptacles

Description	Catalog Number
Thermoplastic, WET LOCATIONS with cover "open," gray.	HBL7774WO*
Thermoplastic, WET LOCATIONS with cover "open," yellow.	HBL77CM74WO*
Cast aluminum, WET LOCATIONS with cover "closed."	HBL7770
Galvanized Steel, fits 4" square or 2-gang box.	HBL50SC



HBL9420

### For 30A, 4 Wire Hubbellock<sup>®</sup> Receptacles

Description	Catalog Number
Cast aluminum, WET LOCATIONS with cover "closed."	HBL20405
Cast aluminum, WET LOCATIONS with cover "closed," red.	HBL20446
Cast aluminum, no lift cover, NOT weatherproof.	HBL20406

Note: <sup>▲</sup> Will fit FS/FD boxes having plate mounting holes on 3.25 in. x 3.75 in. (82.6 x 95.3) centers.

<sup>▽</sup> Will only fit old style porcelain face devices.

\* The "CS" versions of 50A Twist-Lock<sup>®</sup> will only fit these plates.

### Weatherproof Covers for Single Receptacles for Use on FS/FD Boxes

Note: All weatherproof plates are UL Listed for WET LOCATIONS WITH COVER CLOSED, for intermittent use in wet locations or use in damp locations. Those with suffix "WO" are listed for WET LOCATIONS with cover open in continuous use. All plates are gasketed and self-closing.



HBL20405


### Accessories

Description	Catalog Number
Sub-plate for mounting and weatherproofing flanged devices with mounting centers of 1.76", 1.94" or 2.13" such as HBL7556, HBL4716, etc. when used with a HBL7420 or HBL7425WOA type weatherproof plate.	7452**
Adapter plate for mounting HBL7423WO, HBL7424WO, HBL7425WOA or HBL7420 plates to standard boxes.	HBL7349**


Note: \*\* Not listed by Underwriter's Laboratories Inc.



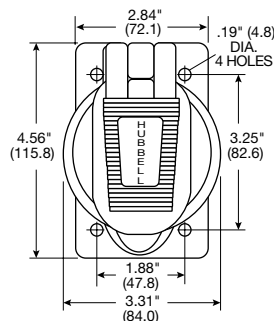HBL7770



Typical Plate, 1-Gang

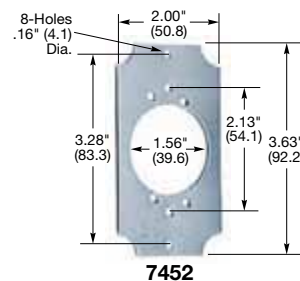

7452



HBL7349



## Wallplates

### Weatherproof Covers for Receptacles and Switches

Vertical, for FS/FD box mounting

**IP44**  
SUITABILITY

#### For Receptacles with Face Diameters of 1.36–1.39 in. (34.5–35.3)

Description	Catalog Number
Thermoplastic, WET LOCATIONS with cover "open," gray.	HBL7423WO
Thermoplastic, WET LOCATIONS with cover "open," yellow.	HBL74CM23WO
Cast aluminum, WET LOCATIONS with cover "closed."	HBL7420
Cast aluminum, no lift cover, NOT weatherproof.	HBL7320



HBL7423WO

#### For Switches & Receptacles with Face Diameters of 1.55–1.58 in. (39.4–40.1)

Description	Catalog Number
Thermoplastic, WET LOCATIONS with cover "open," gray.	HBL7425WOA
Thermoplastic, WET LOCATIONS with cover "open," yellow.	HBL74CM25WOA
Thermoplastic, WET LOCATIONS with cover "open," white.	HBL74CM25WOAW
Cast aluminum, WET LOCATIONS with cover "closed."	HBL7420*
Cast aluminum, no lift cover, NOT weatherproof.	HBL7320
Thermoplastic, WET LOCATIONS with cover "open," gray.	HBL7428WOG†
Thermoplastic, WET LOCATIONS with cover "open," yellow.	HBL7428WOY†
Thermoplastic, WET LOCATIONS with cover "open," red.	HBL7428WOR†



HBL7425WOA

#### For Receptacles with Face Diameters of 1.68–1.72 in. (42.7–43.7)

Description	Catalog Number
Thermoplastic, WET LOCATIONS with cover "open," gray.	HBL7424WO
Thermoplastic, WET LOCATIONS with cover "open," yellow.	HBL74CM24WO
Cast aluminum, WET LOCATIONS with cover "closed."	HBL3393
Cast aluminum, no lift cover, NOT weatherproof.	HBL3394



HBL7424WO

Note: \* Cast aluminum lift cover with fibershield for standard toggle and PresSwitch® Switches.

† Features two #6-32 threaded inserts to back mount device to cover.

All weatherproof lift cover plates on this page are listed by Underwriters Laboratories, Inc. as "WDL Closed" for use in wet locations with cover closed and in damp locations.

#### Weatherproof Covers for Single Receptacles on FS/FD Boxes

Note: All weatherproof plates are UL Listed for WET LOCATIONS WITH COVER CLOSED for intermittent use in wet locations or use in damp locations. Those with suffix "WO" are listed for WET LOCATIONS with cover open in continuous use. All plates are gasketed and self-closing.




HBL7420

#### 2011 National Electrical Code (NEC®)

##### 406.9 Receptacles in Damp or Wet Locations.

**(A) Damp Locations.** A receptacle installed outdoors in a location protected from the weather or in other damp locations shall have an enclosure for the receptacle that is weatherproof when the receptacle is covered (attachment plug cap not inserted and receptacle covers closed). An installation suitable for wet locations shall also be considered suitable for damp locations. A receptacle shall be considered to be in a location protected from the weather where located under roofed open porches, canopies, marquees, and the like, and will not be subjected to a beating rain or water runoff. All 15- and 20-ampere, 125- and 250-volt nonlocking receptacles shall be listed weather-resistant type. FPN: The types of receptacles covered by this requirement are identified as 5-15, 5-20, 6-15 and 6-20 in ANSI/NEMA WD 6-2002, National Electrical Manufacturers Association Standard for Dimensions of Attachment Plugs and Receptacles.

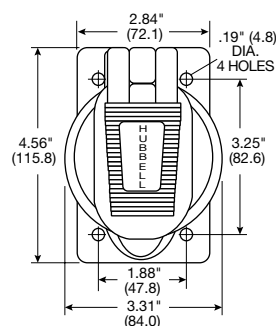**(B) Wet Locations.** 15- and 20-ampere, 125- and 250-volt receptacles installed in a wet location shall have an enclosure that is weatherproof whether or not the attachment plug cap is inserted. For other one- or two-family dwellings, an outlet box hood installed for this purpose shall be listed, and where installed on an enclosure supported from grade as described in 314.23(B) or as described in 314.23(F) shall be identified as "extra-duty." All 15- and 20-ampere, 125- and 250-volt nonlocking-type receptacles shall be listed weather-resistant type.



Typical Plate, 1-Gang

HBL7320

HBL3393

NEC® is a registered trademark of the The National Electrical Code.




Wallplates


# Weatherproof Covers for Flanged Devices

For Flanged Inlets and Flanged Receptacles

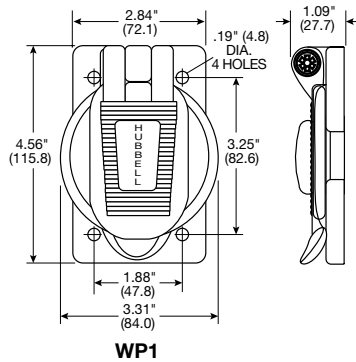**IP44**  
SUITABILITY



**WP1**

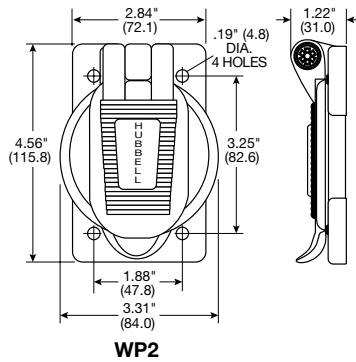

**WP2**



**WP1**

**Weatherproof Cover For Flanged Inlets and Flanged Receptacles**

For 15 and 20A, 2-pole 2-wire and 3-wire Insulgrip® flanged inlets and flanged outlets.


Straight Blade, 2-Pole, 3-Wire Flanged Inlets		Flanged Receptacles
	HBL5278C HBL5378C HBL5478C HBL5678C	HBL5279C HBL5379C HBL5479C HBL5679C


Twist-Lock® 2-Pole, 2-Wire and 2-Pole, 3-Wire Flanged Inlets		Flanged Receptacles
	HBL8815C HBL7524C HBL4716C HBL4586C HBL4786C	HBL8809C HBL7526C HBL4715C HBL4585C HBL4785C

**WP2**

**Weatherproof Cover For Flanged Inlets and Flanged Receptacles**

For 20 and 30A, 3-, 4- and 5-wire Insulgrip flanged inlets and flanged outlets.

Twist-Lock 2-pole, 3-wire; 3-pole, 4-wire; 4-pole, 4-wire; 5-wire Flanged Inlets		
	HBL2315 HBL2325 HBL2335 HBL2345 HBL2615 HBL2625 HBL2635 HBL2645 HBL2655 HBL3325C HBL2415	HBL2425 HBL2435 HBL2445 HBL2455 HBL2465 HBL2715 HBL2725 HBL2735 HBL2745 HBL2755 HBL2765
		HBL2775 HBL2515 HBL2525 HBL2535 HBL2815 HBL2825 HBL2835 HBL3325C HBL3334C HBL7408C

Flanged Receptacles		
	HBL2316 HBL2326 HBL2336 HBL2346 HBL2356 HBL2616 HBL2626 HBL2636 HBL2646 HBL2656 HBL3326C	HBL2416 HBL2426 HBL2436 HBL2446 HBL2456 HBL2466 HBL2716 HBL2726 HBL2736 HBL2746 HBL2756
		HBL2766 HBL2776 HBL2516 HBL2526 HBL2536 HBL2816 HBL2826 HBL2836 HBL3326C HBL3335C HBL7409C



# Wallplates


## Weatherproof Switch Plates, Covers and Locking Covers



**IP44**  
SUITABILITY

### Weatherproof Plates

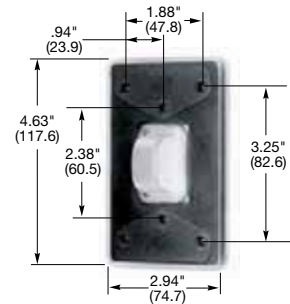Description	Catalog Number
Clear bubble plate, silicone rubber for use with all general purpose AC toggle and PresSwitch® Switches. Fits both FS/FD and standard boxes.	<b>HBL1795</b>




**HBL1795**

### Weatherproof Plates

Description	Catalog Number
Gray neoprene PresSwitch® Plate. Fits FS/FD and standard boxes.	<b>HBL1750*</b>
Same as above except yellow.	<b>HBL17CM50*</b>

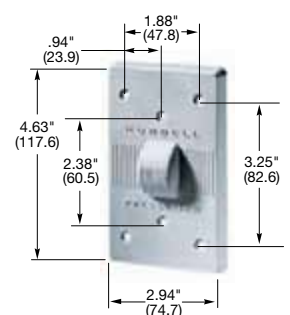*Note: \* Not listed by Underwriter's Laboratories Inc.*




**HBL1750**

### Weatherproof Plates

Description	Catalog Number
Gray neoprene PresSwitch® Plate with 125V red pilot light. Fits only FS/FD boxes.	<b>HBL1785*</b>
Same as above except yellow.	<b>HBL17CM85*</b>

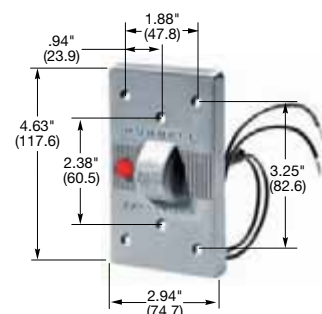
*Note: \* Not listed by Underwriter's Laboratories Inc.*



**HBL1785**

### Weatherproof Covers

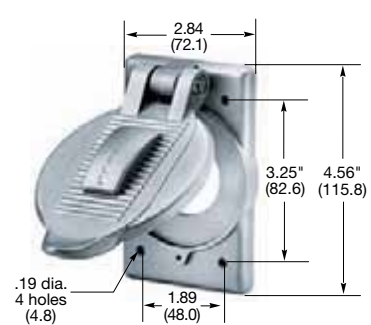Description	Catalog Number
Cast aluminum lift cover plate with fiber shield. For standard toggle and PresSwitch® Switches. Fits only FS/FD boxes.	<b>HBL7420</b>



**HBL7420**

### Brass Locking Covers Attachment for Switches

Description	Catalog Number
Straight keying (all locks alike) appropriate for most applications. Straight cylinder type lock, each HBL96061 ordered operates on the same key—all locks are keyed alike.	<b>HBL96061*</b>
Same as above except in dull chrome finish to match stainless steel plates.	<b>HBL96061DCH*</b>
Straight keying (individual). Straight cylinder type lock, each HBL96062 ordered operates on a different key. All locks are keyed differently and individually. This type cannot be master keyed.	<b>HBL96062*</b>

*Note: \* Not listed by Underwriter's Laboratories Inc.*



**HBL96061**  
shown with wallplate and switch  
(sold separately)





## Wallplates

# Heavy Duty Weatherproof Covers for Duplex, GFCI, Surge Receptacles and Style Line® Devices

**IP44**  
 SUITABILITY


HBL5221

## Duplex Covers For Vertical Mounting

Description	Dimensions		Catalog Number
	Height	Width x Depth	
Thermoplastic, gray, for FS/FD box mounting.	4.56"	2.89" x 1.08"	<b>HBL5221</b>
Thermoplastic, yellow, for FS/FD box mounting.	4.56"	2.89" x 1.08"	<b>HBL52CM21</b>
Thermoplastic, gray, for device mounting.	4.56"	2.89" x 1.08"	<b>HBL5222</b>
Thermoplastic, yellow, for device mounting.	4.56"	2.89" x 1.08"	<b>HBL52CM22</b>



HBL5206WO

## Duplex Covers For Horizontal Mounting

Description	Dimensions		Catalog Number
	Height	Width x Depth	
Cast aluminum, for device mounting.	2.88"	4.56" x 0.79"	<b>HBL5205WO</b>
Cast aluminum, for FS/FD box mounting.	2.88"	4.56" x 0.79"	<b>HBL5206WO</b>
Zinc die cast, commercial grade, for device mounting.	2.90"	4.60" x 0.75"	<b>CWP8H</b>



CWP8H



WPFS26

## GFCI, Surge and Style Line Covers

Description	Dimensions		Catalog Number
	Height	Width x Depth	
Die cast aluminum, vertical position, device mount.	4.56"	2.81" x 0.75"	<b>WP26</b>
Die cast aluminum, vertical position, FS/FD box mount.	4.56"	2.81" x 0.75"	<b>WPFS26</b>
Zinc die cast, commercial grade, horizontal position, device mount.	2.30"	4.75" x 0.73"	<b>CWP26H</b>

Note: All weatherproof plates are UL Listed for WET LOCATIONS WITH COVER CLOSED, for intermittent use in wet locations or use in damp locations. Those with Suffix "WO" are listed for WET LOCATIONS with cover open in continuous use. All plates are gasketed and self-closing.



CWP26H





## Wallplates

# Weatherproof Covers for Duplex, Single, GFCI, Surge Receptacles and Style Line® Devices and Switches

## Weatherproof Covers for Vertical Mounting

Description	Dimensions		Catalog Number
	Height x Width x Depth		
Zinc die cast, gray, duplex cover for box mounting.	4.58" x 2.82" x 0.57"		<b>RW51470</b>
Zinc die cast, gray, 1.40 in. (35.6) cover for single receptacle or toggle switch for device mounting.	4.56" x 2.81" x 0.88"		<b>RW51550*</b>
Zinc die cast, gray, GFCI, Surge and Style Line® cover for device mounting.	4.58" x 2.81" x 0.57"		<b>RW51040</b>



RW51550



RW51470



RW51040

## 1-Gang Weatherproof Covers for Horizontal Mounting

Description	Dimensions		Catalog Number
	Height x Width x Depth		
Zinc die cast, gray, duplex cover for device mounting.	2.82" x 4.57" x 0.79"		<b>RW51810</b>
Zinc die cast, gray, 1.40 in. (35.6) cover for single receptacle or toggle switch for device mounting.	2.81" x 4.56" x 0.99"		<b>RW51520*</b>
Zinc die cast, gray, GFCI, Surge and Style Line® cover for device mounting.	2.82" x 4.56" x 0.52"		<b>RW51020</b>



RW51810



RW51020



RW51520

## 2-Gang Weatherproof Covers for Vertical Mounting

Description	Dimensions		Catalog Number
	Height x Width x Depth		
Zinc die cast, gray, duplex cover for device mounting.	4.54" x 4.54" x 0.75"		<b>RW51320</b>
Zinc die cast, gray, one duplex/one GFCI, Surge and Style Line® cover for box mounting.	4.54" x 4.54" x 0.77"		<b>RW51330</b>
Zinc die cast, gray, 1.40 in. (35.6) cover for single receptacle or toggle switch for device mounting.	4.54" x 4.54" x 0.77"		<b>RW51380</b>
Zinc die cast, gray, two GFCI, Surge and Style Line® cover for box mounting.	4.54" x 4.56" x 0.73"		<b>RW51450</b>



RW51330



RW51450



RW51320



RW51380

Note: All weatherproof plates are UL Listed for WET LOCATIONS WITH COVER CLOSED, for intermittent use in wet locations or use in damp locations. All plates are gasketed and self-closing.  
\* C-UL US Listed.



## Wallplates

**While-In-Use Weatherproof Covers**

For Maximum In-Use Protection

**Cast Aluminum, 1-Gang, Vertical**

WP826

Description	Dimensions		Catalog Number
	Height x Width x Depth		
Rectangular, multi-application. Adapter plates included: Duplex, toggle, single receptacle 1.56" dia., and GFCI/Style Line® devices.	6.13" x 3.38" x 3.50"		WP826

**Cast Aluminum, 1-Gang, Horizontal**

WP826H

Description	Dimensions		Catalog Number
	Height x Width x Depth		
Rectangular, multi-application. Adapter plates included: Duplex, toggle, single receptacle 1.56" dia., and GFCI/Style Line® devices.	3.38" x 6.13" x 3.50"		WP826H

**Cast Aluminum, 1-Gang, Vertical Deep**

WP700

Description	Dimensions		Catalog Number
	Height x Width x Depth		
Rectangular, multi-application. Adapter plates included: Duplex, toggle, single receptacle 1.56" dia., and GFCI/Style Line® devices.	6.13" x 3.38" x 5.00"		WP700

**Specifications****Metallic**

- Die cast Alloy 360 copper-free® aluminum for maximum corrosion resistance and durability. Alloy 360 has less than .004% copper content.
- Finish is baked aluminum lacquer.
- NEMA® 3R rating when used with the appropriate weatherproof outlet box which is intended for outdoor use primarily to provide a degree of protection against rain, sleet, and damage from external ice formation.
- Box or device mount for flexibility of installation.
- Gaskets are closed-cell foam.
- Meets OSHA lockout/tagout requirements.
- Latching covers hold securely.
- Large cord openings.
- Clearly marked UL and CSA logos.
- Covers include gasket and mounting screws. Lids have gasketless design.
- UL Listed/CSA Certified.
- Devices not included.
- Holes for padlocks are ¼ inch (6.4) diameter.
- Drill points in four corners for box mounting.

**Locking Device**

HBLWLC

Description	Catalog Number
Locking device for weatherproof covers.	HBLWLC

NEMA® is a registered trademark of The National Electrical Manufacturers Association.



# Wallplates While-In-Use Weatherproof Covers

For Maximum In-Use Protection

**IP66**  
SUITABILITY



## 1-Gang Weatherproof Covers for Vertical Mounting

Description	Dimensions	Catalog Number
	Height x Width x Depth	
Thermoplastic, gray, duplex, GFCI, toggle and single receptacles, diameter 1.34", 1.40", 1.60", 1.72", 2.03" and 2.15"	5.91" x 4.32" x 2.84"	<b>RW57300</b>



**RW57300**

Thermoplastic, gray, extra deep, duplex, GFCI, toggle and single receptacles, diameter 1.34", 1.40", 1.60", 1.72", 2.03" and 2.15"	5.91" x 4.32" x 4.82"	<b>RW57350</b>
------------------------------------------------------------------------------------------------------------------------------------	-----------------------	----------------



**RW57350**

## 1-Gang Weatherproof Covers for Horizontal Mounting

Description	Dimensions	Catalog Number
	Height x Width x Depth	
Thermoplastic, gray, duplex, GFCI, toggle and single receptacles, diameter 1.34", 1.40", 1.60", 1.72", 2.03" and 2.15"	5.91" x 4.32" x 2.84"	<b>RW57400</b>



**RW57400**

## 2-Gang Weatherproof Covers for Vertical Mounting

Description	Dimensions	Catalog Number
	Height x Width x Depth	
Thermoplastic, gray, duplex, GFCI, toggle and single receptacles, diameter 1.34", 1.40", 1.60", 1.72", 2.03" and 2.15"	5.94" x 5.54" x 2.84"	<b>RW57750</b>



**RW57750**

Thermoplastic, gray, duplex, GFCI, toggle and single receptacles, diameter 1.34", 1.40", 1.60", 1.72", 2.03" and 2.15"	5.94" x 5.54" x 4.82"	<b>RW57900</b>
------------------------------------------------------------------------------------------------------------------------	-----------------------	----------------



**RW57900**

Thermoplastic, gray, single receptacles, diameter 1.34", 1.40", 1.60", 1.72", 2.03" and 2.15"	5.94" x 5.54" x 4.82"	<b>RW57950</b>
-----------------------------------------------------------------------------------------------	-----------------------	----------------



**RW57950**

Note: Required by the NEC® for while-in-use outdoor power distribution. Thermoplastic covers provide protection for use in wet locations with the cover closed, NEMA® 3R rated. Meets NEC 406.8 – receptacles in damp or wet locations. Holes for padlocks are .40 inch.

 
NEC® is a registered trademark of the The National Electrical Code.  
NEMA® is a registered trademark of The National Electrical Manufacturers Association.





## Wallplates Screws and Accessories

### Screws, 6-32 Thread, 100 Count



RA12AL



RA756I



RA40



HBL7298



HBL7341



HBL7342RKL



HBL7372RKL

Description	Color	Catalog Number	Material	Catalog Number
Decorator Wallplate Screws, Oval Head Milled Slot, 3/8 in. Long – 6-32 Thread, 100 per Box (Order 1 to receive a box of 100)	Almond	<b>RA38ALPK100</b>	Brass	<b>RA38BR</b>
	Black	<b>RA38BKPK100</b>	Chrome	<b>RA38CH</b>
	Brown	<b>RA38PK100</b>	Stainless Steel	<b>RA38SS</b>
	Gray	<b>RA38GYPK100</b>		
	Ivory	<b>RA38IPK100</b>		
	Light Almond	<b>RA38LAPK100</b>		
Standard Wallplate Screws, Oval Head Milled Slot, 1/2 in. Long – 6-32 Thread, 100 per Box (Order 1 to receive a box of 100)	Almond	<b>RA12ALPK100</b>	Brass	-
	Black	<b>RA12BKPK100</b>	Chrome	-
	Brown	<b>RA12PK100</b>	Stainless Steel	-
	Gray	<b>RA12GYPK100</b>		
	Ivory	<b>RA12IPK100</b>		
	Light Almond	<b>RA12LAPK100</b>		
Standard Wallplate Screws, Oval Head Milled Slot, 5/8 in. Long – 6-32 Thread, 100 per Box (Order 1 to receive a box of 100)	Almond	-	Brass	<b>RA58BR</b>
	Black	-	Chrome	<b>RA58CH</b>
	Brown	-	Stainless Steel	<b>RA58SS</b>
	Gray	-		
	Ivory	-		
	Light Almond	-		
Standard Wallplate Screws, Oval Head Milled Slot, 1.0 in. Long – 6-32 Thread, 100 per Box (Order 1 to receive a box of 100)	Ivory	<b>RA88IPK100</b>	Stainless Steel	<b>RA88SS</b>
	White	<b>RA88WPK100</b>		

### Single Count Screws and Accessories

Description	Color	Catalog Number
Blank toggle adapter, to fill a toggle opening.	Brown	<b>RA756</b>
	Ivory	<b>RA756I</b>
	White	<b>RA756W</b>
Mounting strap, with screws.	Steel	<b>RA40</b>
Red rectangular jewel in metal frame for switch plates.	Red	<b>HBL7298</b>
Brass plated screw, standard slot, .38 in. (9.7) long.		<b>HBL7341</b>
Stainless steel screw, standard slot, .38 in. (9.7) long.		<b>HBL7341SS</b>
Security spanner head screws, 6-32 thread, 100 count.		<b>HBL7342RKL</b>
Screwdriver with spanner head security bit.		<b>HBL7372RKL</b>



# Wallplates

## Technical Information

### Specifications

#### Listings

Non-Metallic Plates	UL Standard 514D.
Metallic Plates	UL Standard 514D.
Certification	UL Files #E31999, E92074. CSA Standard C22.2 No. 42.1. CSA File 1733174.

#### Nylon Plate

Thickness	.06 in. (1.5).
Mounting Screw(s)	Steel (painted slotted screw head).
Feature	Captive mounting screw hole.
Operating Temperature	-40°C to 85°C.
Appearance	Smooth.

#### 302/304 Stainless Steel (18% Chromium, 8% Nickel) Plate

Thickness	.035 in. (0.9) nominal.
Mounting Screw(s)	302/304 stainless steel (18% chromium, 8% nickel). Slotted screw head.
Appearance	Horizontal brushed finish.

#### 430 Stainless Steel (17% Chromium, less than 0.5% Nickel) Plate

Thickness	.035 in. (0.9) nominal.
Mounting Screw(s)	302/304 stainless steel (17% chromium, less than 0.5% nickel). Slotted screw head.
Appearance	Horizontal brushed finish.

#### Brass (70% Copper, 30% Zinc) Plate

Thickness	.04 in. (1.0).
Mounting Screw(s)	Brass (70% Copper, 30% Zinc). Slotted screw head.
Appearance	Horizontal brushed finish.

#### Aluminum Plate

Thickness	.05 in. (1.3).
Mounting Screw(s)	302/304 stainless steel (17% chromium, less than 0.5% nickel). Slotted screw head.
Appearance	Horizontal brushed finish.

#### Brass Plated Steel Plate

Thickness	.03 in. (0.8) nominal.
Mounting Screw(s)	Brass slotted head.
Appearance	Polished, coated to inhibit oxidation.

#### Chrome Plated Steel Plate

Thickness	.03 in. (0.8) nominal.
Mounting Screw(s)	302/304 stainless steel (17% chromium, less than 0.5% nickel). Slotted screw head.
Appearance	Polished, coated to inhibit oxidation.

#### Steel Painted Plate

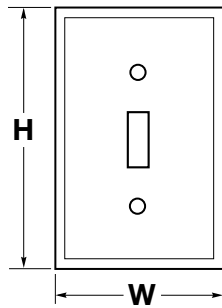
Thickness	.03 in. (0.8) nominal.
Mounting Screw(s)	Steel (painted slotted screw head).
Appearance	Powder coat paint.




# Wallplates

## Wallplate Dimensions


### Product Dimensions



Size	Standard Metal		Painted Metal	Size	Jumbo Metal	
	Height	Width	Width		Height	Width
1-Gang	4.50" (114.3)	2.87" (72.9)	2.75" (69.8)	1-Gang	5.25" (133.4)	3.50" (88.9)
2-Gang	4.50" (114.3)	4.60" (116.8)	4.56" (115.8)	2-Gang	5.25" (133.4)	5.31" (134.9)
3-Gang	4.50" (114.3)	6.41" (162.8)	6.38" (162.1)	3-Gang	5.25" (133.4)	7.12" (180.8)
4-Gang	4.50" (114.3)	8.22" (208.8)	8.18" (207.8)			
5-Gang	4.50" (114.3)	10.03" (254.8)	10.00" (254.0)			
6-Gang	4.50" (114.3)	11.81" (300.0)	11.81" (300.0)			
7-Gang	4.50" (114.3)	13.68" (347.5)				
8-Gang	4.50" (114.3)	15.44" (392.1)				

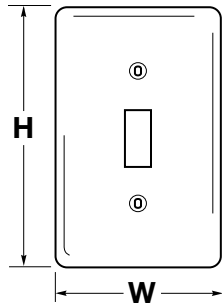


Size	Standard Nylon		Size	Mid-Size Nylon	
	Height	Width		Height	Width
1-Gang	4.63" (117.6)	2.88" (73.2)	1-Gang	4.88" (124.0)	3.13" (79.5)
2-Gang	4.63" (117.6)	4.69" (119.1)	2-Gang	4.88" (124.0)	4.94" (125.4)
3-Gang	4.63" (117.6)	6.50" (165.1)	3-Gang	4.88" (124.0)	6.75" (171.5)
4-Gang	4.63" (117.6)	8.31" (211.1)	4-Gang	4.88" (124.0)	8.56" (217.4)
5-Gang	4.63" (117.6)	10.12" (256.1)			
6-Gang	4.63" (117.6)	11.93" (303.0)			

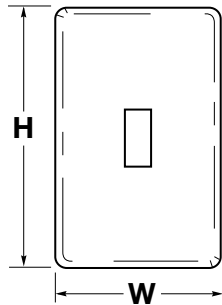

Size	Height	Width
1-Gang	4.68" (118.9)	2.94" (74.7)
2-Gang	4.68" (118.9)	4.75" (120.7)
3-Gang	4.68" (118.9)	6.56" (166.6)
4-Gang	4.68" (118.9)	8.37" (212.6)
5-Gang	4.68" (118.9)	10.18" (258.6)
6-Gang	4.68" (118.9)	11.99" (304.5)

### Wallplate Openings and Mounting Dimensions
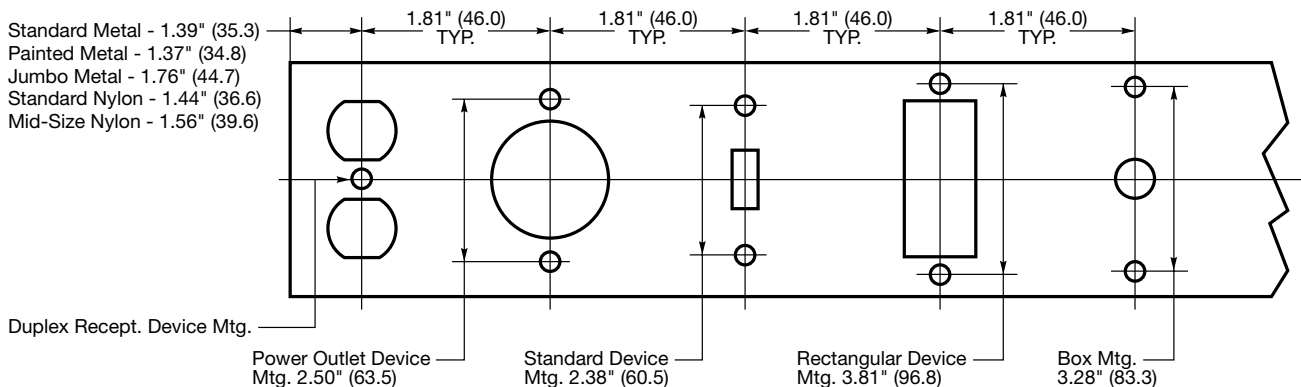
#### #6-32 Oval Head Screws Typical



Note: Specifications are subject to change without notice.





# Wallplates

## Custom Metal Wallplates

How To Select A Custom Metal Wallplate

**Step 1:**  
Determine wallplate material and enter in box marked "Catalog Number"

Smooth Metal Material	Code
Anodized Aluminum	AL
Brass plated steel	BP
Solid brass	BR
Chrome plated steel	CH
Stainless steel 302/304	SS

Determine number of gangs required and enter in box marked "Catalog Number" next to material.

Number of Gangs	Code
1-gang	1
2-gang	2
3-gang	3
4-gang	4
5-gang	5
6-gang	6
7-gang	7
8-gang	8

Enter Catalog Number

◆ WC\* SS 4

**Step 2:**  
Enter quantity.


**Step 3:** Select the custom metal wallplate configuration.

Refer to the custom wallplate configuration chart to select a configuration for each gang in the wallplate. Each configuration has a specific 3-digit code located in the right hand side of the chart on pages K-34 to K-38. Enter this 3-digit configuration code in the corresponding box on the order form grid to match the position required on the finished custom wallplate.

Item No.	Catalog Number	Quantity	Code	Position 1	Position 2	Position 3	Position 4
1	WCSS4		H*	001	149	008	026
2							

Note: \* WC and H are preprinted on the distributor order form. Number to use for pricing.

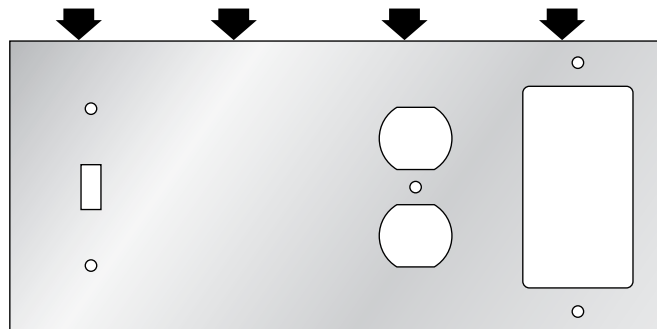The 3-digit numbers listed at the upper right of the Sample Order Form (001, 149, etc.) represent the custom metal wallplate selected on the right. See Configuration Chart and Hubbell Configuration Selector Guide on pages K-34 to K-38 for additional configuration choices.





## Wallplates

## Custom Metal Wallplates

## Configuration Chart

	<b>001</b> Switch.		<b>079</b> Barrel Key Switch with hash marks.		<b>456</b> .375" (9.5) Dia. Round Box Mtd.
	<b>007</b> Single Receptacle. 1.40" ID (35.6)		<b>080</b> Barrel Key Switch with On/Off and hash marks.		<b>458</b> .500" (12.7) Dia. Round Box Mtd.
	<b>008</b> Duplex Receptacle.		<b>091</b> Single Receptacle. 1.60" ID (40.5) Hole.		<b>411</b> .635" (16.1) Dia. Round Box Mtd.
	<b>011</b> 1-gang .635" ID (16.1) Hole Box Mounted with .50" ID (12.7) Nylon Bushing.		<b>098</b> Single Receptacle. 2.16" ID (54.7) Hole.		<b>435</b> 9-Pin Vertical Box Mtd.
	<b>012</b> 1-gang .635" ID (16.1) Hole Strap Mtd. incl. Strap with .50" ID (12.7) Nylon Bushing.		<b>135</b> Vertical Mounted Louver.		<b>438</b> 15-Pin Vertical Box Mtd.
	<b>013</b> Blank Box Mount.		<b>149</b> Totally Blank (no mounting holes).		<b>295</b> 25-Pin Vertical Box Mtd.
	<b>014</b> Blank Strap Mtd. incl. Strap.	<b>Coax/Twinax and Modular Jack Openings</b>			<b>314</b> IBM® Type Opening Box Mounted.
	<b>026</b> Rectangular Opening.		<b>422</b> .51" (12.8) Dia. "D" Box Mtd. .44" (11.1) Flat Dia.		<b>415</b> IBM® Type Opening with One .586" X .762" (14.9 X 19.3).
	<b>055</b> 1-gang .375" ID (9.5) Hole Strap Mtd. incl. Strap.		<b>425</b> .51" (12.8) Dia. "D" Box Mtd. .47" (12) Flat Dia.	<b>Voice/Data Opening</b>	
	<b>056</b> 1-gang .375" ID (9.5) Hole Box Mounted.		<b>428</b> .58" (14.7) Dia. "D" Box Mtd. .55" (14) Flat Dia.		<b>470</b> .542" X .750" Vertical Box Mtd. (13.8 X 19.0).
	<b>057</b> 1-gang .50" ID (12.7) Hole Strap Mtd. incl. Strap.		<b>430</b> .76" (19.2) Dia. "D" Box Mtd. .73" (18.6) Flat Dia.		<b>473</b> .586" X .762" Vertical Box Mtd. (14.9 X 19.4).
	<b>058</b> 1-gang .50" ID (12.7) Hole Box Mounted.		<b>431</b> .76" (19.2) Dia. "D" Box Mtd. .73" (18.6) Flat Dia.		<b>476</b> .586" X .815" Vertical Box Mtd. (14.9 X 20.7).
	<b>078</b> Barrel Key Switch.		<b>423</b> .51" (12.8) Dia. "D" Box Mtd. .44" (11.1) Flat Dia.		<b>477</b> .586" X .815" Vertical Box Mtd. (14.9 X 20.7).
			<b>426</b> .51" (12.8) Dia. "D" Box Mtd. .47" (12) Flat Dia.		<b>480</b> .575" X .783" Vertical Box Mtd. (14.6 X 19.9).
			<b>429</b> .58" (14.7) Dia. "D" Box Mtd. .55" (14) Flat Dia.		<b>471</b> .542" X .750" Vertical Box Mtd. (13.8 X 19.0).
			<b>431</b> .76" (19.2) Dia. "D" Box Mtd. .73" (18.6) Flat Dia.		<b>474</b> .586" X .762" Vertical Box Mtd. (14.9 X 19.4).

Note: For detailed dimensions of the above configurations, see pages K-35 to K-38. Available in smooth metal, standard size only up to and including 8-gang type.

IBM® is a registered trademark of International Business Machines Corporation.



# Wallplates

## Custom Metal Wallplates

Configuration Selector Guide

**Configuration 001**

Toggle Switch Plate.

**Configuration 014**

Blank Plate (Strap Mount).

**Configuration 007**

Single 15 or 20A Straight Blade Receptacle.  
15A Twist-Lock® Receptacle.

**Configuration 026**

GFI/Rectangular Opening.

**Configuration 008**

Duplex Receptacle.

**Configuration 055**

Single, .375" (9.5) Telephone (Strap Mount).

**Configuration 011**

Single, .635" (16.1) Telephone (Box Mount).

**Configuration 056**

Single, .375" (9.5) Telephone (Box Mount).

**Configuration 012**

Single, .635" (16.1) Telephone (Strap Mount).

**Configuration 057**

Single, .50" (12.7) Telephone (Strap Mount).

**Configuration 013**

Blank Plate (Box Mount).

**Configuration 058**

Single, .50" (12.7) Telephone (Box Mount).

Note: Specifications are subject to change without notice.

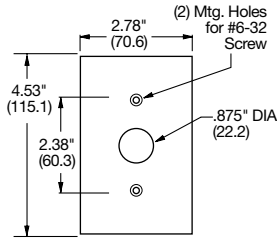




# Wallplates


## Custom Metal Wallplates

Configuration Selector Guide




Configuration  
**078**

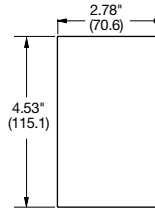Barrel Key Switch.




Configuration  
**149**

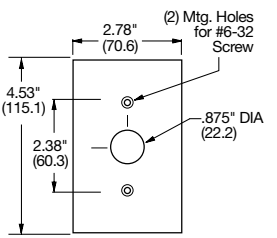Totally Blank Plate.




Configuration  
**079**

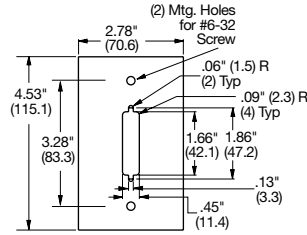Barrel Key Switch with hash marks.




Configuration  
**295**

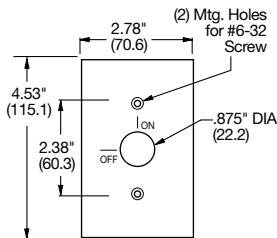RS232 Port Single 25-Pin (Box Mount).




Configuration  
**080**

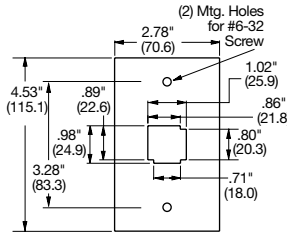Barrel Key Switch with On/Off and hash marks.




Configuration  
**314**

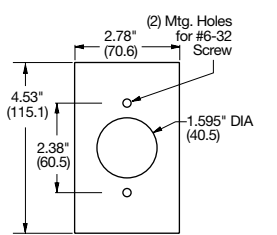IBM® Type (Box Mount).




Configuration  
**091**

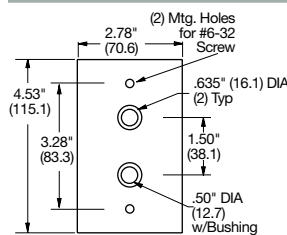Single 20 or 30A Twist-Lock® Receptacle.




Configuration  
**411**

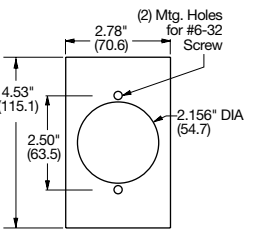Dual .635" (16.1) Holes (Box Mount).




Configuration  
**098**

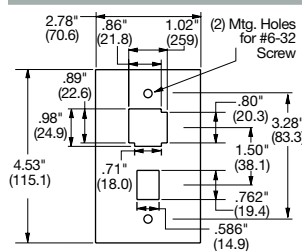Single Receptacle, 30 or 50A Straight Blade, 3 Wire Power Outlet.




Configuration  
**415**

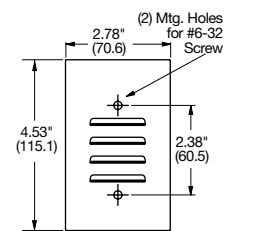IBM® Type and Modular Jack (Box Mount).



Configuration  
**135**

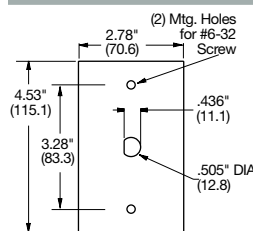Louvered Plate, Strap Mount.



Configuration  
**422**

Single .505" (12.8) D-Hole (Box Mount).

Note: Specifications are subject to change without notice.


IBM® is a registered trademark of International Business Machines Corporation.




# Wallplates
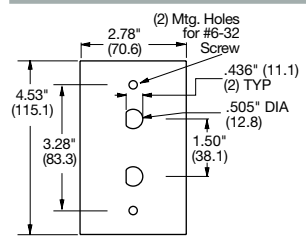
## Custom Metal Wallplates


Configuration Selector Guide



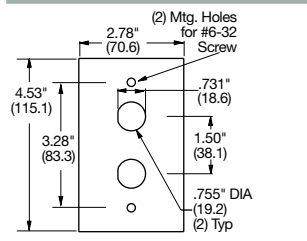
**Configuration 423**  
Dual .505" (12.8) D-Holes (Box Mount).



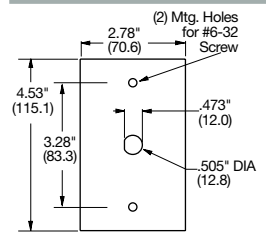
**Configuration 431**  
Dual .755" (19.2) D-Holes (Box Mount).



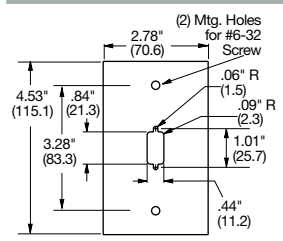
**Configuration 425**  
Single .505" (12.8) D-Hole (Box Mount).



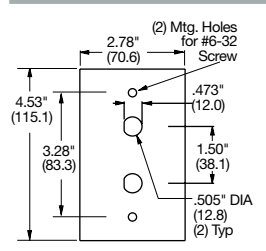
**Configuration 435**  
Single 9-Pin RS232 (Box Mount).



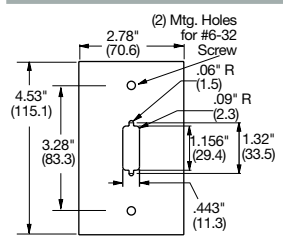
**Configuration 426**  
Dual .505" (12.8) D-Holes (Box Mount).



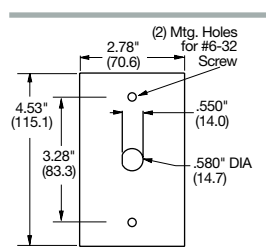
**Configuration 438**  
Single 15-Pin RS232 (Box Mount).



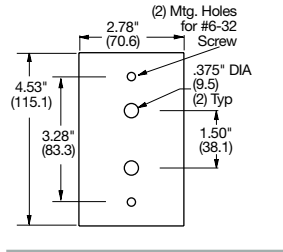
**Configuration 428**  
Single .580" (14.7) D-Hole (Box Mount).



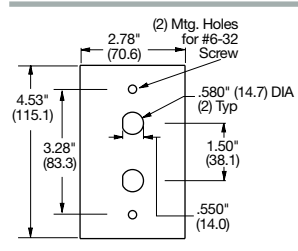
**Configuration 456**  
Dual .375" (9.5) Round (Box Mount).



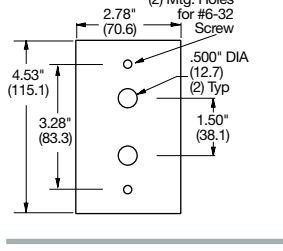
**Configuration 429**  
Dual .580" (14.7) D-Holes (Box Mount).



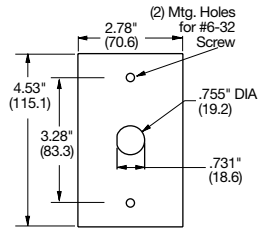**Configuration 458**  
Dual .50" (12.7) Round (Box Mount).



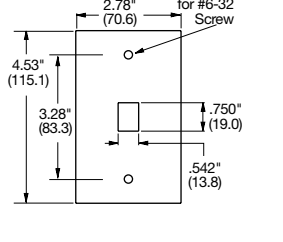**Configuration 430**  
Single .755" (19.2) D-Hole (Box Mount).



**Configuration 470**  
Single Modular Jack (Box Mount).

Note: Specifications are subject to change without notice.












## Wallplates
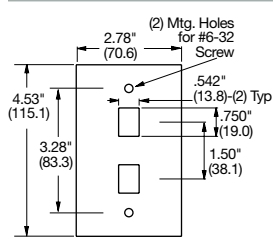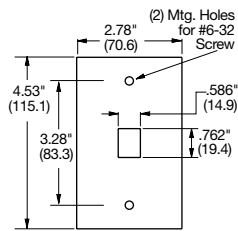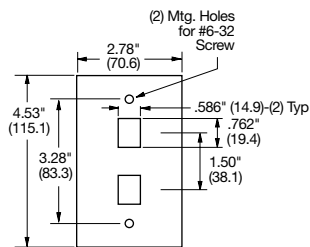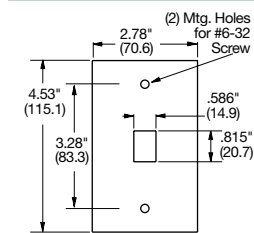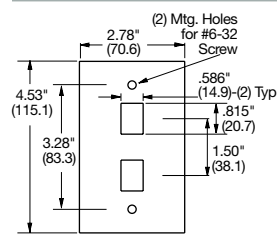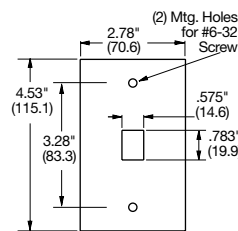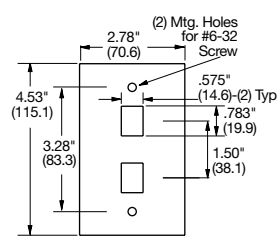
## Custom Metal Wallplates

## Configuration Selector Guide

Configuration  
471Dual Modular Jack  
(Box Mount).Configuration  
473Single Modular Jack  
(Box Mount).Configuration  
474Dual Modular Jack  
(Box Mount).Configuration  
476Dual Modular Jack  
(Box Mount).Configuration  
477Dual Modular Jack  
(Box Mount).Configuration  
479Single Modular Jack  
(Box Mount).Configuration  
480Dual Modular Jack  
(Box Mount).

Note: Specifications are subject to change without notice.