

Straight Blade Devices 15 and 20 Ampere, 125 Volts

2 Pole, 3 Wire Grounding


**HBL® Extra Heavy Duty, Specification Grade, Weather Resistant,
Single and Special Purpose Receptacles**




15A 125V
NEMA 5-15R
UL CSA
0.5 HP




20A 125V
NEMA 5-20R
UL Listed
1 HP

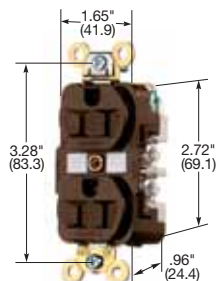


HBL5262

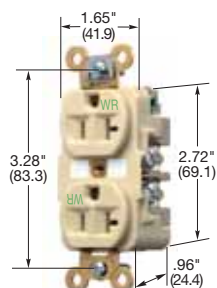

HBL5362IWR

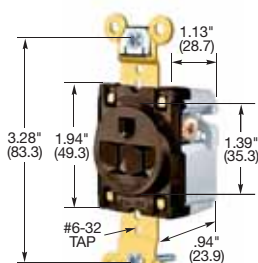

HBL5261

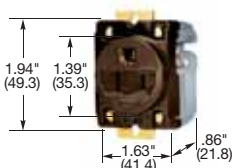

HBL5284

Receptacles

HBL® Extra Heavy Duty, Specification Grade, Duplex

Description	Color	Catalog Numbers	
Flush, nylon face, back and side wired, multiple drive screws.	Black	HBL5262BK	HBL5362BK
	Blue	-	HBL5362BL
	Brown	HBL5262	HBL5362
	Gray	HBL5262GY	HBL5362GY
	Ivory	HBL5262I	HBL5362I
	Red	HBL5262R	HBL5362R
	White	HBL5262W	HBL5362W
Isolated ground. ⁽¹⁾	Gray	IG5262GY	IG5362GY
	Ivory	IG5262I	IG5362I
	Orange	IG5262	IG5362
	Red	IG5262R	IG5362R
	White	-	IG5362W
Non-isolated ground, bulk pack of 100.	Orange	-	HBL5362M4
Weather resistant, flush, nylon face, back and side wired, multiple drive screws.	Black	HBL5262BKWR	HBL5362BKWR
	Brown	HBL5262WR	HBL5362WR
	Gray	HBL5262GYWR	HBL5362GYWR
	Ivory	HBL5262IWR	HBL5362IWR
	Red	HBL5262RWR	HBL5362RWR
Corrosion resistant.	White	HBL5262WWR	HBL5362WWR
	Yellow	HBL52CM62I	-
Weather resistant, Isolated ground. ⁽¹⁾	Gray	IG5262GYWR	IG5362GYWR
	Ivory	IG5262IWR	IG5362IWR
	Orange	IG5262WR	IG5362WR
	Red	IG5262RWR	IG5362RWR
	White	-	IG5362WWR
On 4 in. (101.6) round cover.	Brown	HBL5282	-



15A 125V
NEMA 5-15R
UL CSA
0.5 HP



20A 125V
NEMA 5-20R
UL Listed
1 HP

HBL® Extra Heavy Duty, Specification Grade, Single

Description	Color	Catalog Numbers	
Flush, nylon face, back and side wired, multiple drive screws.	Black	HBL5261BK	HBL5361BK
	Brown	HBL5261	HBL5361
	Gray	-	HBL5361GRY
	Ivory	HBL5261I	HBL5361I
	White	-	HBL5361W
Isolated ground. ⁽¹⁾	Orange	IG5261	IG5361
Weather resistant, Isolated ground. ⁽¹⁾	Orange	IG5261WR	IG5361WR
	Brown	HBL5261RT	HBL5361RT
	White	HBL5261WRT	-
Ring terminal connection.	Yellow	HBL5261YRT	-
Weather resistant, flush, nylon face, back and side wired, multiple drive screws.	Brown	HBL5261WR	HBL5361WR
	Gray	HBL5261GYWR	HBL5361GYWR
	Ivory	HBL5261IWR	HBL5361IWR
Corrosion resistant.	Yellow	HBL52CM61	HBL53CM61
Panel mount on 1.94 in. (49.3) centers.	Brown	HBL5284	HBL5357



Notes: See page A-44 for accessories.

See Section K for wallplates.

(1) See Section J for complete line of isolated ground devices.

See page A-15 for NEC® Tamper and Weather Resistant Code Requirements.