

Straight Blade Devices

15 and 20 Ampere, 250 Volts

2 Pole, 3 Wire Grounding

Insulgrip® Plugs and Flanged Inlets



15A 250V
NEMA 6-15P
UL CSA
1.5 HP




20A 250V
NEMA 6-20P
UL CSA
2 HP




HBL5666C



HBL5666CA

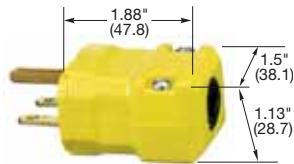

HBL5666VY

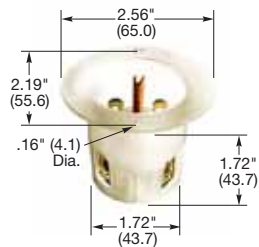

HBL5678C

Plugs

15 and 20 Ampere

Description	Cord Diameter	Catalog Numbers	
Insulgrip® Plug, black and white nylon.	.230"-.720" (5.8-18.3)	HBL5666C	HBL5466C
Insulgrip® Plug, corrosion resistant, yellow nylon.	.230"-.720" (5.8-18.3)	HBL56CM66C	HBL54CM66C
8-Position Insulgrip® Angle Plug, black and white nylon.	.325"-.655" (8.3-16.6)	HBL5666CA	HBL5466CA
Valise® Plug, yellow nylon.	.220"-.660" (5.6-16.8)	HBL5666VY	HBL5464VY

Note: See page A-45 for accessories.

Insulgrip® Flanged Inlets

Description	Catalog Numbers	
Nylon casing, back wired.	HBL5678C	HBL5478C

Notes: Flanged inlets are not HP rated.
See page A-45 for accessories.