


Twist-Lock® Devices

20 Ampere, 125, 250 Volts and 277 Volts AC

2 Pole, 3 Wire Grounding
Insulgrip® Plugs and Flanged Inlets

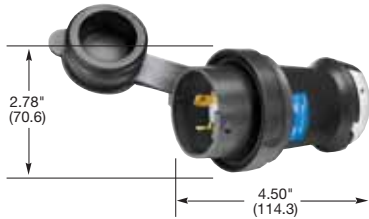


HBL2321SW



HBL2321S




HBL2311

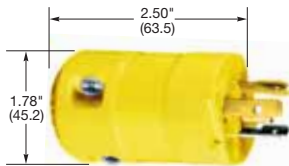

HBL2311VY



HBL2325SW

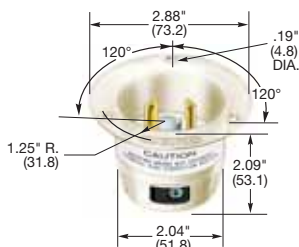

HBL2315

Plugs

Watertight Safety-Shroud®		IP66 SUITABILITY		
Description	Cord Dia.	Catalog Numbers		
Black Valox® housing, white Valox® clamps.	.360"-.930" (9-24)	HBL2311SW	HBL2321SW	HBL2331SW

Safety-Shroud		IP20 SUITABILITY		
Description	Cord Dia.	Catalog Numbers		
Black and white nylon body, white Valox® shroud. Can be used with the Insulgrip Connector Bodies.	.360"-.930" (9-24)	HBL2311S	HBL2321S	HBL2331S

Insulgrip		IP20 SUITABILITY		
Description	Cord Dia.	Catalog Numbers		
Black and white nylon.	.360"-.930" (9-24)	HBL2311	HBL2321	HBL2331
Corrosion resistant, yellow nylon.	.360"-.930" (9-24)	HBL23CM11	HBL23CM21	-
All black nylon.	.360"-.930" (9-24)	HBL2311BK	HBL2321BK	-
Cord clamps with removable inserts. All black nylon.	.360"-.930" (9-24)	HBL2311EBK	HBL2321EBK	-

Accessories on page B-40.

Valise®		IP20 SUITABILITY		
Description	Cord Dia.	Catalog Numbers		
Yellow nylon.	.325"-.720" (8.26-18.3)	HBL2311VY	HBL2321VY	HBL2331VY
Corrosion resistant, yellow nylon.	.325"-.720" (8.26-18.3)	HBL23CM11V	-	-
Black nylon.	.325"-.720" (8.26-18.3)	HBL2311VBK	HBL2321VBK	HBL2331VBK

Accessories on page B-51.

Flanged Inlets

Watertight Safety-Shroud		IP66 SUITABILITY		
Description	Catalog Numbers			
Gray Valox® housing and flange.	HBL2315SW HBL2325SW HBL2335SW			

Insulgrip		IP20 SUITABILITY		
Description	Catalog Numbers			
Nylon casing, back wired.	HBL2315 HBL2325 HBL2335			

Notes: For technical information on Twist-Lock® and Watertight Safety-Shroud Devices see pages B-69 and B-70. For technical information on Valise plugs and connectors see page B-74.

HBLMITL - For use with Watertight Safety-Shroud receptacles, see page B-39.



Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.