


Twist-Lock® Devices

20 Ampere, 3Ø Y 120/208, 277/480 and 347/600 Volts AC

4 Pole, 5 Wire Grounding

Insulgrip® Plugs and Flanged Inlets

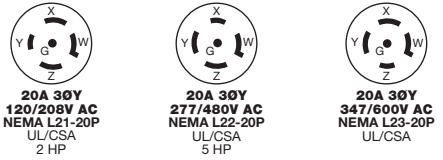

HBL2511SW




HBL2511S



HBL2511



HBL2515SW

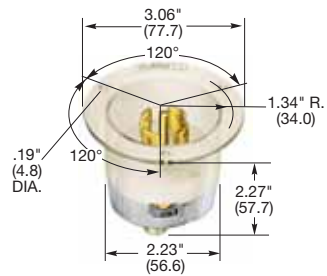

HBL2515

Plugs

Watertight Safety-Shroud®		IP66 SUITABILITY		
Description	Cord Dia.	Catalog Numbers		
Black Valox® housing, white Valox® clamps.	.35"-1.15" (9-29)	HBL2511SW	-	-

Safety-Shroud		IP20 SUITABILITY		
Description	Cord Dia.	Catalog Numbers		
Black and white nylon body, white Valox® shroud. Can be used with the Insulgrip Connector Bodies.	.35"-1.15" (9-29)	HBL2511S	-	-

Accessories on page B-40.

Insulgrip		IP20 SUITABILITY		
Description	Cord Dia.	Catalog Numbers		
Black and white nylon.	.35"-1.15" (9-29)	HBL2511	HBL2521	HBL2531
All black nylon.	.35"-1.15" (9-29)	HBL2511BK	-	-
Corrosion resistant, yellow nylon.	.35"-1.15" (9-29)	HBL25CM11	-	-
Black and white for flat cable.	.35"-1.15" (9-29)	HBL2511FC	-	-

Accessories on page B-53.

Flanged Inlets

Watertight Safety-Shroud		IP66 SUITABILITY		
Description	Catalog Numbers			
Gray Valox® housing and flange.	HBL2515SW - - -			

Accessories on page B-52.

Insulgrip		IP20 SUITABILITY		
Description	Catalog Numbers			
Nylon casing, back wired.	HBL2515 HBL2525 HBL2535			

Accessories on page B-52.

Notes: For technical information on Twist-Lock® and Watertight Safety-Shroud Devices see pages B-69 and B-70.



HBLMITL - For use with Watertight Safety-Shroud receptacles, see page B-39.

Valox® is a trademark of SABIC Innovative Plastics, acquired from General Electric Company.