

Twist-Lock® Devices
30 Ampere, 480 and 600 Volts AC
 2 Pole, 3 Wire Grounding
**Insulgrip® Plugs, Flanged Inlets,
 Connector Bodies and Receptacles**



IP20
SUITABILITY



30A 480V AC
NEMA L8-30P
UL/CSA
5 HP




30A 600V AC
NEMA L9-30P
UL/CSA

Plugs

Description	Cord Dia.	Catalog Numbers
Black and white nylon.	.325"-.930" (8.25-24)	HBL2641 HBL2651

Accessories on page B-51.

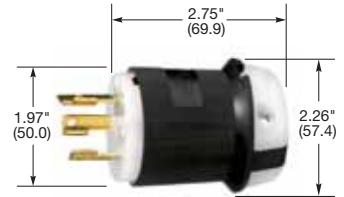


HBL2651

Flanged Inlets

Description	Catalog Numbers
Nylon casing, back wired.	HBL2645 HBL2655

Accessories on page B-50.

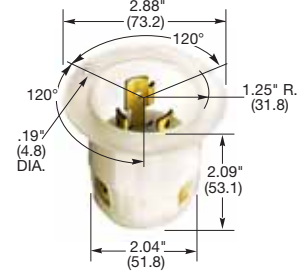

HBL2655

IP20
SUITABILITY



30A 480V AC
NEMA L8-30R
UL/CSA
5 HP



30A 600V AC
NEMA L9-30R
UL/CSA

Connector Bodies

Description	Cord Dia.	Catalog Numbers
Black and white nylon.	.325"-.930" (8.25-24)	HBL2643 HBL2653

Accessories on page B-51.




HBL2653

Single Flush Receptacles, Back and Side Wired

Description	Catalog Numbers
Black nylon face.	HBL2640 HBL2650

Accessories on page B-50.

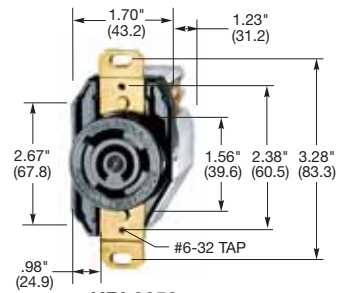


HBL2650

Flanged Receptacles

Description	Catalog Numbers
Nylon casing, back wired.	HBL2646 HBL2656

Accessories on page B-50.

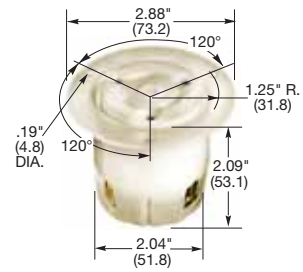

HBL2656

Note: For technical information on Twist-Lock® Devices see page B-69.

