


## Support Grips

### Standard Duty Support


Double Eye, Single Weave, Tin-Coated Bronze

#### IMPORTANT!


It is important that you read all breaking strength, safety and technical data relating to this product on pages T-43 through T-48.

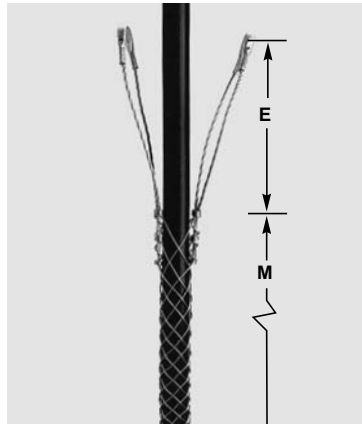

Double Eye, Closed Mesh

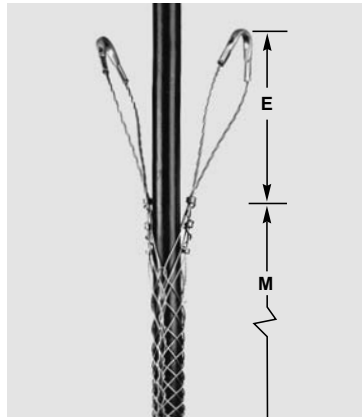

Double Eye, Split Mesh, Lace Closing

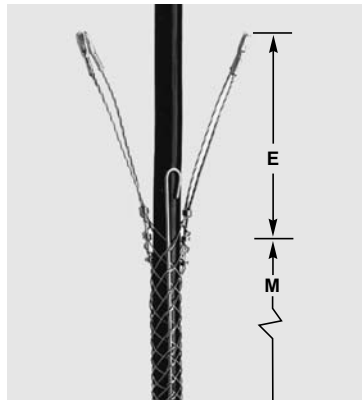

Double Eye, Split Mesh, Rod Closing

#### Double Eye, Closed Mesh\*

For permanent support when cable end is available to be installed through grip.

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs. (N)	E Inches (cm)	M Inches (cm)	Catalog Numbers
.50"- .62" (1.27-1.57)	530 (2,357)	4" (10.16)	10" (25.40)	<b>02201001</b>
.63"- .74" (1.60-1.88)	790 (3,514)	4" (10.16)	10" (25.40)	<b>02201002</b>
.75"- .99" (1.90-2.51)	1,020 (4,537)	4" (10.16)	13" (33.02)	<b>02201003</b>
1.00"-1.24" (2.54-3.15)	1,610 (7,161)	5" (12.70)	14" (35.56)	<b>02201005</b>
1.25"-1.49" (3.17-3.78)	1,610 (7,161)	5" (12.70)	15" (38.10)	<b>02201006</b>
1.50"-1.74" (3.81-4.42)	1,610 (7,161)	5" (12.70)	17" (43.18)	<b>02201007</b>
1.75"-1.99" (4.44-5.05)	2,150 (9,563)	6" (15.24)	19" (48.26)	<b>02201008</b>
2.00"-2.49" (5.08-6.32)	3,260 (14,500)	6" (15.24)	21" (53.34)	<b>02201009</b>
2.50"-2.99" (6.35-7.59)	3,260 (14,500)	6" (15.24)	23" (58.42)	<b>02201010</b>
3.00"-3.49" (7.62-8.86)	4,900 (21,795)	8" (20.32)	25" (63.50)	<b>02201011</b>
3.50"-3.99" (8.89-10.13)	4,900 (21,795)	8" (20.32)	27" (68.58)	<b>02201012</b>

#### Double Eye, Split Mesh, Lace Closing\*

For permanent support when cable end is not available.

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs. (N)	E Inches (cm)	M Inches (cm)	Catalog Numbers
.50"- .62" (1.27-1.57)	530 (2,357)	4" (10.16)	10" (25.40)	<b>02202001</b>
.63"- .74" (1.60-1.88)	790 (3,514)	4" (10.16)	10" (25.40)	<b>02202002</b>
.75"- .99" (1.90-2.51)	1,020 (4,537)	4" (10.16)	13" (33.02)	<b>02202003</b>
1.00"-1.24" (2.54-3.15)	1,610 (7,161)	5" (12.70)	14" (35.56)	<b>02202005</b>
1.25"-1.49" (3.17-3.78)	1,610 (7,161)	5" (12.70)	15" (38.10)	<b>02202006</b>
1.50"-1.74" (3.81-4.42)	1,610 (7,161)	5" (12.70)	17" (43.18)	<b>02202007</b>
1.75"-1.99" (4.44-5.05)	2,150 (9,563)	6" (15.24)	19" (48.26)	<b>02202008</b>
2.00"-2.49" (5.08-6.32)	3,260 (14,500)	6" (15.24)	21" (53.34)	<b>02202009</b>
2.50"-2.99" (6.35-7.59)	3,260 (14,500)	6" (15.24)	23" (58.42)	<b>02202010</b>
3.00"-3.49" (7.62-8.86)	4,900 (21,795)	8" (20.32)	25" (63.50)	<b>02202011</b>
3.50"-3.99" (8.89-10.13)	4,900 (21,795)	8" (20.32)	27" (68.58)	<b>02202012</b>

#### Double Eye, Split Mesh, Rod Closing\*

For support when cable end is not available.

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs. (N)	E Inches (cm)	M Inches (cm)	Catalog Numbers
.50"- .62" (1.27-1.57)	790 (3,514)	4" (10.16)	8 1/2" (21.59)	<b>02203001</b>
.63"- .74" (1.60-1.88)	790 (3,514)	4" (10.16)	8 1/2" (21.59)	<b>02203002</b>
.75"- .99" (1.90-2.51)	1,020 (4,537)	4" (10.16)	10 1/2" (26.67)	<b>02203003</b>
1.00"-1.24" (2.54-3.15)	1,610 (7,161)	5" (12.70)	12 1/2" (31.75)	<b>02203005</b>
1.25"-1.49" (3.17-3.78)	1,610 (7,161)	5" (12.70)	14 1/2" (36.83)	<b>02203006</b>
1.50"-1.74" (3.81-4.42)	1,610 (7,161)	5" (12.70)	15 1/2" (39.37)	<b>02203007</b>
1.75"-1.99" (4.44-5.05)	2,150 (9,563)	6" (15.24)	16 1/2" (41.91)	<b>02203008</b>
2.00"-2.49" (5.08-6.32)	3,260 (14,500)	6" (15.24)	19 1/2" (49.53)	<b>02203009</b>
2.50"-2.99" (6.35-7.59)	3,260 (14,500)	6" (15.24)	21 1/2" (54.61)	<b>02203010</b>
3.00"-3.49" (7.62-8.86)	5,750 (25,576)	8" (20.32)	23 1/2" (59.69)	<b>02203011</b>
3.50"-3.99" (8.89-10.13)	5,750 (25,576)	8" (20.32)	25 1/2" (64.77)	<b>02203012</b>

E-Eye length M-Mesh length at nominal diameter

\* Change catalog number from 022 to 024 for stainless steel. Consult factory for availability.