



Support Grips

Standard Duty Support

Universal Eye, Single Weave, Tin-Coated Bronze

Universal Eye, Closed Mesh*

For permanent support when cable end is available to be installed through grip.

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs. (N)	E Inches (cm)	M Inches (cm)	Catalog Numbers
.50"- .62" (1.27-1.57)	530 (2,357)	18" (45.72)	10" (25.40)	02201051
.63"- .74" (1.60-1.88)	790 (3,514)	18" (45.72)	10" (25.40)	02201052
.75"- .99" (1.90-2.51)	1,020 (4,537)	18" (45.72)	13" (33.02)	02201053
1.00"-1.24" (2.54-3.15)	1,610 (7,161)	18" (45.72)	14" (35.56)	02201050
1.25"-1.49" (3.17-3.78)	1,610 (7,161)	18" (45.72)	15" (38.10)	02201054
1.50"-1.74" (3.81-4.42)	1,610 (7,161)	18" (45.72)	17" (43.18)	02201055
1.75"-1.99" (4.44-5.05)	2,150 (9,563)	18" (45.72)	19" (48.26)	02201056
2.00"-2.49" (5.08-6.32)	3,260 (14,500)	18" (45.72)	21" (53.34)	02201057
2.50"-2.99" (6.35-7.59)	3,260 (14,500)	18" (45.72)	23" (58.42)	02201058

Universal Eye, Split Mesh, Lace Closing*

For permanent support when cable end is not available.

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs. (N)	E Inches (cm)	M Inches (cm)	Catalog Numbers
.50"- .62" (1.27-1.57)	530 (2,357)	18" (45.72)	10" (25.40)	02202050
.63"- .74" (1.60-1.88)	790 (3,514)	18" (45.72)	10" (25.40)	02202051
.75"- .99" (1.90-2.51)	1,020 (4,537)	18" (45.72)	13" (33.02)	02202052
1.00"-1.24" (2.54-3.15)	1,610 (7,161)	18" (45.72)	14" (35.56)	02202054
1.25"-1.49" (3.17-3.78)	1,610 (7,161)	18" (45.72)	15" (38.10)	02202055
1.50"-1.74" (3.81-4.42)	1,610 (7,161)	18" (45.72)	17" (43.18)	02202056
1.75"-1.99" (4.44-5.05)	2,150 (9,563)	18" (45.72)	19" (48.26)	02202057
2.00"-2.49" (5.08-6.32)	3,260 (14,500)	18" (45.72)	21" (53.34)	02202058
2.50"-2.99" (6.35-7.59)	3,260 (14,500)	18" (45.72)	23" (58.42)	02202059
3.00"-3.49" (7.62-8.86)	4,900 (21,795)	18" (45.72)	25" (63.50)	02202060
3.50"-3.99" (8.89-10.13)	4,900 (21,795)	18" (45.72)	27" (68.58)	02202061

Universal Eye, Split Mesh, Rod Closing*

For support when cable end is not available.


Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs. (N)	E Inches (cm)	M Inches (cm)	Catalog Numbers
.50"- .62" (1.27-1.57)	790 (3,514)	18" (45.72)	8 1/2" (21.59)	02203064
.63"- .74" (1.60-1.88)	790 (3,514)	18" (45.72)	8 1/2" (21.59)	02203065
.75"- .99" (1.90-2.51)	1,020 (4,537)	18" (45.72)	10 1/2" (26.67)	02203066
1.00"-1.24" (2.54-3.15)	1,610 (7,161)	18" (45.72)	12 1/2" (31.75)	02203068
1.25"-1.49" (3.17-3.78)	1,610 (7,161)	18" (45.72)	14 1/2" (36.83)	02203069
1.50"-1.74" (3.81-4.42)	1,610 (7,161)	18" (45.72)	15 1/2" (39.37)	02203070
3.00"-3.49" (7.62-8.86)	5,750 (25,576)	18" (45.72)	23 1/2" (59.69)	02203074

E-Eye length M-Mesh length at nominal diameter


* Change catalog number from 022 to 024 for stainless steel. Consult factory for availability.

IMPORTANT!

It is important that you read all breaking strength, safety and technical data relating to this product on pages T-43 through T-48.

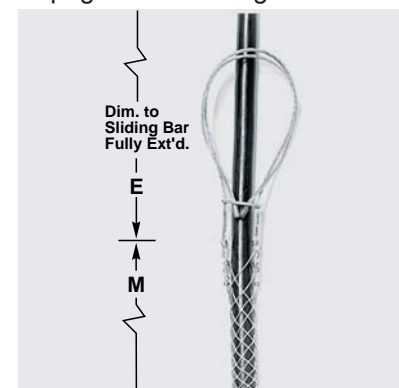

Universal Eye, Closed Mesh

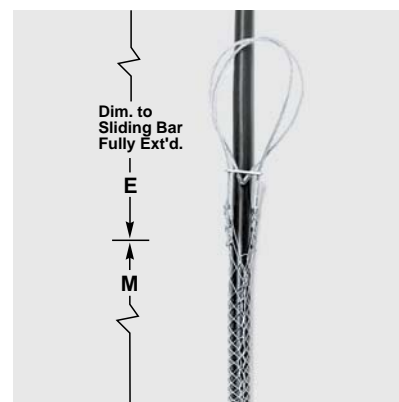

Universal Eye Split Mesh, Lace Closing



Universal Eye Split Mesh, Rod Closing