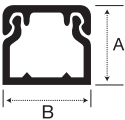

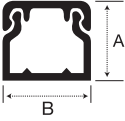

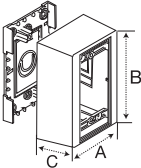

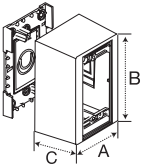

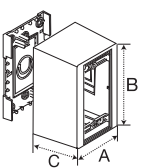

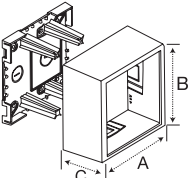

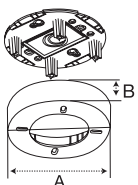



# PT1 PremiseTrak® (Non-Latching) Non-Metallic Raceway

Raceway		Catalog Number	Length	Color	
<b>Base and Cover</b> Single channel raceway. Available in 5 ft. (1.5m) and 7 ft. (2.1m) lengths.			<b>PT1BC5</b>	5 ft.	Office
			<b>PT1BC7</b>	7 ft.	White
		A: .68" (17.30) B: .75" (18.90)			
<b>Base and Cover (with adhesive)</b> Single channel raceway. Available in 5 ft. (1.5m) and 7 ft. (2.1m) lengths.			<b>PT1ABC5</b>	5 ft.	Office
			<b>PT1ABC7</b>	7 ft.	White
		A: .68" (17.30) B: .75" (18.90)			
Switch and Receptacle Boxes		Catalog Number	Color		
<b>One-Gang Low Profile Box</b> For shallow switches and receptacles. See pages 81-82 for recommended plate options.			<b>PT12LPB</b>	Office	
				White	
		A: 3.25" (82.55) B: 4.90" (124.46) C: 1.12" (28.50)			
<b>One-Gang Standard Box</b> For standard switches and receptacles. See pages 81-82 for recommended plate options.			<b>PT12SBA</b>	Office	
				White	
		A: 3.25" (82.55) B: 4.90" (124.46) C: 1.63" (41.40)			
<b>One-Gang Deep Box</b> For deep devices or applications where additional room is beneficial. See pages 81-82 for recommended plate options.			<b>PT12DBA</b>	Office	
				White	
		A: 3.25" (82.55) B: 4.90" (124.46) C: 1.91" (48.40)			
<b>Two-Gang Deep Box</b> For deep devices or applications where additional room is beneficial. Uses two-gang "KP" or "IFP" plates for data application. Uses two-gang KP plate for power application. See pages 81-82 for recommended plate options.			<b>PT12TGB</b>	Office	
				White	
		A: 5.06" (128.52) B: 4.90" (124.46) C: 1.91" (48.40)			
Round Box		Catalog Number	Color		
<b>Round Lighting Fixture Box</b> To hang fixtures.			<b>PT12LFB</b>	Office	
				White	
		A: 5.31" (134.87) B: 1.04" (26.50)			