



◆ DEMANDING ENVIRONMENTS ◆



HI-Impact™ Connectors

Call for additional product information



Type	Cat. No.
Category 6 Connector	HBLHI6*
Category 5e Connector	HBLHI5E
Category 5e In-Line Coupler	HBLHI5EC
Category 5e Shielded Connector	HBLHI5ESC
M12 Micro Quick, Male	MBMS14314*

* Available Q2-2004.

Communication Jacks



Description	Cat. No.
Category 6	HBL6XX
Category 5e	HBL5EXX

XX = Color

BK = Black	B = Blue	EI = Electric Ivory
GY = Gray	GN = Green	OW = Office White
OR = Orange	R = Red	TI = Telco Ivory
W = White	Y = Yellow	

Multimedia Connector

Description	Cat. No.
F-type	HBLHIF**

** Available Q3-2004.



Connector Cover

Description	Cat. No.
Protective Cover	HBLHIC



HI-Impact™ Frames

Call for additional product information

StyleLine® Frames

Ports	Cat. No.
2	FCX244xx
3	FCX344xx
4	FCX444xx
6	FCX644xx



Duplex Frames

Ports	Cat. No.
2	DJOxx
4	DJ106xx

xx = Color


BK = Black	EI = Electric Ivory
GY = Gray	OW = Office White
W = White	



HI-Impact™ Plates


Call for additional product information

Stainless Steel

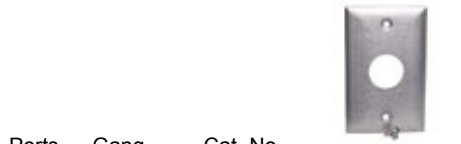

Ports	Gang	Cat. No.
1	1	HBLHISF11
2	1	HBLHISF12
2	2	HBLHISF22
4	2	HBLHISF24

Thermoplastic, 4-Point, 1-Gang

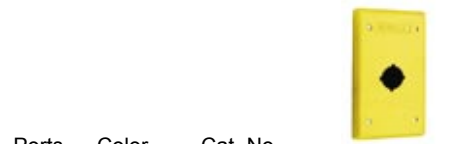

Ports	Color	Cat. No.
1	Gray	HBLHI14GY
2	Gray	HBLHI24GY
1	Yellow	HBLHI14PY
2	Yellow	HBLHI24PY

Flip-Cover, Die-Cast Aluminum, 1-Gang



Type	Orientation	Cat. No.
Duplex	Vertical	WP26
4-Point	Vertical	WPFS26

Flip-Cover, Thermoplastic, 1-Gang



Type	Orientation	Cat. No.
Duplex	Horizontal	HBL5222
4-Point	Horizontal	HBL5221

Weatherproof, NEMA 3R



Type	Orientation	Gang	Cat. No.
Bell®Box	Horizontal	1	WP826MHP
Bell®Box	Vertical	1	WP826MP
Bell®Box	Vertical	2	WP8262MP
Secure-IT™	Vertical	1	HBLTWP1GY

HI-Impact™ Boxes

Call for additional product information

Fiberglass Weatherproof Device Box with Lugs



Knockout Size	Color	Cat. No.
3/4"	Yellow	HBL60CM83

Cast Aluminum Device Box with Lugs

Knockout Size	Color	Cat. No.
1/2"	Gray	HBLHIFD1L*
3/4"	Gray	HBLHIFD2L*

* Available Q2-2004.

Cast Aluminum Weatherproof Device Box with Lugs

Knockout Size	Color	Cat. No.
1/2"	Gray	HBLHIWP05GY*
3/4"	Gray	HBLHIWP75GY*

* Available Q2-2004.

NEMA 4X Box



Port	Material	Cat. No.
1	Thermoplastic, Gray	HBLHI14XGY*
2	Thermoplastic, Gray	HBLHI24XGY*
4	Thermoplastic, Gray	HBLHI44XGY*
6	Thermoplastic, Gray	HBLHI64XGY*
1	Stainless steel	HBLHI1CBSS*
2	Stainless steel	HBLHI2CBSS*

* Available Q2-2004.

NEMA 4/12 Box



Port	Material	Cat. No.
1	Gray	HBLHI1CBG*
2	Gray	HBLHI2CBG*

* Available Q2-2004.

Portable Outlet with Strain Relief Kit

Port	Cat. No.
1	HBLHI1POB*
Multiport	HBLHIPOB*

* Available Q3-2004.



Hubbell Wiring Device-Kellems
Hubbell Incorporated (Delaware)
1-203-882-4800
www.hubbell-wiring.com

www.hubbell-solutions.com/edu

HI-Impact™ Cords

Call for additional product information



HI-Impact to HI-Impact Connector

Type	Cat. No.
Category 6	HBLHI6XXEE*
Category 5e	HBLHI5EXXEE
Category 5e, Shielded	HBLHI5ESXXEE**
F-type	HBLHIFXXEE**
M12, 4-P Female	HBLHIM12XXEE**



HI-Impact Connector to RJ-45

Type	Cat. No.
Category 6	HBLHI6XXAE*
Category 5e	HBLHI5EXXAE
Category 5e, Shielded	HBLHI5ESXXAE**
F-type	HBLHIFXXAE**
M12, 4-P Female	HBLHIM12XXAE**



HI-Impact RJ-45 to RJ-45

Type	Cat. No.
Category 6	HBLHI6XXAA*
Category 5e	HBLHI5EXXAA
Category 5e, Shielded	HBLHI5ESXXAA**
XX = Length	
03 = 3'	05 = 5'
10 = 10'	12 = 12'
20 = 20'	25 = 25'

* Available Q2-2004.

** Available Q3-2004.

HI-Impact™ Plugs and Cable

Call for additional product information

Type	Cat. No.
Category 5e Plug	HBLHI5EP
Category 5e Patch Cable, 100'	HBLHIPC100
F-type Connector	HBLHIFP**
RG-59 Patch Cable, 100'	HBLHIFC100**

** Available Q3-2004.

HI-Impact™ Cord Connectors & Grips

Call for additional product information



Cord Connectors, 0.250" - 0.375"

Description	Cat. No.
SS, 1/2"	SHC1022SS
Aluminum, 1/2"	SHC1022
Aluminum, 3/4"	SHC1032
Nylon, Gray, 3/4"	SHC1022CR

Deluxe Cord Connectors, 0.250" - 0.375"

Description	Cat. No.
SS, 1/2"	07401006
SS, 3/4"	07401013
Aluminum, 1/2"	CG406NM
Nylon, Gray, 1/2"	074011332

HI-Impact™ Enclosures

Call for additional product information



REbox® NEMA 4/12/13, Gray

Height	Type	Cat. No.
24"	Unloaded	HBLIR2UG
36"	Unloaded	HBLIR3UG
48"	Unloaded	HBLIR4UG
36"	Loaded	HBLIR3PG
48"	Loaded	HBLIR4PG

REbox® NEMA 4X, Stainless Steel

Height	Type	Cat. No.
24"	Unloaded	HBLIR2USS*
36"	Unloaded	HBLIR3USS*

REbox® NEMA 3R, Gray

Height	Type	Cat. No.
24"	Unloaded	HBLIR2U2R
36"	Unloaded	HBLIR2U3R

REbox® Accessories

Description	Cat. No.
Plywood Backboard 20"H x 19"W (for wall mounting)	HBLREKBB20
Plywood Backboard 30"H x 19"W (for wall mounting)	HBLREKBB30
Plywood Backboard 40"H x 19"W (for wall mounting)	HBLREKBB40
Equipment Mounting Bracket, 5U	HBLREKZ
110/66 Block Mounting Rails (accepts five 100-pair/ 110-pair blocks)	HBLREK110
Patch Panel Bracket Bottom-hinged, 4U	HBLREK19
Fiber Patch Panel Bracket (accepts 1 FSP adapter panel)	HBLREKFP
Economy Power Supply Kit, 15A	HBLREKP



DIN Rail Utility Box, Duplex

Description	Cat. No.
15A, 5A Breaker	DRUBTVSS15*
Duplex, Communication	HBLHIDRUBC**

* Available Q2-2004.

** Available Q3-2004.



Consolidation Point

Type	Size	Cat. No.
SS	NEMA 4X	HBLHICPSS*
Gray	NEMA 4/12	HBLHICPG*

* Available Q2-2004.

HI-Impact™ Delivery

Call for additional product information



PolyTuff Conduit

Size	Feet	Cat. No.
1/2"	100	G1050
3/4"	100	G1075




LiquidTight, Metallic Fittings

Size	Fitting Type	Cat. No.
1/2"	Straight Male	H0501A
3/4"	Straight Male	H0751A



LiquidTight, Non-Metallic Fittings

Size	Fitting Type	Cat. No.
1/2"	Straight Male	P050NGYA
3/4"	Straight Male	P075NGYA
1/2"	SwivelLok® Male	PS0509NGY
3/4"	SwivelLok® Male	PS0759NGY

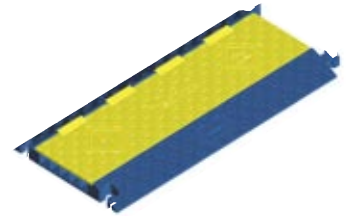

TredTrak, 5-Channel

Description	Cat. No.
Track, 3' Section	HBLTRED5B
End Caps	HBLTRED5ECB
"X" Section	HBLTRED5XB
"Y" Section	HBLTRED5YB



TrukTrak, 5-Channel

Description	Cat. No.
Track, 3' Section	HBLTT5B
End Caps	HBLTT5ECB
Right Turn	HBLTT545RB
Left Turn	HBLTT545LB

H5143LC 03/04



© Hubbell Wiring Device-Kellems
Hubbell Incorporated (Delaware)
1-203-882-4800
www.hubbell-wiring.com

www.hubbell-solutions.com/edu