


Coaxial PCB Connector 82_MCX-S75-0-2/111_N

Description

Straight PCB jack

Interface Standards

IEC 60169-36_CECC 22220

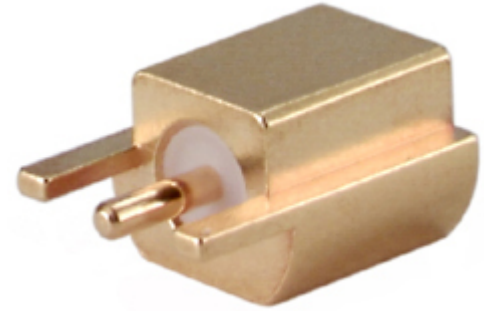

Technical Data

Electrical Data

Impedance	75 Ω
Interface frequency max.	6 GHz

Mechanical Data

Board mounting type	edge mount
Weight	0.0009 kg

Environmental Data

Operating temperature	-65 °C to 165 °C
2011/65/EC (RoHS)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	SUCOPRO Plating
Outer contact	Brass	SUCOPRO Plating
Body	Brass	SUCOPRO Plating
Insulator	PFA / PTFE	

Related Documents

Outline drawing	DOU-00013375
Catalogue drawing	DCA-00013377

Ordering Information

Single package	82_MCX-S75-0-2/111_NE
Tape and Reel package	82_MCX-S75-0-2/111_NM
Bulk 100 pcs package	82_MCX-S75-0-2/111_NH

Remarks

PCB connector without stand-offs