

“Stay Connected” with



Liquid Tight Conduit, Tubing & Fittings


 
a PennEngineering® Company




Heyco® Metal Locknuts

NPT Thread—Straight NPS Threads for use with NPT Threaded Fittings


• DFARS Compliant

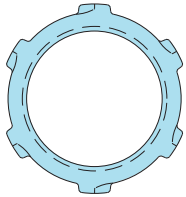

Stamped Steel Nut

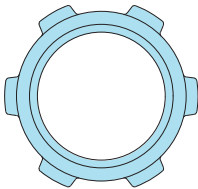



Extruded Nut

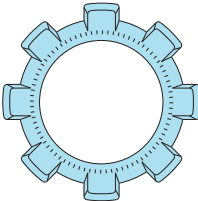

Zinc Die-cast Nut



 Nickel-Plated Brass

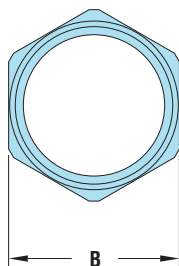

| TRADE SIZE | STAMPED STEEL | | EXTRUDED** NEW! | | ZINC DIE-CAST | |
|------------|---------------|-------------|------------------------|-------------|---------------|-------------|
| | PART NO. | DESCRIPTION | PART NO. | DESCRIPTION | PART NO. | DESCRIPTION |
| 1/4 | 2238 | LN 1/4* | — | — | — | — |
| 3/8 | 2242 | LN 3/8* | — | — | — | — |
| 1/2 | 2250 | LN 1/2 | 2250E | LN 1/2 EXT | 9800 | LN 1/2 DC |
| 3/4 | 2251 | LN 3/4 | 2251E | LN 3/4 EXT | 9801 | LN 3/4 DC |
| 1 | 2252 | LN 1 | 2252E | LN 1 EXT | 9802 | LN 1 DC |
| 1-1/4 | 9806 | LN 1-1/4 | — | — | 9803 | LN 1-1/4 DC |
| 1-1/2 | 9807 | LN 1-1/2 | — | — | 9804 | LN 1-1/2 DC |
| 2 | 9808 | LN 2 | — | — | 9805 | LN 2 DC |
| 2-1/2 | 9809 | LN 2-1/2 | — | — | — | — |
| 3 | 9810 | LN 3 | — | — | — | — |

*Wrenching flats are not crenellated

**Features wider thread engagement area than standard Stamped Steel locknuts

PG Thread—Nickel-Plated Brass

| THREAD TYPE AND SIZE | PART NO. | DESCRIPTION | PART DIMENSIONS | | | |
|----------------------|----------|----------------|-----------------|-----|----------------------|------|
| | | | A Thickness | | B Wrenching Flats | |
| | | | in. | mm. | in. | mm. |
| PG 7 | 2257 | Brass LN PG 7 | .110 | 2,8 | .591 | 15,0 |
| PG 9 | 2258 | Brass LN PG 9 | .110 | 2,8 | .709 | 18,0 |
| PG 11 | 2259 | Brass LN PG 11 | .118 | 3,0 | .827 | 21,0 |
| PG 13.5 | 2260 | Brass LN PG 13 | .118 | 3,0 | .906 | 23,0 |
| PG 16 | 2261 | Brass LN PG 16 | .118 | 3,0 | 1.024 | 26,0 |
| PG 21 | 2262 | Brass LN PG 21 | .138 | 3,5 | 1.261 | 32,0 |
| PG 29 | 2263 | Brass LN PG 29 | .158 | 4,0 | 1.615 | 41,0 |
| PG 36 | 2268 | Brass LN PG 36 | .197 | 5,0 | 2.009 | 51,0 |
| PG 42 | 2269 | Brass LN PG 42 | .197 | 5,0 | 2.364 | 60,0 |

Metric Thread—Nickel-Plated Brass

| THREAD TYPE AND SIZE | PART NO. | DESCRIPTION | PART DIMENSIONS | | | |
|----------------------|----------|--------------|-----------------|-----|----------------------|------|
| | | | A Thickness | | B Wrenching Flats | |
| | | | in. | mm. | in. | mm. |
| M6 x 1 | 2243 | Brass LN M6 | .110 | 2,8 | .354 | 9,0 |
| M8 x 1,25 | 2244 | Brass LN M8 | .110 | 2,8 | .433 | 11,0 |
| M10 x 1,5 | 2245 | Brass LN M10 | .110 | 2,8 | .512 | 13,0 |
| M12 x 1,5 | 2246 | Brass LN M12 | .118 | 3,0 | .591 | 15,0 |
| M16 x 1,5 | 2247 | Brass LN M16 | .118 | 3,0 | .748 | 19,0 |
| M20 x 1,5 | 2248 | Brass LN M20 | .138 | 3,5 | .945 | 24,0 |
| M25 x 1,5 | 2249 | Brass LN M25 | .138 | 3,5 | 1.181 | 30,0 |
| M32 x 1,5 | 2253 | Brass LN M32 | .177 | 4,5 | 1.417 | 36,0 |
| M40 x 1,5 | 2254 | Brass LN M40 | .177 | 4,5 | 1.811 | 46,0 |
| M50 x 1,5 | 2255 | Brass LN M50 | .217 | 5,5 | 2.165 | 55,0 |