





Heyco® Universal Bushings

- Flexible shutters adjust to accommodate and support any shape from .125" (3,2 mm) to a maximum diameter of 1.500" (38,1 mm).
- Absorbs vibration and cushions and insulates cables, tubing, hoses or shafts with limited internal clearance.
- Fingertip pressure snap-locks the bushing into its mounting hole.
- See Quick Specs on 4-8.

PANEL DIMENSIONS				PART NO.	DESCRIPTION	PART DIMENSIONS						
Maximum Thickness		Mounting Hole Diameter				Black	Maximum Inside Diameter		A Head Diameter		B Overall Height	
in.	mm.	in.	mm.		in.		mm.	in.	mm.	in.	mm.	
.125	3,2	.500	12,7	2055	UB-500	.312	7,6	.600	15,2	.385	9,8	
.125	3,2	.625	15,9	2077	UB-625	.437	11,1	.718	18,3	.406	10,3	
.125	3,2	.750	19,1	2089	UB-750	.500	12,7	.844	21,4	.390	9,9	
.125	3,2	.812	20,6	2106	UB-812	.500	12,7	.890	22,6	.390	9,9	
.125	3,2	.875	22,2	2119	UB-875	.562	14,3	.937	23,8	.453	11,5	
.125	3,2	1.000	25,4	2137	UB-1000	.750	19,1	1.063	27,0	.453	11,5	
.125	3,2	1.093	27,8	2157	UB-1093	.812	20,6	1.156	29,4	.453	11,5	
NEW!	.125	3,2	1.187	30,2	2153	UB-1187	.950	24,1	1.250	31,8	.453	11,5
NEW!	.125	3,2	1.250	31,8	2155	UB-1250	1.015	25,8	1.314	33,4	.453	11,5
.125	3,2	1.375	34,9	2184	UB-1375	1.000	25,4	1.490	37,8	.453	11,5	
.125	3,2	1.500	38,1	2213	UB-1500	1.062	26,9	1.610	40,9	.450	11,4	
NEW!	.125	3,2	1.750	44,5	2298	UB-1750	1.375	34,9	1.870	47,5	.465	11,8
NEW!	.125	3,2	2.000	50,8	2422	UB-2000	1.640	41,6	2.130	54,0	.490	12,4
NEW!	.250	6,35	2.500	63,5	2440	UB-2.500	1.970	50,0	2.660	67,6	.750	19,05
NEW!	.250	6,35	3.000	76,2	2460	UB-3.000	2.470	62,7	3.160	80,3	.750	19,05

Standard color black. Consult Heyco for white and other colors.
Locking fingers in fractional increments up to maximum panel thickness.

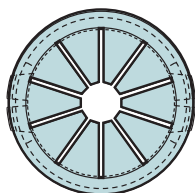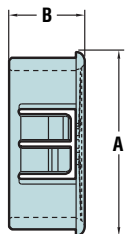

NEW!

NEW!



Heyco® Shorty Universal Bushings

- Absorbs vibration and cushions and insulates cables, tubing, hoses or shafts with limited internal clearance.
- Fingertip pressure snap-locks the bushing into its mounting hole.
- Flexible shutters adjust to accommodate and support any shape from .125" (3,2 mm) to a maximum diameter of .820" (27,8 mm).
- See Quick Specs on 4-8.

PANEL DIMENSIONS				PART NO.	DESCRIPTION	PART DIMENSIONS						
Maximum Thickness		Mounting Hole Diameter				Black	Maximum Inside Diameter		A Head Diameter		B Overall Height	
in.	mm.	in.	mm.		in.		mm.	in.	mm.	in.	mm.	
.062	1,6	.500	12,7	2858	SUB 500	.312	7,6	.600	15,2	.250	6,4	
.062	1,6	.625	15,9	2861	SUB 625	.437	11,1	.729	18,5	.250	6,4	
.062	1,6	.750	19,1	2862	SUB 750	.500	12,7	.859	21,8	.250	6,4	
.062	1,6	.875	22,2	2863	SUB 875	.560	14,2	.937	23,8	.250	6,4	
.062	1,6	1.000	25,4	2864	SUB 1000	.750	19,0	1.063	27,0	.250	6,4	
NEW!	.062	1,6	1.093	27,8	2158	SUB 1093	.820	27,8	1.156	29,4	.250	6,4

Standard color black. Consult Heyco for white and other colors.

