




Heyco® Nylon PCB Supports - Imperial Spacing

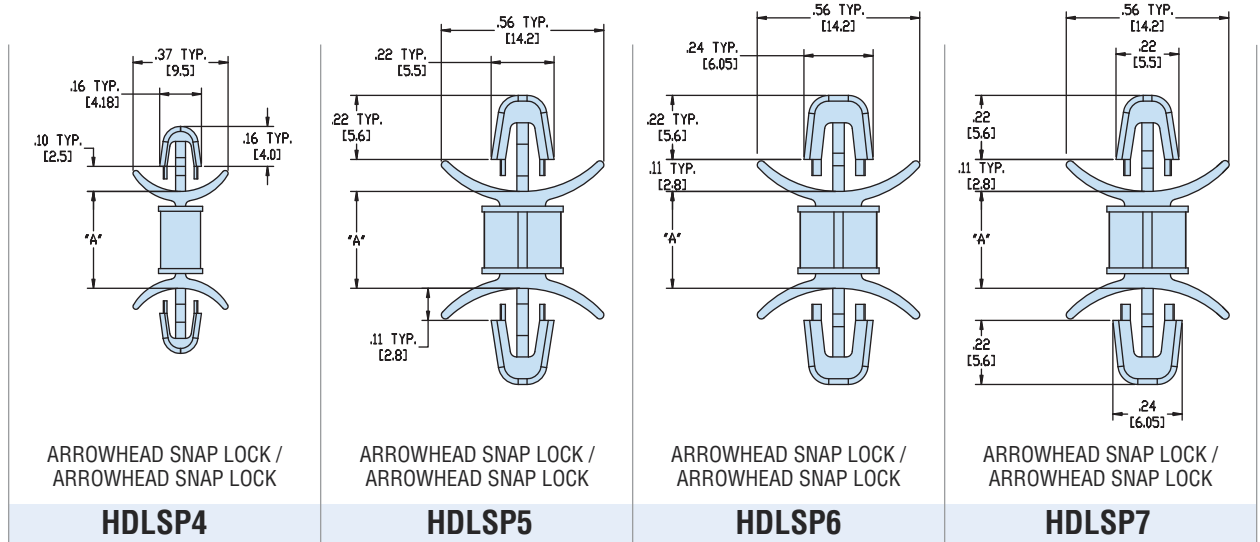

ARROWHEAD SNAP LOCK /
ARROWHEAD SNAP LOCK

HDLSP4

ARROWHEAD SNAP LOCK /
ARROWHEAD SNAP LOCK

HDLSP5

ARROWHEAD SNAP LOCK /
ARROWHEAD SNAP LOCK

HDLSP6

ARROWHEAD SNAP LOCK /
ARROWHEAD SNAP LOCK

HDLSP7

| | Maximum Thickness | | Mounting Hole Diameter | | Maximum Thickness | | Mounting Hole Diameter | | Maximum Thickness | | Mounting Hole Diameter | | Maximum Thickness | | Mounting Hole Diameter | |
|----------------|-------------------|-----|------------------------|-----|-------------------|-----|------------------------|-----|-------------------|-----|------------------------|-----|-------------------|-----|------------------------|-----|
| | in. | mm. | in. | mm. | in. | mm. | in. | mm. | in. | mm. | in. | mm. | in. | mm. | in. | mm. |
| PCB | .078 | 2,0 | .125 | 3,2 | .078 | 2,0 | .157 | 4,0 | .078 | 2,0 | .187 | 4,8 | .078 | 2,0 | .157 | 4,0 |
| Chassis | .078 | 2,0 | .125 | 3,2 | .078 | 2,0 | .157 | 4,0 | .078 | 2,0 | .187 | 4,8 | .078 | 2,0 | .187 | 4,8 |

| A | PART NO. Natural | DESCRIPTION | PART NO. Natural | DESCRIPTION | PART NO. Natural | DESCRIPTION | PART NO. Natural | DESCRIPTION |
|------|---------------------|-------------|---------------------|-------------|---------------------|-------------|---------------------|-------------|
| | | | | | | | | |
| .187 | 10199 | HDLSP4-03 | 10209 | HDLSP5-03 | 10217 | HDLSP6-03 | 10225 | HDLSP7-03 |
| .250 | 10200 | HDLSP4-04 | 10210 | HDLSP5-04 | 10218 | HDLSP6-04 | 10226 | HDLSP7-04 |
| .312 | 10201 | HDLSP4-05 | | | | | | |
| .375 | 10202 | HDLSP4-06 | 10211 | HDLSP5-06 | 10219 | HDLSP6-06 | 10227 | HDLSP7-06 |
| .437 | 10203 | HDLSP4-07 | | | | | | |
| .500 | 10204 | HDLSP4-08 | 10212 | HDLSP5-08 | 10220 | HDLSP6-08 | 10228 | HDLSP7-08 |
| .562 | 10205 | HDLSP4-09 | | | | | | |
| .625 | 10206 | HDLSP4-10 | 10213 | HDLSP5-10 | 10221 | HDLSP6-10 | 10229 | HDLSP7-10 |
| .750 | | | 10214 | HDLSP5-12 | 10222 | HDLSP6-12 | 10230 | HDLSP7-12 |
| .875 | 10207 | HDLSP4-14 | 10215 | HDLSP5-14 | 10223 | HDLSP6-14 | 10231 | HDLSP7-14 |

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No.

*Quick
Specs*

Material Nylon 6/6
Flammability Rating 94V-2
Temperature Range .4°F (-18°C) to 185°F (85°C)