



Section

F

Sockets

Selection Guide..... F-2

Din Rail Snap/Surface-Mount Sockets

- SU Series F-6
- SR Series F-9
- SH Series F-12
- SY Series F-16
- SM Series..... F-18

Through Panel Mount Sockets

- SR Series F-19
- SH Series F-20
- SY Series F-22

PCB Mount Sockets

- SH Series F-23
- SY Series F-24

Surface Mount Sockets

- SH Series F-26

Panel Mounted Sockets for Timers

- SR Series F-26

Accessories..... F-27


Dimensions..... F-29

SM2S Sockets



SM2S-05

Style	8-blade, snap-mount/surface mount
Terminal/Torque	M3 screw with captive wire clamp (5.5 - 9 in •lbs)
Wire Size	Maximum up to 2-#14AWG
Electrical Rating	300V, 10A
Compatible Relay	RU2S, RM2S
Compatible Timer	—
Hold-Down Spring	SY4S-51F1
Hold-Down Clip	SFA-101 (top notch), SFA-202 (side notch)

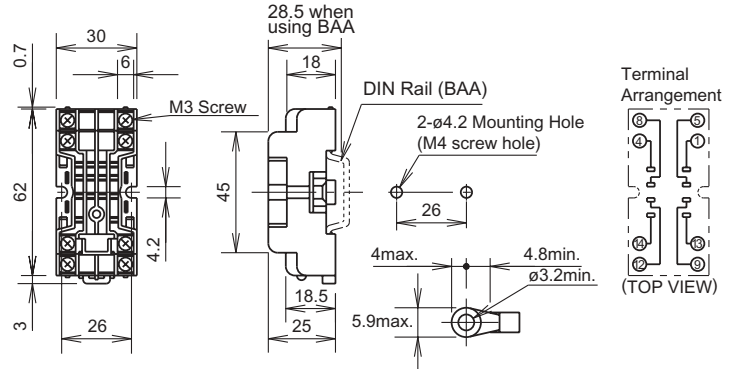


F

Sockets



SM2S-05C Fingersafe

Style	8-blade, snap-mount/surface mount
Terminal/Torque	M3 screw with captive wire clamp, fingersafe (5.5 - 9 in •lbs)
Wire Size	Maximum up to 2-#14AWG
Electrical Rating	300V, 10A
Compatible Relay	RU2S, RM2S
Compatible Timer	—
Hold-Down Spring	SY4S-51F1
Hold-Down Clip	SFA-101 (top notch), SFA-202 (side notch)

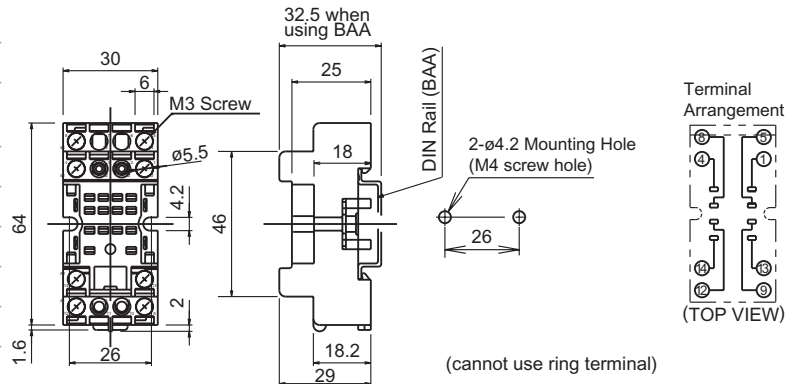

1. For socket mounting accessories, see page F-27.
2. For hold-down clip/spring selections, see page F-4.