



Pan-Flex Flat Cable For Use With 120 Series IDC Connectors



PAN-FLEX™ / Flat cable (UL Style 2651)

32 and 64 conductors

96 conductors

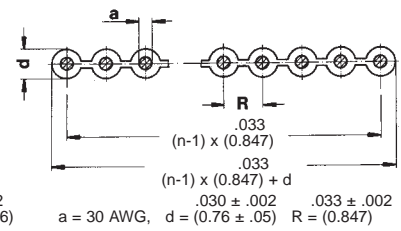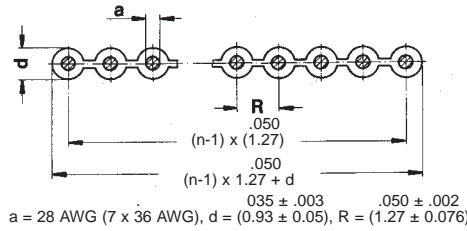

Part Numbers

Conductors	only 1st conductor is color-marked	per reel
32	050F28V32CR	100 ft (30.48 m)
64	050F28V64CR	
96	033F30V96CR	

Conductors	32, 64	96
Conductors	tinned	
Insulation	PVC grey (RAL 7032)*	
Conductor resistance	≤ 230 Ω/km	
Insulation resistance	≥ 90 x 10 ⁶ Ω/km	
Capacitance	56 pF/m	83 pFm
Voltage rating	300 V	150 V
Temperature rating	-020°C/ + 105°C	