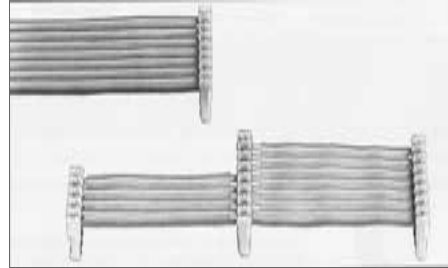


PANCON CONNECTORS

Part Number: 100F24V6CR

Agency Cert	CSA
Product Family	Pancon Connectors
Product Name	PAN-FLEX™ Flat Ribbon Cable
Brand Name	UL 2651 Flat Ribbon Cable (.100")
Rohs Status	COMPLIANT
Comp Type	Flat Cable
Wire Awg	24 awg
Packaging Type	Reel
Standard Pack Size	100 ft
Product Specification	PS 1302
Sales Drawing	KA-10117-REVQ(100FXXVXXR).pdf
Voltage Max	300 volts
Wire Size Awg	24
Pitch Termination	.100"
Spacing	.100"


[Request Quote](#)
[Request Sample](#)
[View PDF](#)
[Compliance Specifications](#)

Pancon Corporation
 350 Revolutionary Drive
 East Taunton, MA 02718
 800-342-6472 (toll-free)
 781-297-6000
info@panconcorp.com

Ark-Les Connectors
 Flag
 Quick Connects
 Rings and Spades
 Splices
 Stationary

Pancon Connectors
 Cross Reference
 HI-CON Products
 I/O Connectors
 Jumper Switches
 LAT-CON Products
 PAN-Flex Products

Paktron Capacitors
 Metallized PET
 Metallized PET-SMD
 Multilayer Polymer
 RC Snubber

Pancon MIE
 Insert Molded Connectors
 Insert Molded Housings
 Over Molded Leadframes

Pancon S3
 Stamped Terminals
 Compliant Pins
 Bandolier Pins

