


Flat Washers

#2 [M2] Screw Size - Fibre & Nylon

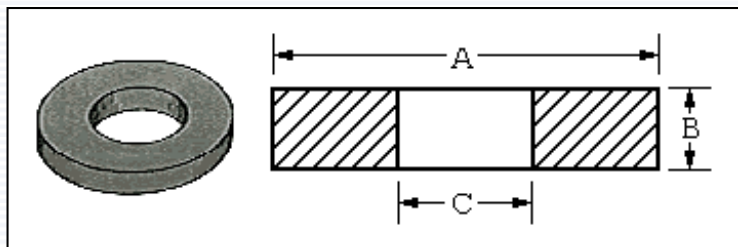


| "C" Dimension I. D. Inch [mm] | Material | "A" Dimension O.D. Inch [mm] | "B" Dimension - Washer Thickness | | |
|--|----------|---------------------------------------|-------------------------------------|----------------|----------------|
| | | | .032 [0,81] | .047 [1,19] | .062 [1,57] |
| .098 [2,49] | FIBRE | .187 [4,75] | 3111 | 3148 | 3366 |
| | | .250 [6,35] | 3112 | 3149 | 3367 |
| | | .312 [7,92] | 3113 | 3150 | 3194 |
| | NYLON | .187 [4,75] | 3114 | 3151 | 3356 |
| | | .250 [6,35] | 3347 | 3152 | 3357 |
| | | .312 [7,92] | 3115 | 3153 | 3195 |

[Click to Request Samples](#)

[VIEW PRODUCT OVERVIEW](#)

#4 [M2,5] Screw Size - Fibre & Nylon

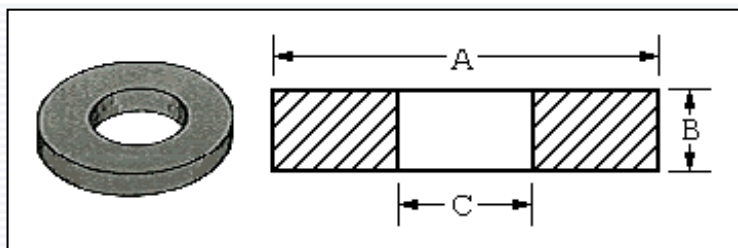


| "C" Dimension I. D. Inch [mm] | Material | "A" Dimension O.D. Inch [mm] | "B" Dimension - Washer Thickness | | |
|-------------------------------------|----------|---------------------------------------|-------------------------------------|----------------|----------------|
| | | | .032 [0,81] | .047 [1,19] | .062 [1,57] |
| .120 [3,05] | FIBRE | .250 [6,35] | 3116 | 3154 | 3368 |
| | | .312 [7,92] | 348 | 3155 | 3196 |
| | | .375 [9,53] | 3117 | 3156 | 3197 |
| | NYLON | .250 [6,35] | 3348 | 345 | 3358 |
| | | .312 [7,92] | 3359 | 3157 | 3198 |
| | | .375 [9,53] | 3118 | 3158 | 3200 |

[Click to Request Samples](#)

[VIEW PRODUCT OVERVIEW](#)

#6 [M3] Screw Size - Fibre & Nylon

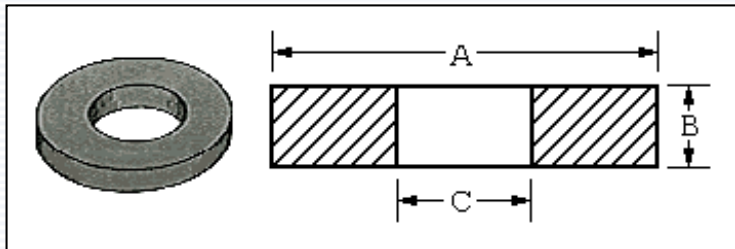


| "C" Dimension I. D. Inch [mm] | Material | "A" Dimension O.D. Inch [mm] | "B" Dimension - Washer Thickness | | |
|-------------------------------------|----------|---------------------------------------|-------------------------------------|----------------|----------------|
| | | | .032 [0,81] | .047 [1,19] | .062 [1,57] |
| .140 [3,56] | FIBRE | .250 [6,35] | 3119 | 3159 | 3369 |
| | | .312 [7,92] | 3120 | 3160 | 3370 |
| | | .375 [9,53] | 3121 | 3161 | 3201 |
| | NYLON | .250 [6,35] | 3122 | 3162 | 3360 |
| | | .312 [7,92] | 3349 | 346 | 3361 |
| | | .375 [9,53] | 3123 | 3163 | 3202 |

[Click to Request Samples](#)

[VIEW PRODUCT OVERVIEW](#)

#8 [M4] Screw Size - Fibre & Nylon

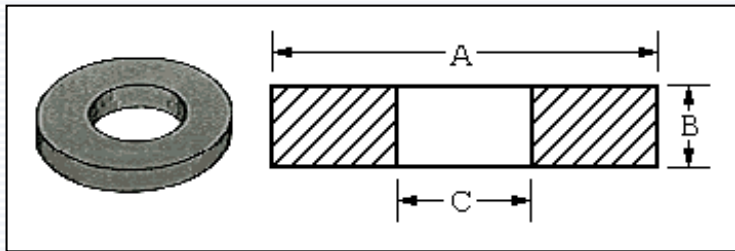


| "C" Dimension I. D. Inch [mm] | Material | "A" Dimension O.D. Inch [mm] | "B" Dimension - Washer Thickness | | |
|-------------------------------------|----------|---------------------------------------|-------------------------------------|----------------|----------------|
| | | | .032 [0,81] | .047 [1,19] | .062 [1,57] |
| .171 [4,34] | FIBRE | .312 [7,92] | 3124 | 3165 | 3203 |
| | | .375 [9,53] | 3125 | 3164 | 3372 |
| | | .437 [11,10] | 3126 | 3166 | 3204 |
| | NYLON | .312 [7,92] | 3127 | 3167 | 3205 |
| | | .375 [9,53] | 3350 | 3168 | 3363 |
| | | .437 [11,10] | 3128 | 3169 | 3206 |

[Click to Request Samples](#)

[VIEW PRODUCT OVERVIEW](#)

#10 [M5] Screw Size - Fibre & Nylon

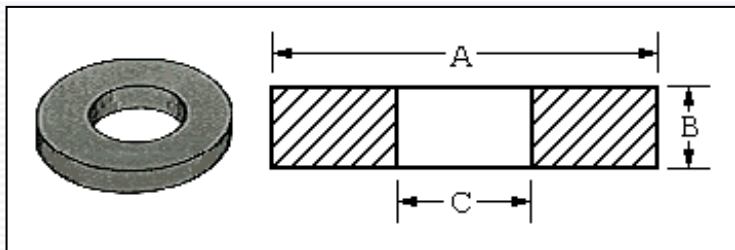


| "C" Dimension I. D. Inch [mm] | Material | "A" Dimension O.D. Inch [mm] | "B" Dimension - Washer Thickness | | |
|-------------------------------------|----------|---------------------------------------|-------------------------------------|----------------|----------------|
| | | | .032 [0,81] | .047 [1,19] | .062 [1,57] |
| .196 [4,29] | FIBRE | .312 [7,92] | 349 | 3170 | 3207 |
| | | .375 [9,53] | 3129 | 3171 | 3208 |
| | | .437 [11,10] | 3130 | 3172 | 3209 |
| | | .500 [12,70] | 3131 | 3173 | 3210 |

| | | | | | |
|--|-------|--------------|-------------|-------------|-------------|
| | NYLON | .312 [7,92] | 3364 | 3174 | 3211 |
| | | .375 [9,53] | 3352 | 3175 | 3212 |
| | | .437 [11,10] | 3132 | 3176 | 3213 |
| | | .500 [12,70] | 3133 | 3177 | 3214 |

[Click to Request Samples](#)

[VIEW PRODUCT OVERVIEW](#)

.250 [M6] Screw Size - Fibre & Nylon

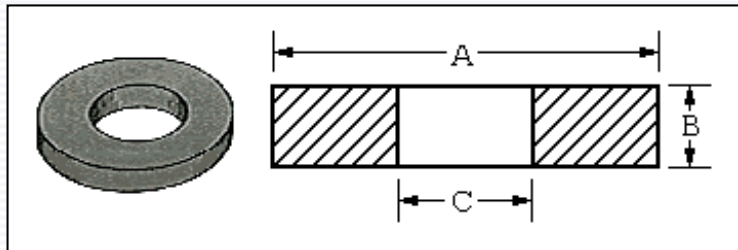


| "C" Dimension I. D. Inch [mm] | Material | "A" Dimension O.D. Inch [mm] | "B" Dimension - Washer Thickness | | |
|-------------------------------------|----------|---------------------------------------|-------------------------------------|----------------|----------------|
| | | | .032 [0,81] | .047 [1,19] | .062 [1,57] |
| .260 [6,60] | FIBRE | .437 [11,10] | 3134 | 3178 | 3215 |
| | | .500 [12,70] | 3135 | 3179 | 3373 |
| | | .625 [15,88] | 3136 | 3180 | 3216 |
| | | .750 [19,05] | 3137 | 3181 | 3217 |
| | NYLON | .437 [11,10] | 3138 | 3182 | 3218 |
| | | .500 [12,70] | 3353 | 3183 | 3365 |
| | | .625 [15,88] | 3139 | 3184 | 3219 |
| | | .750 [19,05] | 3140 | 3185 | 3220 |

[Click to Request Samples](#)

[VIEW PRODUCT OVERVIEW](#)

.375 [M8] Screw Size - Fibre & Nylon

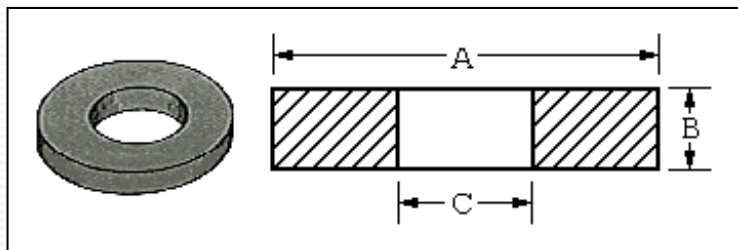

| "C" Dimension I. D. Inch [mm] | Material | "A" Dimension O.D. Inch [mm] | "B" Dimension - Washer Thickness | | |
|-------------------------------------|----------|---------------------------------------|-------------------------------------|----------------|----------------|
| | | | .032 [0,81] | .047 [1,19] | .062 [1,57] |
| .385 [9,65] | FIBRE | .500 [12,70] | 3141 | 3186 | 3221 |
| | | .625 [15,88] | 3142 | 3187 | 3222 |
| | | .750 [19,05] | 3143 | 3188 | 3223 |
| | | 1.000 [25,40] | 3144 | 3189 | 3224 |
| | NYLON | .500 [12,70] | 3145 | 3190 | 3225 |
| | | .625 [15,88] | 3354 | 3191 | 3226 |
| | | .750 [19,05] | 3146 | 3192 | 3227 |

| | | | | | |
|--|--|---------------|-------------|-------------|-------------|
| | | 1.000 [25,40] | 3147 | 3193 | 3228 |
|--|--|---------------|-------------|-------------|-------------|

[Click to Request Samples](#)

[VIEW PRODUCT OVERVIEW](#)