


Cable Tester Kit with Scout® Pro 3 Tester, Remotes, Adapter, Battery

VDV501-851

- Cable tester tests voice (RJ11/12), data (RJ45) and video (coax F-connector)_ terminated cables with clearly defined results
- Measure cable length up to 2000 feet (610 m)
- Test for Open, Short, Miswire or Split-Pair faults
- Backlit LCD screen displays cable length, wiremap, cable ID and test results
- Trace cables, wire pairs and individual conductor wires with multiple style tone generator (requires analog probe Cat. No. VDV500-123; sold separately)
- Hub blink mode to identify port location on a hub or a switch
- LanMap™ and CoaxMap™ Location Remotes (5 each) map and ID multiple cable runs in a single step
- Includes voltage warning, shield detection, auto power off, low battery indicator and a self-storing remote
- Auto Power-off feature to conserve battery life (9V included)
- Kit includes: Scout® Pro 3 Tester, (1) self-storing remote, (5) LanMap™ RJ45 locator remotes, (5) CoaxMap™ F-connector locator remotes, (1) coax F-connector, manual and 9V battery

 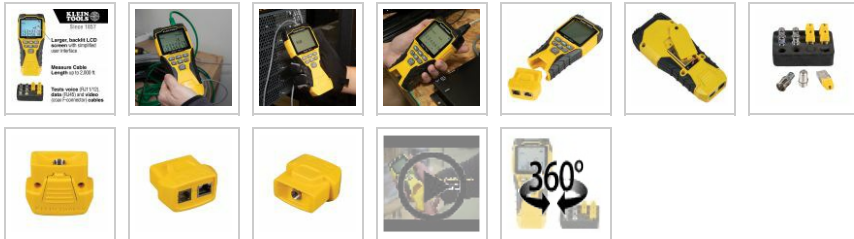


[BUY ONLINE](#)

[FIND LOCAL RETAILER](#)



VIDEO



DOWNLOADS

- [VDV501-851](#)
- [Entire line of testers](#)
- [Instructions](#)
- [Safety Data Sheet](#)

IMAGES

- JPG (High Resolution):** [vdv501851_photo.jpg](#)
- PNG (Transparent Background):** [vdv501851.png](#)

INTERACTIVE CATALOG

- [Product Page](#)
- [Product Section](#)

The Scout® Pro 3 Tester Starter Kit is a versatile cable tester that locates and tests voice, data and video cables. Identify multiple cable runs with included location mapping remotes. This kit verifies accurate cable installations each time. Backlit display assists in reading results in lower light.

Specifications

Type:	Twisted Pair, DATA, Voice, LAN, and Coaxial	Drop Protection:	2 m
Application:	Cable Testing	Supported Remotes:	18
Special Features:	Measures Cable Length; Backlit LCD; Hub Blink	Connection & Adapter Types:	RJ11, RJ12, RJ45, Coax F
Cable Type:	DATA:, Shielded or Unshielded, CAT3, CAT5E, CAT6, CAT6A, CAT7; COAXIAL: RG59, RG6/6Q	Display:	Backlit LCD
Overall Length:	7" (17.8 cm)	Multiple Style Tone Generator:	Yes (5); Requires Tracing Probe (Cat. No. VDV500-123); Sold Separately
Overall Height:	3" (7.6 cm)	Faults Detected:	Open, Short, Miswire
Overall Width:	1.25" (3.2 cm)	Test & Measure Types:	Ethernet / Data and Coaxial
Material:	Plastic and Metal	Included:	Tester, Self-Storing Remote, (5) LanMap RJ45 Locator Remotes, (5) CoaxMap F-connector Locator Remotes, (1) Coax F-adapter, Manual, (1) 9V Battery
Test-n-Map ID Remotes:	(1) Self-Storing	Standard:	CE
Location ID:	(5) RJ45 Data and (5) F-Coax connector Locator Remotes	Weight:	1.2 lb 0.54 kg
Batteries:	9V Alkaline	UPC:	092644692260
Battery Life:	50 Hours Active		

Additional Information



WARRANTY

WARNINGS

- Read, understand and follow all instructions, cautions and warnings attached to and/or packed with all test and measurement devices before each use.

- Always wear approved eye protection.
- Do NOT use on energized circuits.

REPLACEMENT PARTS



VDV501-218
Test + Map™
Remote #8 for
Scout® Pro 3
Tester



VDV501-219
Test + Map™
Remote #9 for
Scout® Pro 3
Tester



VDV501-220
Test + Map™
Remote #10 for
Scout® Pro 3
Tester



VDV501-221
Test + Map™
Remote #11 for
Scout® Pro 3
Tester



VDV501-222
Test + Map™
Remote #12 for
Scout® Pro 3
Tester

[VIEW ALL REPLACEMENT PARTS](#)

ACCESSORIES




VDV500-123
Probe-PRO Tracing
Probe



VDV512-056
CoaxMap™ Kit



VDV526-055
LanMap™ Kit

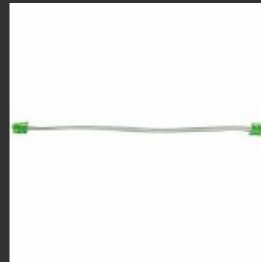

VDV726-125
Universal
RJ11/RJ12 Jumper
Cable for Scout®
Pro Testers



VDV770-850
Test + Map™
Remotes (#2 - #6)
Upgrade Kit for
Scout® Pro 3
Tester

RELATED ITEMS



VDV512-007
Wire Tracer, Coax
Cable Pocket
Continuity Tester
with Remote



VDV501-828
Cable Test Kit with
Commander™ VDV
Tester, Remotes,
Adapter, and Case



VDV501-852
Scout® Pro 3
Tester with Locator
Remote Kit



VDV501-853
Scout® Pro 3
Tester with Test +
Map™ Remote Kit



VDV501-829
Cable Tester,
Commander™ VDV
Tester and Test-n-
Map Remote Kit

CUSTOMER SERVICE

1-800-553-4676

