


Home » Catalog » Lights and Accessories » Lights

Telescoping Magnetic LED Pickup Tool

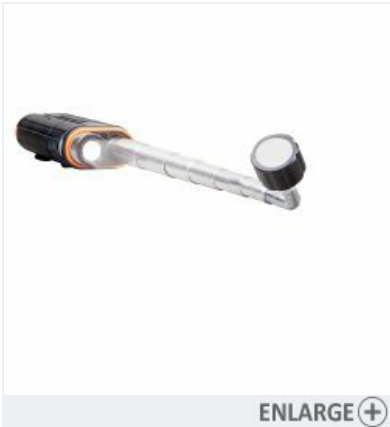

ENLARGE 







Cat. No.56027

Product Features

- ▶ Telescoping arm extends 22-Inches (55.9 cm) beyond your reach
- ▶ Powerful magnetic head with 2 pound (0.9 kg) pickup strength
- ▶ LED light illuminates the path to and from your target, powered by 2 x AAA alkaline batteries (included)
- ▶ Two inch (51 mm) gooseneck end bends to navigate around obstacles
- ▶ Rubberized handle for a secure grip
- ▶ Pocket clip for easy, convenient storage
- ▶ IP54: dust and water resistant. 25 Lumens. 10 hour runtime

BUY NOW

FIND RETAILER

FL 1 STANDARD	
 25 Lumens	 10h
 IP54	 10ft

Specs

Video

Downloads

Related Items

Type: Telescoping Magnetic LED	Application: Pick-up Tool
Special Features: Flexible Gooseneck	Overall Length: Closed 6.313" (16 cm); Open 27.813" (70.6 cm)
Overall Height: 1.594" (40.5 mm)	Overall Width: 0.938" (23.8 mm)
Material: Stainless Steel/Hard Plastic/Rubber	Lumens: 25
Bulb Type: LED	Batteries: 2 x AAA Alkaline Included
Battery Life: 10 Hours	Temperature Range: -20°F to 120°F
Drop Protection: 10 ft (3 m)	Standard: FL1
Weight: 6.4 oz (181.4 g)	UPC: 092644560279