


Home » Catalog » Lights and Accessories » Lights

# Clamping Worklight

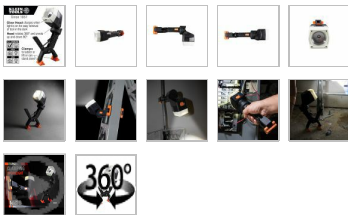

ENLARGE



## Cat. No.56029

### Product Features

- ▶ Worklight can easily clamp to a ladder or lift
- ▶ Head rotates a full 360 degrees and pivots up to 90 degrees directing light wherever you need it
- ▶ Unit can stand up by itself, includes 4 AA batteries
- ▶ Light projects in front of you, reducing shadows
- ▶ Easy to find glow head recharges when the light is on
- ▶ IP54 rating: dust and water resistant
- ▶ High: 250 Lumens and 8 hour runtime, Low: 125 Lumens and 10 hour runtime

**BUY NOW**

**FIND RETAILER**

FL 1 STANDARD	
10ft 	
HIGH	
 250 Lumens	 8h
LOW	
 125 Lumens	 10h

**Specs**

Video

Downloads

Related Items

**Type:** Clamping Worklight  
**Special Features:** 360° Rotating and 90° Pivoting Head  
**Overall Height:** 2.8" (71.1 mm)  
**Material:** ABS, PC, Stainless Steel  
**Bulb Type:** LED  
**Battery Life:** High: 8 hr, Low: 10 hr  
**Drop Protection:** 10' (3 m)  
**Weight:** 15.3 oz (434 g)

**Application:** Work Light  
**Overall Length:** 11.2" (284.5 mm)  
**Overall Width:** 2.5" (63.5 mm)  
**Lumens:** High: 250, Low: 125  
**Batteries:** 4 x AA  
**Temperature Range:** -20° to +120°F (-29° to +49°C)  
**Included:** Batteries  
**UPC:** 092644560293