




## Punchdown Screwdriver Multi-Tool

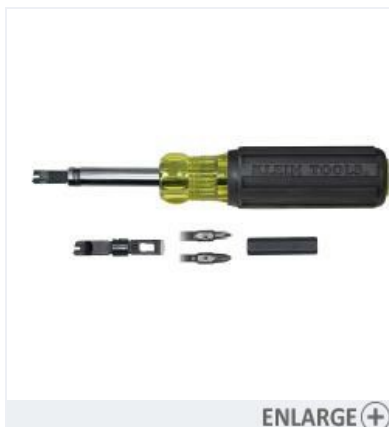

ENLARGE



### Cat. No.VDV001-081

#### Product Features

- ▶ Terminate and cut wire in one step with 110/66 combination cut-type punchdown blade with precision ground cutting edge
- ▶ Non-impact wire termination
- ▶ Machine-tooled steel bits for superior strength
- ▶ Heavy-duty blade barrel provides storage for bits
- ▶ Bayonet-style (twist & lock) socket accepts most manufacturers' punchdown blades
- ▶ Cushion-Grip handle for greater torque and enhanced comfort
- ▶ Tip-Ident® for quick identification of tool
- ▶ Two Phillips screwdriver tips: #1 and #2
- ▶ Two slotted screwdriver tips: 3/16" (5 mm) and 1/4" (6 mm)
- ▶ Two nut drivers: 1/4" (6 mm) and 3/8" (10 mm)
- ▶ One hex key: 3/8"
- ▶ 6-piece counter display also available: VDV001-0816
- ▶ U.S. Patent No. 8,856,994

**BUY NOW**

**FIND RETAILER**



**Specs**

Video

Downloads

Warnings

Buy Now

**Color:** Yellow/Black

**Overall Length:** 8" (203.2 mm)

**Finish:** Chrome

**Weight:** 0.59 lbs. (0.27 kg)