

Class CC Enclosed Fuse Holders - 600 Volt

Specifications:

- Tested and Approved for 200,000 RMS Symmetrical Amps Withstand Rating and Short Circuit Current Ratings (SCCR)
- Touchsafe Design IEC Type IP20
- DIN Rail Mount (35mm)
- Blown Fuse Indication Available
- Handle Allows Quick Easy Fuse Change
- Indication light AC and DC - 80 Volts Min.
- UL Listed File No. IZLT2.E35113
- CSA Certified File No. LR21455
- **CE**
- RoHS Compliant



6SC30A1-B shown with fuse (fuse not included)



6SC30A1-B




6SC30A3I-B

Catalog #	Indicating	Poles (X)	Amps	Base Materials	Wire Range	Fuse Size	Fuses
6SC30A1-B	No	1	30	Thermoplastic	#6-#14 AWG CU	13/32" DIA BY 1 1/2"	ATDR
6SC30A2-B		2					ATMR
6SC30A3-B		3					ATQR
6SC30A4-B		4					CCMR
6SC30A1I-B	Yes	1					FRQ-R
6SC30A2I-B		2					KLDR
6SC30A3I-B		3					KLKR
6SC30A4I-B		4					KTK-R, LP-CC

For electronic drawings or 2D/3D CAD data, send request to drawings@marathonsp.com

Dimensions	mm	Inches
A	17.8	0.70
B	35.6	1.40
C	53.3	2.10
D	71.1	2.80
E	43.2	1.70
F	59.7	2.35
G	12.2	0.48
H	77.2	3.04

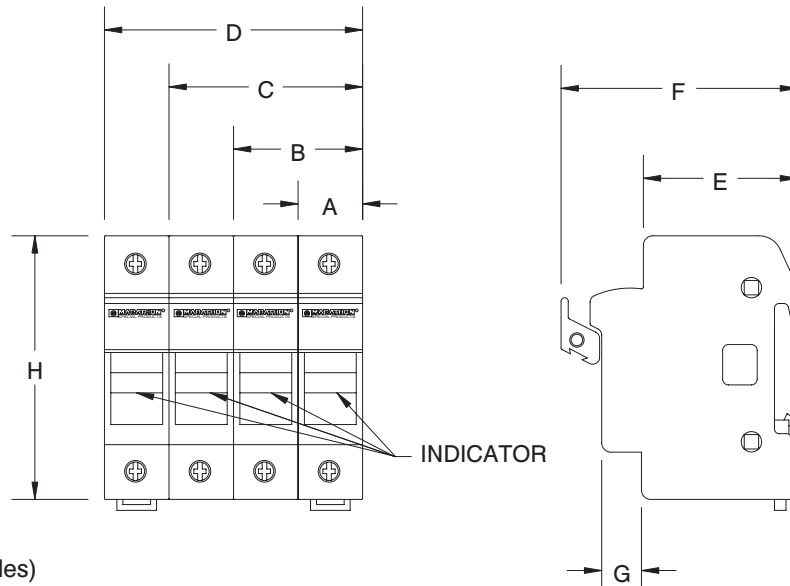

Pin Kit (used for ganging multiple poles)

Catalog Description:
EFH-MCCK

- *Includes 10 handle pins and 20 body clips
- *Use one handle pin and two body clips per pole

Marathon Special Products fuse holders will comply to new harmonized fuse holder standard 4248. Please refer to www.marathonsp.com for the latest updates.