

2321

Locking Plug, 20 Amp, 250 Volt, Industrial Grade - Black & White

20 Amp, 250 Volt, NEMA L6-20P, 2P, 3W, Locking Plug, Industrial Grade, Grounding - Black/White

Leviton's Black & White line of industrial grade plugs, connectors, flanged inlets, and outlets offer superior performance, long lasting reliability and features that are backed by a lifetime warranty:

- One piece contacts reduce friction and overheating
- Unique cord clamp accepts wide range of cord sizes (.245"-.700")
- Rugged nylon construction resists impact, sunlight, chemicals, and rough use
- Industry exclusive lifetime warranty
- Made proudly in the USA



UPC Code : 078477801123

Country Of Origin : United States



Available Colors :



Black



Yellow-White

Technical Information

AC Horsepower Ratings

Horsepower Rating : 2 HP

Electrical Specifications

Amperage : 20 A

Current Interrupting : Certified for current interrupting at full rated current

Dielectric Voltage : Withstands 2000V per UL498

Grounding : Grounding

Pole : 2

Temperature Rise : Max 30C after 250 cycles OL at 200 percent rated current

Voltage : 250 VAC

Wire : 3

Environmental Specifications

Flammability : Rated HB or better UL94

Operating Temperature : -40°C to 60°C

Material Specifications

Assembly Screws : Steel, Zinc Plated

Back Cover : Thermoplastic

Blades/Contacts : Solid Brass

Body Material : Impact Modified Nylon

Clamp Insert : Nylon

Color : Black-White

Cord-Clamp : Nylon

Terminal Screws : Brass

Wire Module : Nylon

Mechanical Specifications

Cord Range : 0.385 to 0.720

Product ID : Ratings are permanently marked on device

Terminal Accom. : 18-10 AWG

Terminal ID : Brass-Hot, Green-Ground, Silver-Neutral

Wire Gauge : 16-10 AWG

Product Features

Color : Black-White

NEMA : L6-20P

Standards and Certifications

ANSI : C-73

CSA C22.2 No. 42 : File LR-406

NEMA : WD-6


NOM : 057

UL Fed Spec WC-596 : File E13393

UL498 : File E13393

Warranty : Limited Lifetime Warranty

Dimensional Diagram

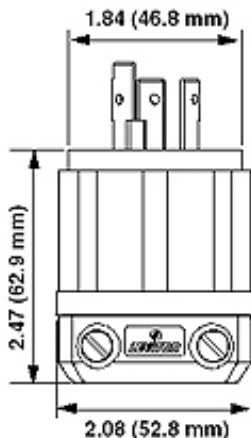

SPECIFICATION SUBMITTAL

JOB NAME:	CATALOG NUMBERS:	
<input type="text"/>	<input type="text"/>	<input type="text"/>
JOB NUMBER:	<input type="text"/>	<input type="text"/>

Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday):

+1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-

1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2018 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:

www.leviton.com/international/contacts/

