


## 0275010. - 275 Series

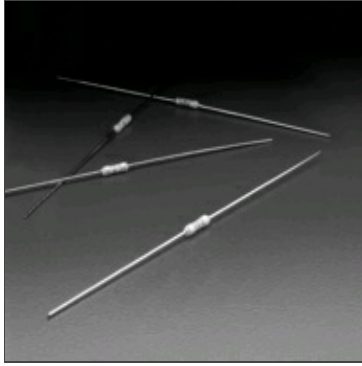

Series: 275 **Obsolete: 2008-05-01** Replaced By: 025101.5

Questions? Contact Littelfuse Support

**Fuse 275 and 276 Datasheet**

The PICO® Very Fast-Acting Fuse is designed to meet an extensive array of performance characteristics in a space-saving subminiature package.

- Features:**
- Very fast-acting
  - Small size
  - High current rating (20A- 30A)
  - RoHS compliant
  - Wide operating temperature range
  - Low temperature derating

**Check Stock**

**Order Samples**

**NEW!**  
Product Selection Guide eCatalog  
[Read Now](#)

**SPEC DESIGN**  
Accelerate Your Design...from Concept to Completion  
*Protecting Technology. Protecting Life.*

**Electronics**  
News and Information  
**SIGN UP NOW**

Electrical Characteristics		Technical Resources	
Property (Mauseover for details)		Value	
Ampere Rating (A)		10	
Body		Ceramic Body	
Nominal Melting I <sup>2</sup> T (A <sup>2</sup> sec)		25.5	
Interrupting Rating		300A@125VDC	
Mbisture Sensitivity Level		ML-STD-202 Method 106.	
MinOperatingTemp		-55	
MaxOperatingTemp		125	
Nominal Voltage Drop (mV)		0.1	
Nominal Cold Resistance (Ohms)		0.00705	
Opening		Very Fast-Acting (FF)	
Package Size		2.80 x 7.11mm	
VAC (V)		125	
VDC (V)		125	

**Connect with Littelfuse**  
Sign up to receive special offers and news

Enter your email  **Submit**

For more details about how we use your information, check our [Privacy Statement](#).

**About Littelfuse**

- About Littelfuse
- Conflict Free Statement
- History
- Investor Relations
- Legal
- Press Room
- Privacy Statement
- Website Feedback

**Explore Littelfuse**

- Capabilities Brochures
- Careers
- Check Distributor Stock
- Competitor Cross Reference
- Industries
- Order Samples
- Products
- Services

**Technical Resources**

- Application Designs
- Education
- FAQs
- iDesign™
- Littelfuse University
- Product Catalogs
- Quality Documents
- Technical Documents