




Multiseal Assortment Kits

Multiseal™ Connector Assortment Kits

CALL US: 1.800.558.9413

- [Ask A Question](#)
- [Request A Catalog](#)
- [View/Print Catalog](#)
- [Receive Master Updates](#)
- [Where To Buy](#)

SHARE THIS PAGE [f](#) [t](#) [in](#) [p](#)

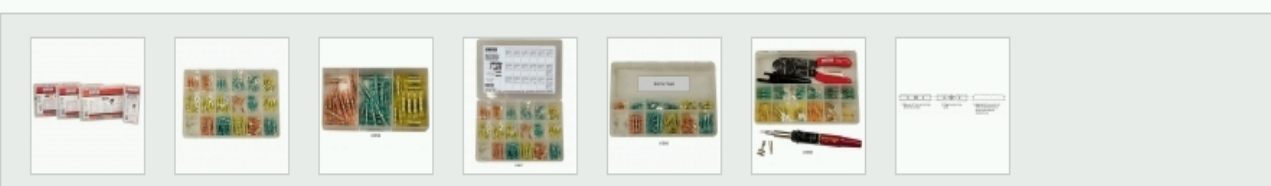

Features

Support Materials

Attachments/Accessories

Refill Packs

High Quality Crimp, Solder & Heat-Seal Connector Kits and Refills

Models

Specifications

- Crimped for mechanical reliability, soldered for strength and conductivity, and heat sealed for superior durability
- Prevents opening of connector barrel for stronger crimp
- Low Temperature pre-measured solder with flux for greater tensile strength and superior current flow
- Uniform adhesive flow does not overflow onto terminal to impede contact
- Heat shrink tubing does not reduce in length creating better insulation along with superior wire support and strain relief
- Translucent, adhesive-lined polyolefin shrink tubing - Allows visual inspection, prevents wire corrosion, and provides a water and contaminant resistant seal
- Color-coded tubing with wire gauge imprint - Provides easy identification of the correct part for the job
- Superior integrity of electrical systems - Sealed electrical systems ensure the original integrity of wire connections and wiring harnesses and conforms with OEM standards. 103 lbs tensile strength
- Refills available in bags of 10 or 50, go to [Replacement Parts](#)

Available Models

MODEL NO.	DESCRIPTION
10058	Multiseal Butt Splice MiniPak, 3 items, 50 pcs.
10067	Multiseal Large Assortment Kit, 20 items, 120 pcs.
10068	Multiseal Assortment Kit w/ UT-100SI & Regular Crimper, 14 items, 90 pcs.
10066	Multiseal Assortment Kit w/ Tool Slot, 14 items, 90 pcs.

10058 - Multiseal Butt Splice Connector Minipak

Description	Qty
18-20 AWG, Red	20
14-16 AWG, Blue	20
10-12 AWG, Yellow	10
3 items and 50 pieces	

10067 Multiseal Connector Kit

Description	Qty
18-20 AWG, #6 Stud, Red	5
18-20 AWG, #10 Stud, Red	5
14-16 AWG, #10 Stud, Blue	5
14-16 AWG, 1/4" Stud, Blue	5
14-16 AWG, 3/8" Stud, Blue	5
10-12 AWG, #10 Stud, Yellow	5
10-12 AWG, 1/4" Stud, Yellow	5
10-12 AWG, 3/8" Stud, Yellow	5
10-12 AWG, 1/2" Stud, Yellow	5
18-20 AWG, #10, Red	5
14-16 AWG, #10, Blue	5
10-12 AWG, #10, Yellow	5
22-24 AWG, Clear	5
18-20 AWG, Red	10
14-16 AWG, Blue	15
10-12 AWG, Yellow	10
18-20 AWG, Female, 1/4" Tab, Red	5
14-16 AWG Female, 1/4" Tab, Blue	5
18-20 AWG, Male, 1/4" Tab, Red	5
14-16 AWG Male, 1/4" Tab, Blue	5
20 items and 120 pieces	

10066 - Multiseal Connector Kit with Tool Slot

10068 - Multiseal Connector Kit with UT-100Si & Crimper

Description	Qty
18-20 AWG, #10 Stud, Red	5
14-16 AWG, #8 Stud, Blue	5
14-16 AWG, #10 Stud, Blue	5
14-16 AWG, 1/4" Stud, Blue	5
14-16 AWG, 3/8" Stud, Blue	5
10-12 AWG, #10 Stud, Yellow	5
18-22 AWG, Red 10	10
14-16 AWG, Blue 10	10
10-12 AWG, Yellow 10	10
10-12 AWG, Yellow 10	10
18-20 AWG, Female, 1/4" Tab, Red	5
14-16 AWG Female, 1/4" Tab, Blue	5
18-20 AWG, Male, 1/4" Tab, Red	5
14-16 AWG Male, 1/4" Tab, Blue	5
14 items and 90 pieces	

Specifications

Temperature rating:	-67°F to 230°F -55°C to 110°C
Longitudinal change:	+1, -10%
Recovery temperature:	275°F / 135°C
Dialectic strength:	900 Volts/Mil.
UL Voltage Rating:	600 Volts
Corrosion resistance:	Non-corrosive
Fungus resistance:	Non-nutrient
Water absorption:	<0.1%

- [HEAT TOOL PRODUCTS](#)
- [REPAIR SERVICE](#)
- [WHERE TO BUY](#)
- [DISTRIBUTORS](#)
- [VIDEOS](#)

- [ABOUT US](#)
- [BLOG](#)
- [SITE MAP](#)
- [SITE MAP \(XML\)](#)

Master Appliance Corp.
2420 18th St.
Racine, Wisconsin 53403 USA
Phone: 262.633.7791
Toll Free: 800.558.9413
Fax: 262.633.9745

© 2013 Master Appliance Corp.