

Magnecraft

191 Waukegan Rd, Ste 206

Northfield, IL 60093-2743

Phone: (847)441-2526

Fax: (847)441-2522

Email: info@magnecraft.com

Item # 6240AXXSZS-AC90, Class 6 Solid State Relays/SPST-NO, SPST-NC, DPST-NO, 10-150 Amp Rating

Class 6 Solid State Relays/SPST-NO, SPST-NC, DPST-NO, 10-150 Amp Rating


Supersedes: W6240ASX-1

The new finger-safe Class 6 "Hockey Puck" Style Solid State Relay (SSR) expands and enhances the current Magnecraft Solid State Relay product line.

This product features a finger-safe cover and LED Status Indicator. The optically coupled circuitry isolates the input from the output to give pure solid state performance. This product carries with it agency certifications from UL, CSA, and CE.

Available for products up to 40 Amps.

This item is normally stocked

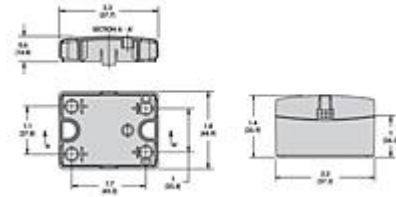

[SPECIFICATIONS](#) · [OUTPUT CHARACTERISTICS](#) · [INPUT CHARACTERISTICS](#)

SPECIFICATIONS

Component Type	Solid State
Mounting Type	Panel
Rated Current Load	40 A
Contact Configuration	SPST-NO
Control Voltage	AC
Load Type	AC
Output Voltage Range	24 to 280 VAC
Switching Type	Zero Cross

OUTPUT CHARACTERISTICS

Switching Device	SCR (2)
------------------	---------

INPUT CHARACTERISTICS

Voltage Range	90 to 280 VAC
---------------	---------------
