

**Magnecraft**

191 Waukegan Rd, Ste 206

Northfield, IL 60093-2743

**Phone:** (847)441-2526

**Fax:** (847)441-2522


**Email:** info@magnecraft.com

**Item # 70-124-2, 70-124-1,2 Socket / 15 Amp Rating, 300 Volts**

**70-124-1,2 Socket / 15 Amp Rating, 300 Volts**

11 Pin, 0.187 Quick Connect terminals with mounting tabs.

This Item is Normally Stocked

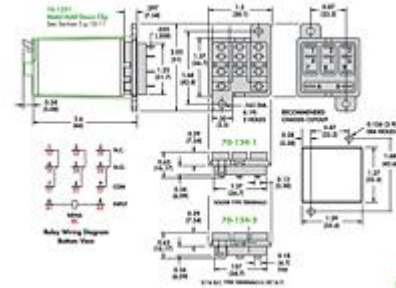

[SPECIFICATIONS](#) · [ELECTRICAL RATING](#) · [TEMPERATURE](#) · [CONSTRUCTION](#) · [MISCELLANEOUS](#) · [PRODUCT CERTIFICATIONS](#)

**SPECIFICATIONS**

Contact Configuration	3PDT
Number of Terminals	11
Mounting Style	Panel mount PC Board mount

**ELECTRICAL RATING**

Nominal Current Rating	15 A
Nominal Voltage Rating	300 V

**TEMPERATURE**

Storage Range	- 40 to + 105 °C
---------------	------------------

## CONSTRUCTION

Internal Metal Tracks	Copper Alloy Zinc Plated
Terminals	Copper Alloy Zinc Plated

## MISCELLANEOUS

Socket Mounting	Chassis
Wire Size Capacity (Maximum), EN 60204-1, Solid Cu	(Output): 16 AWG, 1.0 mm <sup>2</sup>
Wire Size Capacity (Maximum), EN 60204-1, Stranded Cu	(Output): 16 AWG, 1.0 mm <sup>2</sup>
Wire Connection Method	Solder
Flammability Rating	94V-0 Class
Body Color	Light Gray
Conformance	CE RoHS

## PRODUCT CERTIFICATIONS

Agency Approvals	UL CSA
------------------	-----------